

Danfoss A/S6430 Nordborg
Denmark
CVR nr.: 20 16 57 15Telephone: +45 7488 2222
Fax: +45 7449 0949

MANUFACTURER'S DECLARATION

Danfoss A/S**DCS – Sensing Solutions**

declares under our sole responsibility that the

Product category: Pressure transmitter

Type designation(s): DST P110

Covered by this declaration is in conformity with the following standard(s) or other normative document(s), provided that the product is used in accordance with our instructions.

The products covered by this declaration are not a source of ignition from temperature or arcs/sparks when located in enclosures or areas where flammable refrigerant may stagnate.

The transmitter's maximum surface temperature under worst-case rated conditions is < 135 °C, meeting the requirements of EN/IEC 60335-2-40:2023 §22.117 for refrigerants with an Auto Ignition Temperature (AIT) > 235 °C, including but not limited to R290 (468 °C / 874 °F), R32 (648 °C / 1198 °F), and R454C (393 °C / 739 °F).

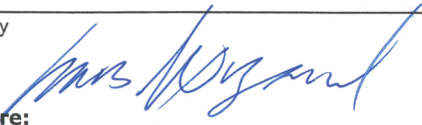
IEC/EN 60335-2-40 , particular requirements for electrical heat pumps , airconditioners and dehumidifiers :

The products comply with Cl. 16 – 22 of IEC/EN 60079-15:2010 and are not considered as source of ignition.

EN 378-2, refrigeration systems and heat pumps :

The products comply with cl. 19.3 IEC/EN 60079-15:2010 and cl. 26.4.2 of IEC/EN IEC 60079-0:2018 and are not considered as source of ignition. The Products must be installed where it is unlikely to be exposed to impacts or it must be protected by an enclosure.

TR075G0450-01

Date: 2026.01.21 Place of issue: DK-8600	Issued by  Signature: Name: Martin Laursen Title: Product Specialist	Date: 2026.01.21 Place of issue: DK-6000	Approved by  Signature: Name: Lars Norgaard Title: Director, Engineering
---	--	---	--

Danfoss only vouches for the correctness of the English version of this declaration. In the event of the declaration being translated into any other language, the translator concerned shall be liable for the correctness of the translation