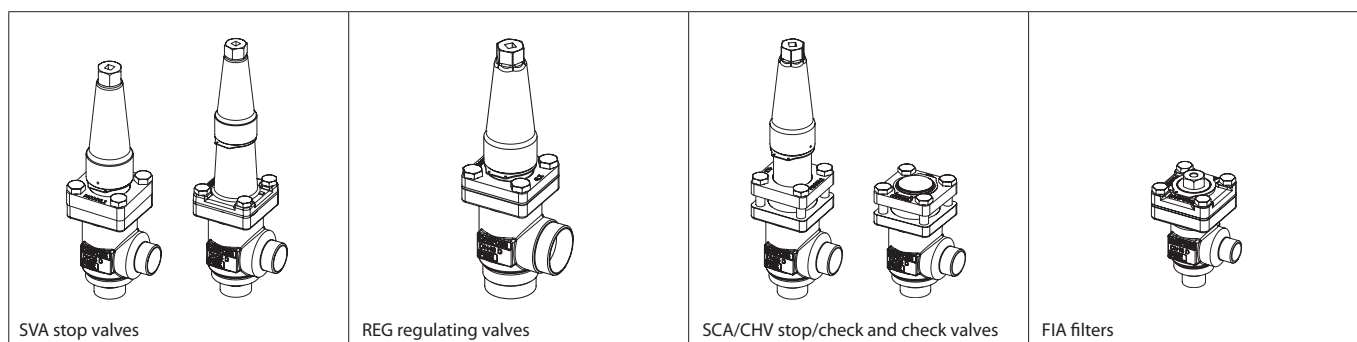


Data sheet

Spare parts and accessories

Shut-off valve, type SVA-S/L, SVA-ST, SVA-LT, SVA-HS | Regulating valve, type REG, REG-SA/SB | Check & stop valve, type SCA, SCA-X | Strainer, type FIA | Check valve, type CHV, CHV-X | ICF 50/65 control modules



Valve type	Size	See details on page #	Code no.
Inspection kits			
SVA-S/L, ST/LT - REG/SA, SB (Size 10 only)	6-10	2	148B6050
SVA-S/L, ST/LT, HS - REG/SA, SB - SCA/X - FIA - CHV/X	15-20	3-4	148B6051
SVA-S/L, ST/LT, HS - REG/SA, SB - SCA/X - FIA - CHV/X	25-40	5-6	148B6052
SVA-S/L, ST/LT, HS - REG/SA, SB - SCA/X - FIA - CHV/X	50	7-8	148B6053
SVA-S/L, ST/LT, HS - REG/SA, SB - SCA/X - FIA - CHV/X	65	9-10	148B6054
SVA-S/L, ST/LT, HS - SCA/X - FIA - CHV/X	80	11-12	148B6055
SVA-S/L, ST/LT, HS - SCA/X - FIA - CHV/X	100	13-14	148B6056
SVA-S/L, ST/LT, HS - SCA/X - FIA - CHV/X	125	15-16	148B6057
SVA-S/L, ST/LT, HS - FIA	150	17	148B6058
SVA-S/L, ST/LT, HS - FIA	200	18	148B6059

Repair kits			
SVA-S/L, ST/LT - REG/SA, SB (Size 10 only)	6-10	19	148B6060
SVA-S/L, ST/LT, HS - REG/SA, SB - SCA/X	15-20	20-21	148B6061
SVA-S/L, ST/LT, HS - REG/SA, SB - SCA/X	25-40	22-23	148B6062
SVA-S/L, ST/LT, HS - REG/SA, SB - SCA/X	50	24-25	148B6063
SVA-S/L, ST/LT, HS - REG/SA, SB - SCA/X	65	26-27	148B6064
SVA-S/L, ST/LT, HS - SCA/X	80	28	148B6065
SVA-S/L, ST/LT, HS - SCA/X	100	29	148B6066
SVA-S/L, ST/LT, HS - SCA/X	125	30	148B6067
SVA-S/L, ST/LT, HS	150	31	148B6068
SVA-S/L, ST/LT, HS	200	32	148B6473

Overhaul kits			
SVA-S/L, ST/LT	6-10	33	148B6150
SVA-S/L, ST/LT, HS	15-20	34	148B6151
SVA-S/L, ST/LT, HS	25-40	35	148B6152
SVA-S/L, ST/LT, HS	50	36	148B6153
SVA-S/L, ST/LT, HS	65	37	148B6154
SVA-S/L, ST/LT, HS	80	38	148B6155
SVA-S/L, ST/LT, HS	100	39	148B6156
SVA-S/L, ST/LT, HS	125	40	148B6157
SVA-S/L, ST/LT, HS	150	41	148B6158
SVA-S/L, ST/LT, HS	200	42	148B6472

All kits are also suitable for the stainless steel versions of the products.

For the Flexline™ products the alternative for the overhaul kit could be the standard top part from the parts programme. Please refer to the technical brochures of the individual Flexline™ products.

Inspection kits:

Contain all gaskets, O-rings and aluminium rings belonging to indicated valve type and valve size. For detailed content, see specific pages.

Repair kits:

Contain all gaskets, O-rings and aluminium rings belonging to indicated valve type and valve size along with a complete packing gland. For detailed content, see specific pages.

Overhaul kits:

Contain all gaskets, O-rings and aluminium rings belonging to indicated valve type and valve size and, where applicable, complete packing gland and parts that could be damaged or worn out. For detailed content, see specific pages.


Valve type	Size	See details on page #	Code no.
Overhaul kits			
SCA / X	15-20	43	148B6160
SCA / X	25-40	44	148B6161
SCA / X	50	45	148B6162
SCA / X	65	46	148B6163
SCA / X	80	47	148B6164
SCA / X	100	48	148B6165
SCA / X	125	49	148B6166
CHV / X	15-20	50	148B6167
CHV / X	25-40	51	148B6168
CHV / X	50	52	148B6169
CHV / X	65	53	148B6170
CHV / X	80	54	148B6171
CHV / X	100	55	148B6172
CHV / X	125	56	148B6173
REG-SA/SB	10	57	148B6174
REG-SA/SB	15-20	58	148B6175
REG-SA/SB	25-40	59	148B6176
REG-SA/SB	50	60	148B6177
REG-SA/SB	65	61	148B6178

Accessories

Cap incl. gasket Hand wheel incl. nut and washer Spring for stop/check and check valves Gasket for housing/top cover Grease for packing gland		62	
---	--	----	--


For REG valves with the previous cone design please refer to the spare part sheets DKRCI.PY.KM0.A and DKRCI.PY.KM0.D.

Inspection kit | Code number 148B6050 SVA-S/L, SVA-ST/LT sizes 6 to 10, REG-SA/SB, REG size 10

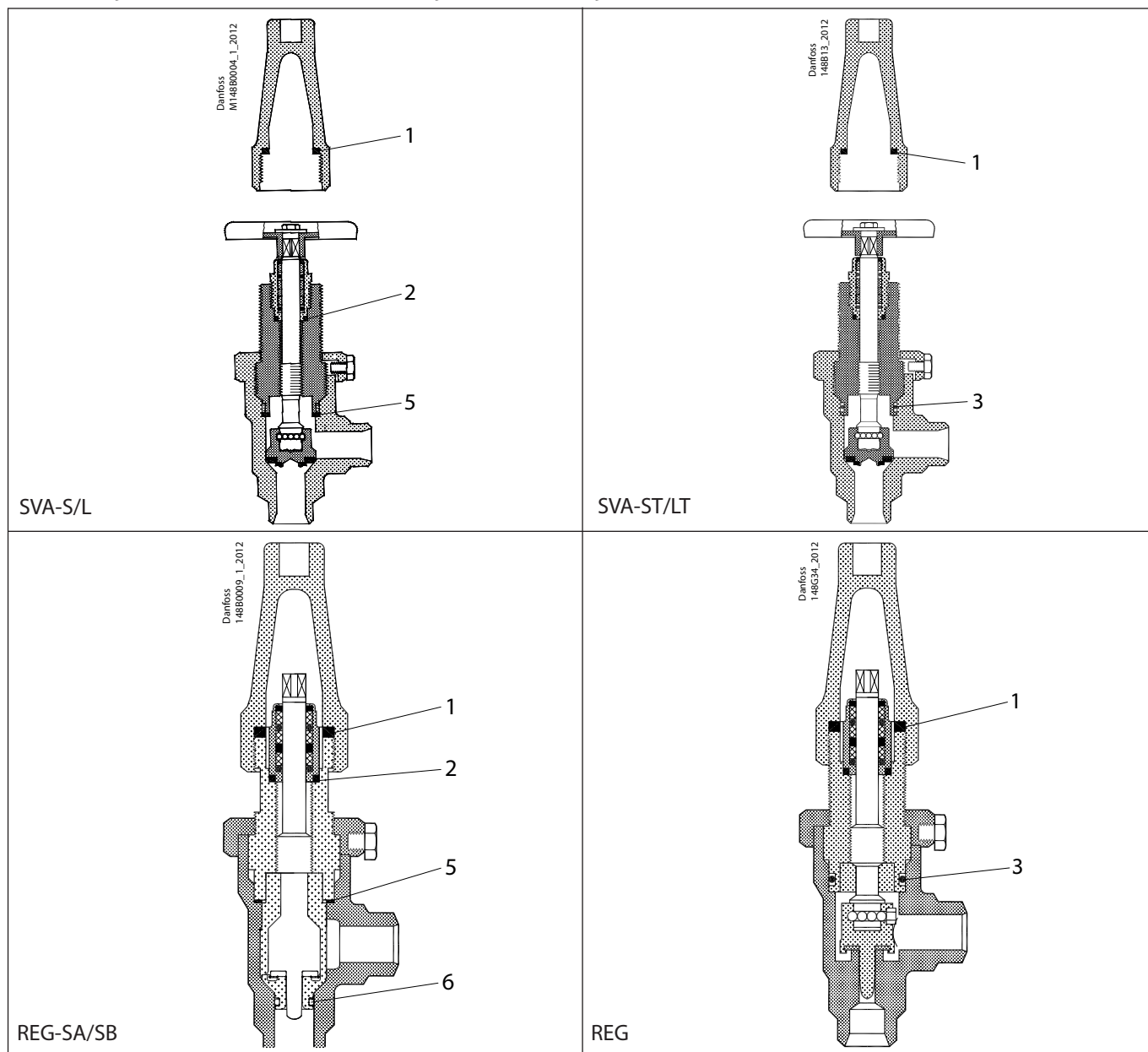


1 = Nylon Ø21 mm Ø0.87 Total no. = 1	2 = Alu. Ø14 mm Ø0.53 Total no. = 1	3 = Alu. Ø17 mm Ø0.67 Total no. = 1	5 = Alu. Ø22 mm Ø0.87 Total no. = 1	6 = Alu. Ø8 mm Ø0.44 Total no. = 1
--	---	---	---	--

Inspection kit | Code number 148B6051
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, FIA, CHV/X sizes 15 - 20

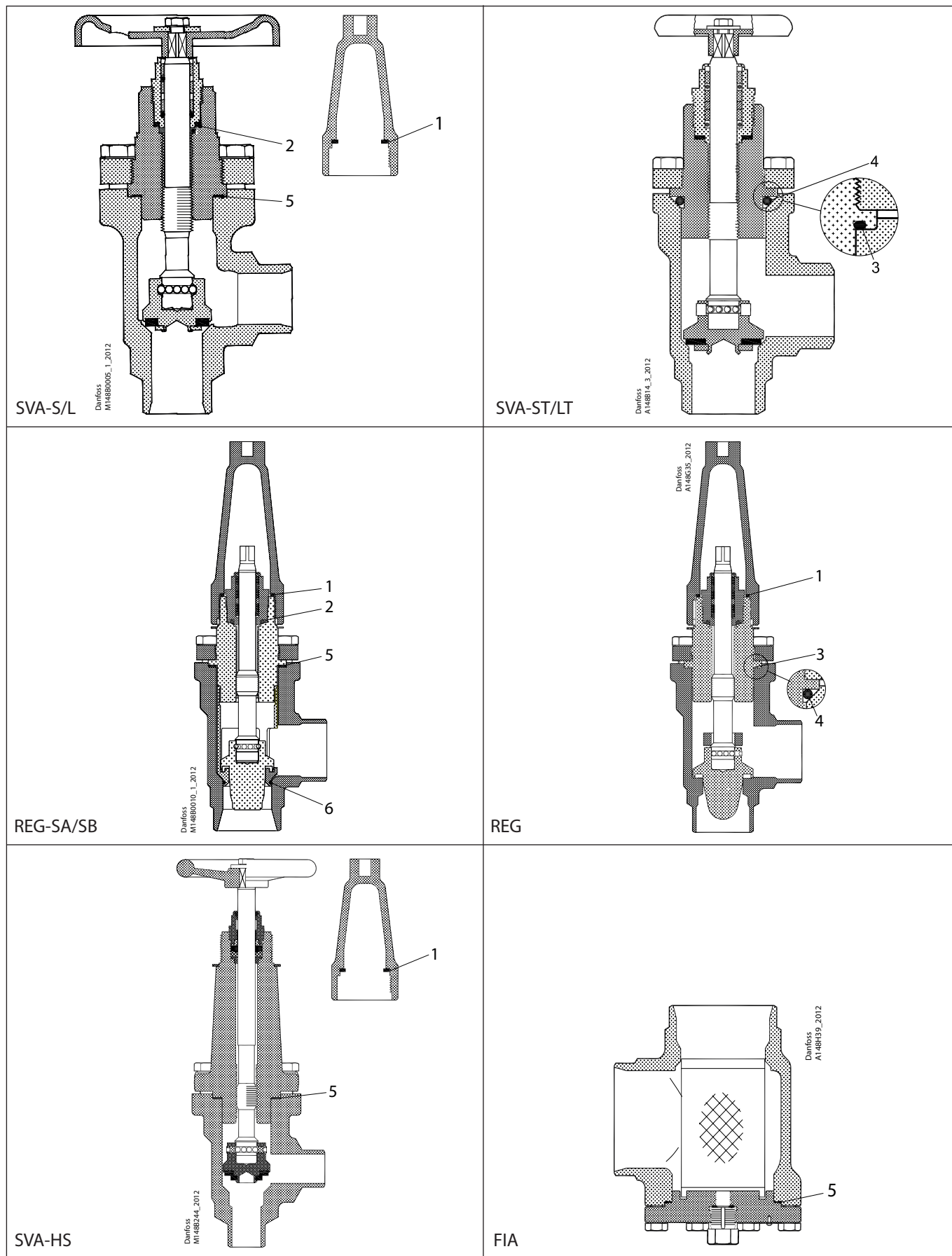


Inspection kit | Code number 148B6051
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, FIA, CHV/X sizes 15 - 20

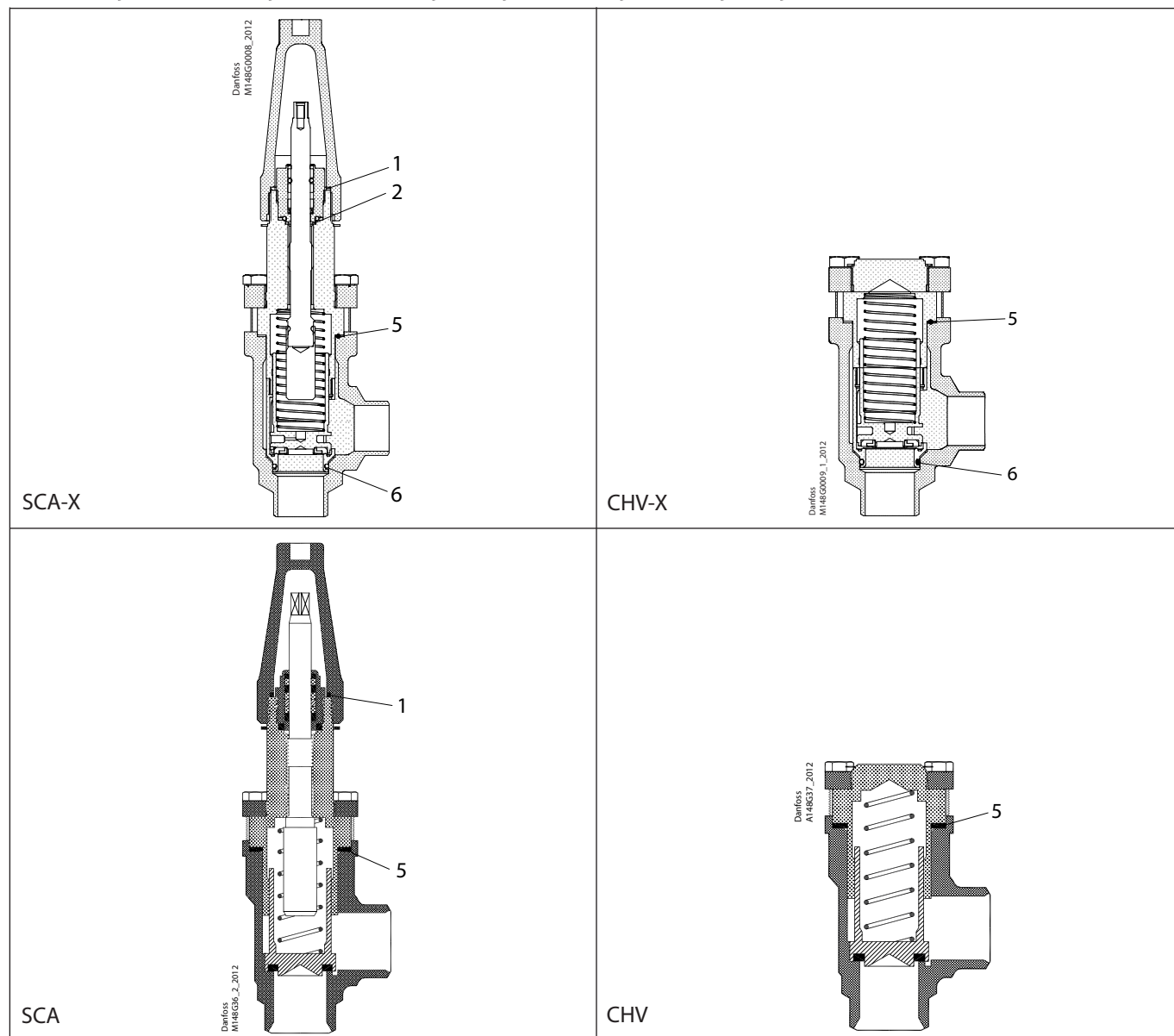


1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 = Seal Total no. = 1	4 = Seal Total no. = 1	5 = Fibre Total no. = 1
6 = Seal Total no. = 1				

Inspection kit | Code number 148B6052

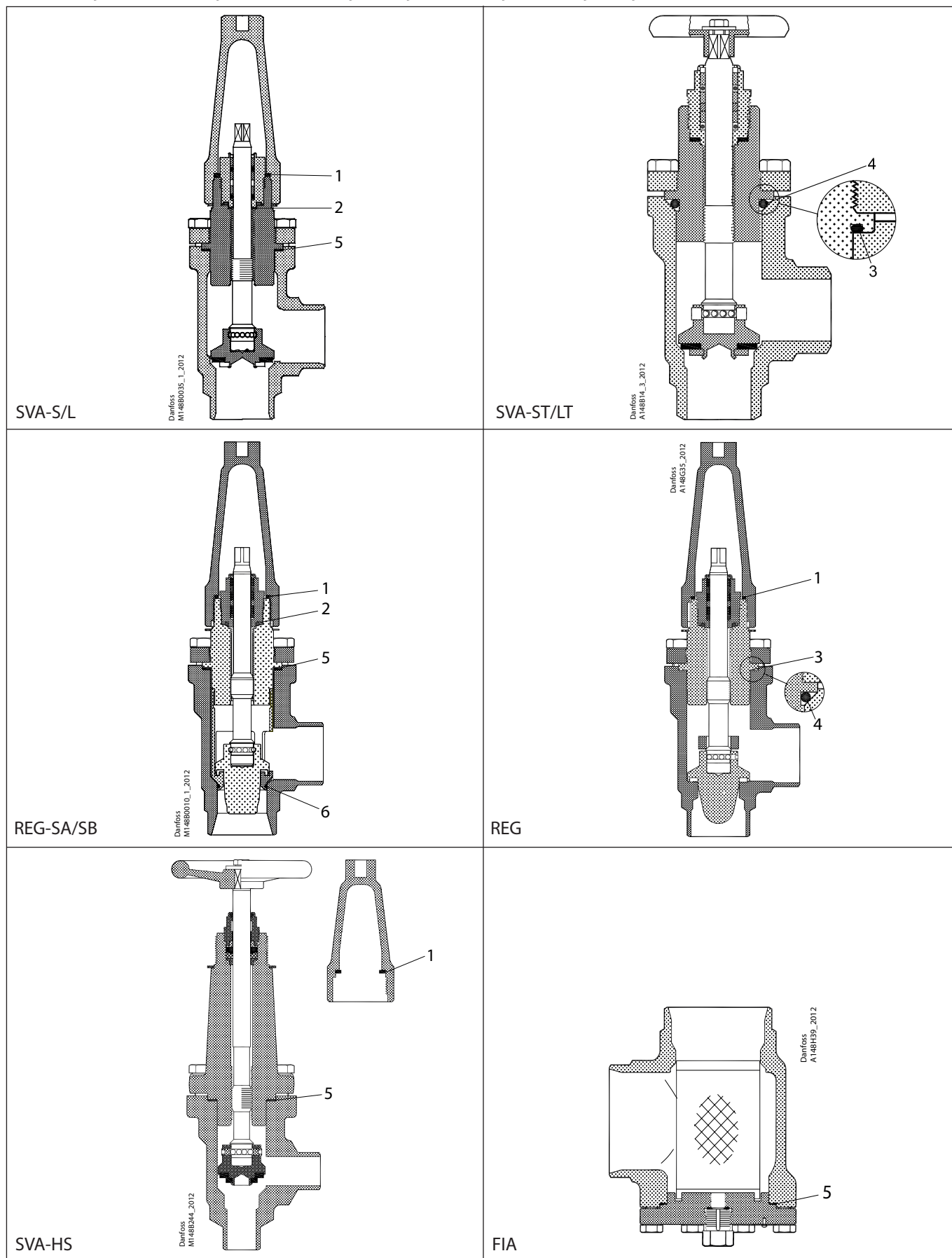SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, FIA, CHV/X sizes 25-40




Inspection kit | Code number 148B6052
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, FIA, CHV/X sizes 25-40

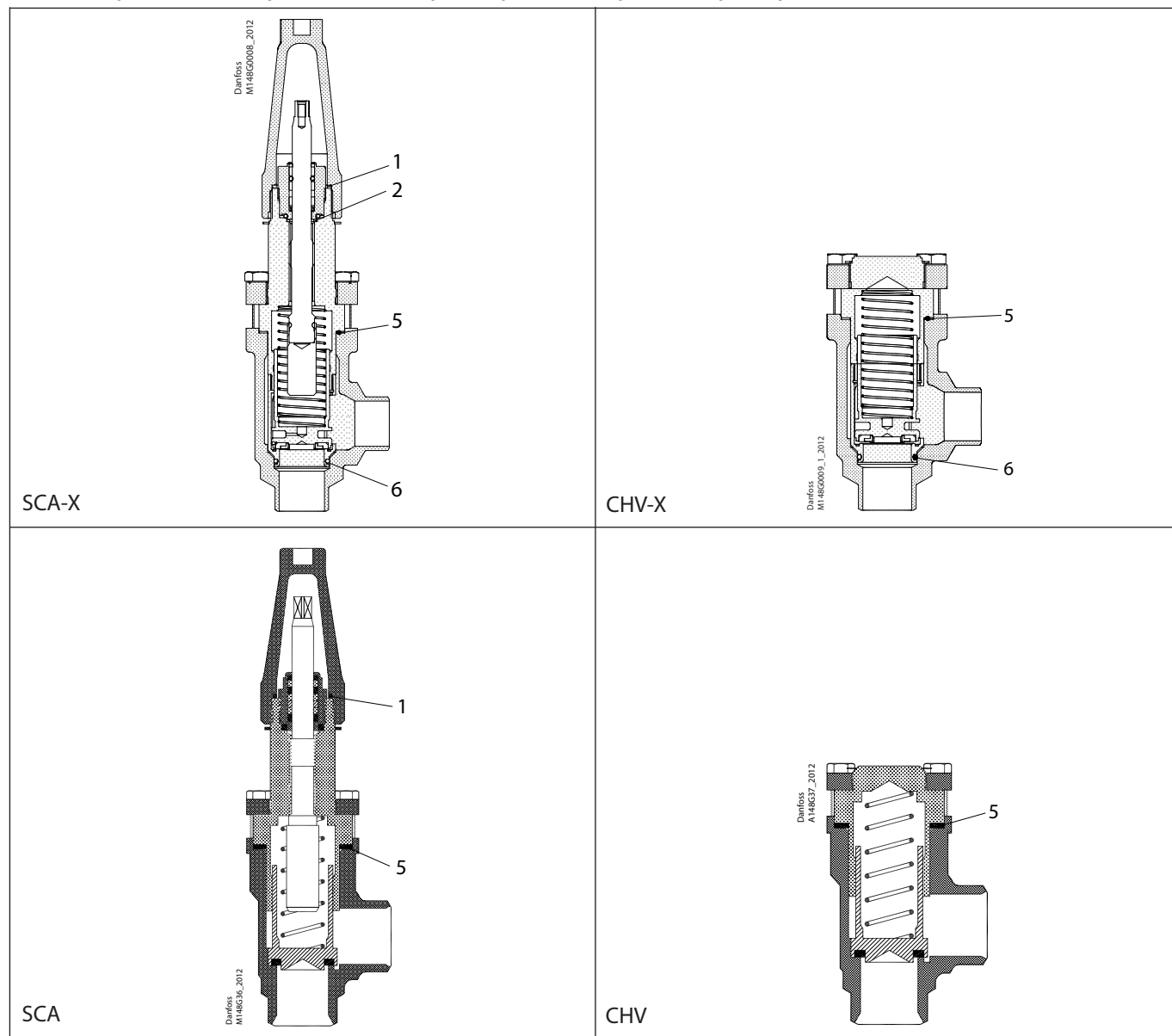








1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	4 Total no. = 1	5 = Fibre Total no. = 1
6 Total no. = 1				

Inspection kit | Code number 148B6053
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, FIA, CHV/X size 50

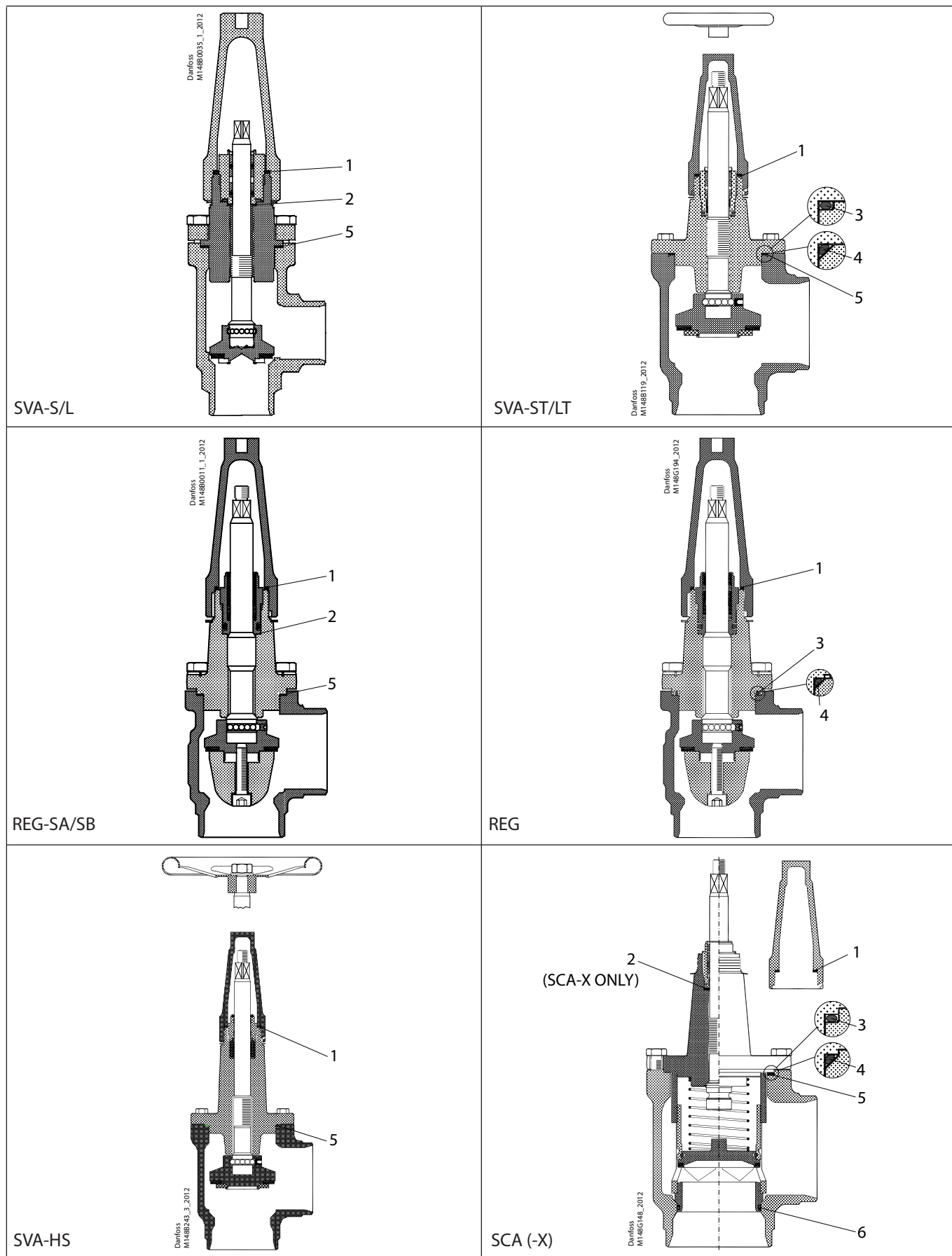


Inspection kit | Code number 148B6053
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, FIA, CHV/X size 50

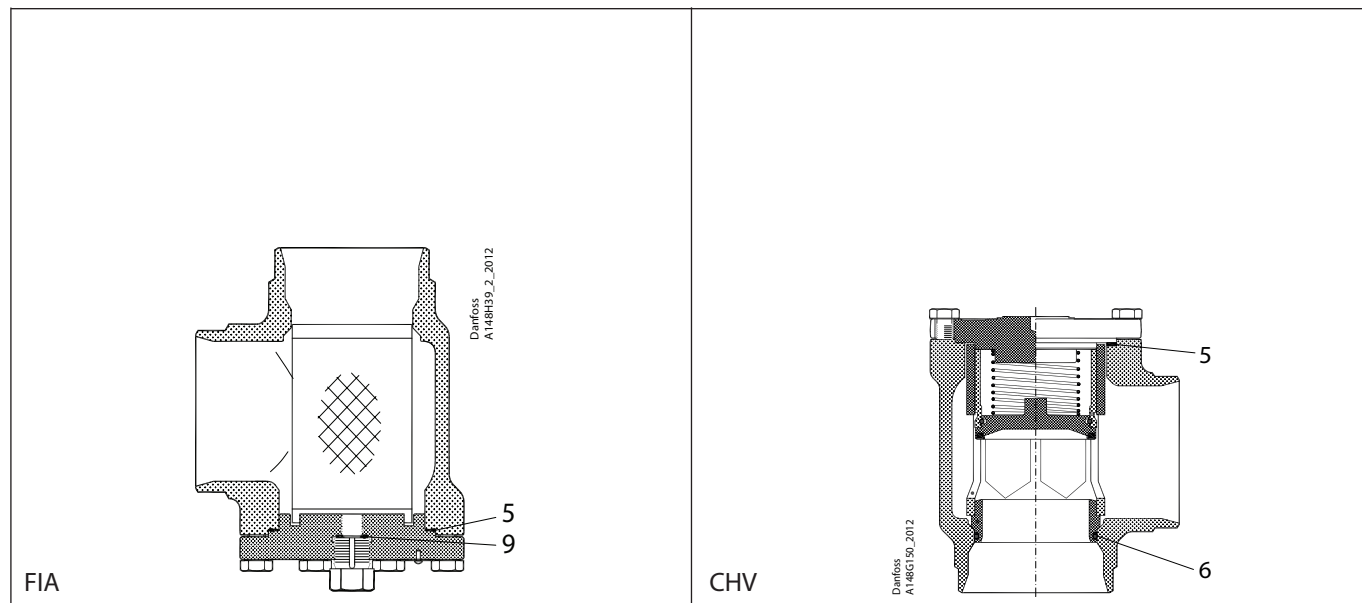

      
1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3   Total no. = 1	4   Total no. = 1	5  = Fibre  Total no. = 1
6   Total no. = 1	9  = Alu.  Total no. = 1			







Inspection kit | Code number 148B6054

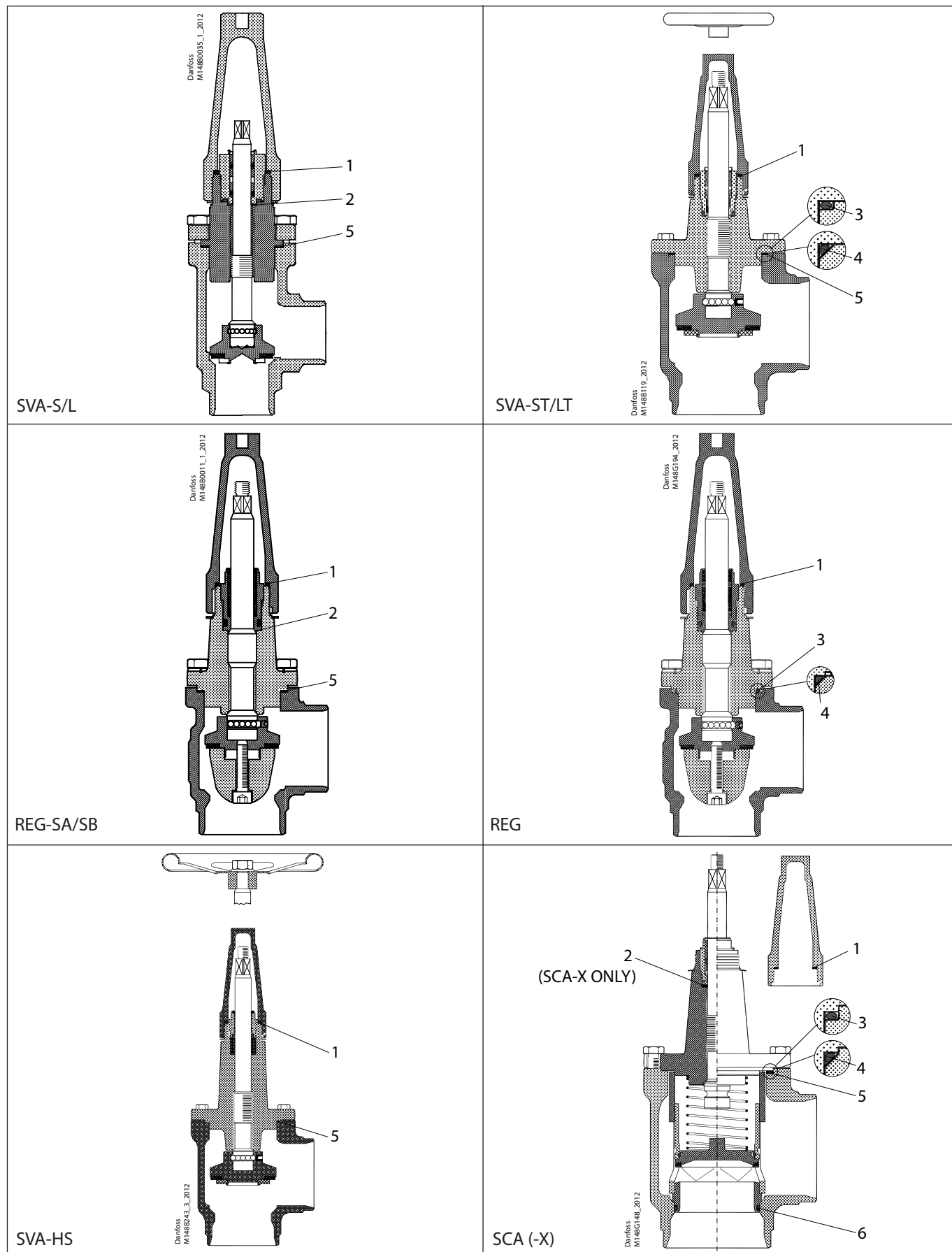SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, FIA, CHV/X size 65




Inspection kit | Code number 148B6054
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, FIA, CHV/X size 65






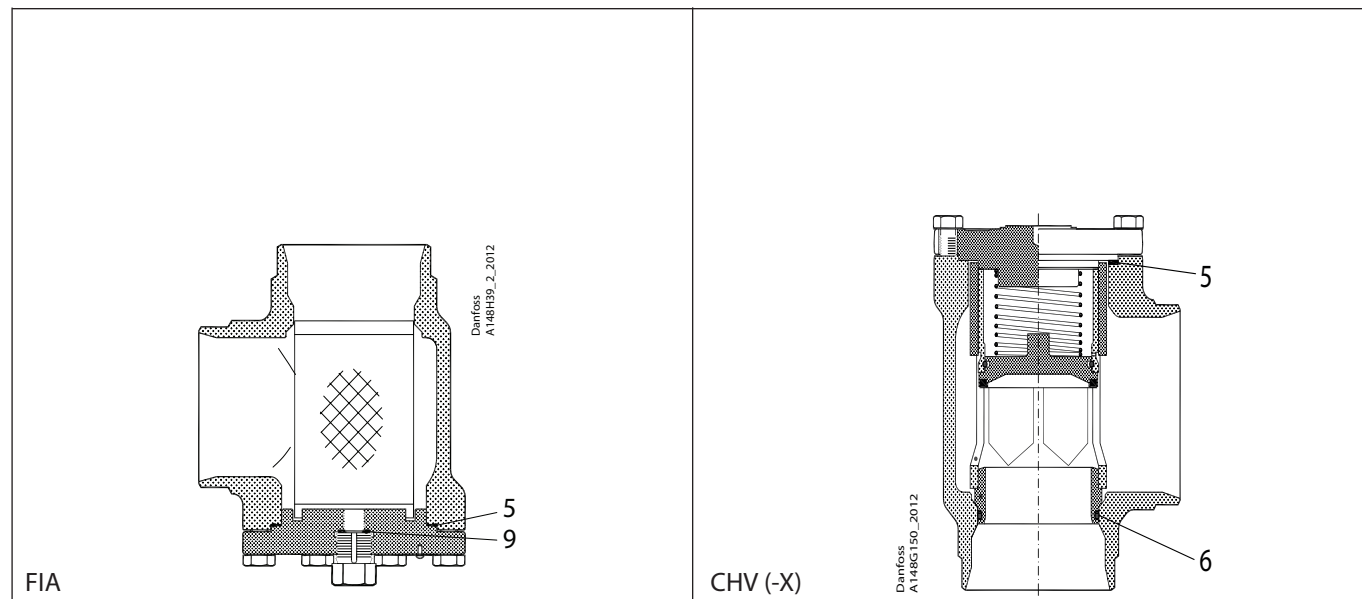


     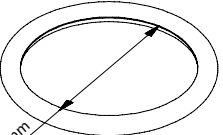1  = Nylon  Ø37 mm Ø1.46" Total no. = 1	2  = Alu.  Ø65 mm Ø2.56" Total no. = 1	3  Ø63 mm Ø2.48" Total no. = 1	4  Ø57 mm Ø2.23" Total no. = 1	5  = Fibre  Ø75 mm Ø2.93" Total no. = 1
6  Ø50 mm Ø1.98" Total no. = 1	9  = Alu.  Ø18 mm Ø0.71" Total no. = 1			


Inspection kit | Code number 148B6055
SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X, FIA, CHV/X size 80

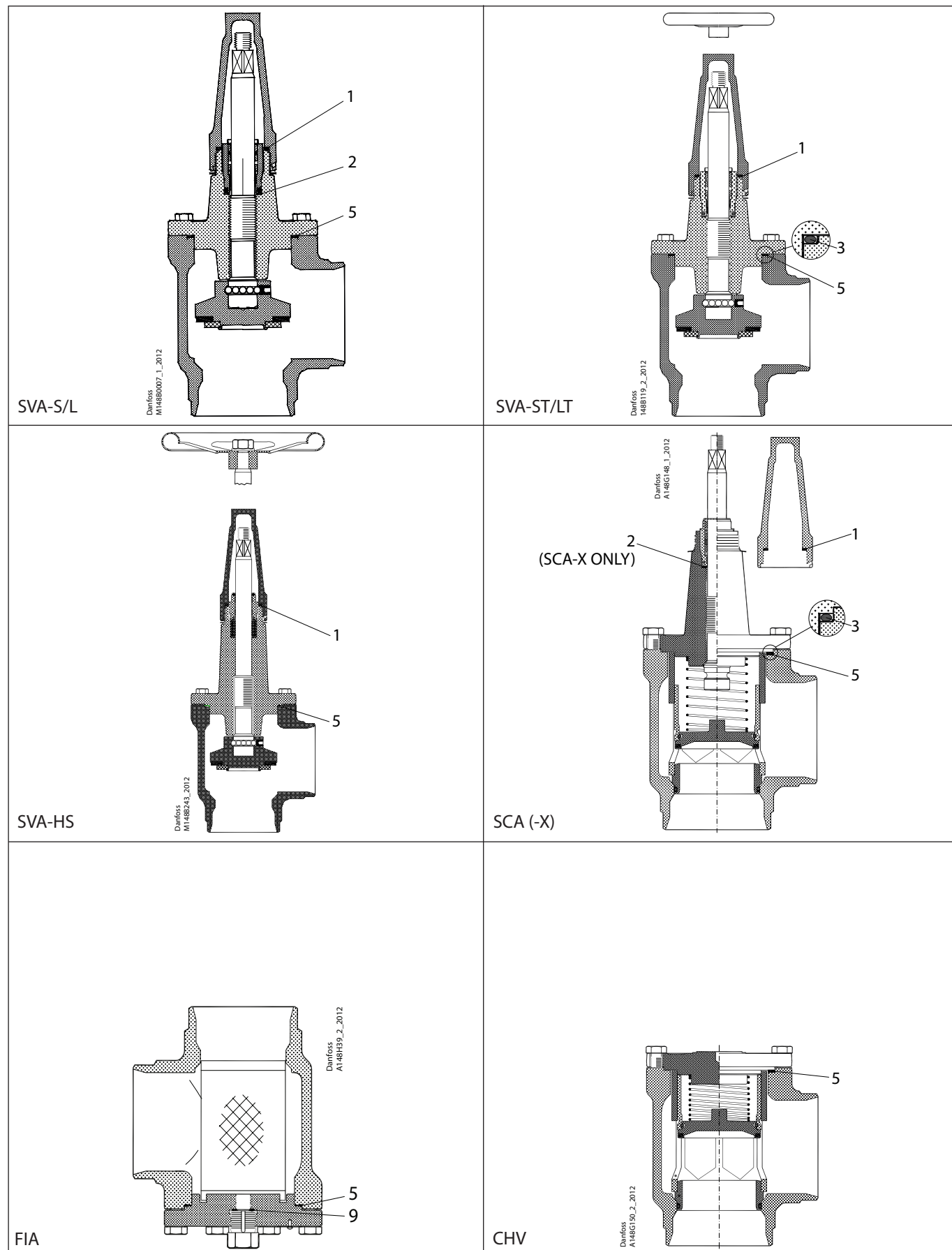







Inspection kit | Code number 148B6055
SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X, FIA, CHV/X size 80

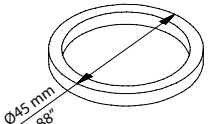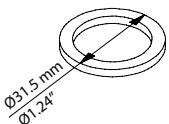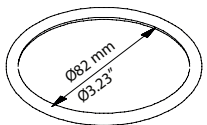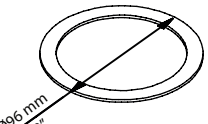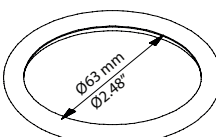 1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3  = Fibre  Total no. = 1	5  = Fibre  Total no. = 1	6  = Fibre  Total no. = 1
9  = Alu.  Total no. = 1				


Inspection kit | Code number 148B6056
SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X, FIA, CHV/X size 100

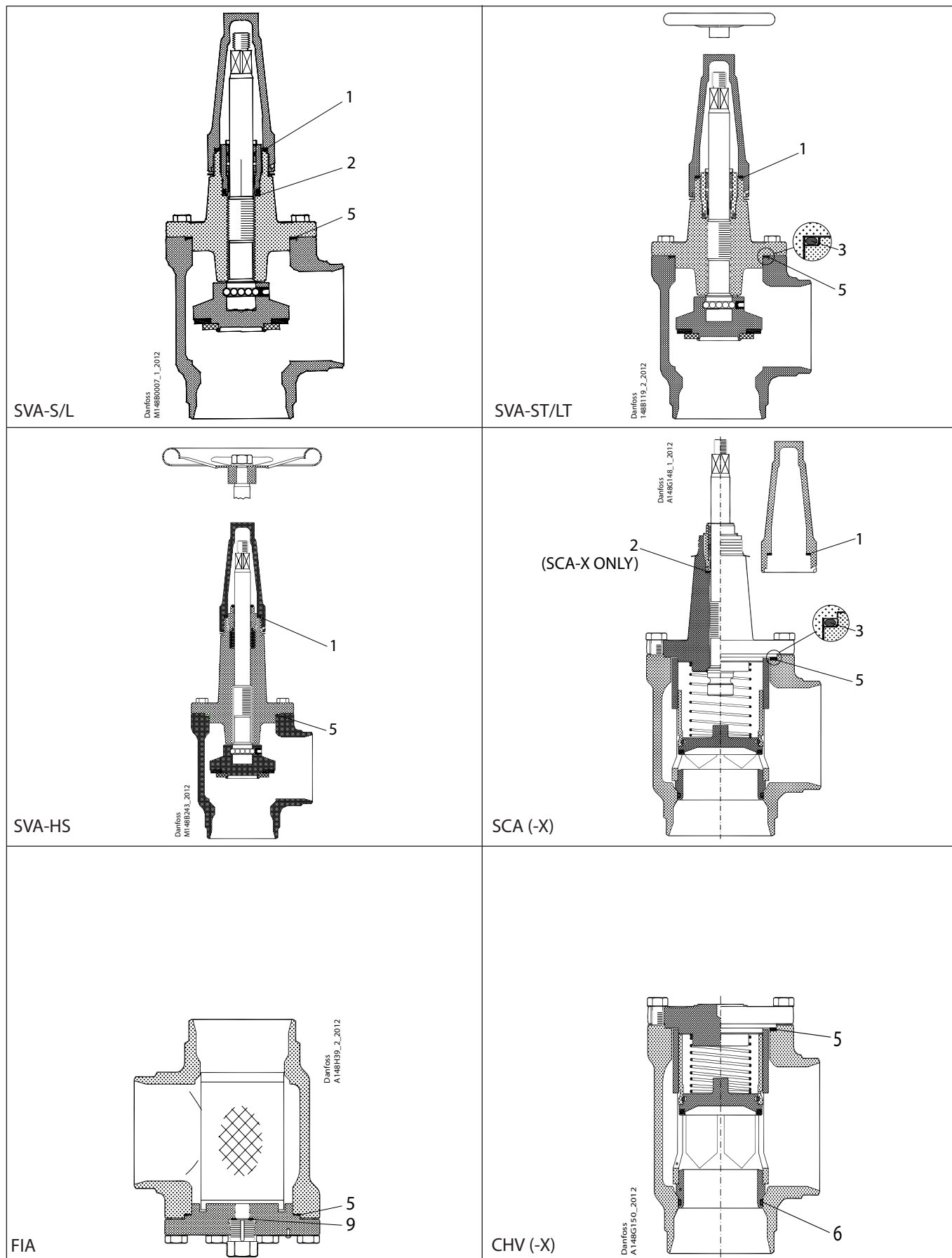






Inspection kit | Code number 148B6056
SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X, FIA, CHV/X size 100

    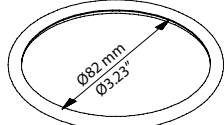 1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3   Total no. = 1	5  = Fibre  Total no. = 1	6   Total no. = 1
9  = Alu.  Total no. = 1				


Inspection kit | Code number 148B6057
SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X, FIA, CHV/X size 125

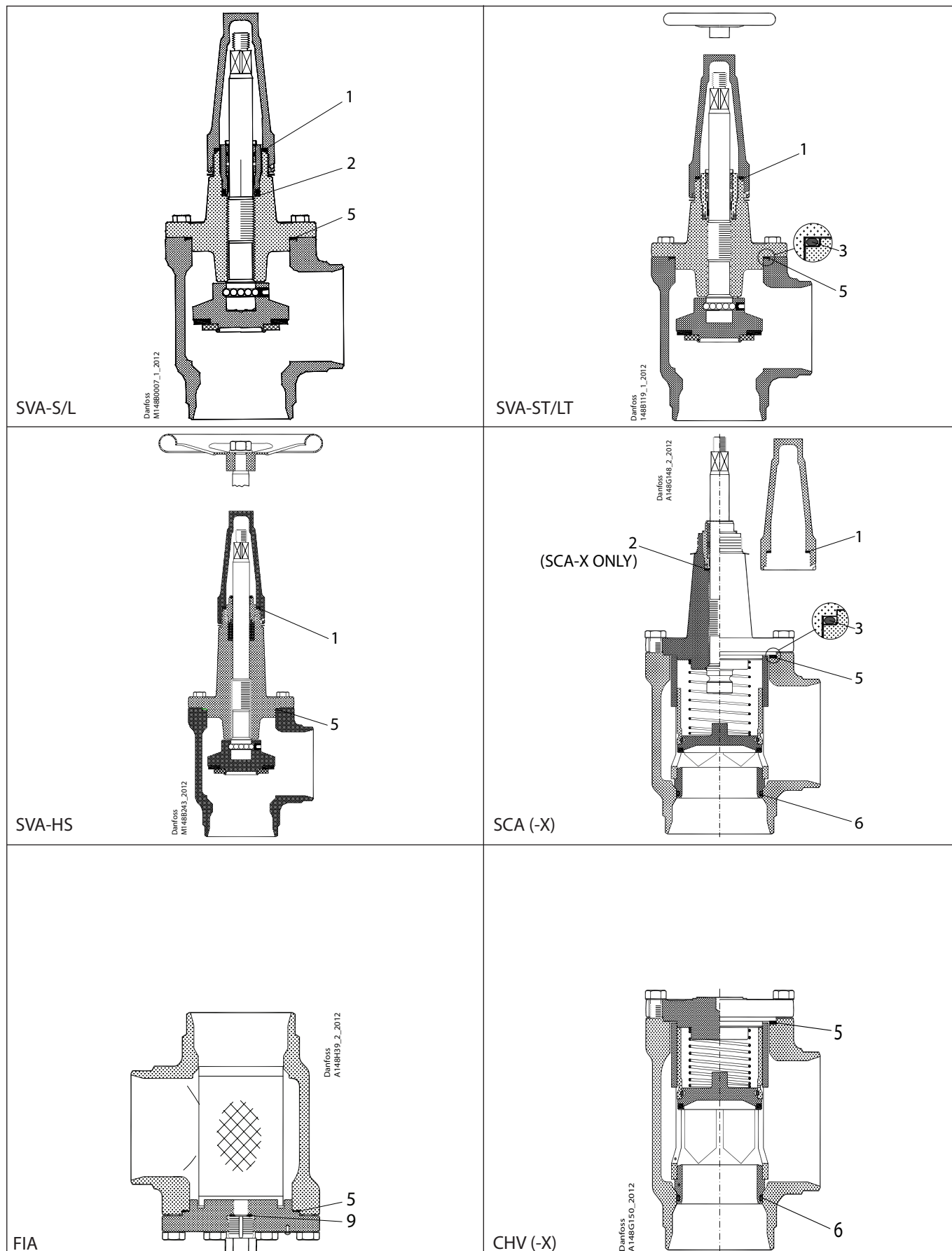

Inspection kit | Code number 148B6057
SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X, FIA, CHV/X size 125

     
1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3   Total no. = 1	5  = Fibre  Total no. = 1	6   Total no. = 1
9  = Alu.  Total no. = 1				





Inspection kit | Code number 148B6058 SVA-S/L, SVA-ST/LT, SVA-HS, FIA size 150

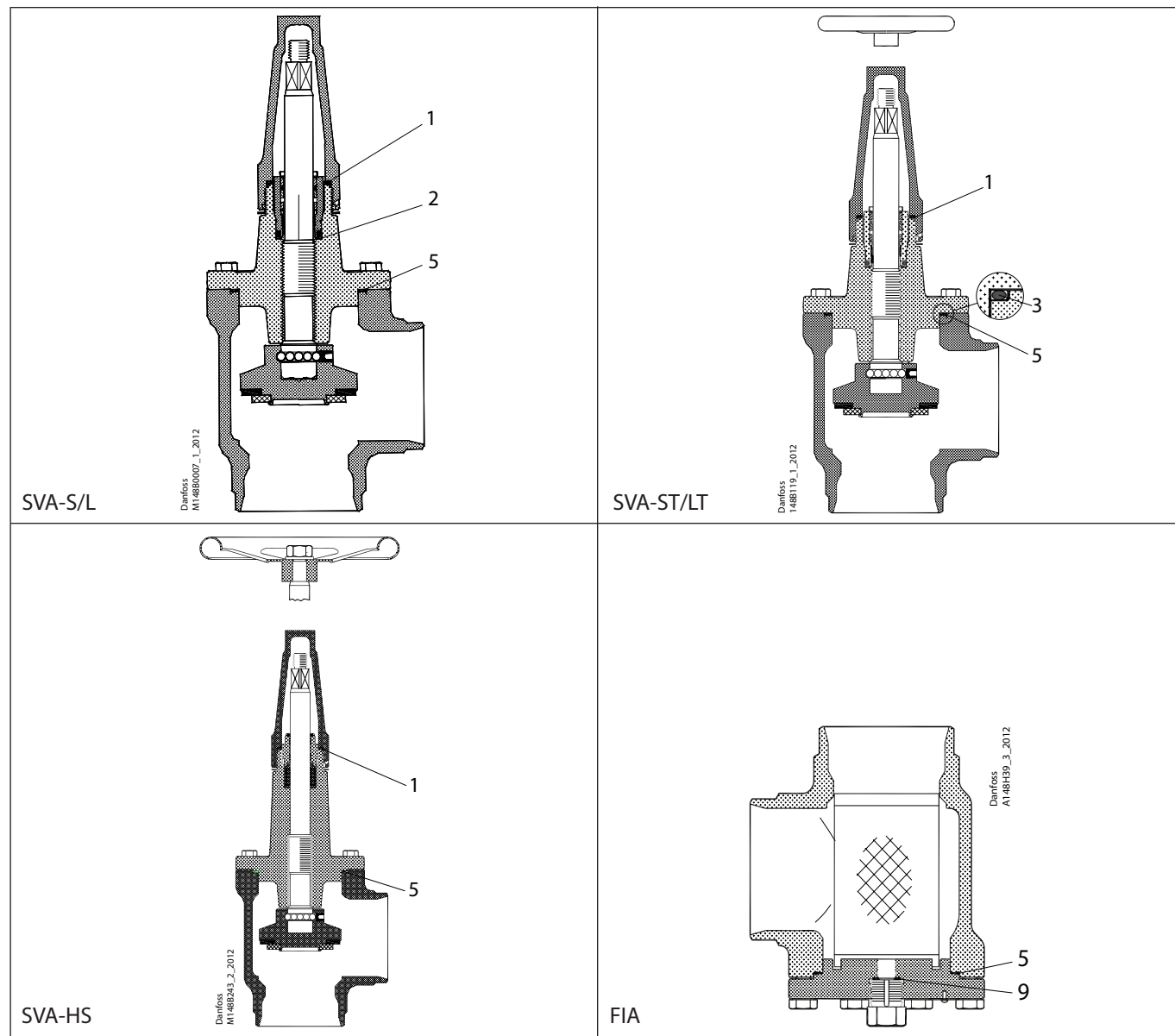


1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	5 = Fibre Total no. = 1	9 = Alu. Total no. = 1
--	---	--------------------------------------	--	---

Inspection kit | Code number 148B6059 SVA-S/L, SVA-ST/LT, SVA-HS, FIA size 200

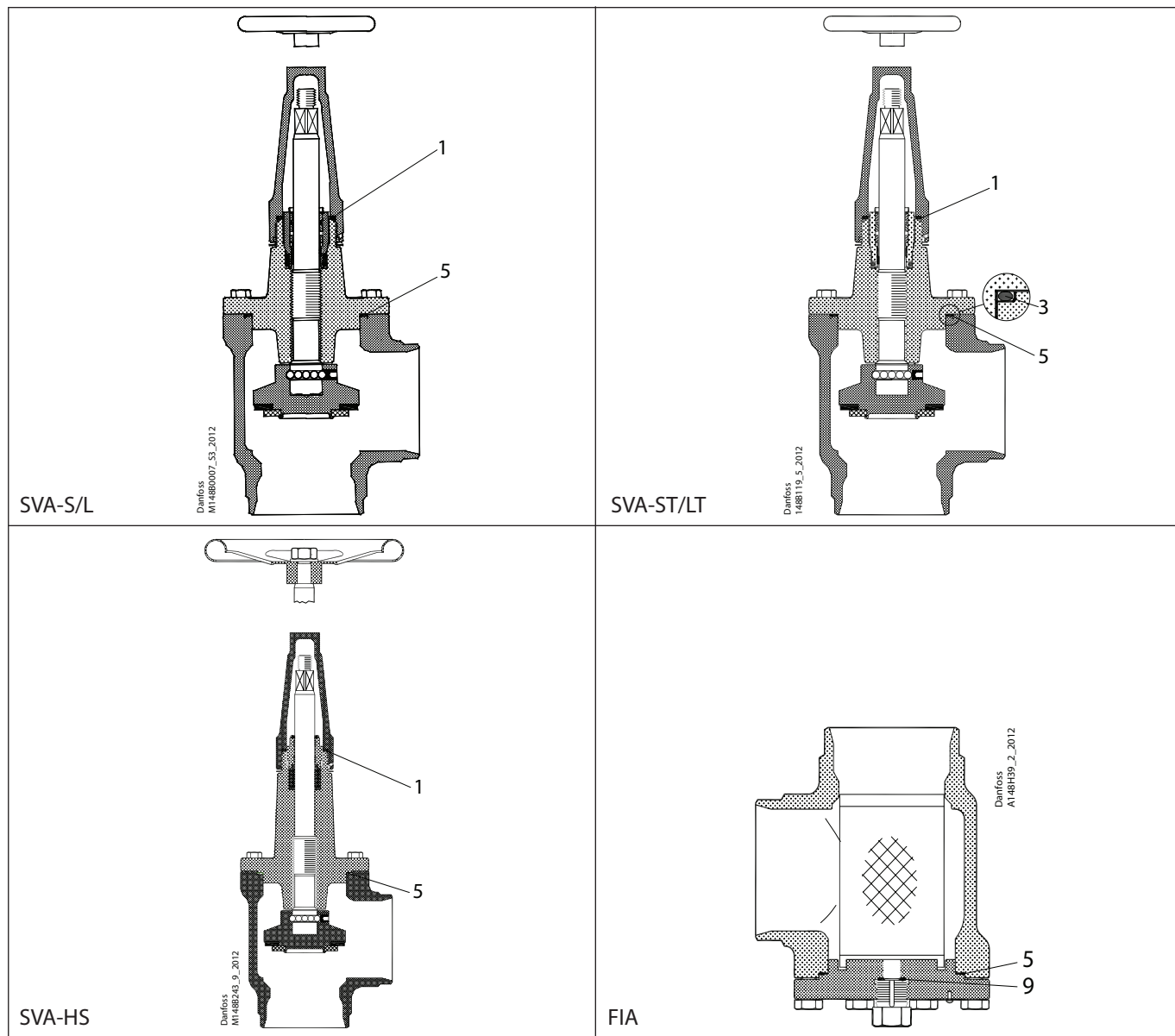

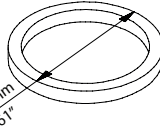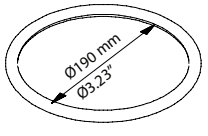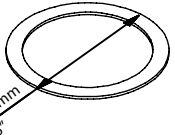 1  = Nylon  Total no. = 1	3  Total no. = 1	5  = Fibre  Total no. = 1	9  = Alu.  Total no. = 1	
---	--	---	---	--

Repair kit | Code number 148B6060 SVA-S/L, SVA-ST/LT sizes 6 to 10, REG-SA/SB, REG size 10

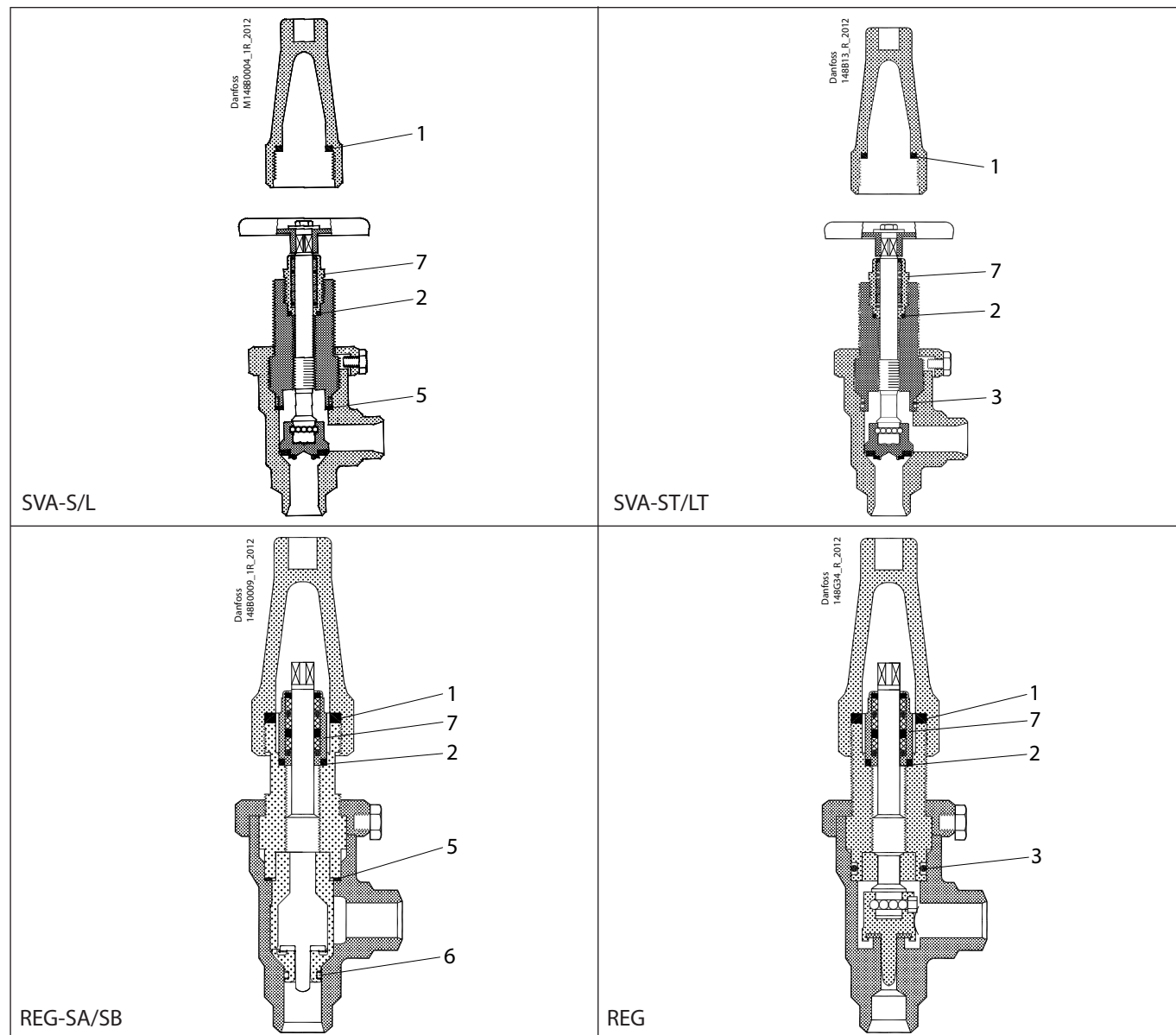


1 = Nylon Ø21 mm Ø0.87" Total no. = 1	2 = Alu. Ø14 mm Ø0.55" Total no. = 1	3 = Alu. Ø17 mm Ø0.67" Total no. = 1	5 = Alu. Ø22 mm Ø0.87" Total no. = 1	6 = Alu. Ø8 mm Ø0.44" Total no. = 1
7 = Alu. Ø14 mm Ø0.55" Total no. = 1				

NOTE: When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L, SVA-HS or REG the aluminium gasket (pos. 2) is needed.


Repair kit | Code number 148B6061






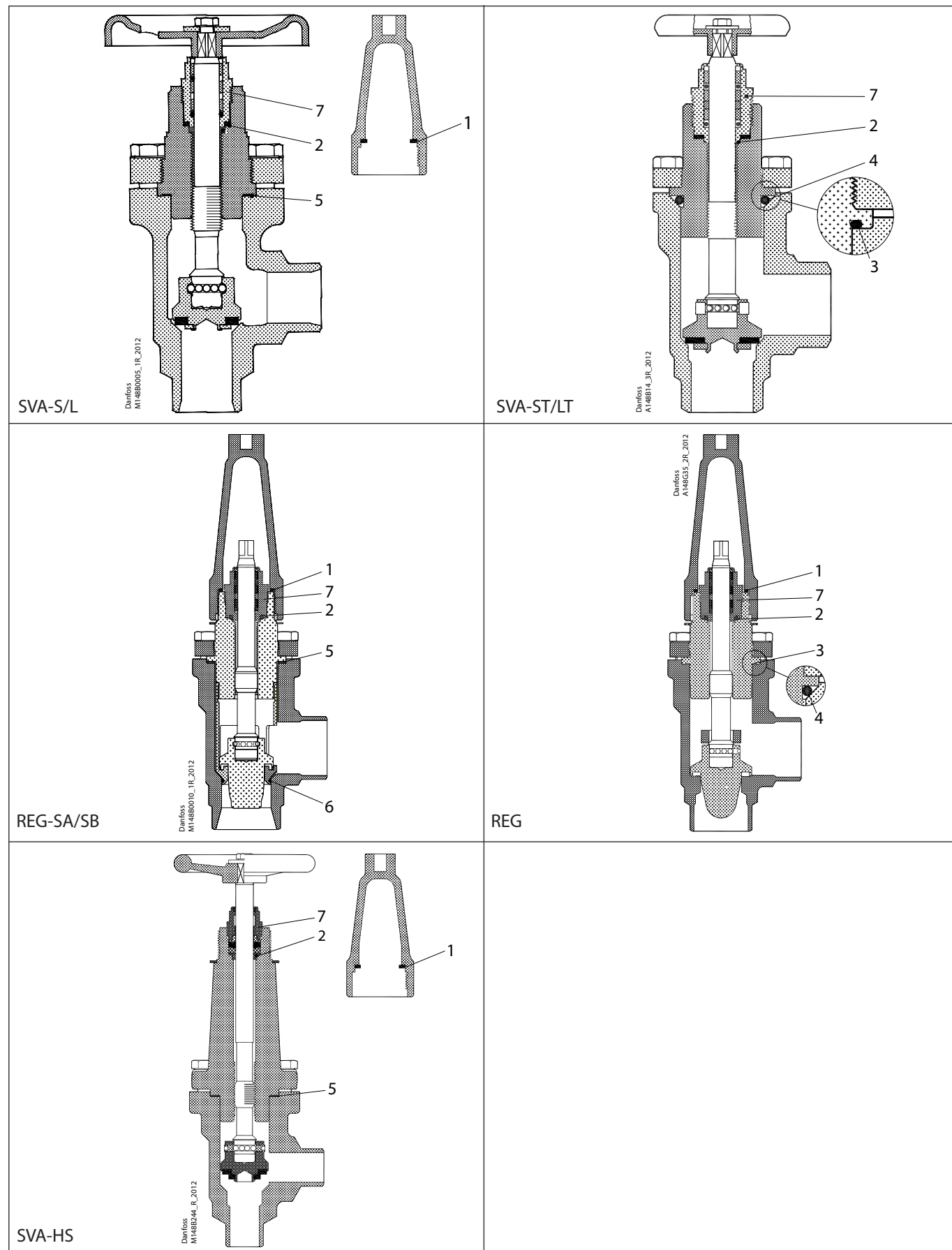
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X sizes 15 - 20



Repair kit | Code number 148B6061

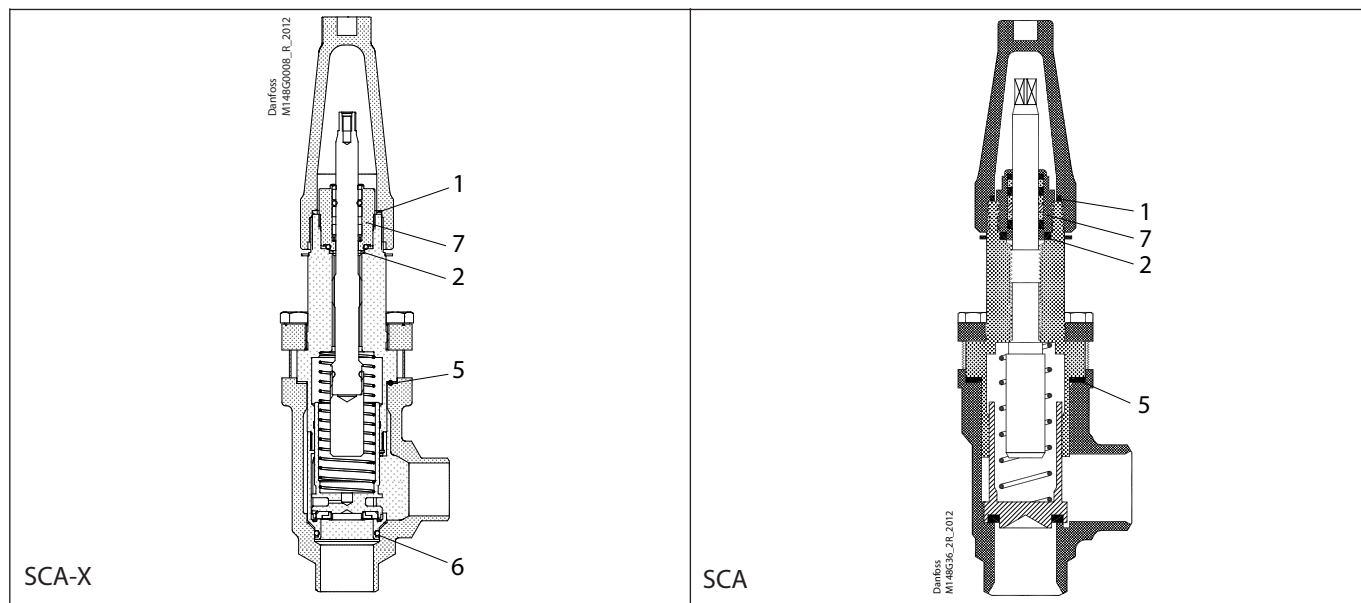      SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X sizes 15 - 20




1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3   Total no. = 1	4   Total no. = 1	5  = Fibre  Total no. = 1
6   Total no. = 1	7  Total no. = 1			

NOTE:


When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L, SVA-HS, REG-SA/SB, REG, SCA or SCA-X the aluminium gasket (pos. 2) is needed.

Repair kit | Code number 148B6062

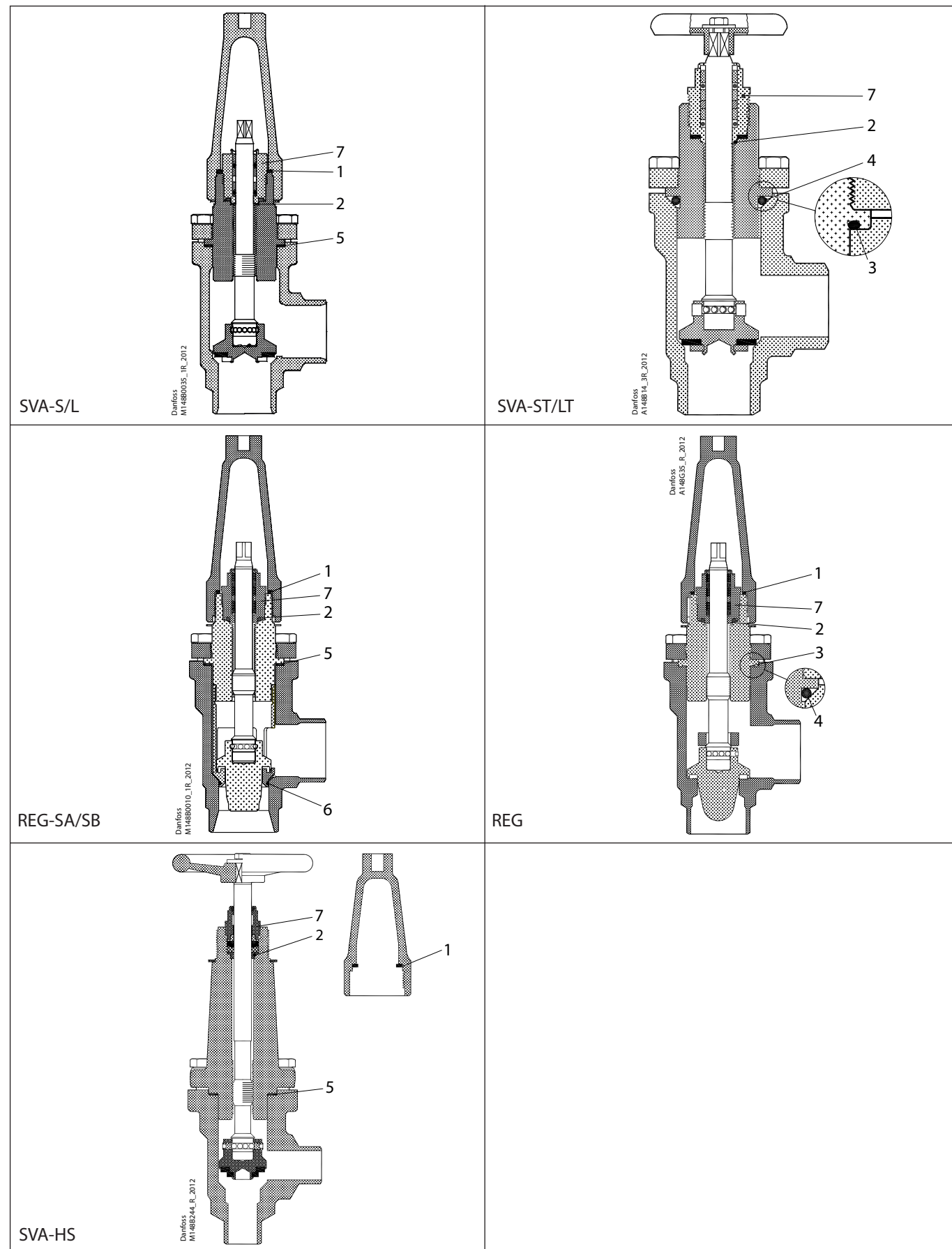SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X sizes 25-40



Repair kit | Code number 148B6062 SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X sizes 25-40

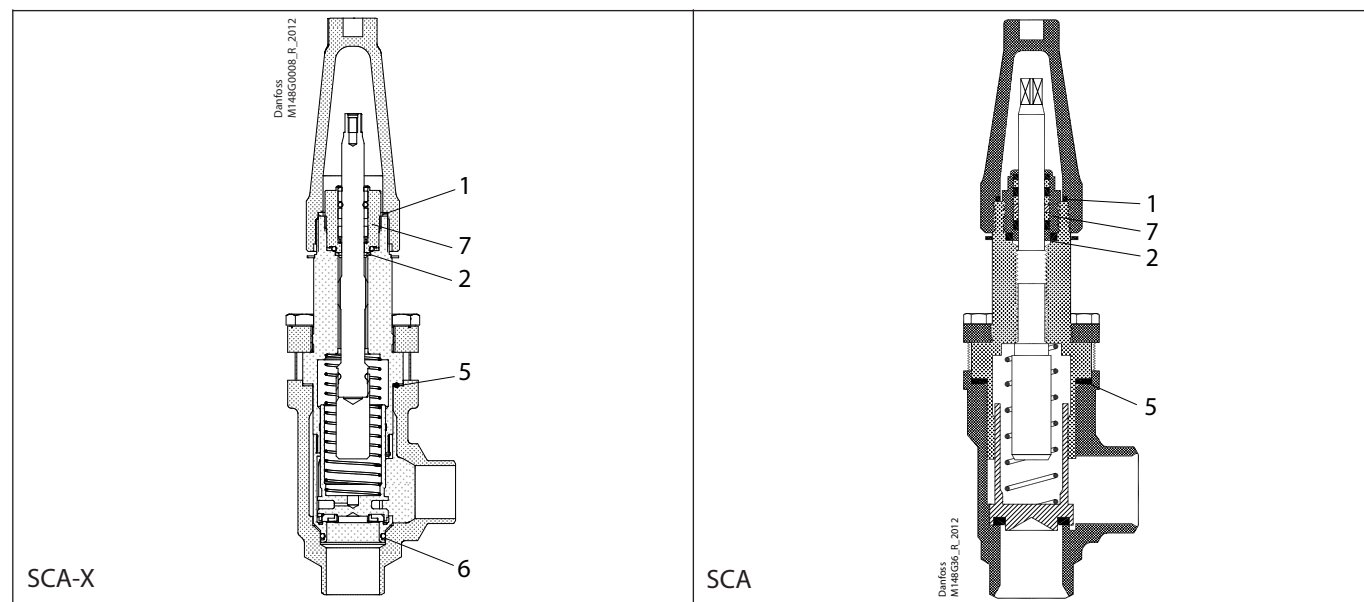


1 = Nylon $\varnothing 37 \text{ mm}$ $\varnothing 1.46''$ Total no. = 1	2 = Alu. $\varnothing 19 \text{ mm}$ $\varnothing 0.75''$ Total no. = 1	3 $\varnothing 31 \text{ mm}$ $\varnothing 1.22''$ Total no. = 1	4 $\varnothing 37 \text{ mm}$ $\varnothing 1.46''$ Total no. = 1	5 = Fibre $\varnothing 54 \text{ mm}$ $\varnothing 2.13''$ Total no. = 1
6 $\varnothing 20 \text{ mm}$ $\varnothing 1.17''$ Total no. = 1	7 $\varnothing 28 \text{ mm}$ $\varnothing 1.1''$ Total no. = 1	8* $\varnothing 41 \text{ mm}$ $\varnothing 1.57''$ Total no. = 1		








NOTE:

When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L, SVA-HS, REG, REG-SA/SB, SCA or SCA-X the aluminium gasket (pos. 2) is needed.

Repair kit | Code number 148B6063
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X size 50

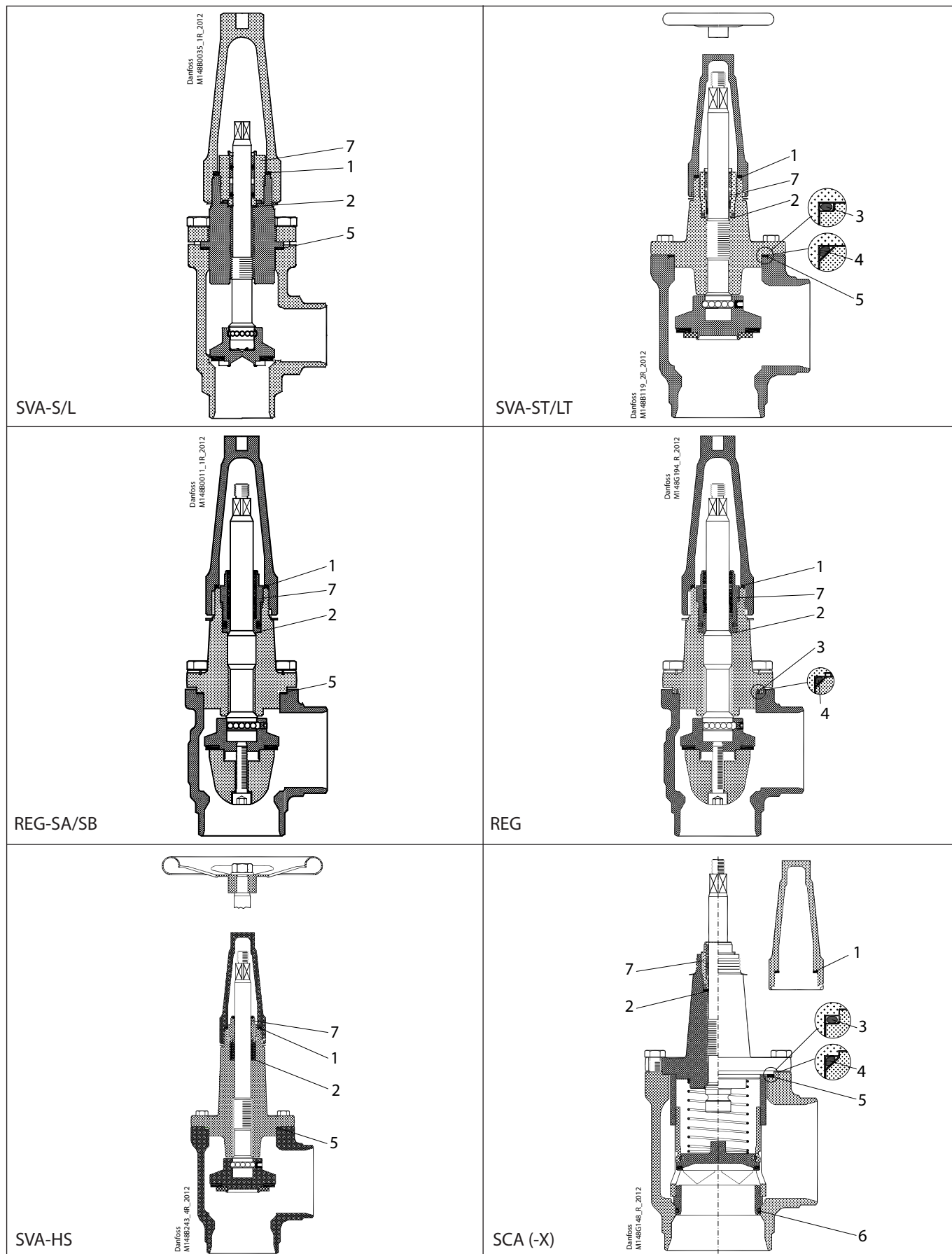


Repair kit | Code number 148B6063
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X size 50

      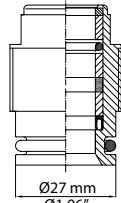1  = Nylon  Ø37 mm Ø1.46" Total no. = 1	2  = Alu.  Ø26.5 mm Ø1.04" Total no. = 1	3   Ø50 mm Ø1.97" Total no. = 1	4   Ø47 mm Ø1.85" Total no. = 1	5  = Fibre  Ø63.5 mm Ø2.5" Total no. = 1
6   Ø41 mm Ø1.61" Total no. = 1	7  Ø27 mm Ø1.06" Total no. = 1			








NOTE:

When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L, SVA-HS, REG-SA/B, REG, SCA-X and SCA the aluminium gasket (pos. 2) is needed.

Repair kit | Code number 148B6064
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, size 65

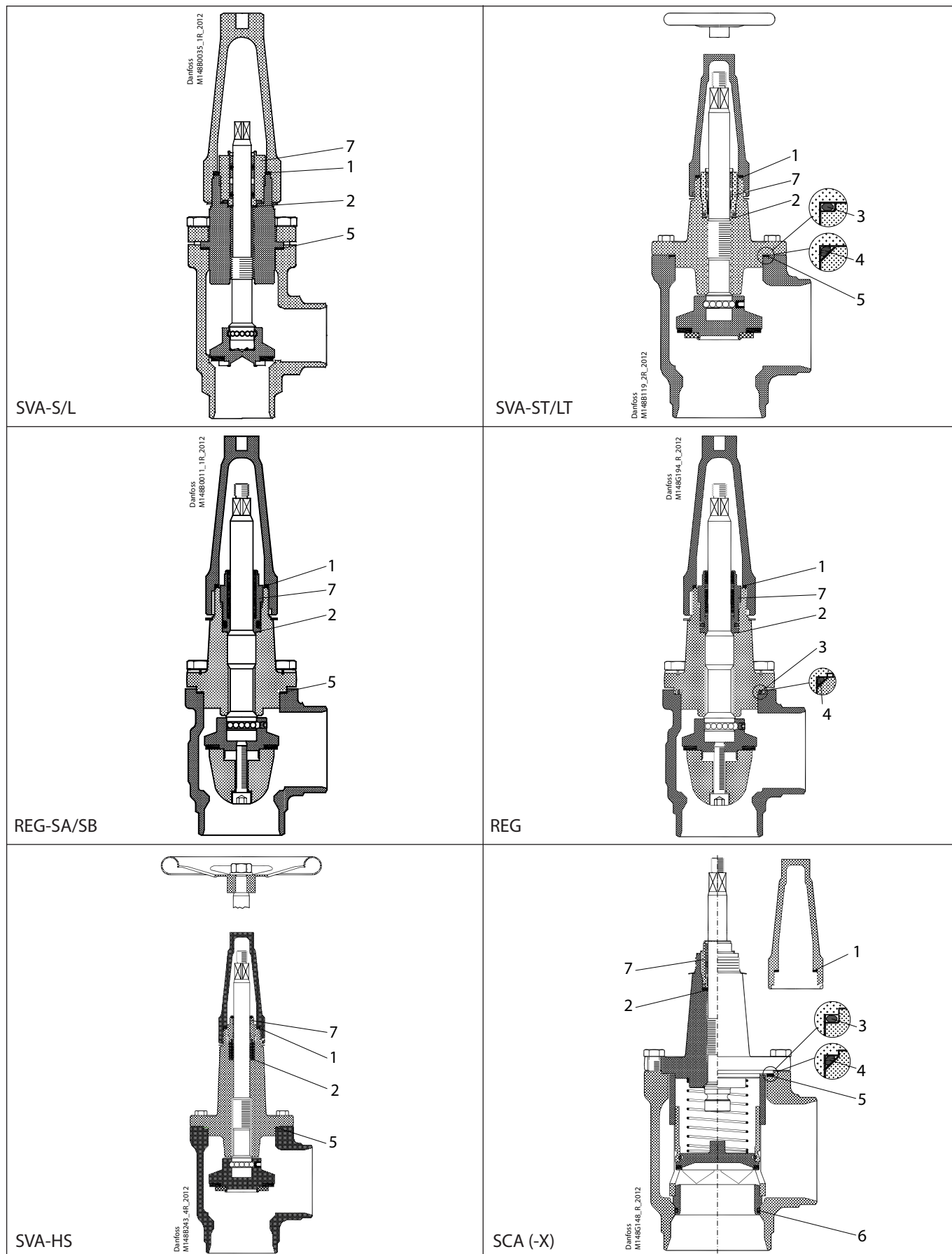


Repair kit | Code number 148B6064
SVA-S/L, SVA-ST/LT, REG-SA/SB, REG, SVA-HS, SCA/X, size 65

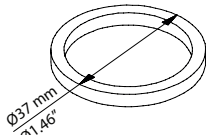
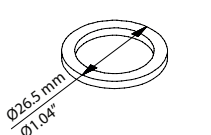
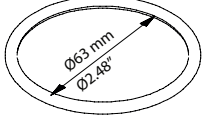
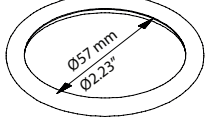
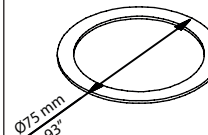
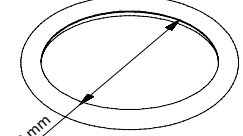
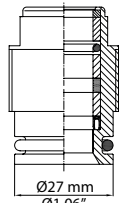
1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3   Total no. = 1	4   Total no. = 1	5  = Fibre  Total no. = 1
6   Total no. = 1	7  Total no. = 1			

NOTE:

When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L, SVA-HS, REG-SA/B, REG, SCA-X and SCA the aluminium gasket (pos. 2) is needed.


Repair kit | Code number 148B6065 SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X size 80







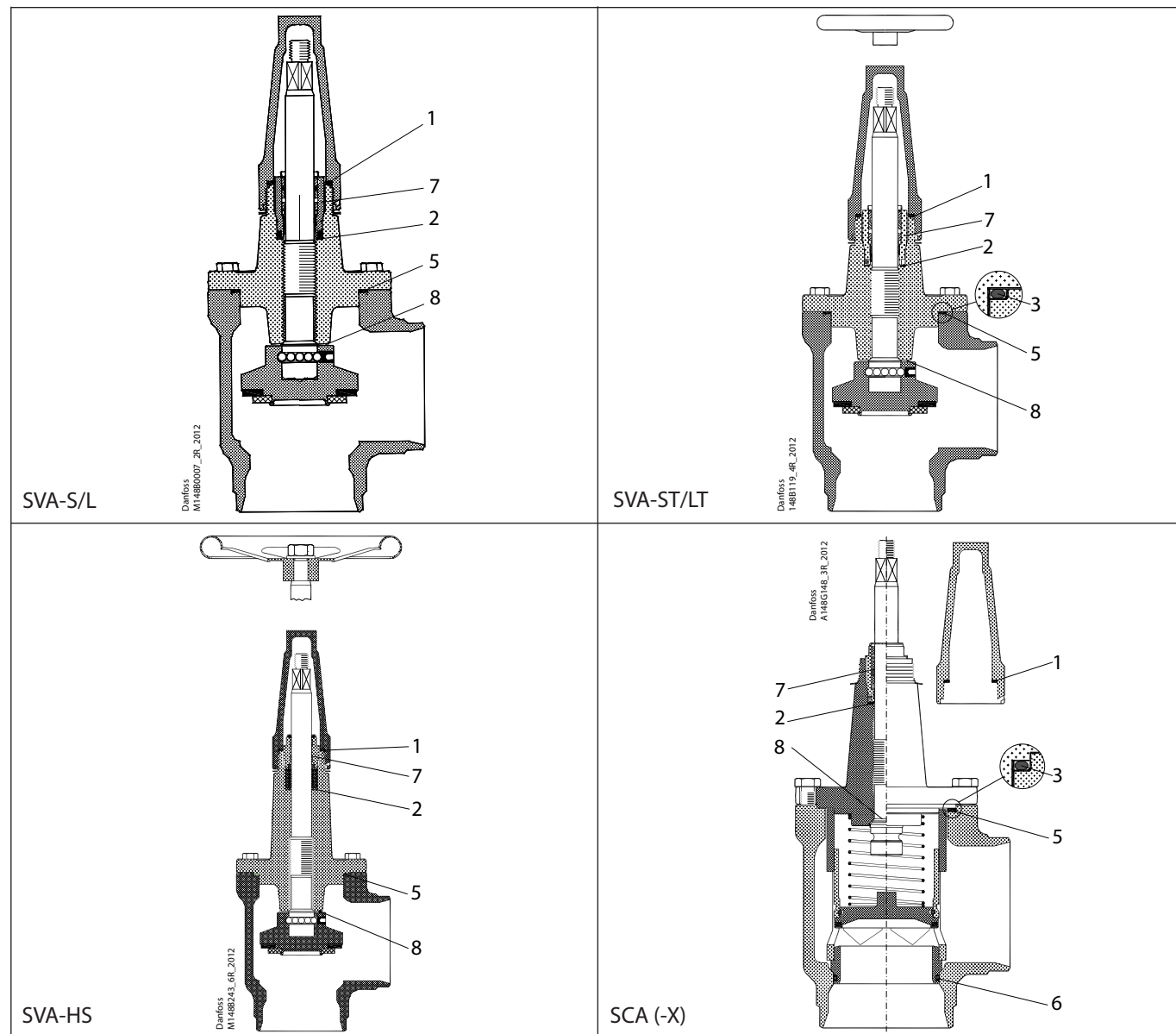


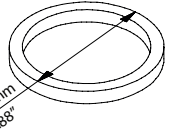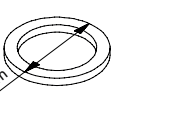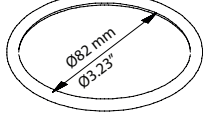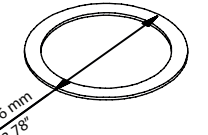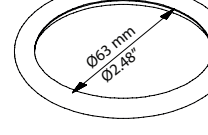 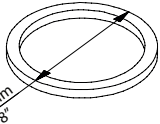1  = Nylon  Ø45 mm Ø1.88" Total no. = 1	2  = Alu.  Ø31.5 mm Ø1.24" Total no. = 1	3  Ø82 mm Ø3.23" Total no. = 1	5  = Fibre  Ø96 mm Ø3.78" Total no. = 1	6  Ø63 mm Ø2.48" Total no. = 1
7  Ø32 mm Ø1.26" Total no. = 1	8  = PTFE  Ø30 mm Ø1.18" Total no. = 1			

NOTE: When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L, SVA-HS, SCA-X and SCA the aluminium gasket (pos. 2) is needed.


Repair kit | Code number 148B6066 SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X size 100







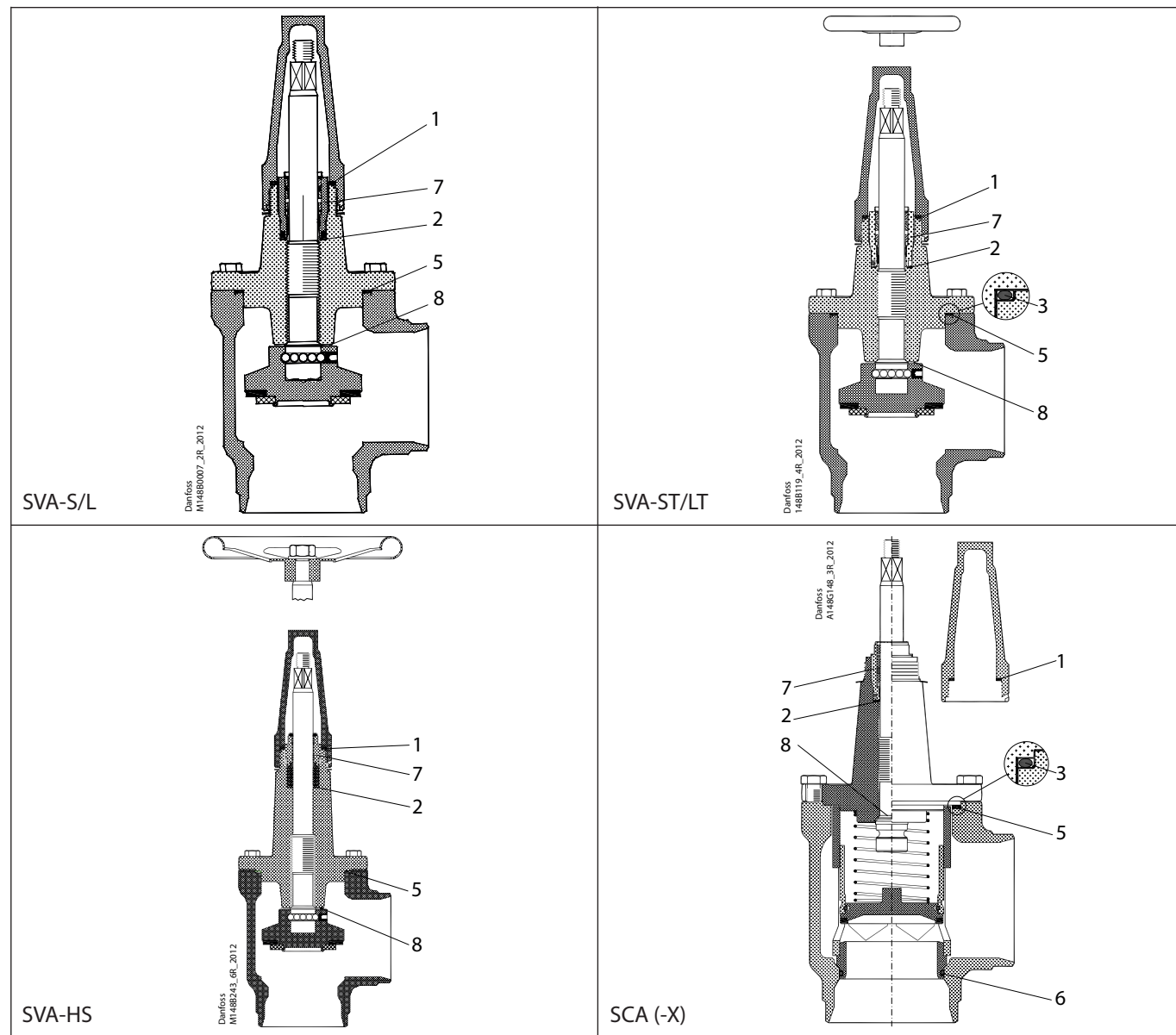


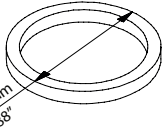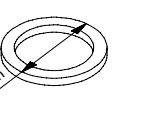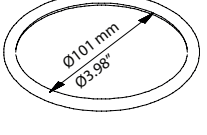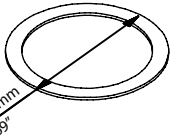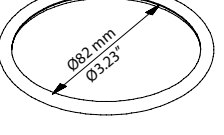 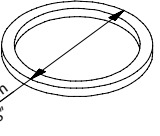1  = Nylon  Ø45 mm Ø1.98" Total no. = 1	2  = Alu.  Ø31.5 mm Ø1.24" Total no. = 1	3   Ø101 mm Ø3.98" Total no. = 1	5  = Fibre  Ø119 mm Ø4.69" Total no. = 1	6   Ø82 mm Ø3.23" Total no. = 1
7  Ø32 mm Ø1.26" Total no. = 1	8  = PTFE  Ø50 mm Ø1.98" Total no. = 1			

NOTE: When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L, SVA-HS, SCA-X and SCA the aluminium gasket (pos. 2) is needed.


Repair kit | Code number 148B6067 SVA-S/L, SVA-ST/LT, SVA-HS, SCA/X size 125






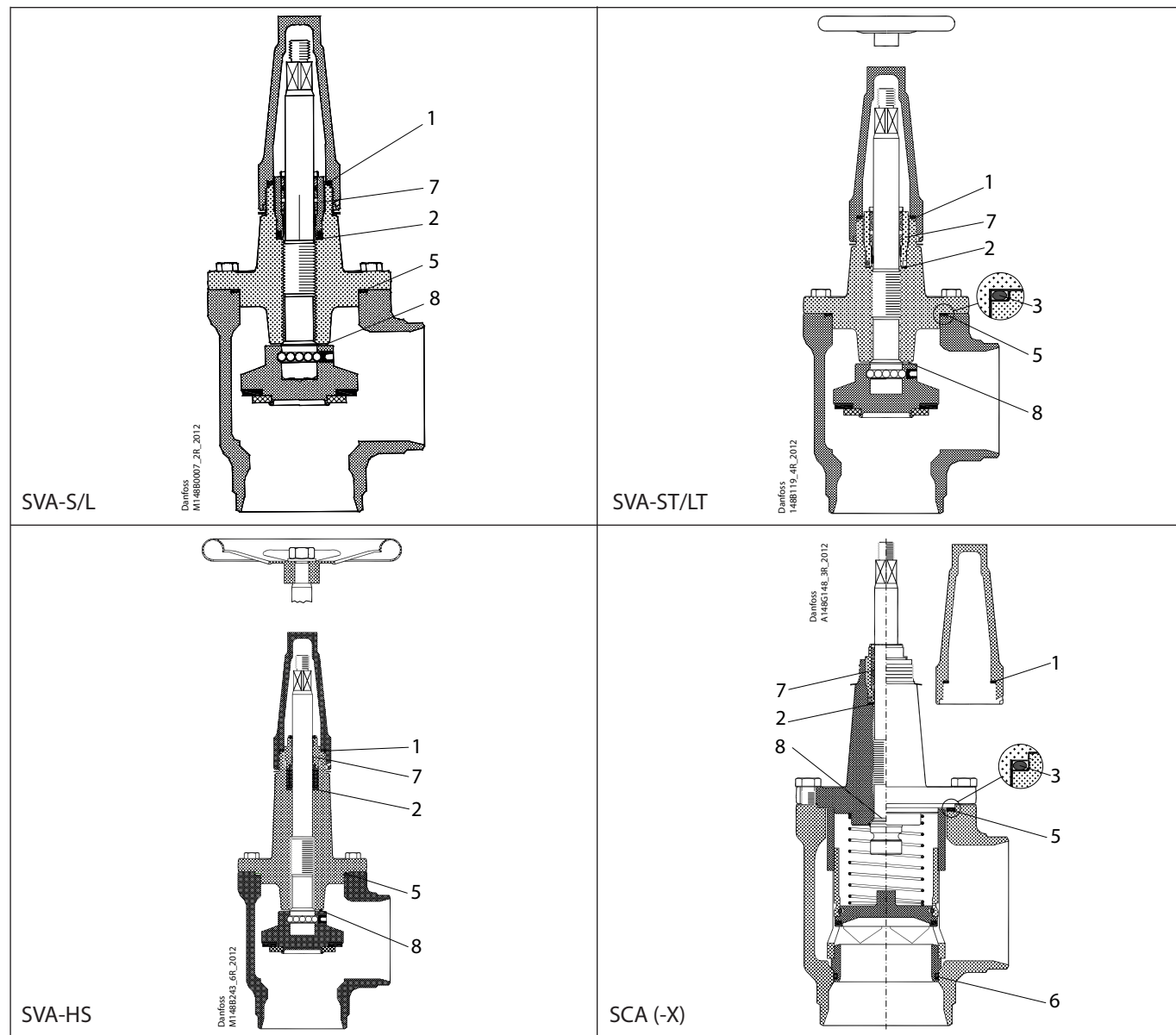


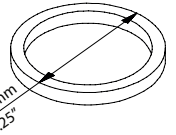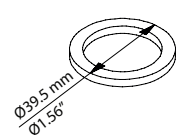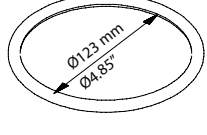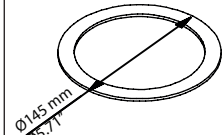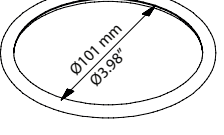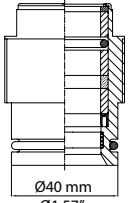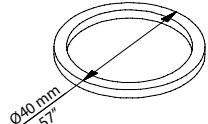1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3  Total no. = 1	5  = Fibre  Total no. = 1	6  Total no. = 1
7  Total no. = 1	8  = PTFE  Total no. = 1			

NOTE: When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L, SVA-HS, SCA-X and SCA the aluminium gasket (pos. 2) is needed.


Repair kit | Code number 148B6068 SVA-S/L, SVA-ST/LT, SVA-HS size 150







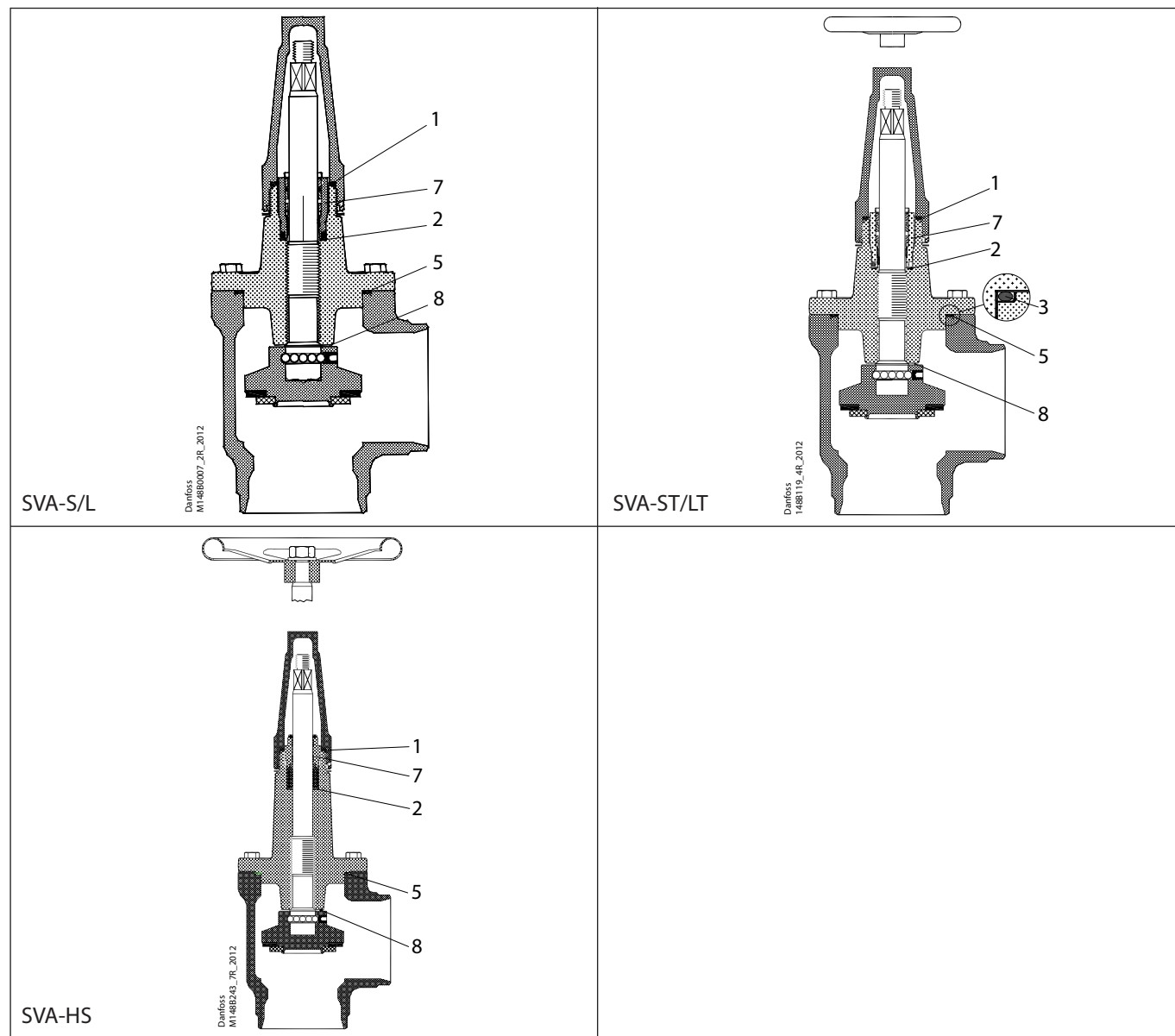


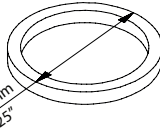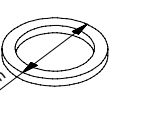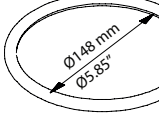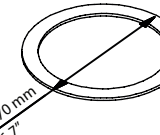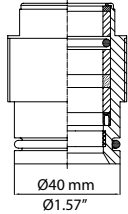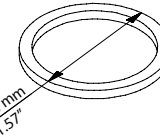1  = Nylon  Ø57 mm Ø2.25" Total no. = 1	2  = Alu.  Ø39.5 mm Ø1.56" Total no. = 1	3  Ø148 mm Ø5.85" Total no. = 1	5  = Fibre  Ø170 mm Ø6.7" Total no. = 1	7  Ø40 mm Ø1.57" Total no. = 1
8  = PTFE  Ø40 mm Ø1.57" Total no. = 1				

NOTE: When replacing the packing gland (pos. 7) in SVA-ST, SVA-S/L or SVA-HS the aluminium gasket (pos. 2) is needed.


Repair kit | Code number 148B6473 Shut-off valves, SVA-S/L, SVA-ST/LT, SVA-HS size 200












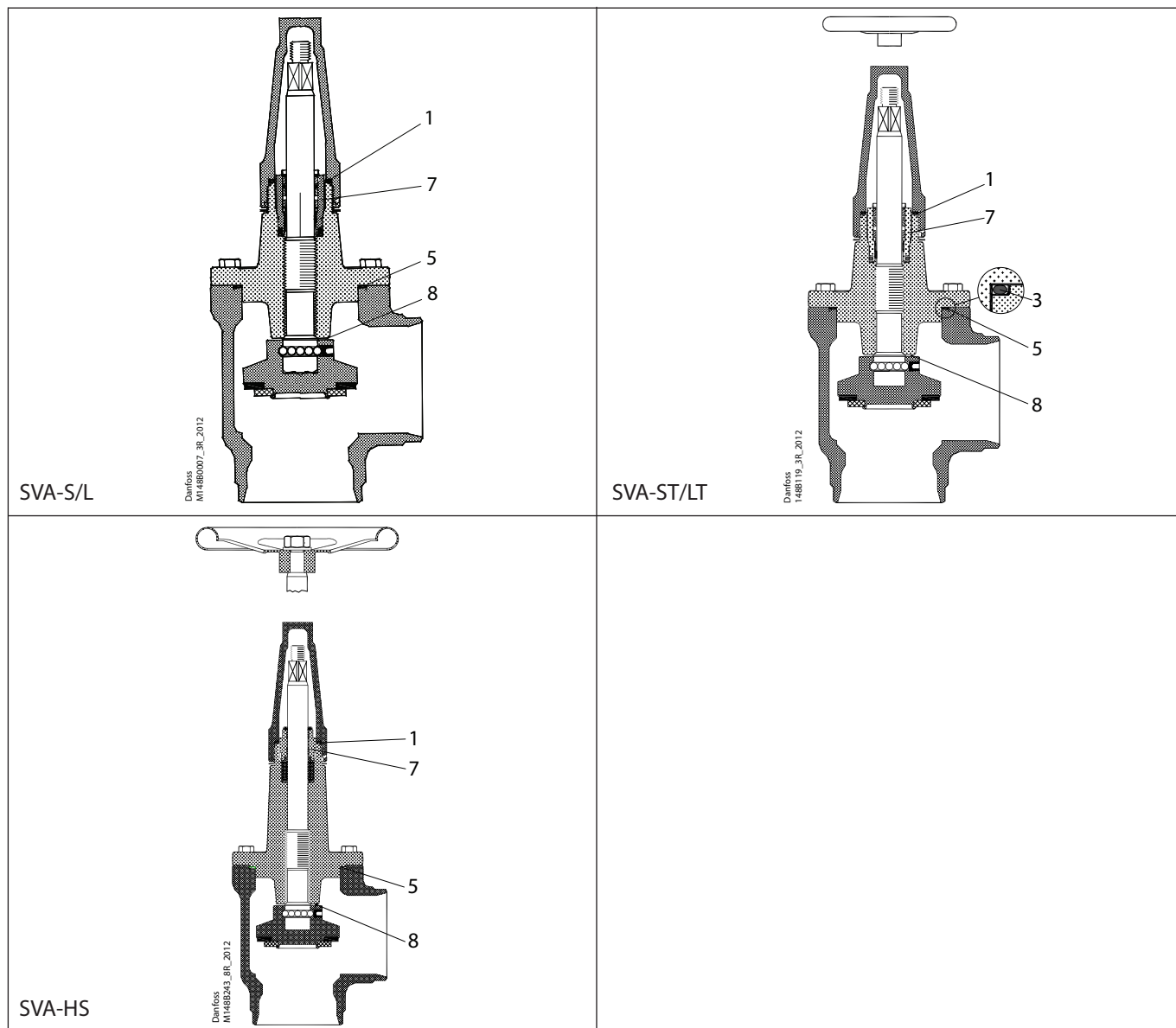


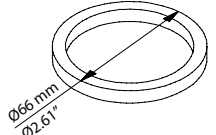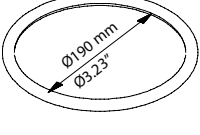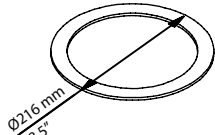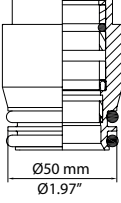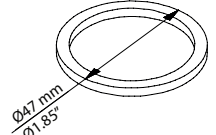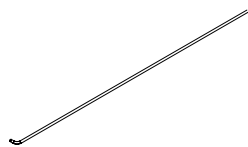 1  = Nylon  Total no. = 1	3  Total no. = 1	5  = Fibre  Total no. = 1	7  Total no. = 1	8  = PTFE  Total no. = 1
9  Total no. = 1	10  Total no. = 1			

Overhaul kit | Code number 148B6150

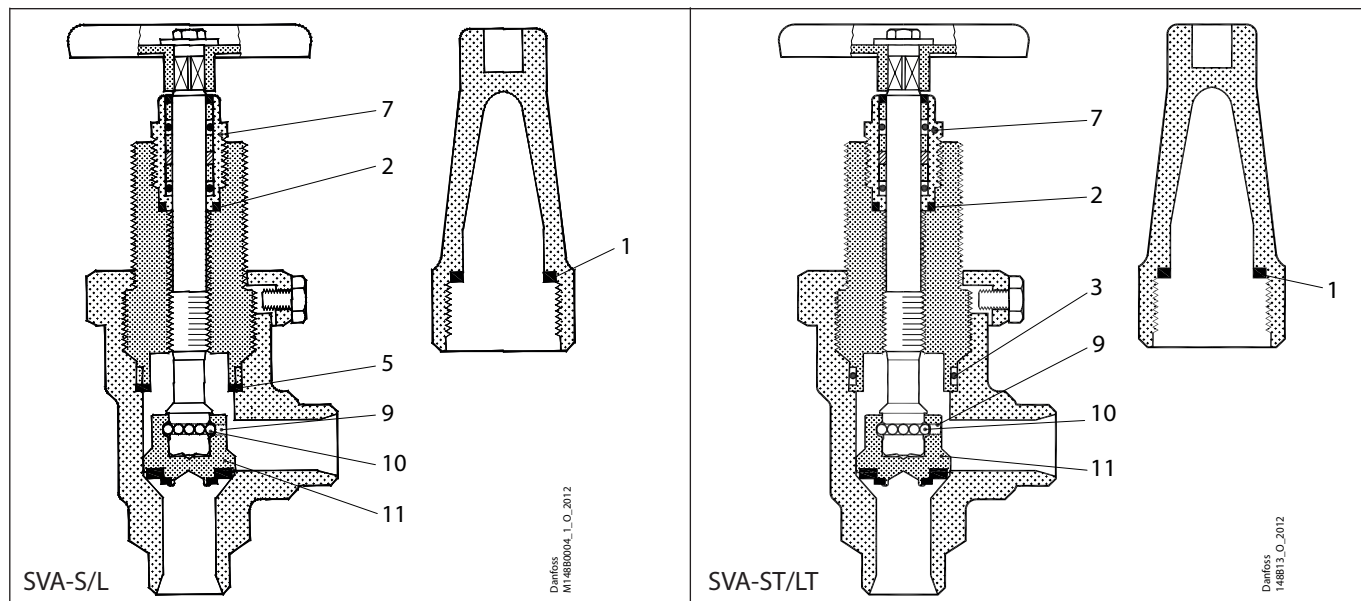         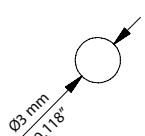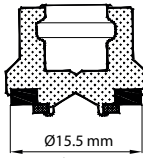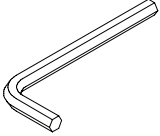SVA-S/L, SVA-ST/LT Sizes 6 to 10




1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3   Total no. = 1	5  = Alu.  Total no. = 1	7  Total no. = 1
9  Total no. = 1	10  Total no. = 6	11  Total no. = 1	12  Total no. = 1	

NOTE:

When replacing the packing gland (pos. 7) in SVA-S/L or SVA-ST/LT the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6151

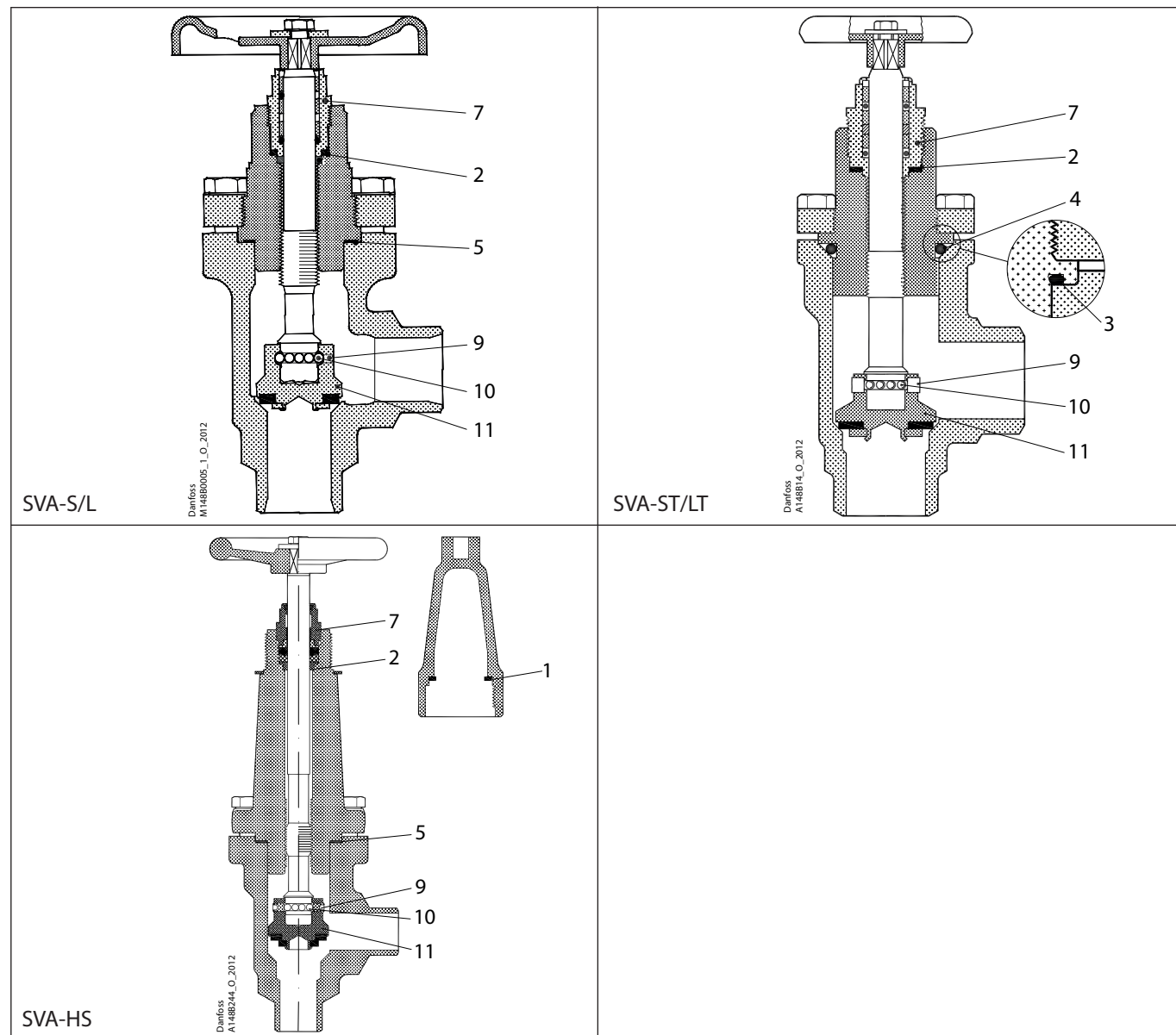SVA-S/L, SVA-ST/LT, SVA-HS sizes 15-20














1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	4 Total no. = 1	5 = Fibre Total no. = 1
7 Total no. = 1	9 Total no. = 1	10 Total no. = 10	11 Total no. = 1	12 Total no. = 1

NOTE: When replacing the packing gland (pos. 7) in SVA-S/L, SVA-ST/LT or SVA-HS the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6152

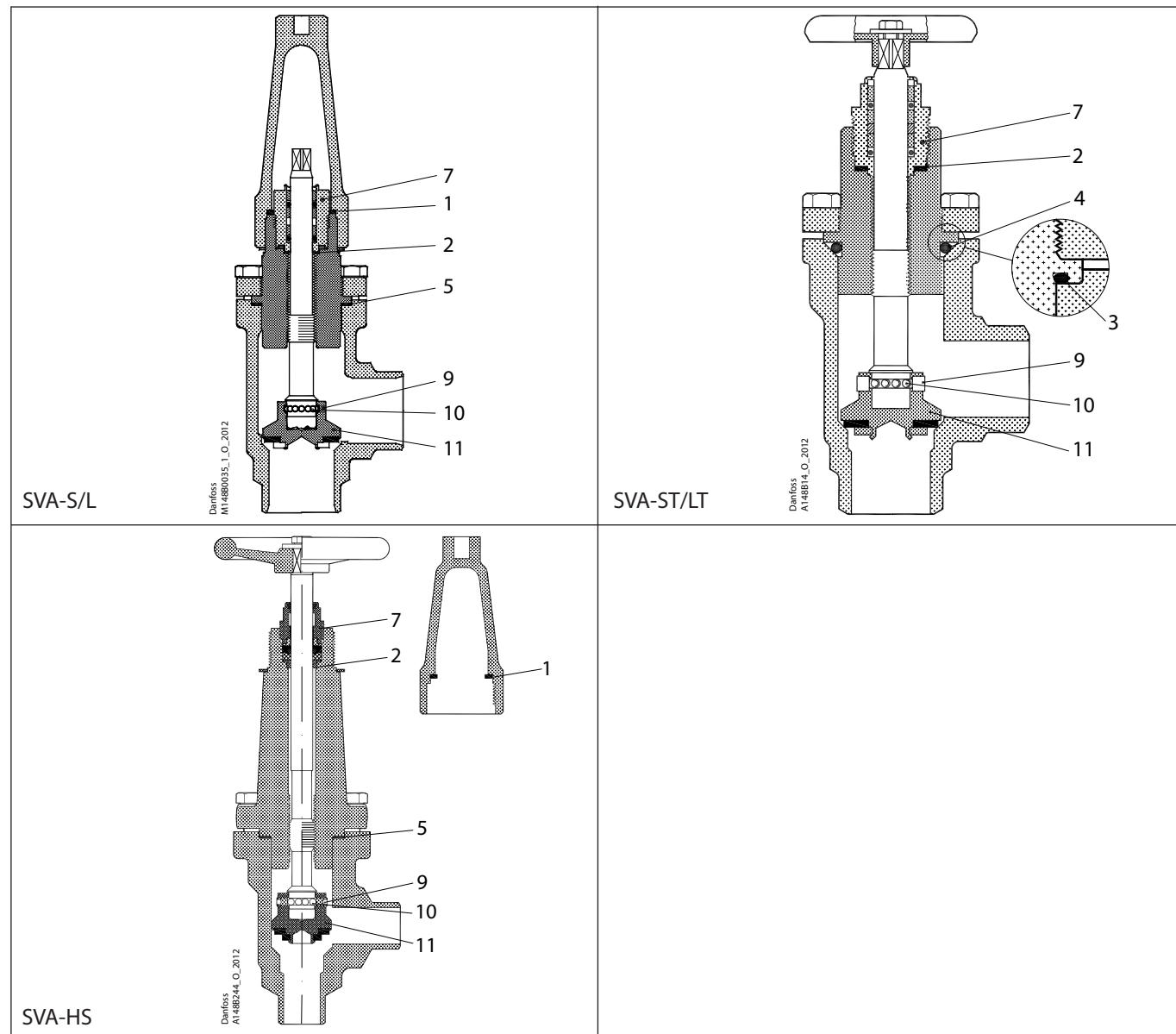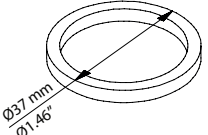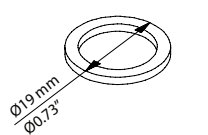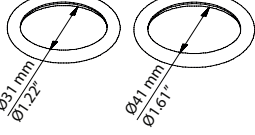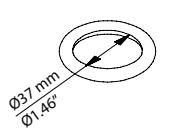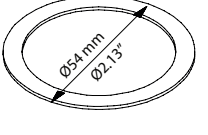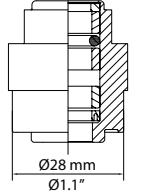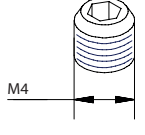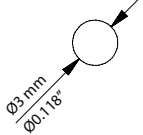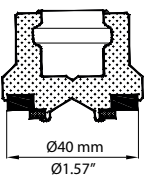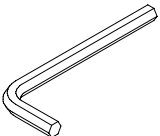
SVA-S/L, SVA-ST/LT, SVA-HS, sizes 25-40



1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3  Total no. = 1	4  Total no. = 1	5  = Fibre  Total no. = 1
7  Total no. = 1	9  Total no. = 1	10  Total no. = 14	11  Total no. = 1	12  Total no. = 1

NOTE: When replacing the packing gland (pos. 7) in SVA-S/L, SVA-ST/LT or SVA-HS the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6153 SVA-S/L, SVA-ST/LT, SVA-HS, size 50

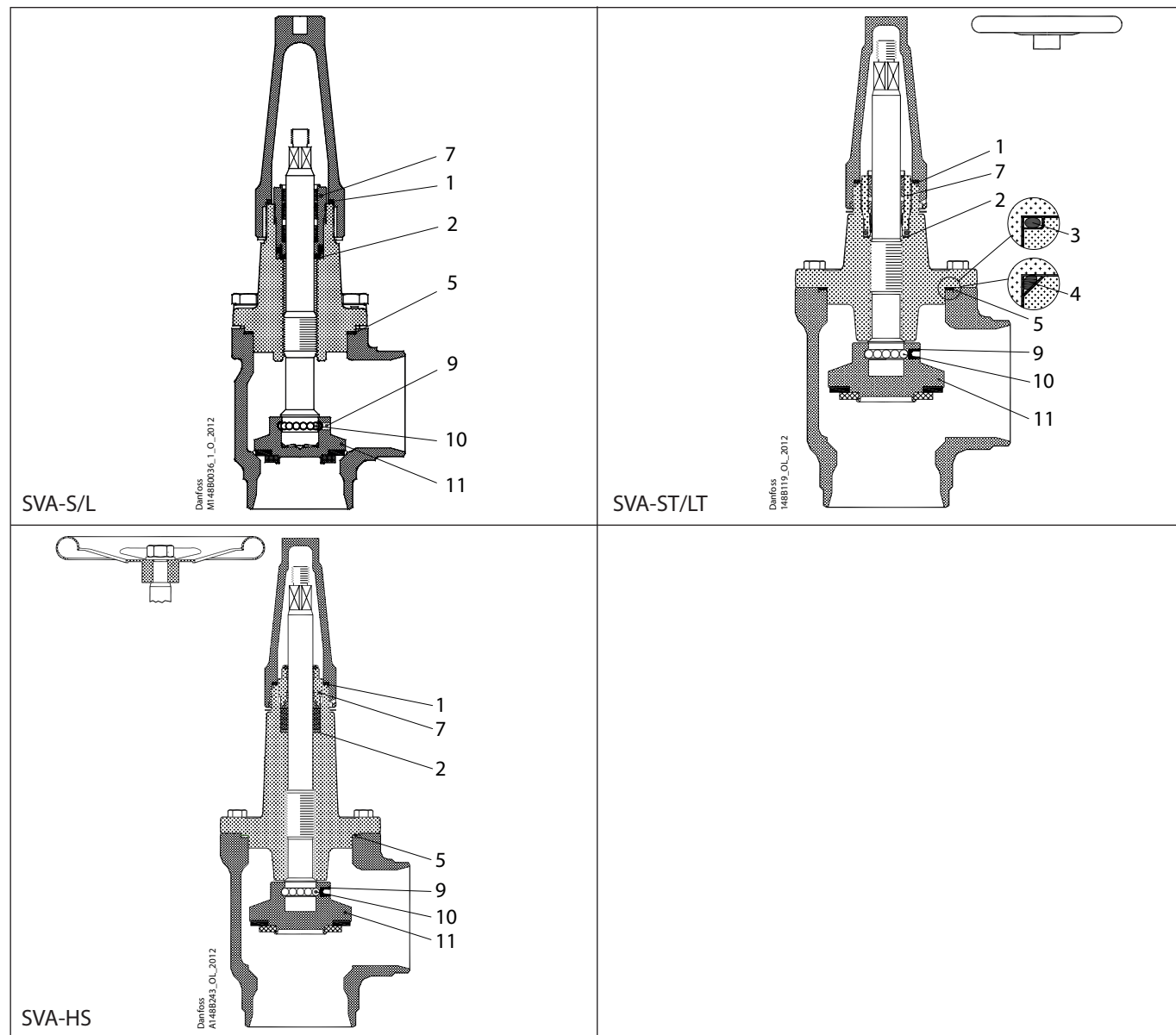


1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	4 Total no. = 1	5 = Fibre Total no. = 1
7 Total no. = 1	9 Total no. = 1	10 Total no. = 14	11 Total no. = 1	12 Total no. = 1

NOTE: When replacing the packing gland (pos. 7) in SVA-S/L, SVA-ST/LT or SVA-HS the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6154

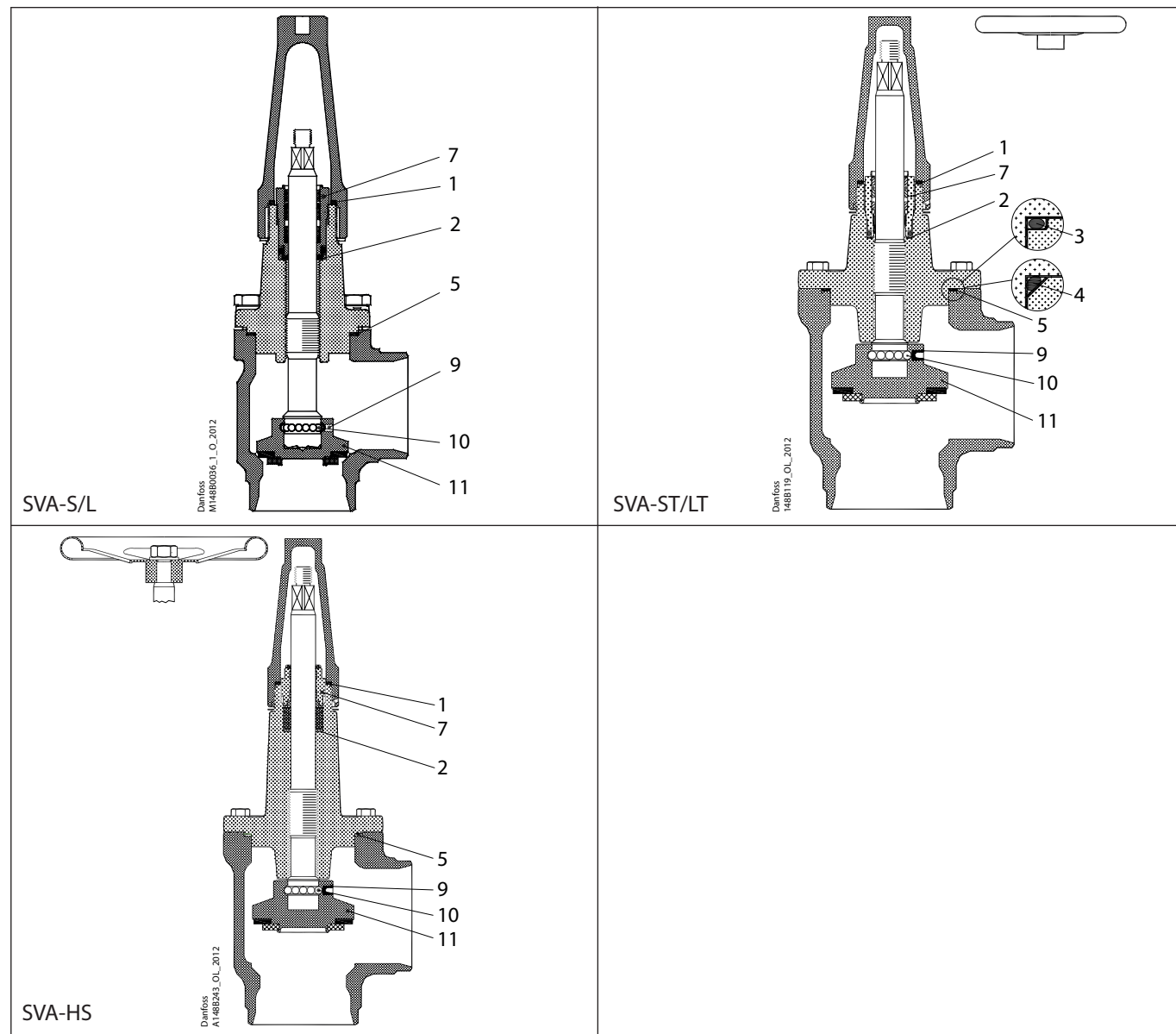SVA-S/L, SVA-ST/LT, SVA-HS, size 65




1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	4 Total no. = 1	5 = Fibre Total no. = 1
7 Total no. = 1	9 Total no. = 1	10 Total no. = 14	11 Total no. = 1	12 Total no. = 1

NOTE: When replacing the packing gland (pos. 7) in SVA-S/L, SVA-ST/LT or SVA-HS the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6155

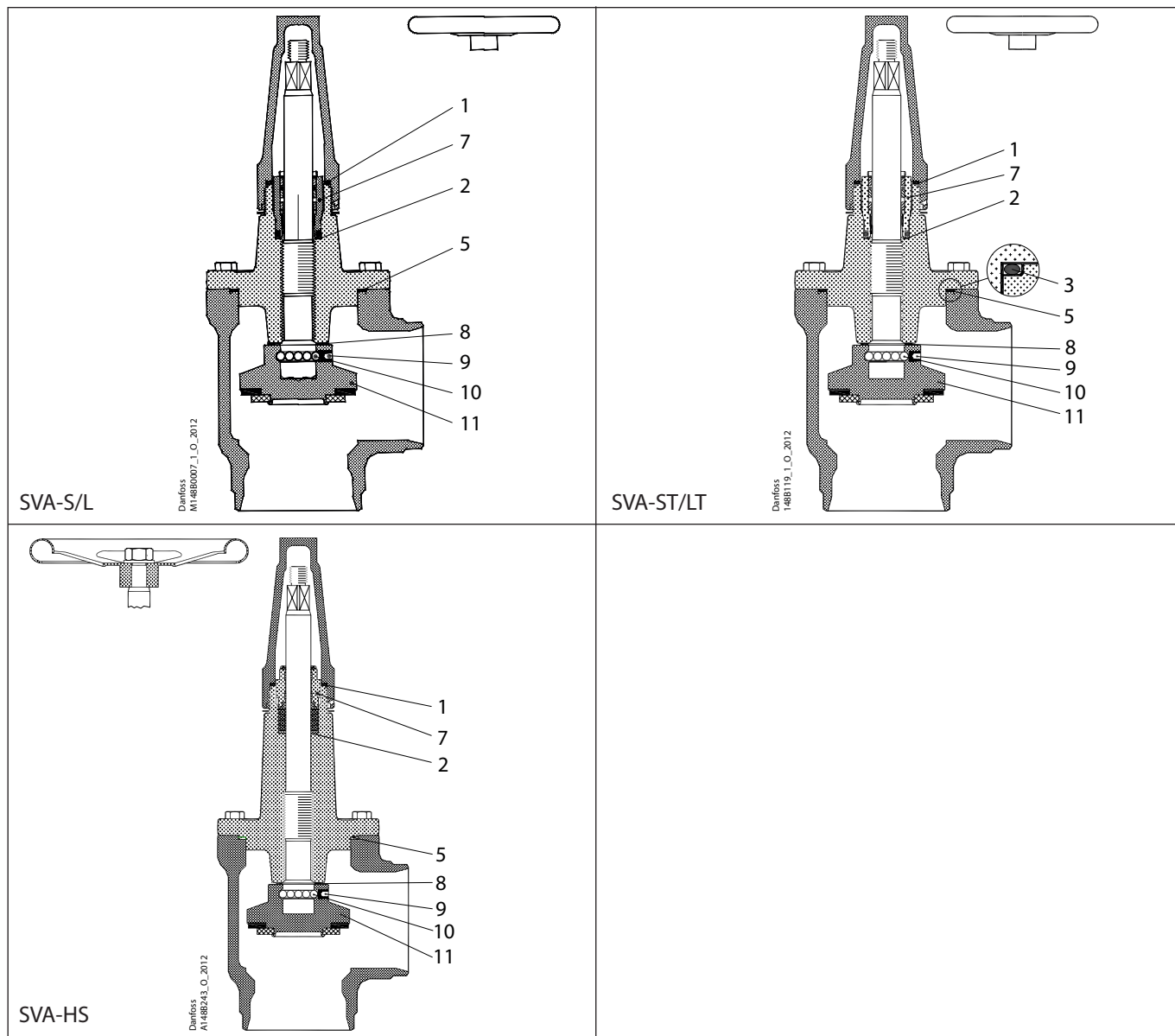
SVA-S/L, SVA-ST/LT, SVA-HS, size 80












1 = Nylon $\varnothing 45 \text{ mm}$ $\varnothing 1.88''$ Total no. = 1	2 = Alu. $\varnothing 31.5 \text{ mm}$ $\varnothing 1.24''$ Total no. = 1	3 $\varnothing 82 \text{ mm}$ $\varnothing 3.23''$ Total no. = 1	5 = Fibre $\varnothing 90 \text{ mm}$ $\varnothing 3.78''$ Total no. = 1	7 $\varnothing 32 \text{ mm}$ $\varnothing 1.26''$ Total no. = 1
8 = PTFE $\varnothing 50 \text{ mm}$ $\varnothing 1.18''$ Total no. = 1	9 M8 Total no. = 1	10 $\varnothing 6 \text{ mm}$ $\varnothing 0.236''$ Total no. = 13	11 $\varnothing 75 \text{ mm}$ $\varnothing 2.95''$ Total no. = 1	12 Total no. = 1

NOTE: When replacing the packing gland (pos. 7) in SVA-S/L, SVA-ST/LT or SVA-HS the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6156 SVA-S/L, SVA-ST/LT, SVA-HS, size 100

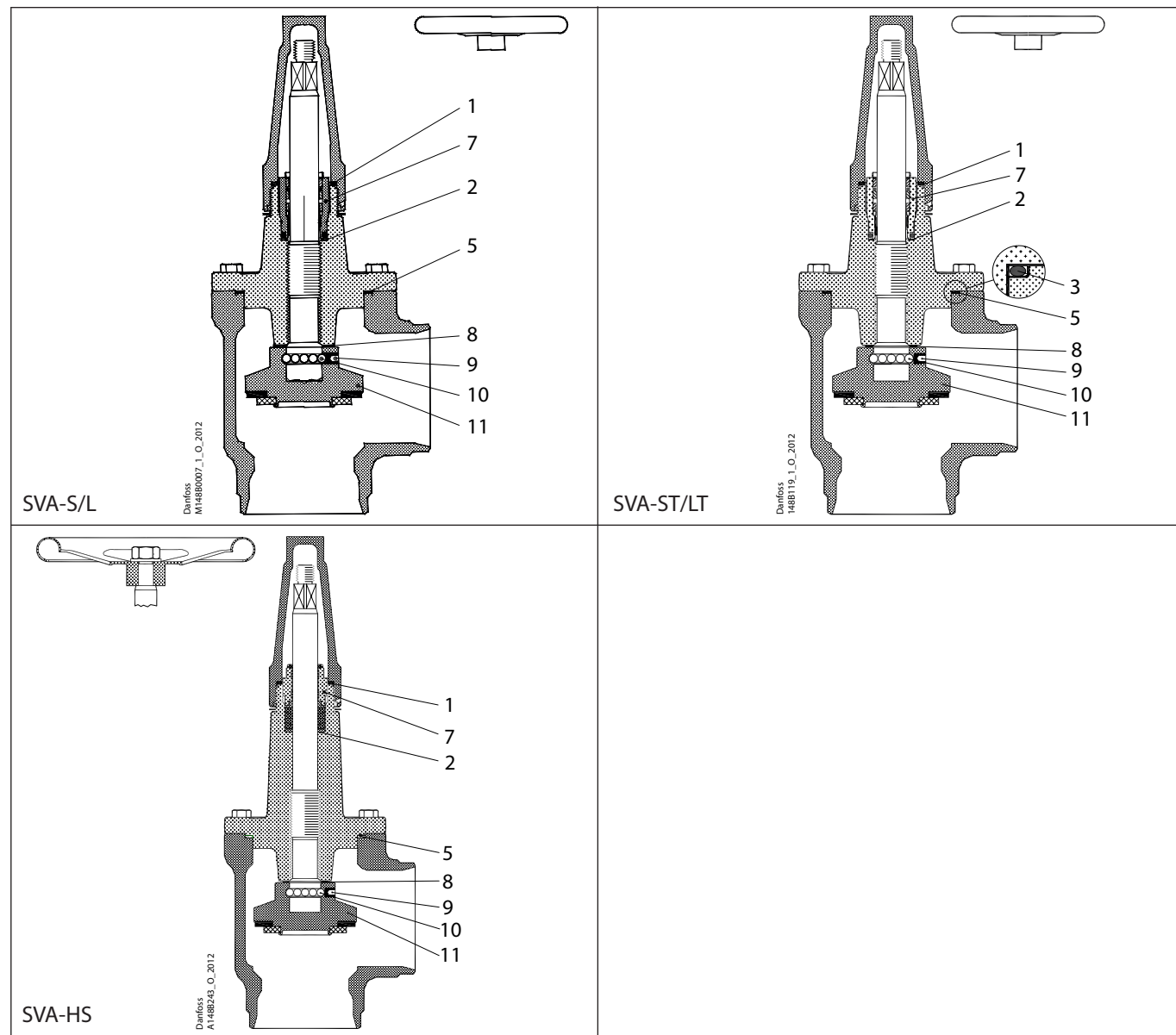


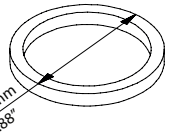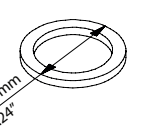
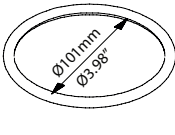
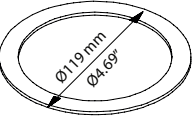
 
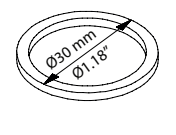
 
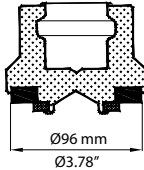
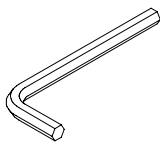
1  = Nylon  Ø45 mm Ø1.88" Total no. = 1	2  = Alu.  Ø31.5 mm Ø1.24" Total no. = 1	3   Ø101 mm Ø3.98" Total no. = 1	5  = Fibre  Ø119 mm Ø4.69" Total no. = 1	7  Ø32 mm Ø1.26" Total no. = 1
8  = PTFE  Ø30 mm Ø1.18" Total no. = 1	9  M8 Total no. = 1	10  Ø6 mm Ø0.236" Total no. = 13	11  Ø96 mm Ø3.78" Total no. = 1	12  Total no. = 1

NOTE: When replacing the packing gland (pos. 7) in SVA-S/L, SVA-ST/LT or SVA-HS the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6157

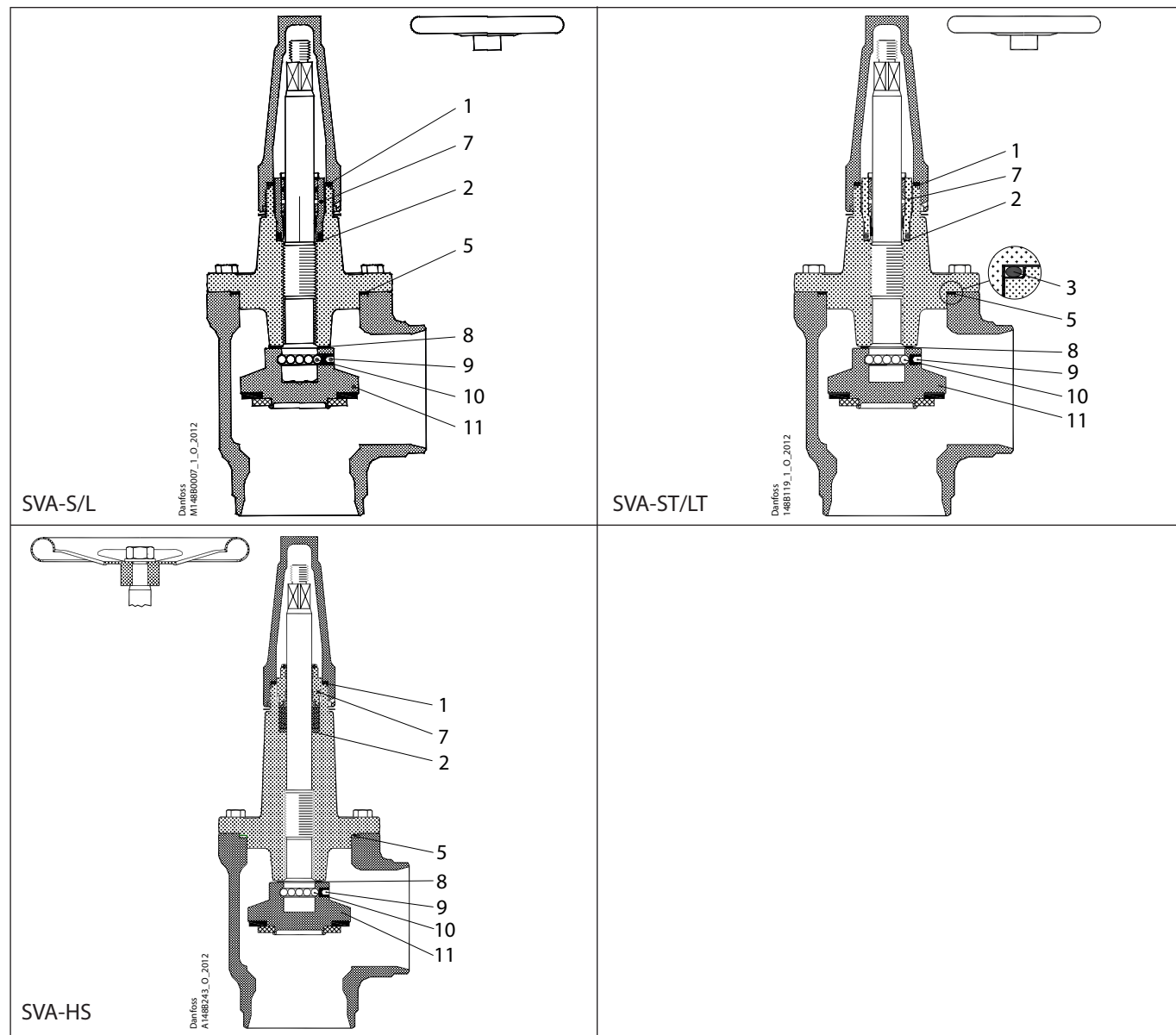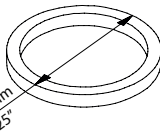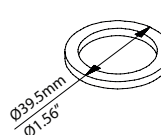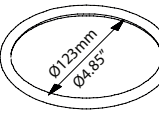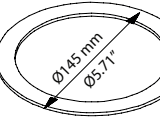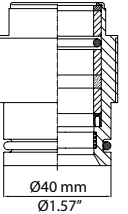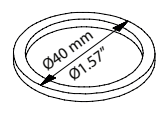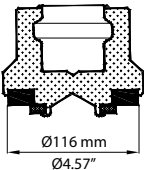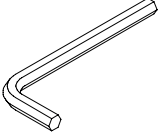
SVA-S/L, SVA-ST/LT, SVA-HS, size 125



1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3   Total no. = 1	5  = Fibre  Total no. = 1	7  Ø40 mm Ø1.57" Total no. = 1
8  = PTFE  Total no. = 1	9  M8 Total no. = 1	10  Ø8 mm Ø0.315" Total no. = 13	11  Ø116 mm Ø4.57" Total no. = 1	12  Total no. = 1

NOTE: When replacing the packing gland (pos. 7) in SVA-S/L, SVA-ST/LT or SVA-HS the aluminium gasket (pos. 2) is needed.


Overhaul kit | Code number 148B6158 SVA-S/L, SVA-ST/LT, SVA-HS, size 150

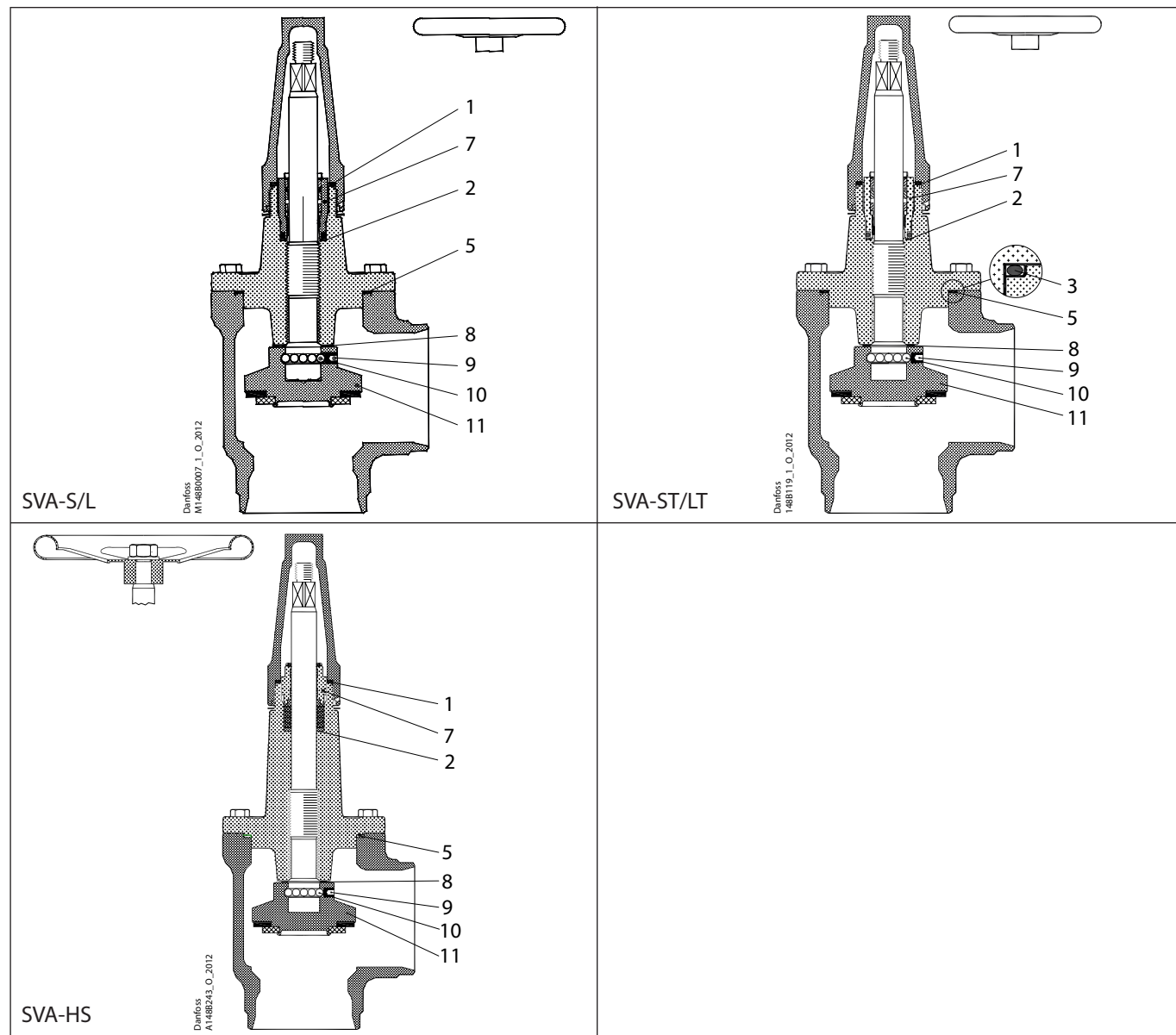

1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	5 = Fibre Total no. = 1	7 Total no. = 1
8 = PTFE Total no. = 1	9 Total no. = 1	10 Total no. = 13	11 Total no. = 1	12 Total no. = 1

NOTE: When replacing the packing gland (pos. 7) in SVA-S/L, SVA-ST/LT or SVA-HS the aluminium gasket (pos. 2) is needed.


Overhaul kit | Code number 148B6472 Shut-off valves, SVA-S/L, SVA-ST/LT, SVA-HS, size 200









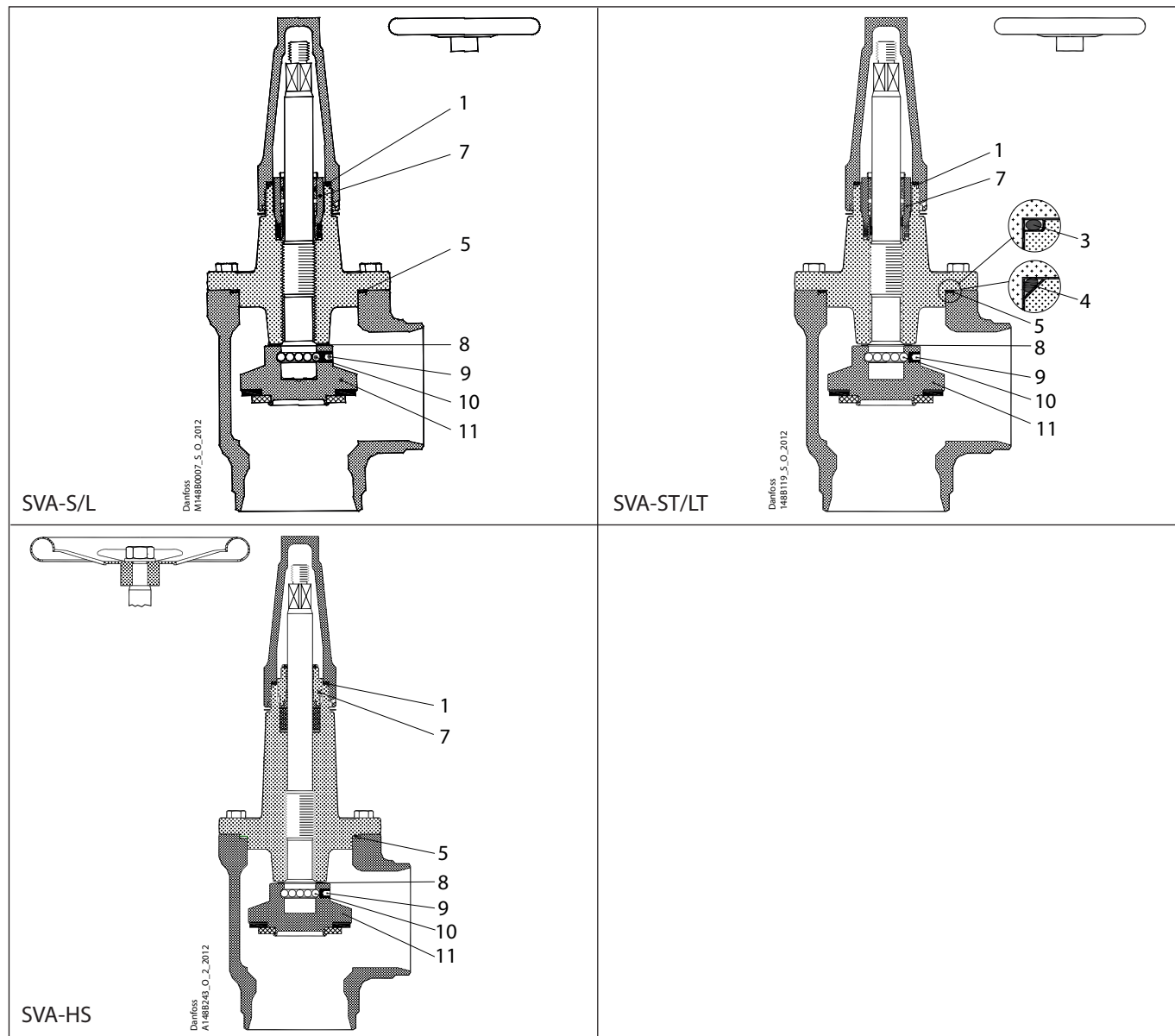


1 Total no. = 1	3 Total no. = 1	5 Total no. = 1	7 Total no. = 1	8 Total no. = 1
9 Total no. = 1	10 Total no. = 13	11 Total no. = 1	12 Total no. = 1	13 Total no. = 1

Overhaul kit | Code number 148B6160

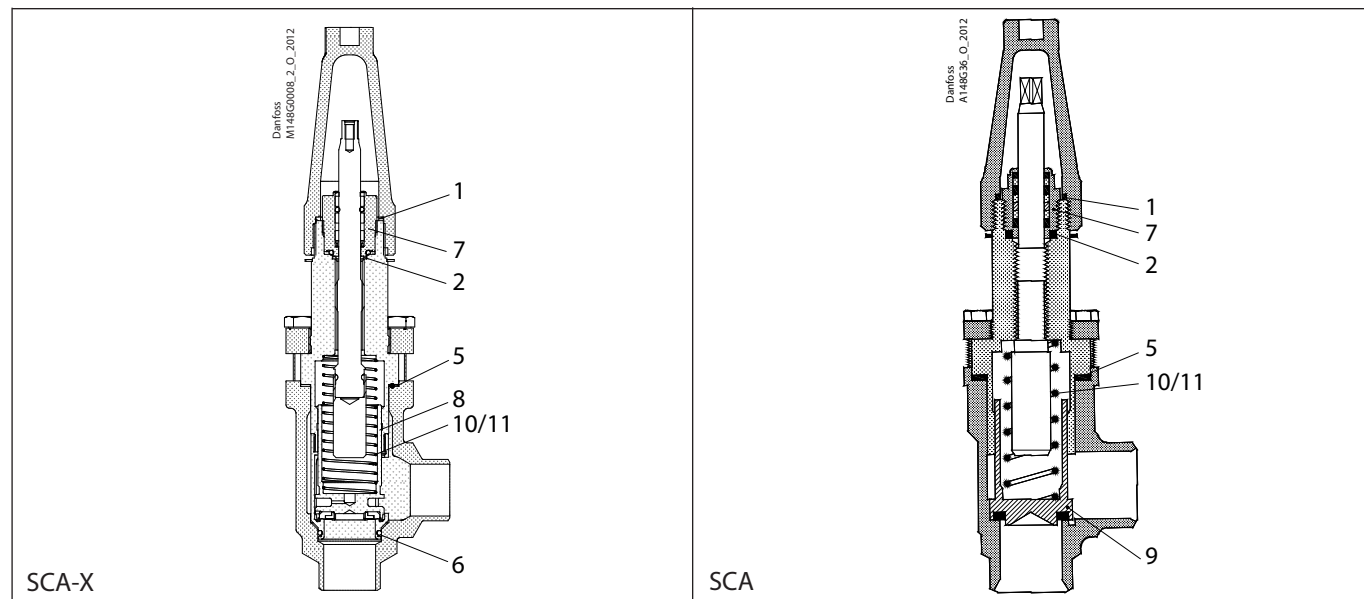        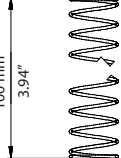SCA / SCA-X sizes 15 - 20












1  = Nylon  Ø28 mm Ø1.1" Total no. = 1	2  = Alu.  Ø18 mm Ø0.69" Total no. = 1	5  = Fibre  Ø39 mm Ø1.55" Total no. = 1	6   Ø17 mm Ø0.67" Total no. = 1	7  Ø18 mm Ø0.71" Total no. = 1
8  Ø28 mm Ø1.1" Total no. = 1	9  Ø28 mm Ø1.1" Total no. = 1	10  77 mm 3.03" Total no. = 1	11  100 mm 3.94" Total no. = 1	

NOTE:

When replacing the packing gland (pos. 7) in SCA-X or SCA the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6161 SCA / SCA-X sizes 25-40

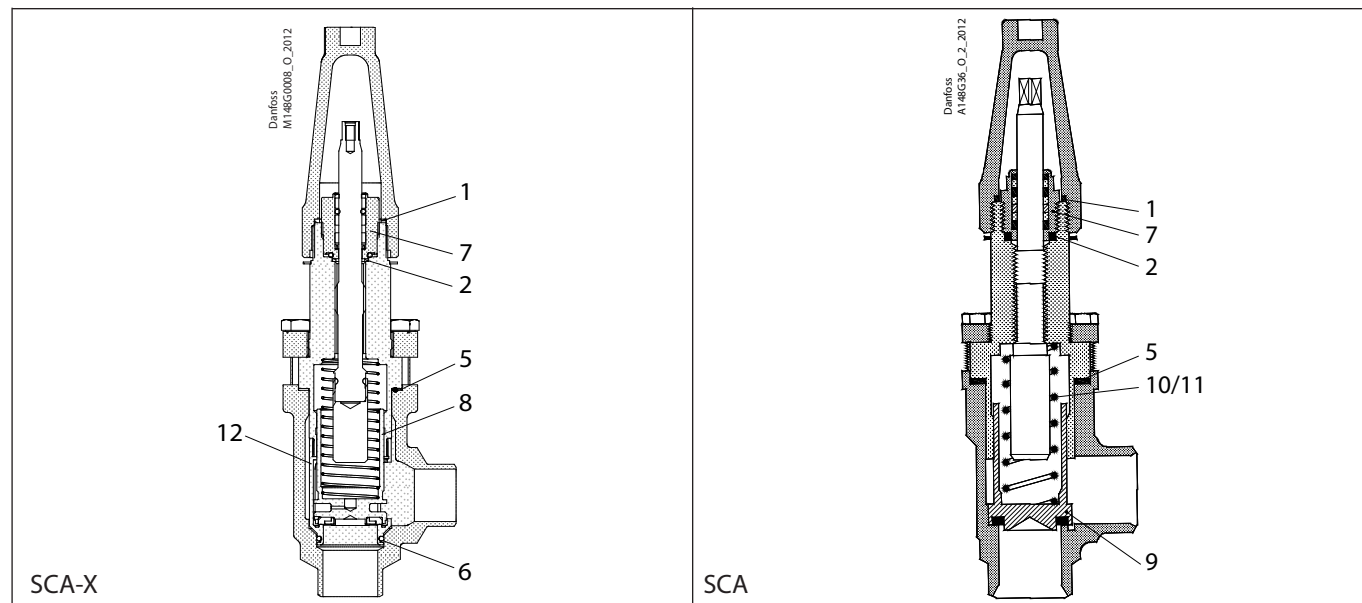

   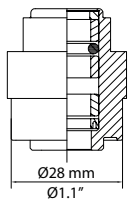    
1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	5  = Fibre  Total no. = 1	6   Total no. = 1	7  Ø28 mm / Ø1.1" Total no. = 1
8  Ø41 mm / Ø1.6" Total no. = 1	9  Ø38 mm / Ø1.5" Total no. = 1	10  147 mm / 5.79" Total no. = 1	11  183 mm / 7.2" Total no. = 1	12  120 mm / 4.72" Total no. = 1

NOTE:

When replacing the packing gland (pos. 7) in SCA-X or SCA the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6162

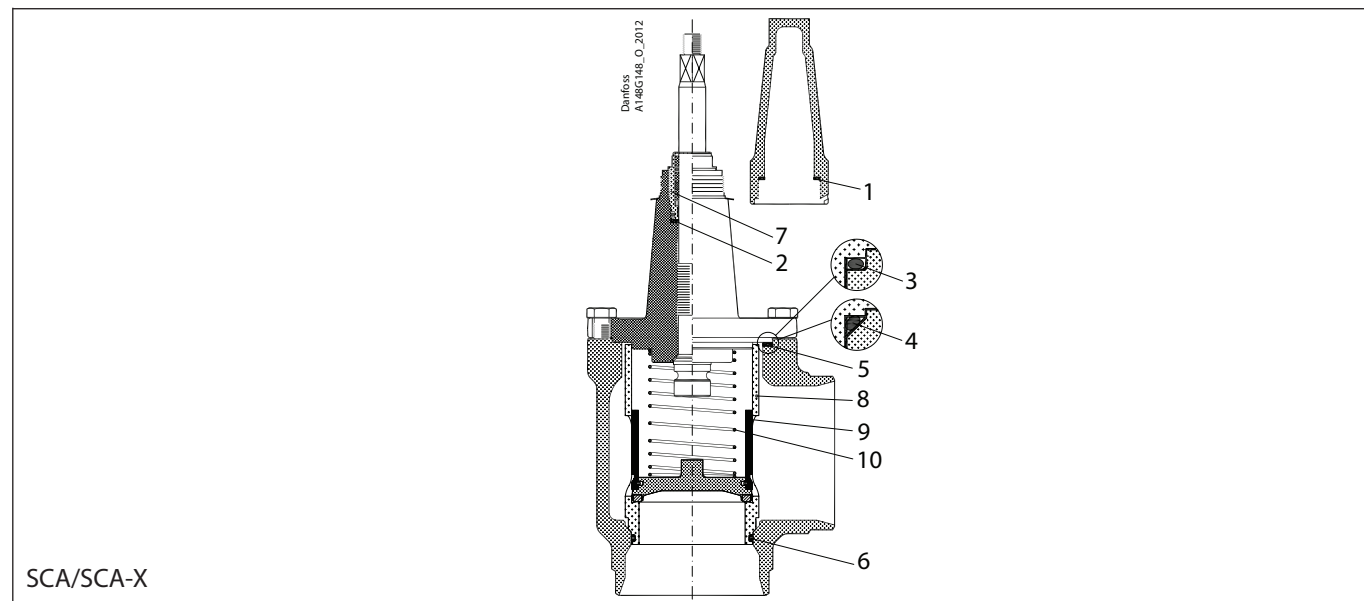SCA / SCA-X sizes 50




1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	4 Total no. = 1	5 = Fibre Total no. = 1
6 Total no. = 1	7 Total no. = 1	8 Total no. = 1	9 Total no. = 1	10 Total no. = 1











NOTE:

When replacing the packing gland (pos. 7) in SCA-X or SCA the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6163

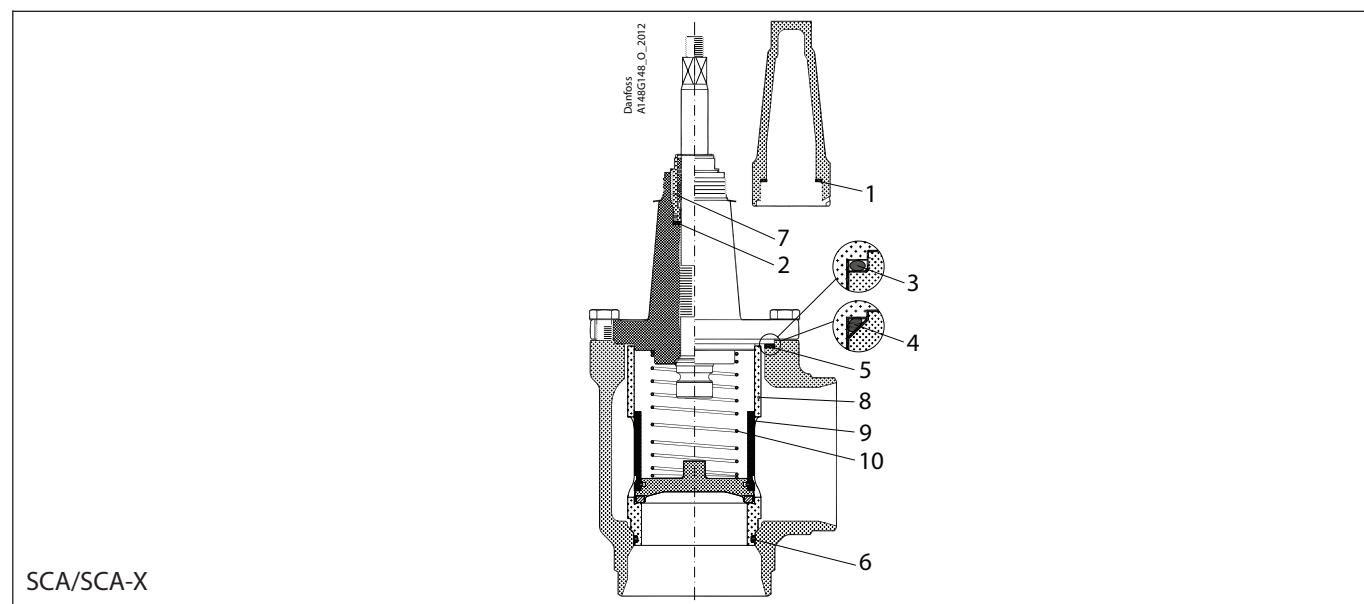      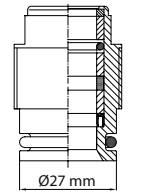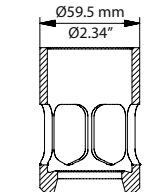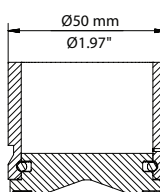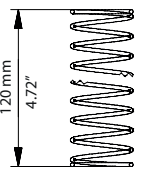SCA / SCA-X sizes 65




1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	3  Total no. = 1	4  Total no. = 1	5  = Fibre  Total no. = 1
6  Total no. = 1	7  Total no. = 1	8  Total no. = 1	9  Total no. = 1	10  Total no. = 1

NOTE:

When replacing the packing gland (pos. 7) in SCA-X or SCA the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6164

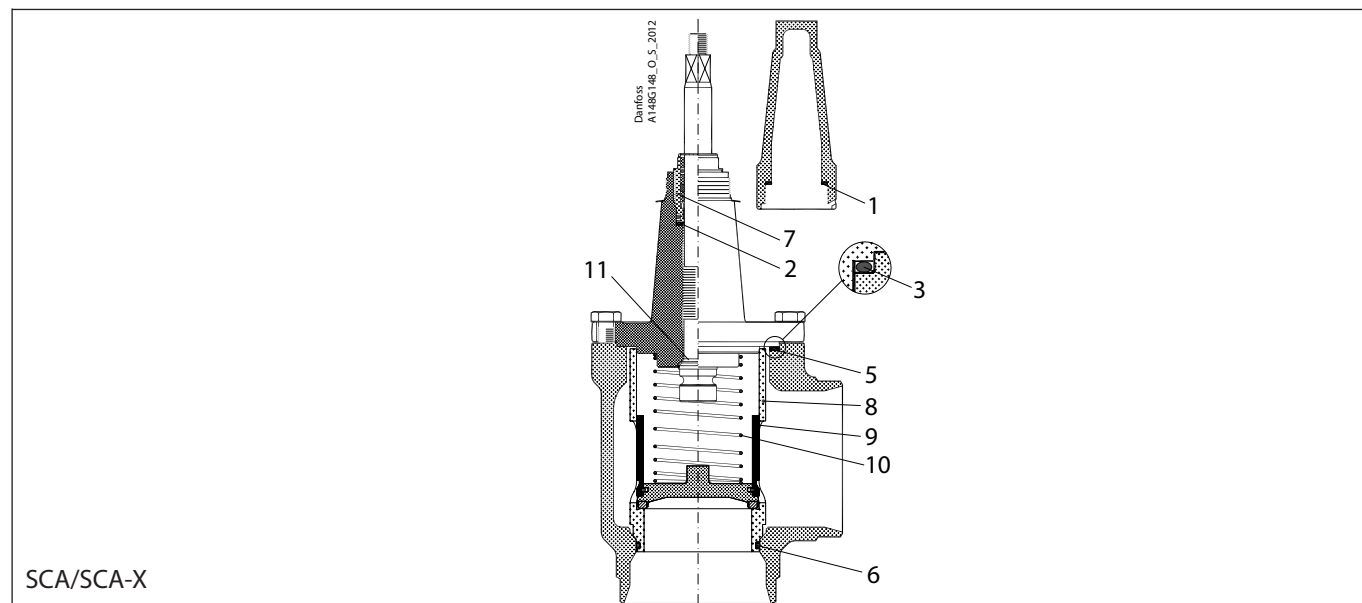SCA / SCA-X sizes 80




1 = Nylon Ø45 mm Ø1.88" Total no. = 1	2 = Alu. Ø31.5 mm Ø1.24" Total no. = 1	3 Ø62 mm Ø2.44" Total no. = 1	5 = Fibre Ø96 mm Ø3.78" Total no. = 1	6 Ø63 mm Ø2.48" Total no. = 1
7 Ø32 mm Ø1.26" Total no. = 1	8 Ø79.5 mm Ø3.13" Total no. = 1	9 Ø70 mm Ø2.76" Total no. = 1	10 160 mm 6.3" Total no. = 1	11 = PTFE Ø50 mm Ø1.97" Total no. = 1

NOTE:

When replacing the packing gland (pos. 7) in SCA-X or SCA the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6165

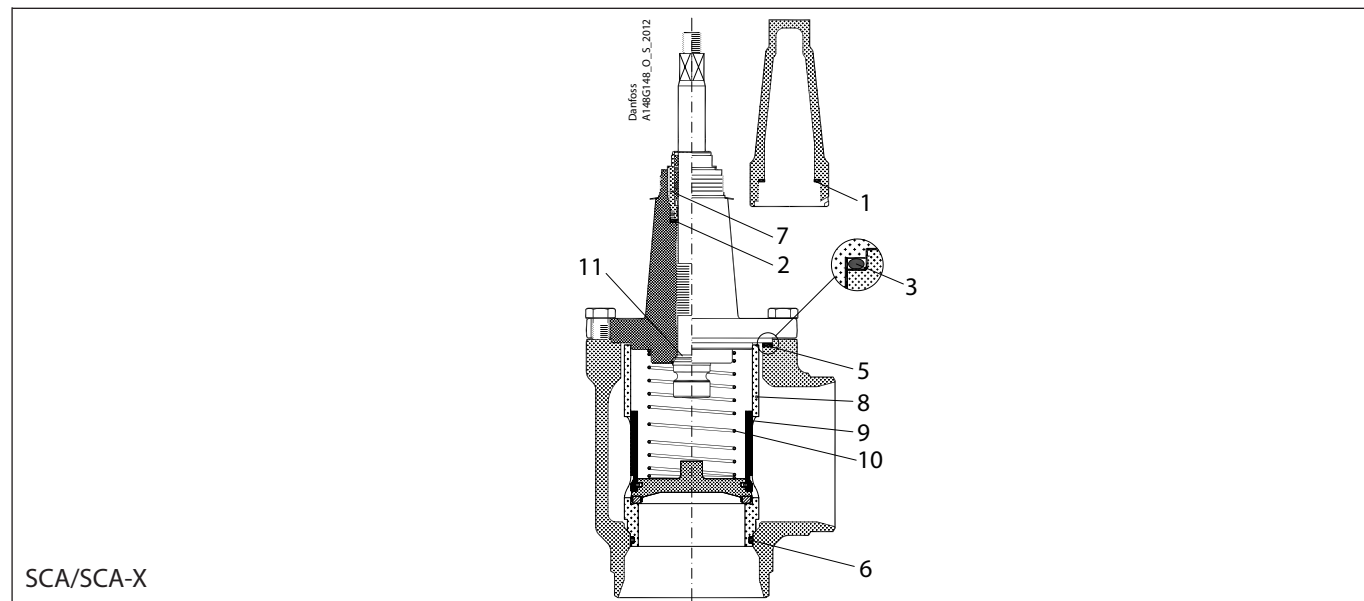SCA / SCA-X sizes 100




1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	5 = Fibre Total no. = 1	6 Total no. = 1
7 Total no. = 1	8 Total no. = 1	9 Total no. = 1	10 Total no. = 1	11 = PTFE Total no. = 1

NOTE:

When replacing the packing gland (pos. 7) in SCA-X or SCA the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6166

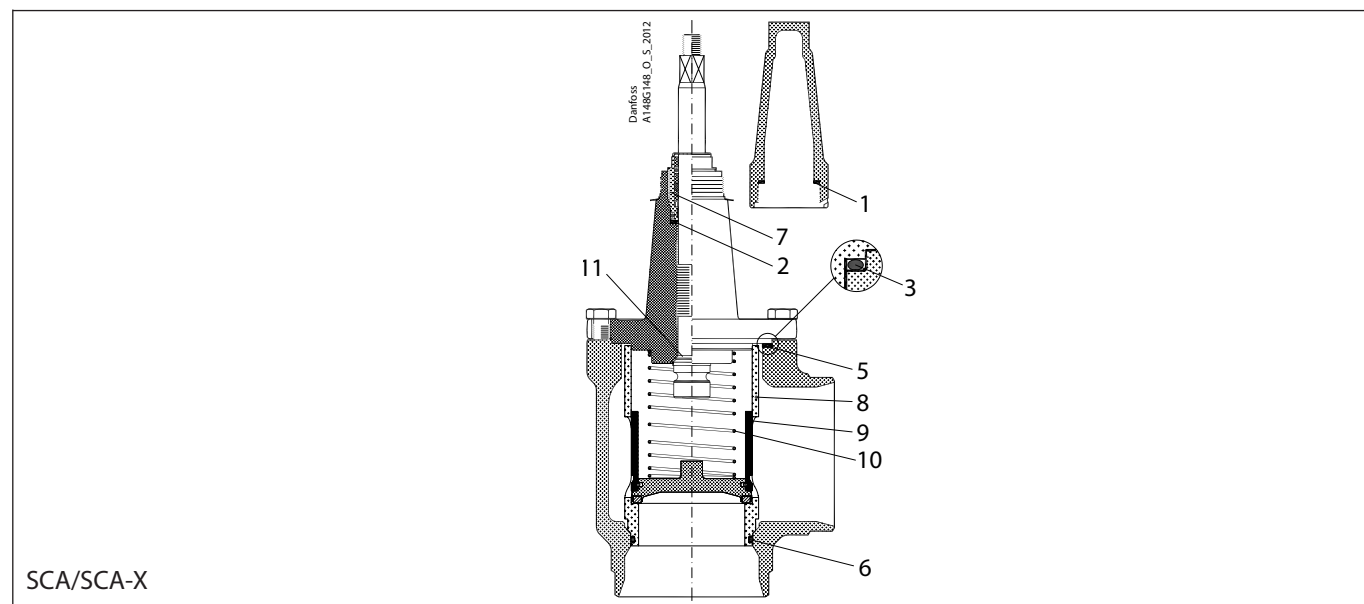SCA / SCA-X sizes 125




1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	3 Total no. = 1	5 = Fibre Total no. = 1	6 Total no. = 1
7 Total no. = 1	8 Total no. = 1	9 Total no. = 1	10 Total no. = 1	11 = PTFE Total no. = 1

NOTE:

When replacing the packing gland (pos. 7) in SCA-X or SCA the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6167

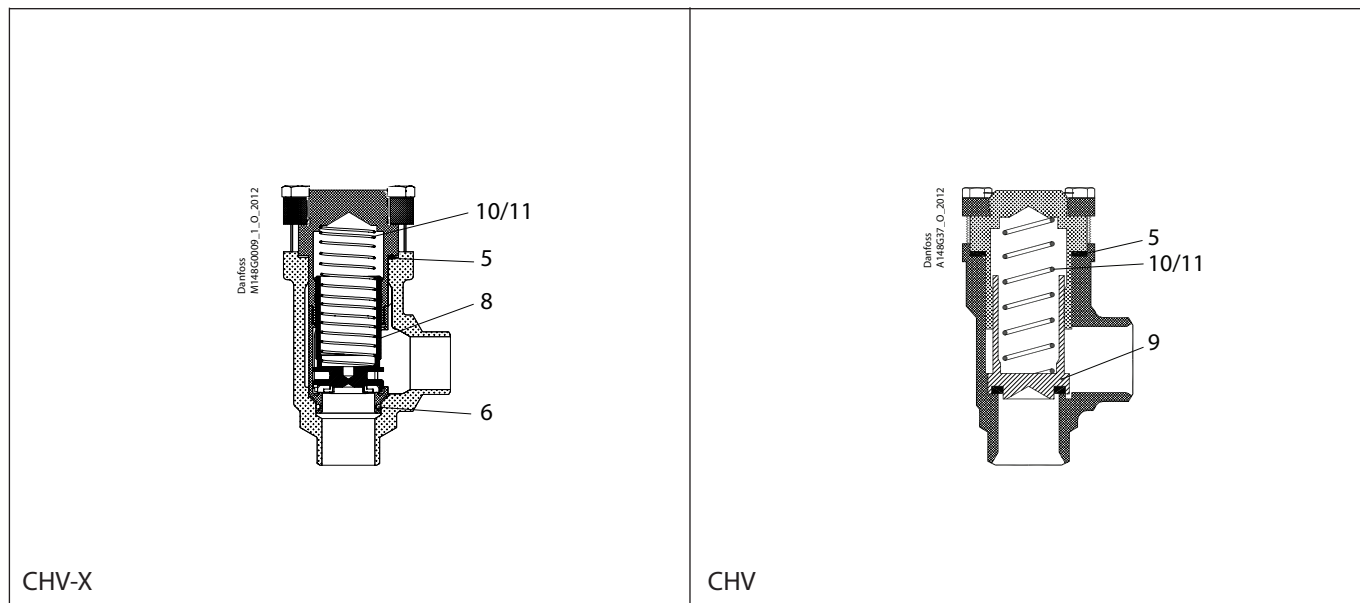
CHV / CHV-X sizes 15 - 20










5 Total no. = 1	6 Total no. = 1	8 Total no. = 1	9 Total no. = 1	10 Total no. = 1
11 Total no. = 1				


Overhaul kit | Code number 148B6168

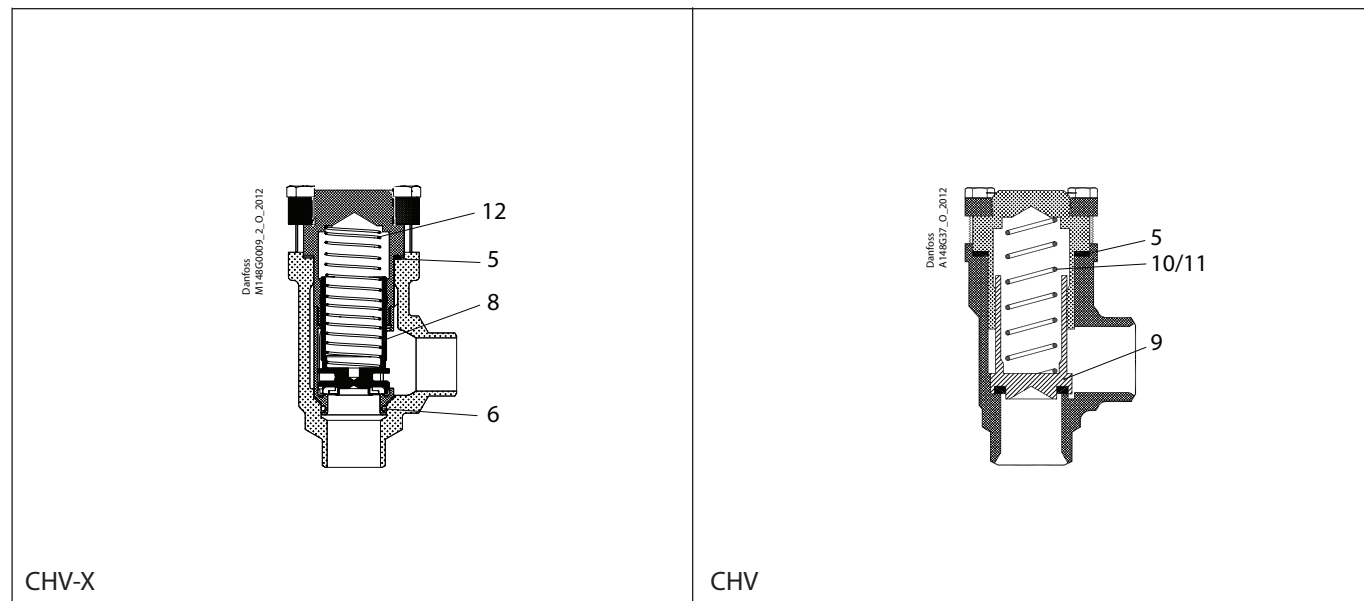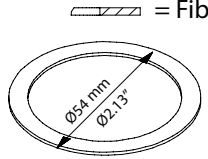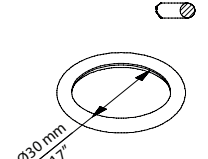 
 
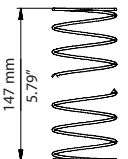
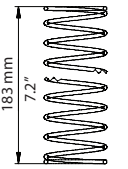
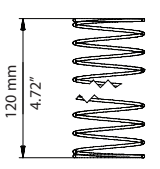
CHV / CHV-X sizes 25 - 40



5  Total no. = 1	6  Total no. = 1	8  Total no. = 1	9  Total no. = 1	10  Total no. = 1
11  Total no. = 1	12  Total no. = 1			


Overhaul kit | Code number 148B6169
CHV / CHV-X sizes 50

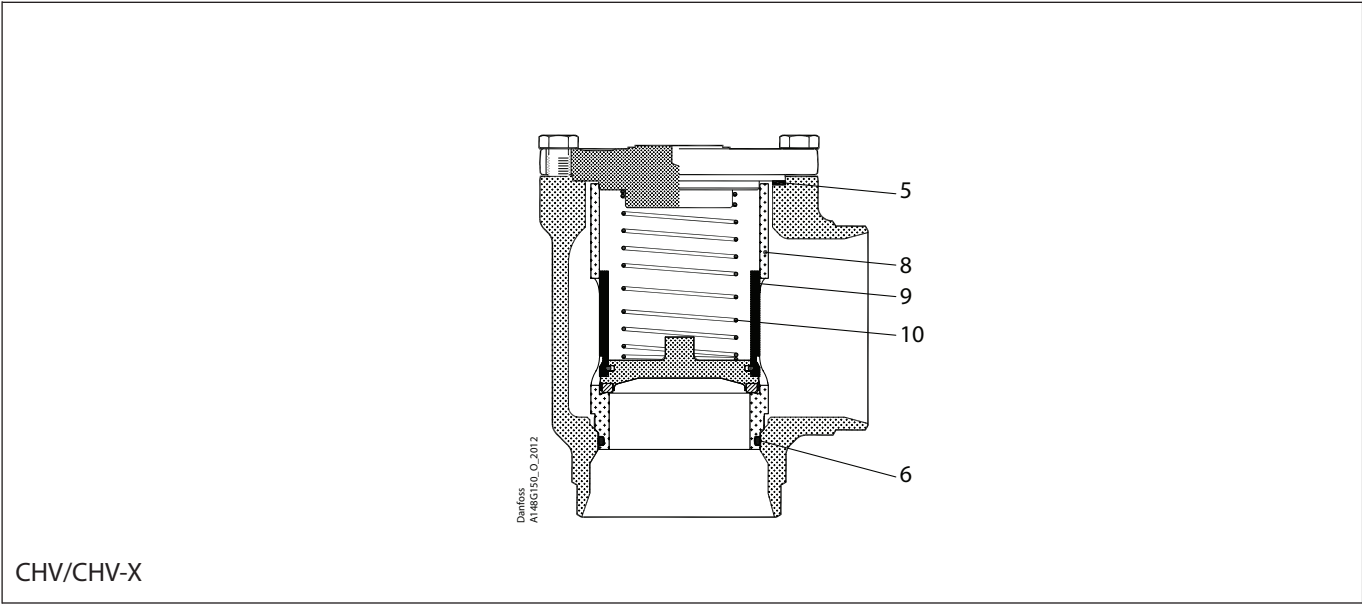

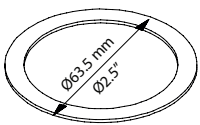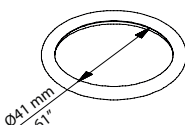 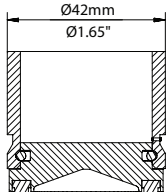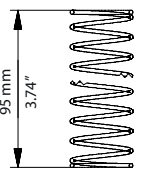5  = Fibre Total no. = 1	6  Total no. = 1	8  Total no. = 1	9  Total no. = 1	10  Total no. = 1
---	---	--	---	---

Overhaul kit | Code number 148B6170

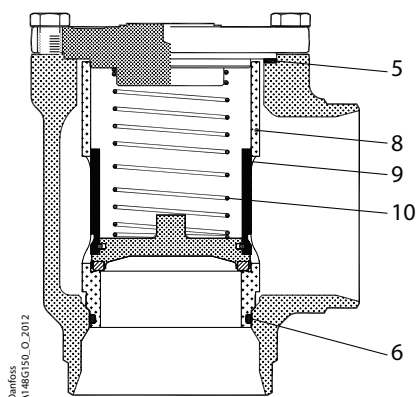CHV / CHV-X sizes 65




CHV/CHV-X

5 Total no. = 1	6 Total no. = 1	8 Total no. = 1	9 Total no. = 1	10 Total no. = 1
--------------------------------------	--------------------------------------	--------------------------------------	--------------------------------------	---------------------------------------

Overhaul kit | Code number 148B6171

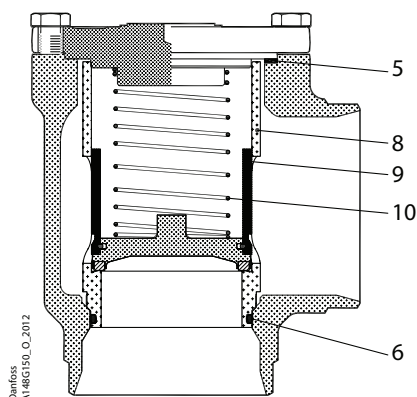CHV / CHV-X sizes 80




CHV/CHV-X

5 = Fibre Total no. = 1	6 Total no. = 1	8 Total no. = 1	9 Total no. = 1	10 Total no. = 1
---	--------------------------------------	--------------------------------------	--------------------------------------	---------------------------------------

Overhaul kit | Code number 148B6172

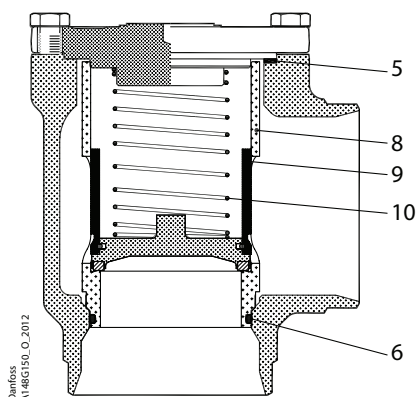CHV / CHV-X sizes 100




CHV/CHV-X

5 = Fibre Ø119 mm Ø69 mm Total no. = 1	6 Ø82 mm Ø73 mm Total no. = 1	8 Ø99.5 mm Ø3.92" Total no. = 1	9 Ø90 mm Ø3.54" Total no. = 1	10 250 mm 9.84" Total no. = 1
---	---	---	---	---

Overhaul kit | Code number 148B6173

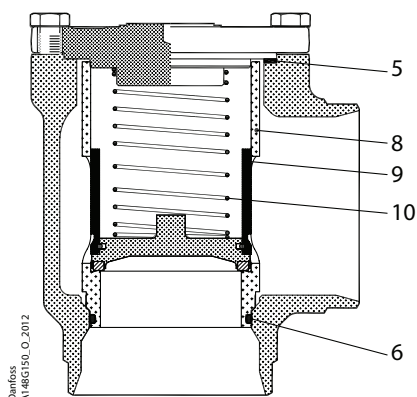CHV / CHV-X sizes 125




CHV/CHV-X

5 = Fibre Total no. = 1	6 Total no. = 1	8 Total no. = 1	9 Total no. = 1	10 Total no. = 1
---	--------------------------------------	--------------------------------------	--------------------------------------	---------------------------------------

Overhaul kit | Code number 148B6174

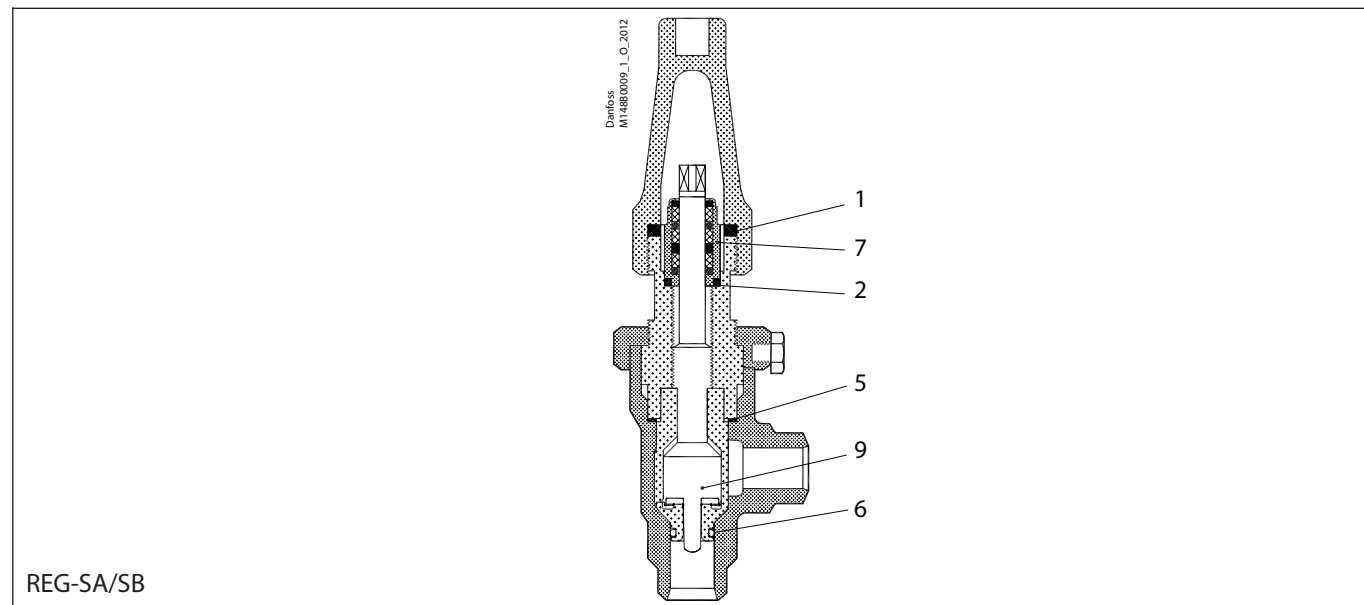REG-SA/SB size 10




1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	5 = Alu. Total no. = 1	9 Total no. = 1	9 Total no. = 1
6 Total no. = 1	7 Total no. = 1			

NOTE:

When replacing the packing gland (pos. 7) in REG-SA/B or REG the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6175

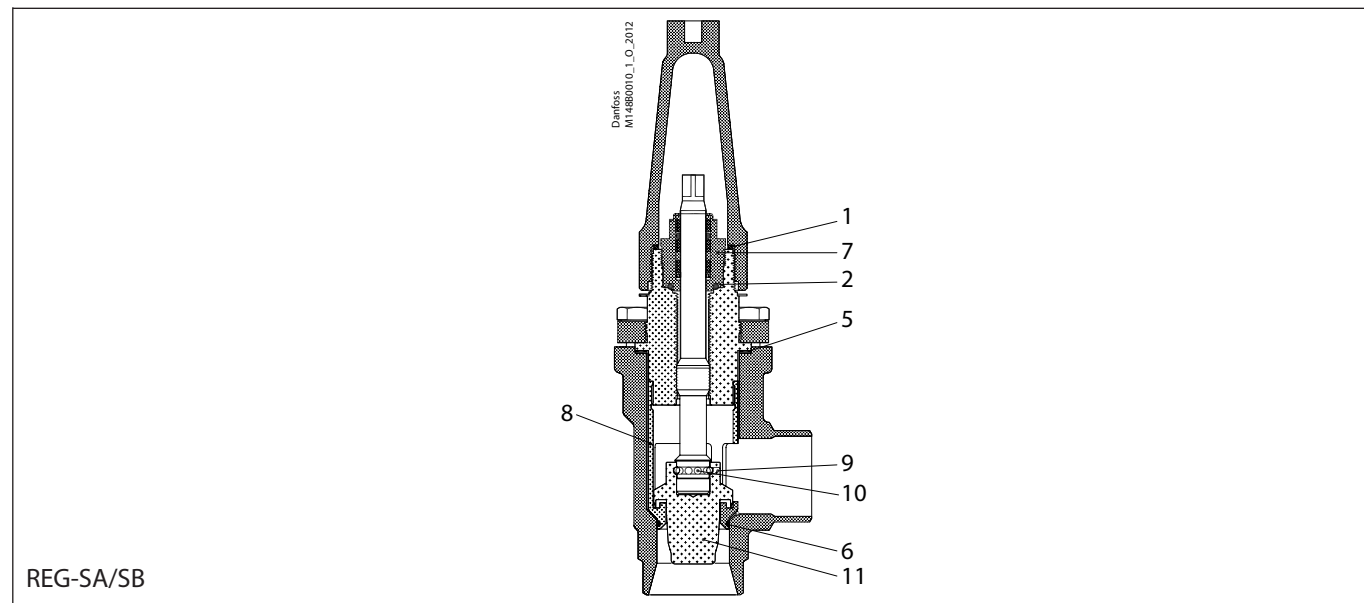REG-SA/SB size 15-20




1 = Nylon Total no. = 1	2 = Alu. Total no. = 1	5 = Fibre Total no. = 1	6 Total no. = 1	7 Total no. = 1
8 Total no. = 1	9 Total no. = 1	10 Total no. = 10	11 Total no. = 1	11 Total no. = 1
12 Total no. = 1				











NOTE:

When replacing the packing gland (pos. 7) in REG-SA/B or REG the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6176

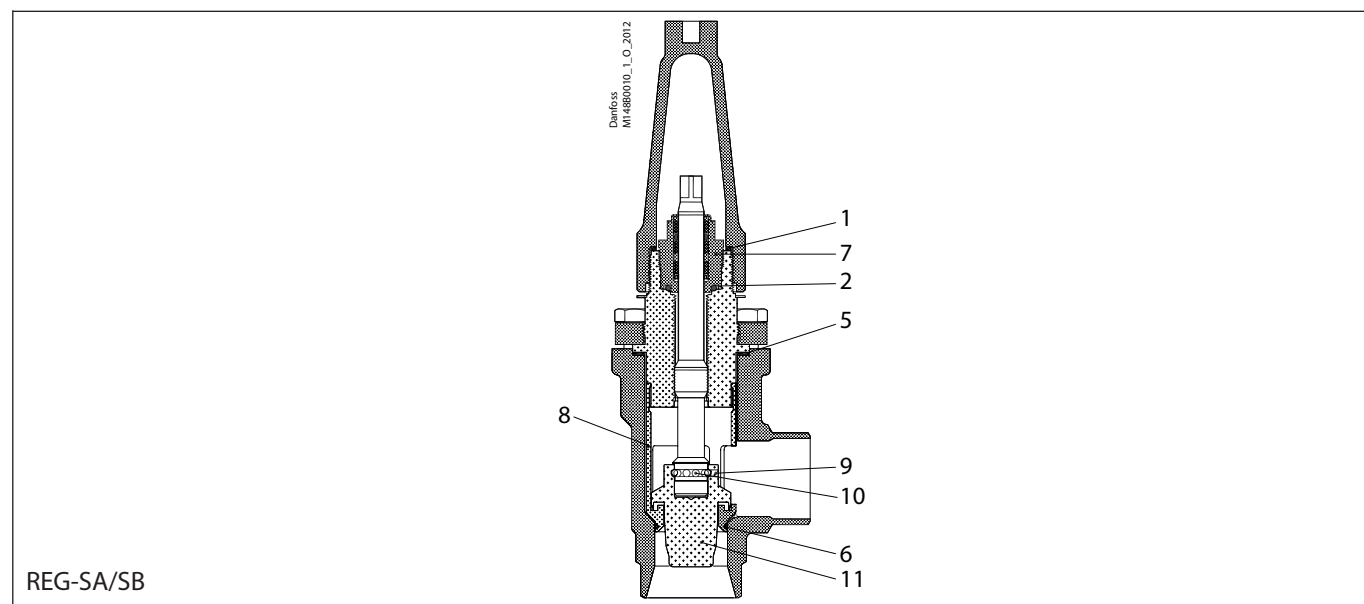       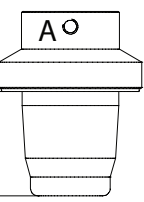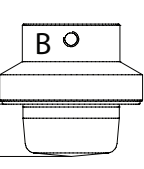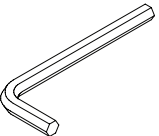REG-SA/SB size 25-40




1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	5  = Fibre  Total no. = 1	6   Total no. = 1	7  Ø28 mm Ø1.1\" data-bbox="805 505 875 515"/> Total no. = 1
8  Ø38.5 mm Ø1.5 in. Total no. = 1	9  M4 Total no. = 1	10  Ø3 mm Ø0.118\" data-bbox="448 598 548 628"/> Total no. = 14	11  A 28 mm 1.09\" data-bbox="598 573 628 633"/> Total no. = 1	11  B 14 mm 0.55\" data-bbox="768 573 798 633"/> Total no. = 1
12  Total no. = 1				









NOTE:

When replacing the packing gland (pos. 7) in REG-SA/B or REG the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6177

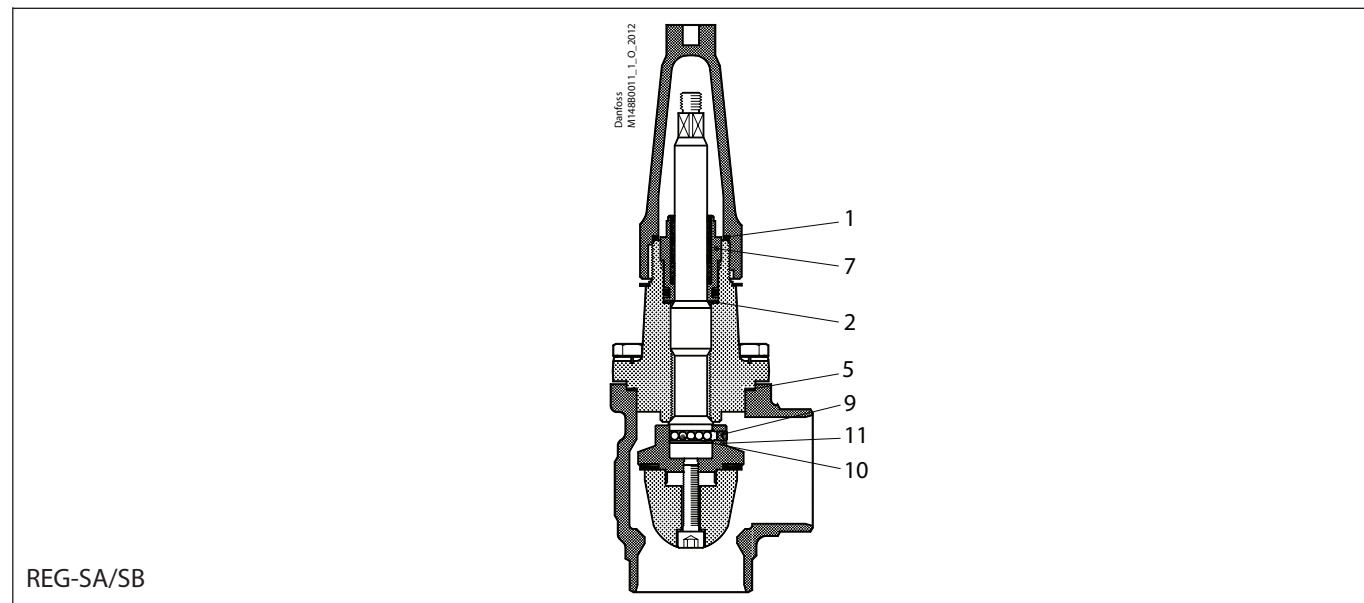     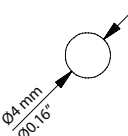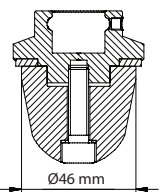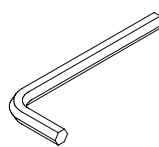REG-SA/SB size 50












1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	5  = Fibre  Total no. = 1	7  Total no. = 1	9  Total no. = 1
10  Total no. = 14	11  Total no. = 1	12  Total no. = 1		

NOTE:

When replacing the packing gland (pos. 7) in REG-SA/B or REG the aluminium gasket (pos. 2) is needed.

Overhaul kit | Code number 148B6178
REG-SA/SB size 65

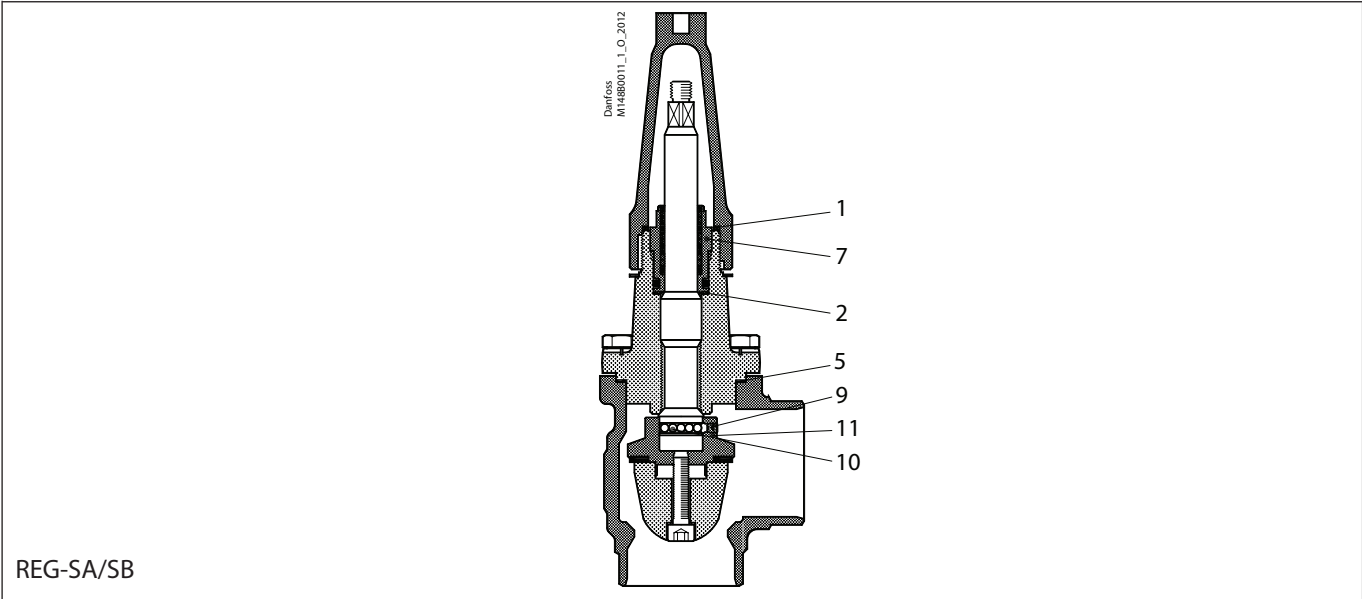

     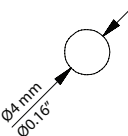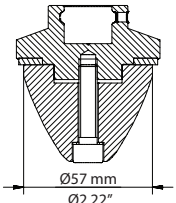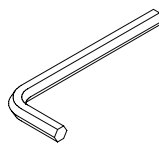1  = Nylon  Total no. = 1	2  = Alu.  Total no. = 1	5  = Fibre  Total no. = 1	7  Total no. = 1	9  Total no. = 1
10  Total no. = 14	11  Total no. = 1	12  Total no. = 1		

NOTE:
When replacing the packing gland (pos. 7) in REG-SA/B or REG the aluminium gasket (pos. 2) is needed.

Accessories

SVA, SVA-ST, SVA-LT, SVA-HS, SVA-S, SVA-L, REG, REG-SA/SB, SCA, SCA-X and FIA

Cap incl. gasket for SVA, SVA-ST, SVA-LT, SVA-HS, SVA-S, SVA-L, REG, REG-SA/SB, SCA and SCA-X


	Valve size	Code number
	3-10	148B4074
	15-20	148B4075
	25-65	148B4076
	80-100	148B4077
	125-150	148B4078
	200	148B4079

Please note: All accessory caps are red.

Hand wheel incl. nut and washer for SVA, SVA-ST, SVA-LT, SVA-HS, SVA-S, SVA-L, REG, REG-SA/SB, SCA and SCA-X

	Valve size	Code number
	3-10	148B4073
	15-20	148B4060
	25-40	148B4062
	50-65	148B4064
	80	148B4065
	100	148B4066
	125-150	148B4067
	200	148B4068

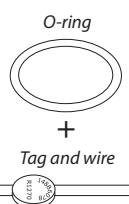Replacement kits* for R717 Ammonia Heat Pump and R1270 Propylene applications** for SCA-X, CHV-X sizes 15-125 and REG SA/SB sizes 10-40

	Valve size	R717 Heat Pump	R1270 Propylene
	10	148B6084	148B6085
	15	148B6070	148B6077
	20	148B6070	148B6077
	25	148B6071 *** 148B6096 ****	148B6078 *** 148B6097 ****
	32		
	40		
	50	148B6072	148B6079
	65	148B6073	148B6080
	80	148B6074	148B6081
	100	148B6075	148B6082
	125	148B6076	148B6083

* Not needed for SVA, FIA and REG50/65

** Replacement kits for R717 Ammonia Heat Pump is applicable for continuous operating temperature between +100 °C to 150 °C (212 °F to 302 °F)

*** For SCA-X, CHV-X 25-40

**** For REG SA/SB 25-40

Spring for SCA, SCA-X, CHV and CHV-X

	Valve size	0.04 bar / 0.58 psi Code number	0.3 bar / 4.35 psi Code number
	15-20	148G3204	148G3206
	25-40*	148G3205	148G3207
	25-40**	148B6180	148B6179
	50	148G3475	148G3480
	65	148G3476	148G3481
	80	148G3477	148G3482
	Special spring for horizontal installation:		
	Valve size	Code number	
	80	148B6181	
	100	148B6182	

* Before Nov. 2012

** After Nov. 2012

Gasket for housing/top cover for SVA-HS, SVA-S, SVA-L and FIA

	Valve / filter size	Code number
	15-20	148B4153
	25-40	148B4154
	50	148B4155
	65	148B4156
	80	148B4157
	100	148B4158
	125	148B4159
	150	148B4160
	200	148B4161

Grease for packing gland	All types and sizes	148H3445
---------------------------------	---------------------	----------

Danfoss can accept no responsibility for possible errors in catalogues, brochures and other printed material. Danfoss reserves the right to alter its products without notice. This also applies to products already on order provided that such alterations can be made without consequential changes being necessary in specifications already agreed. All trademarks in this material are property of the respective companies. Danfoss and the Danfoss logotype are trademarks of Danfoss A/S. All rights reserved.