

Installation guide

Pressure transmitters


DST P40I / DST P 40M

078R0003

078R0003



Forbundet til kapsling
Connected to enclosure
Mit Gehäuse verbunden
Laison au boîtier

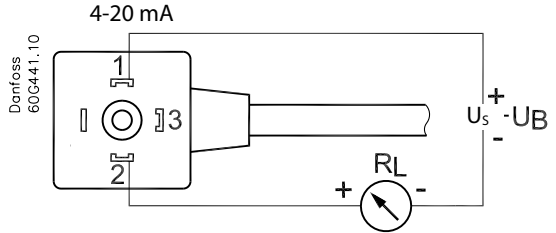

Forsyningsspænding [U_s]:
Supply voltage [U_s]:
Versorgungsspannung [U_s]:
Tension d'alimentation [U_s]:

9 – 32 V

Bemærk | Note | Achtung | Attention

