

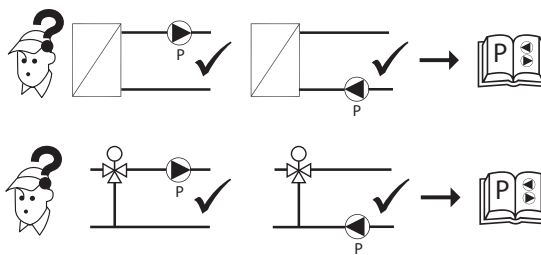
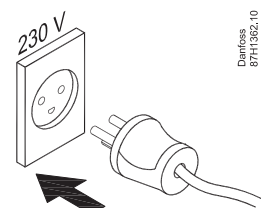
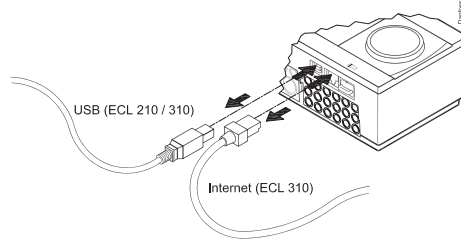


Installation Guide




ECL Comfort 310, P330 (code no. 087H3840)

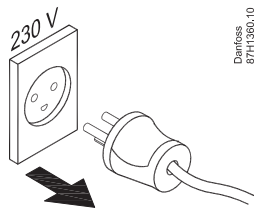





P330.1

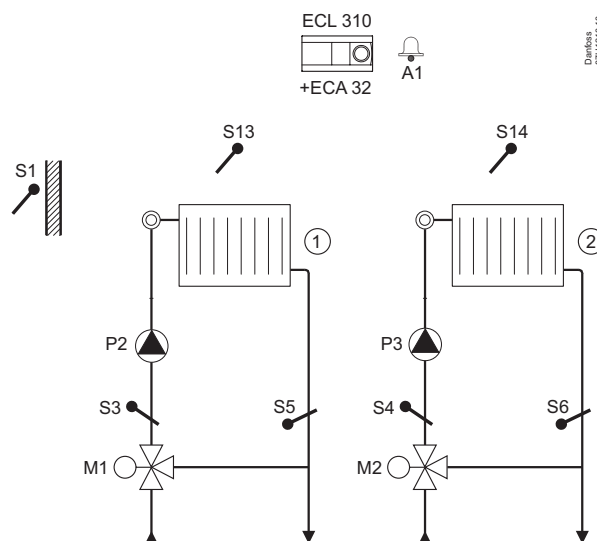

P330.1

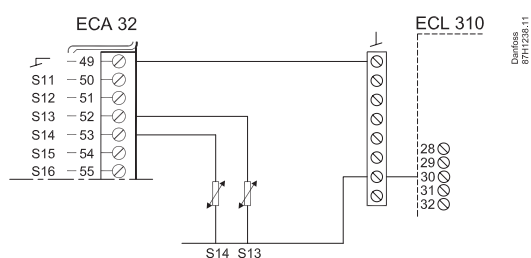
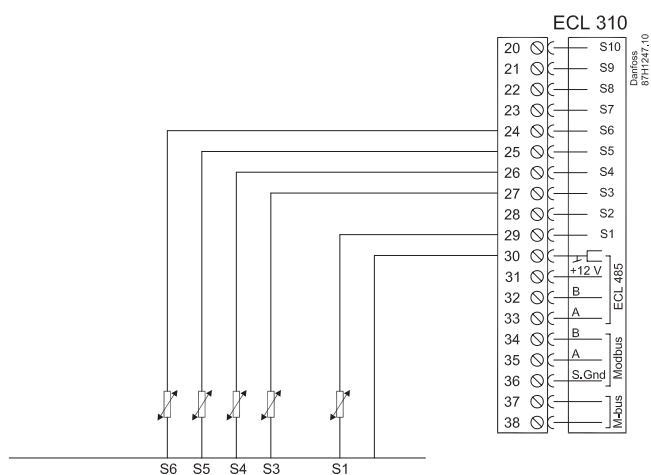
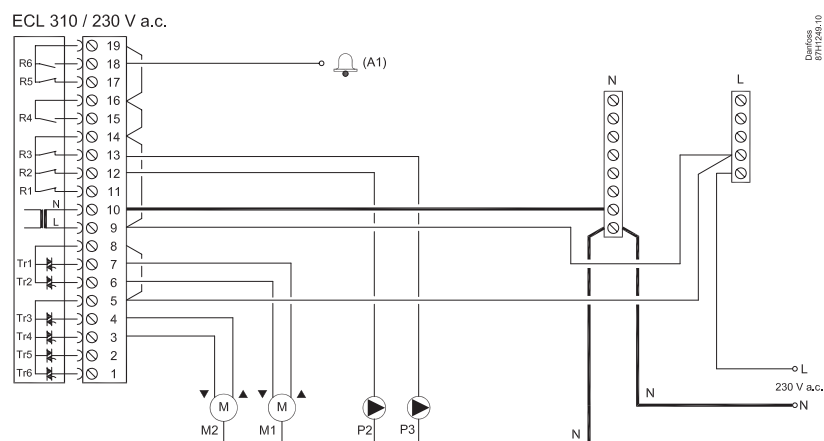


P330.2

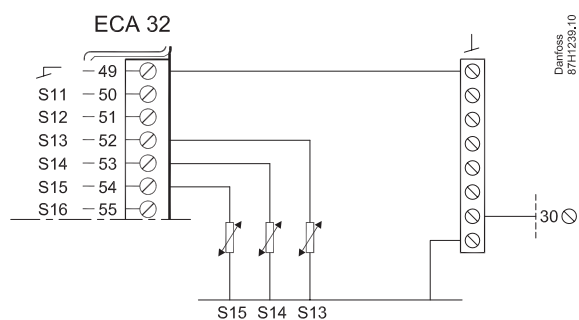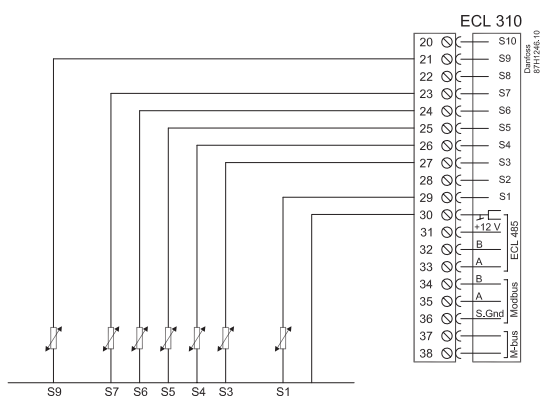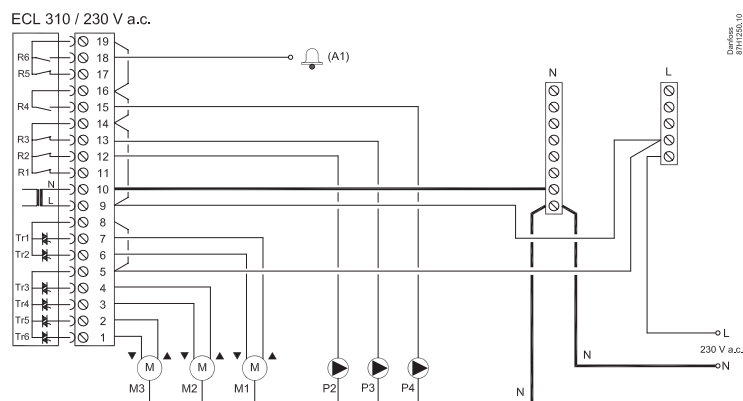
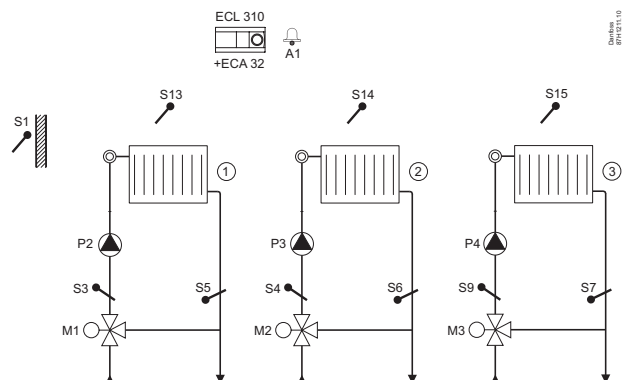


Installation Guide, ECL Comfort 310, P330





P330.3

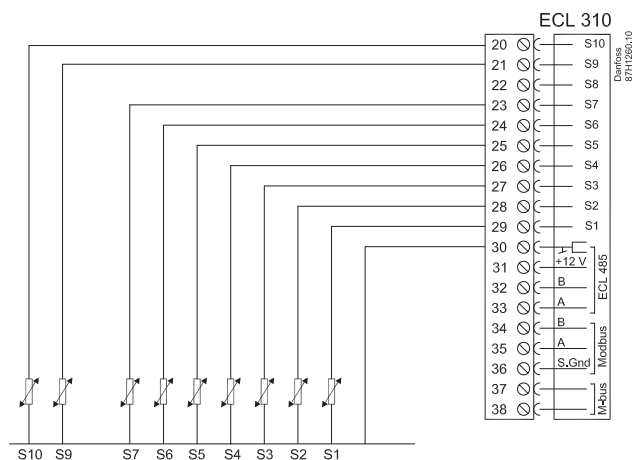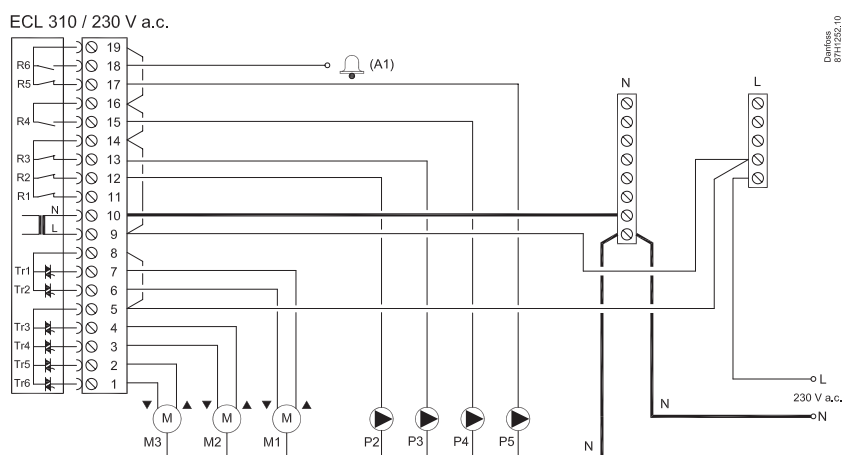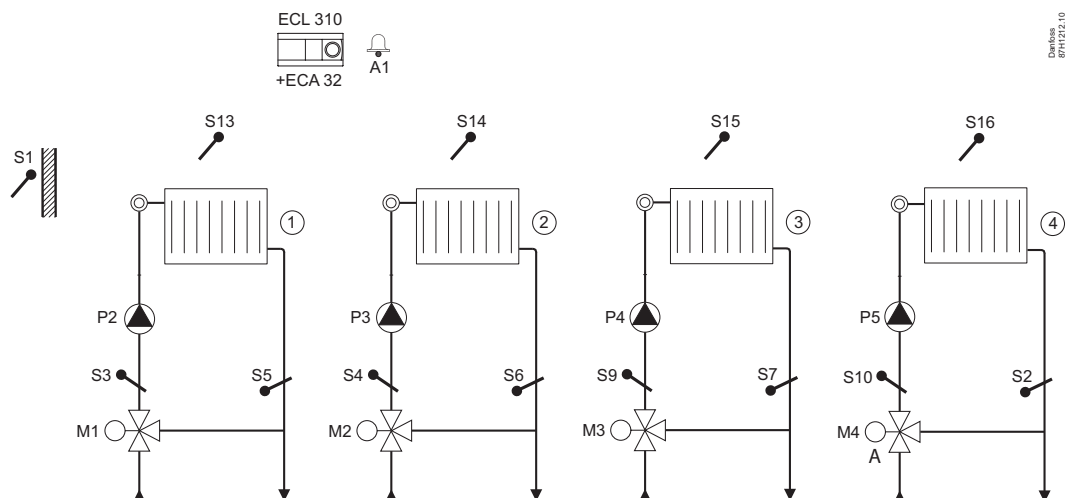


P330.3

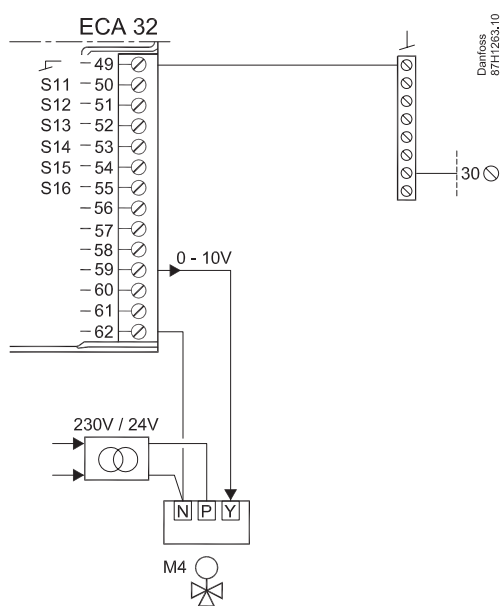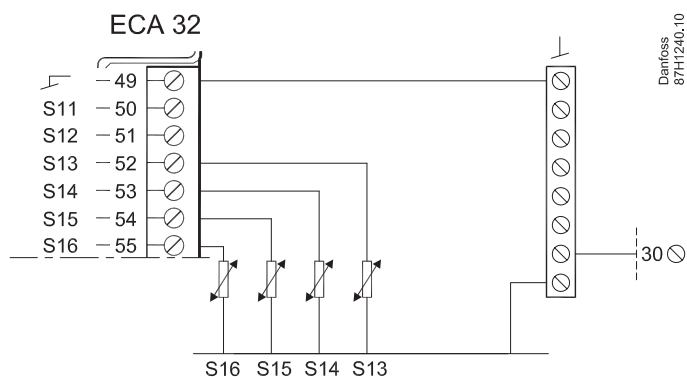

P330.4

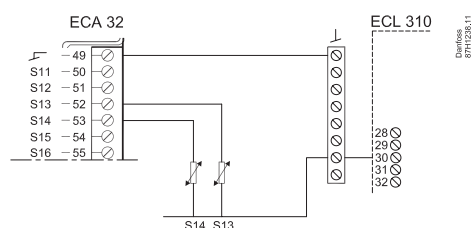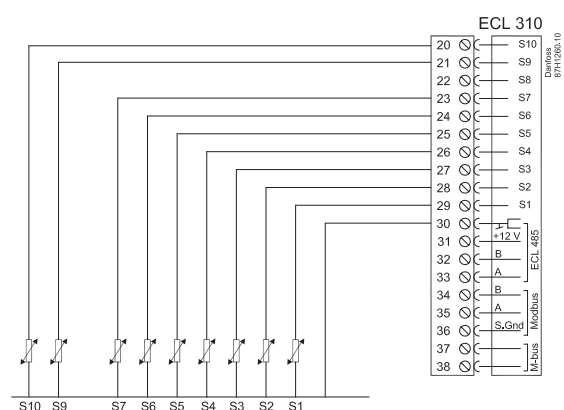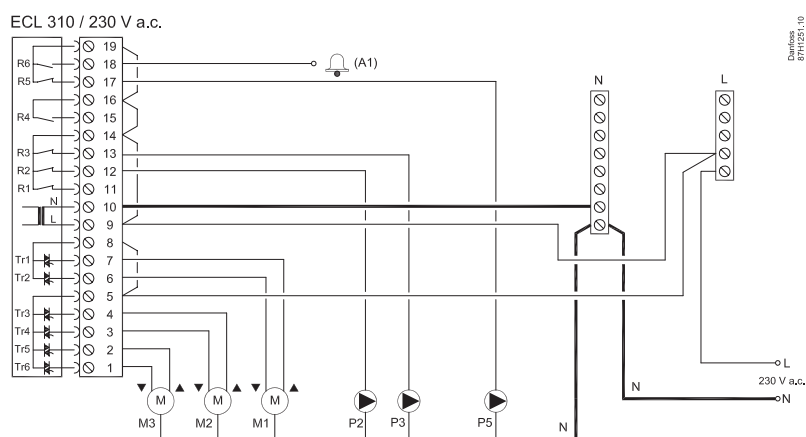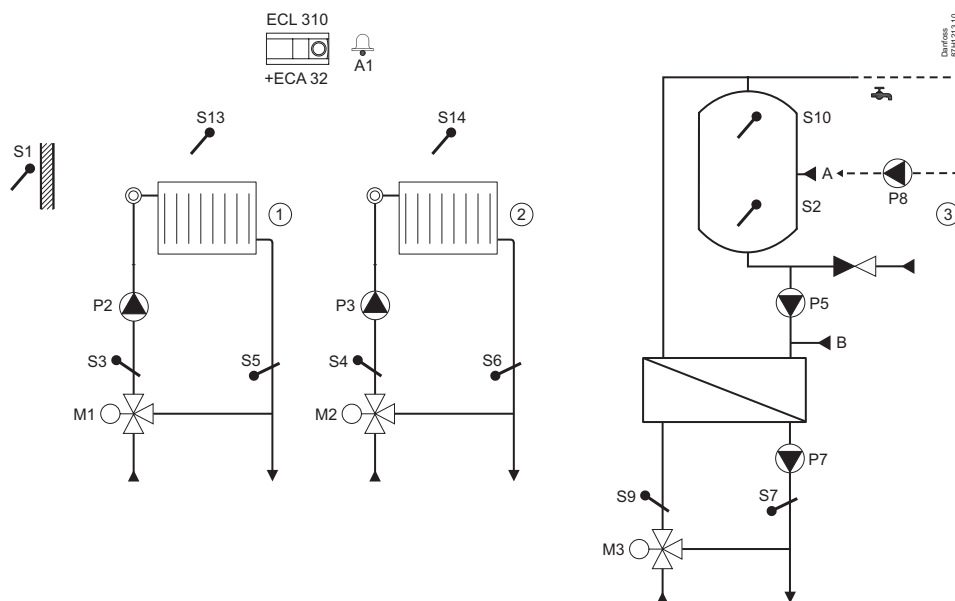


P330.4


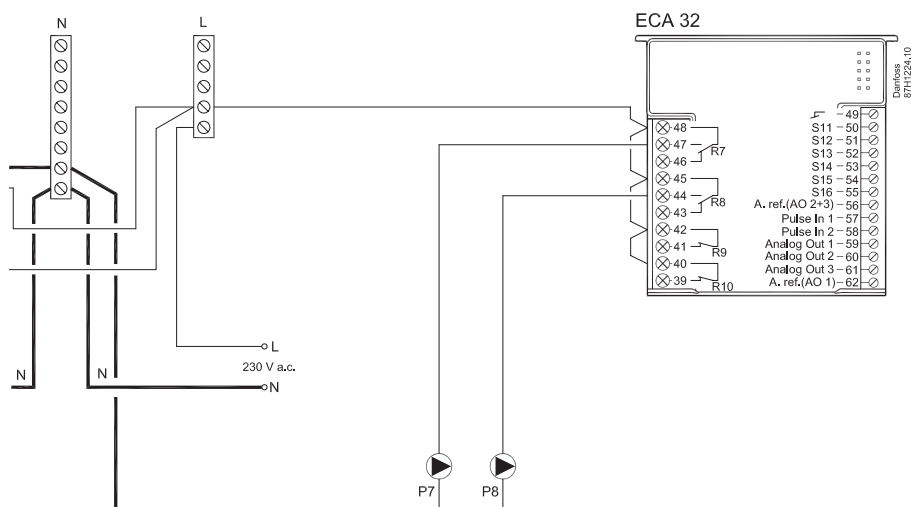


Installation Guide, ECL Comfort 310, P330


P330.5

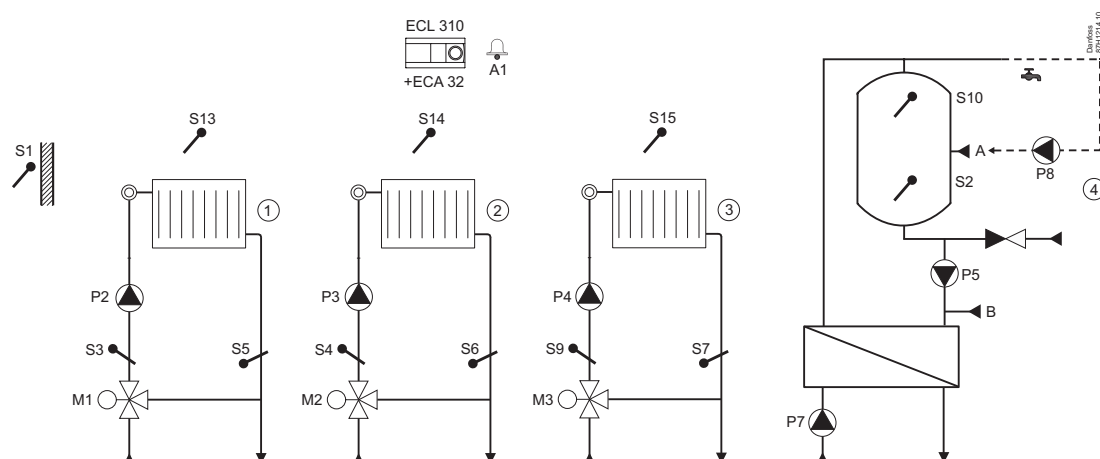


ECL 310 / 230 V a.c.

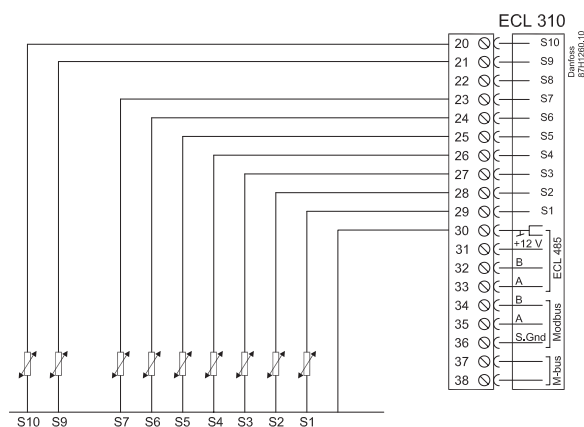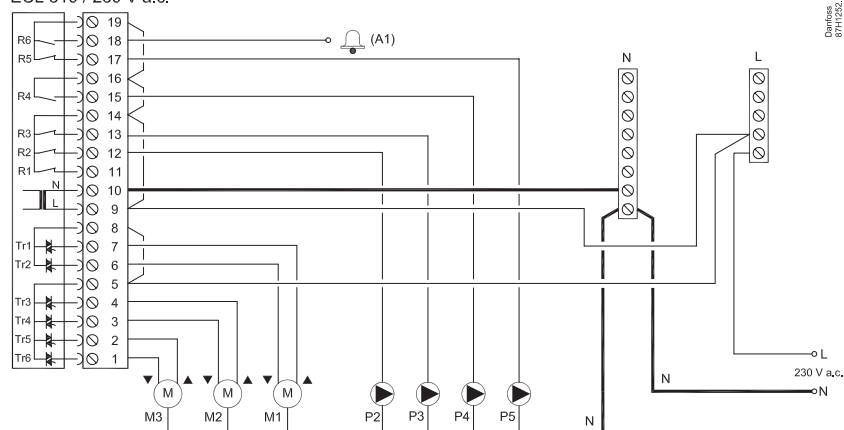





ECA 32

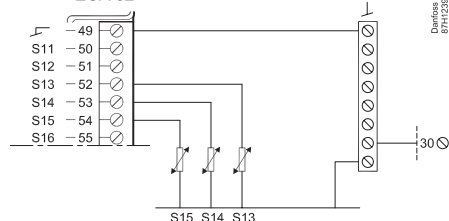





P330.5

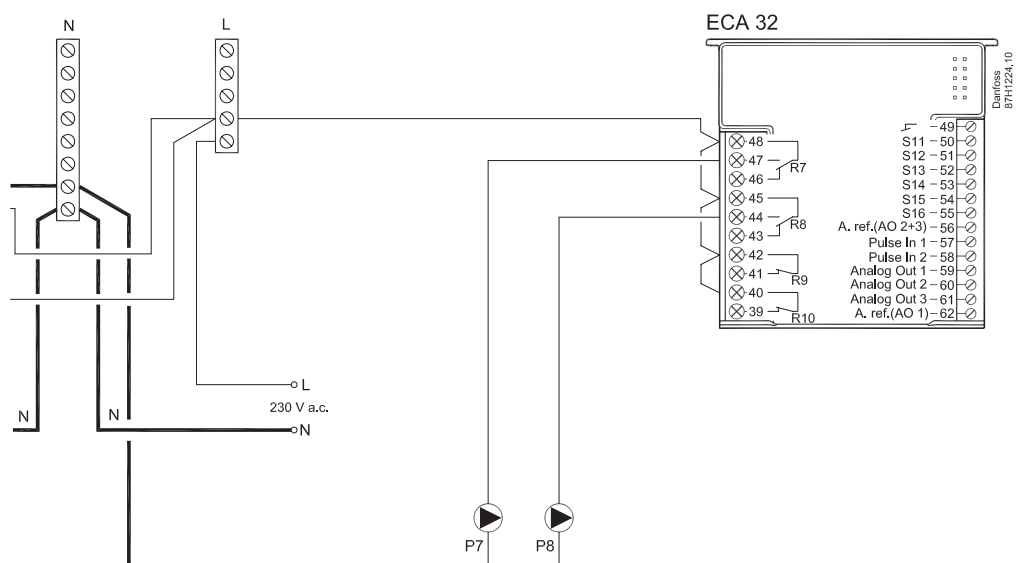





P330.6

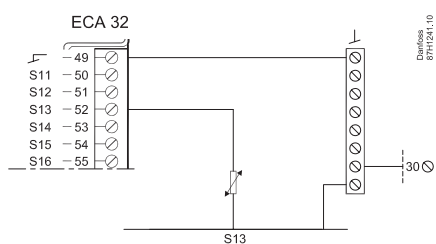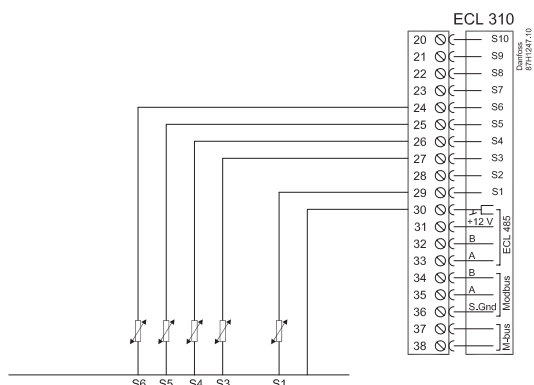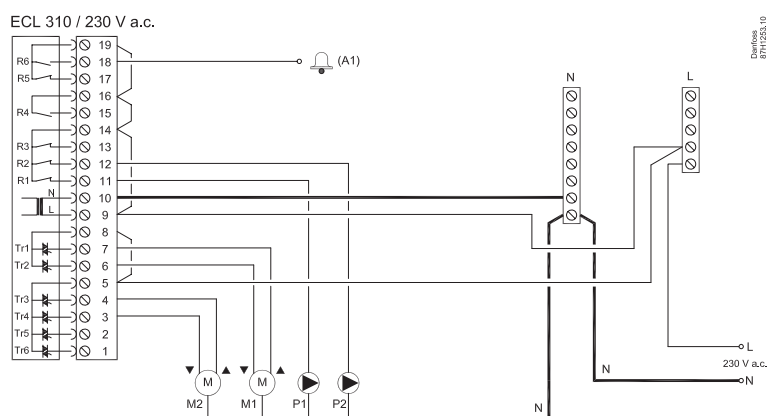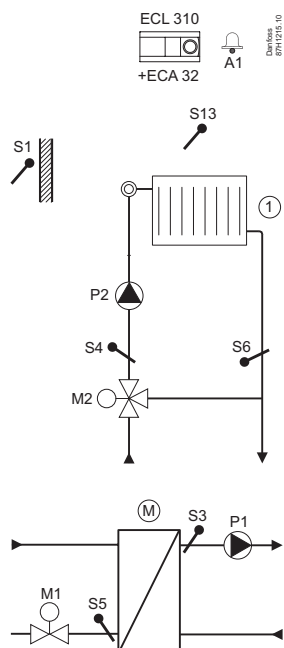


P330.7

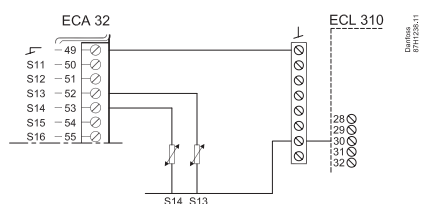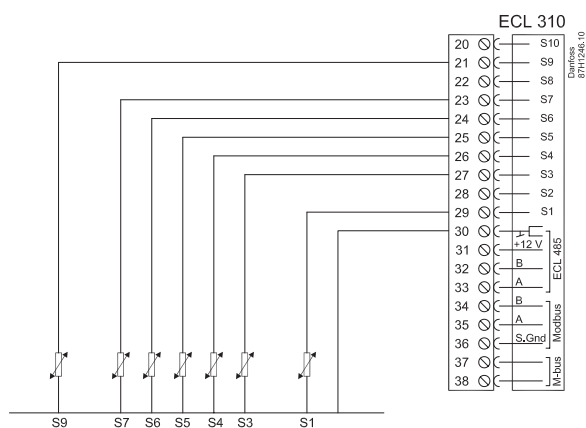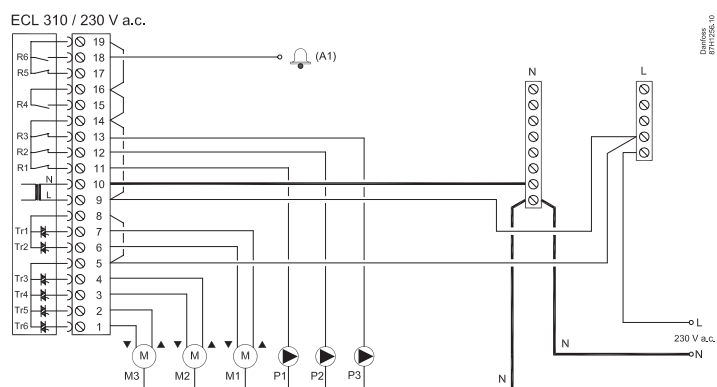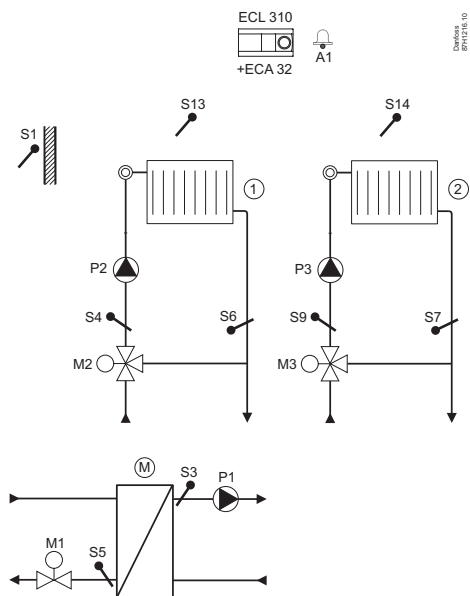




P330.8

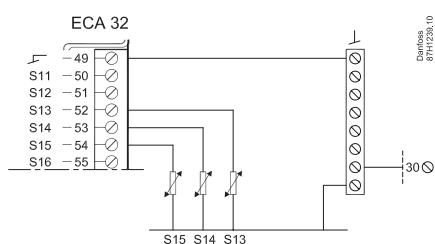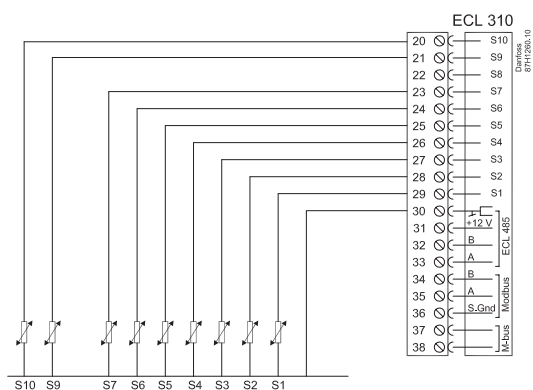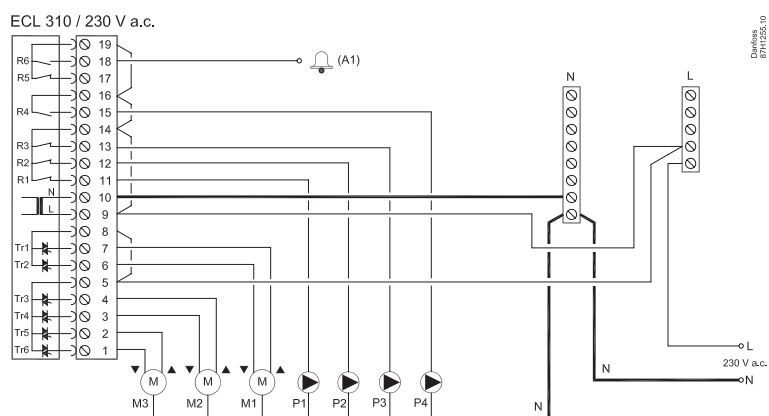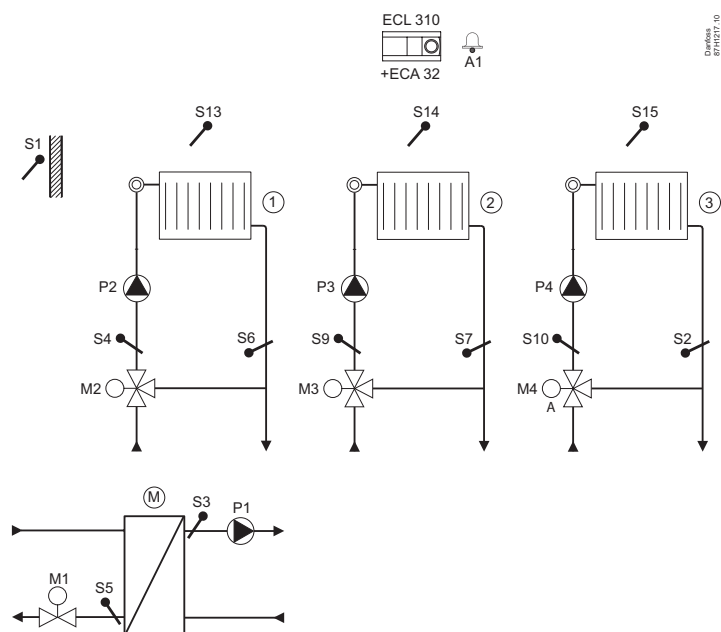



P330.8

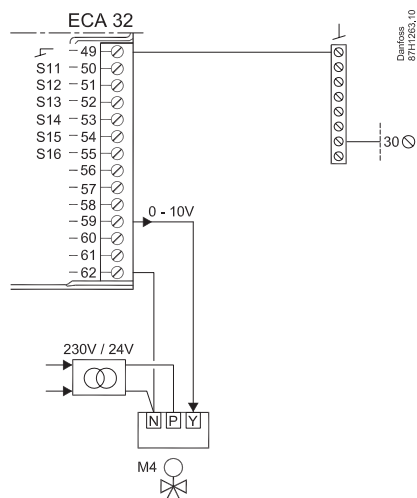


P330.9

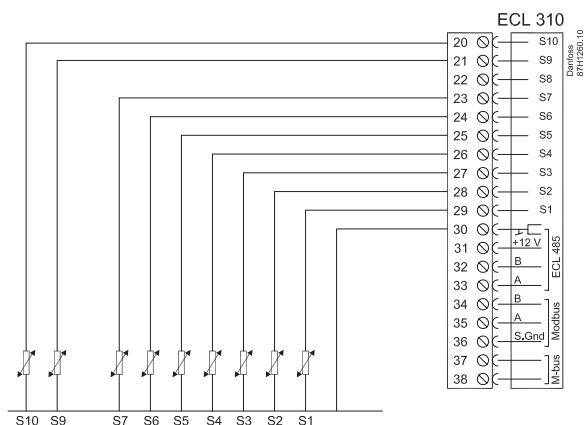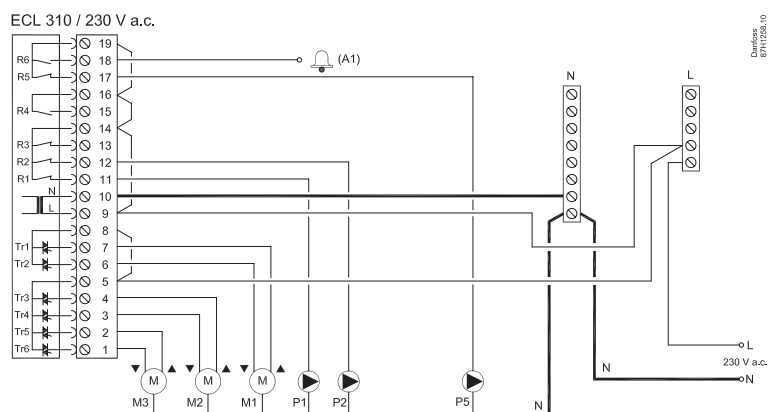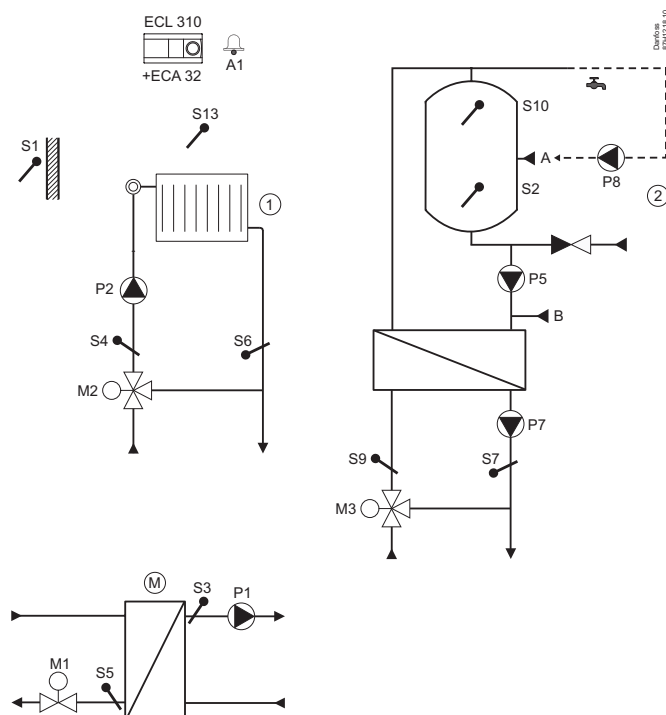


P330.9

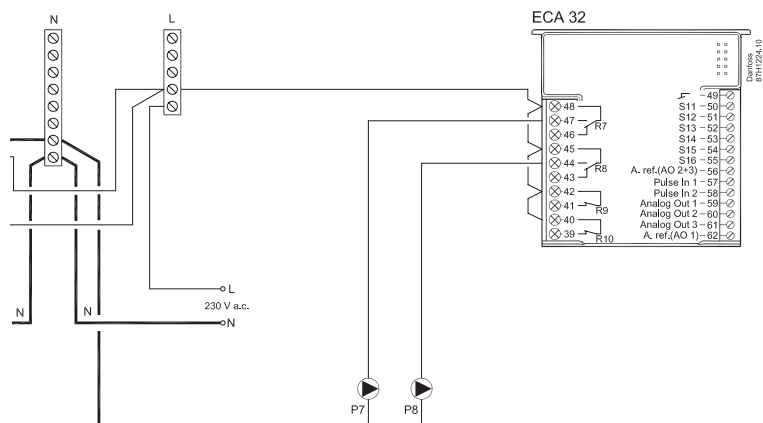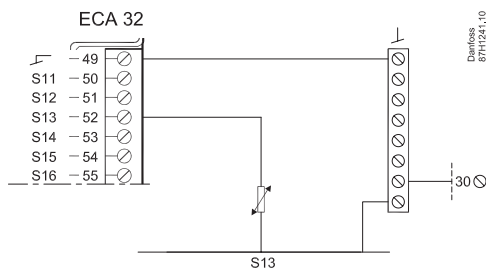


P330.10

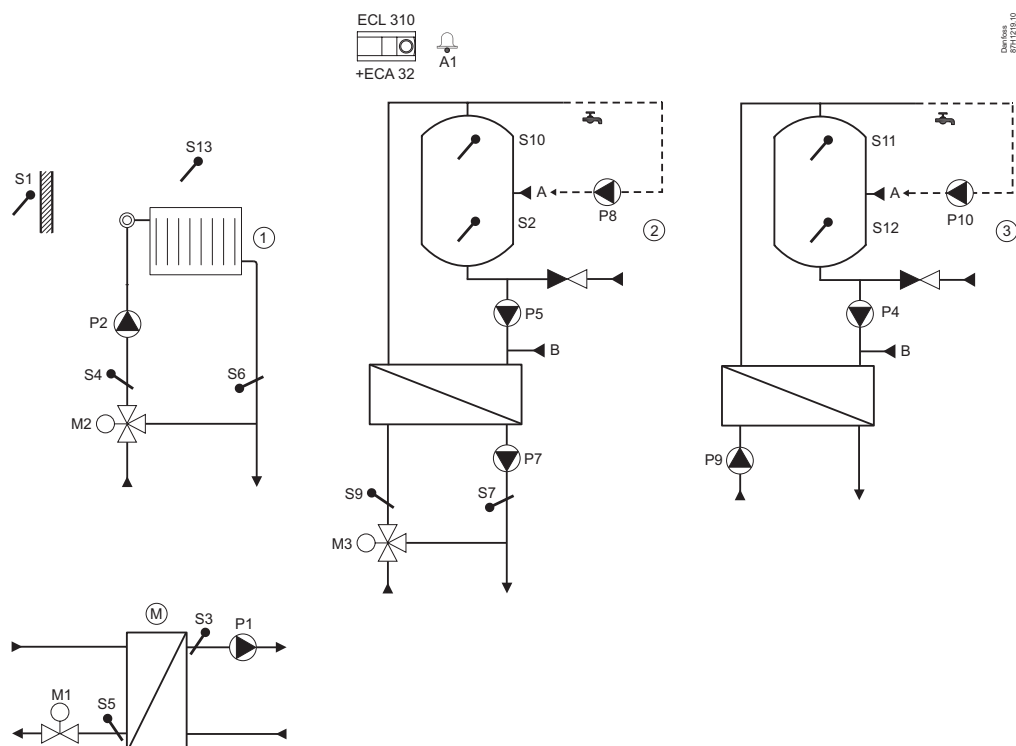



ECL 310 / 230 V a.c.

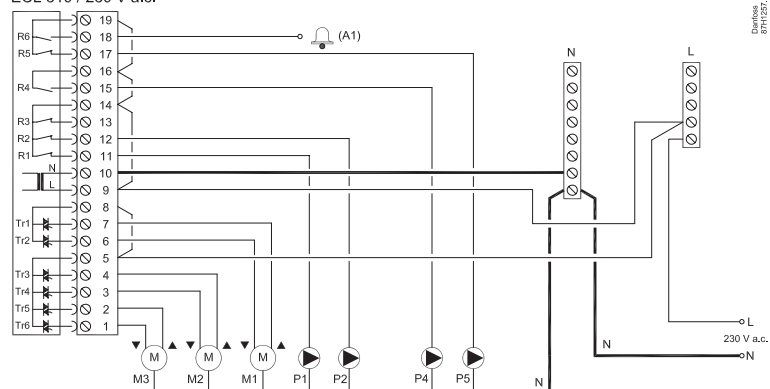




ECL 310

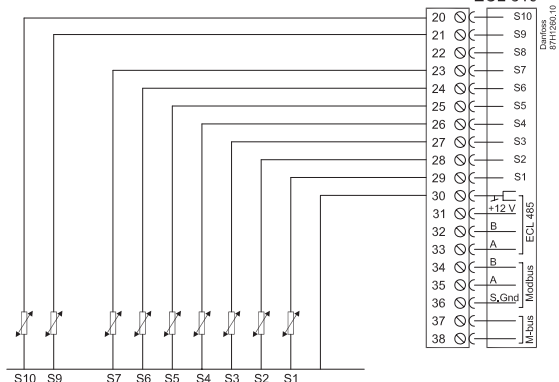



P330.10

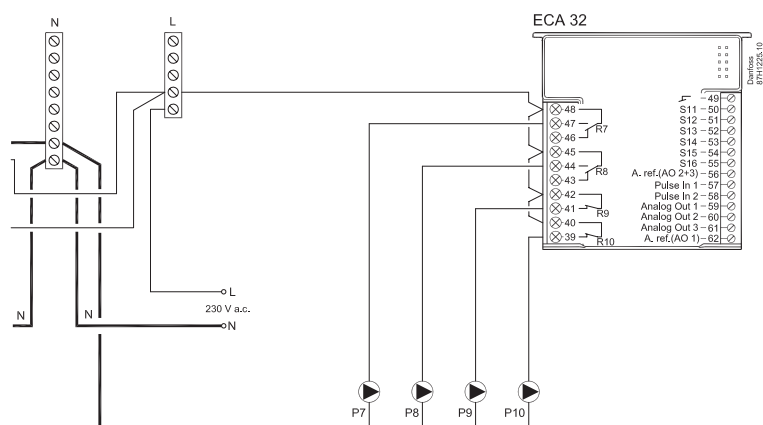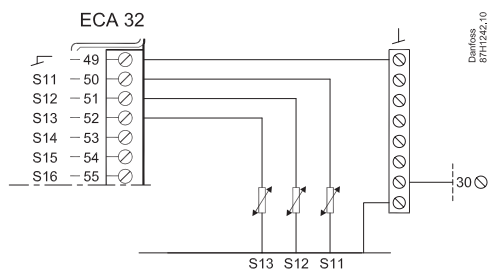


P330.11

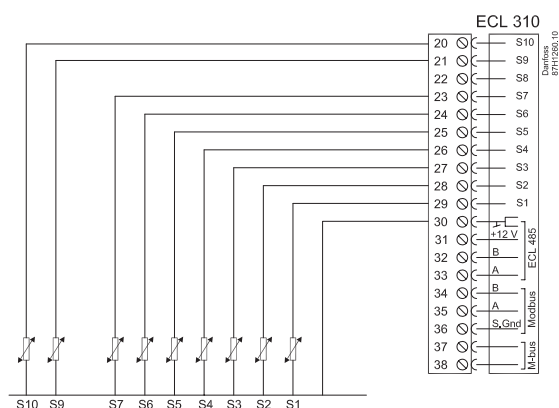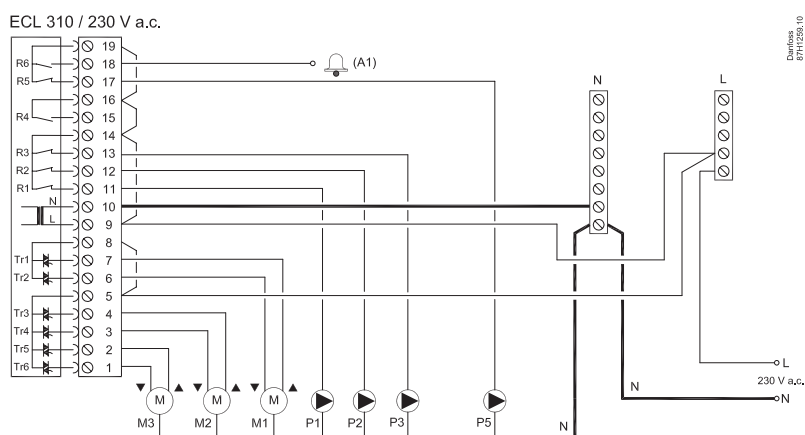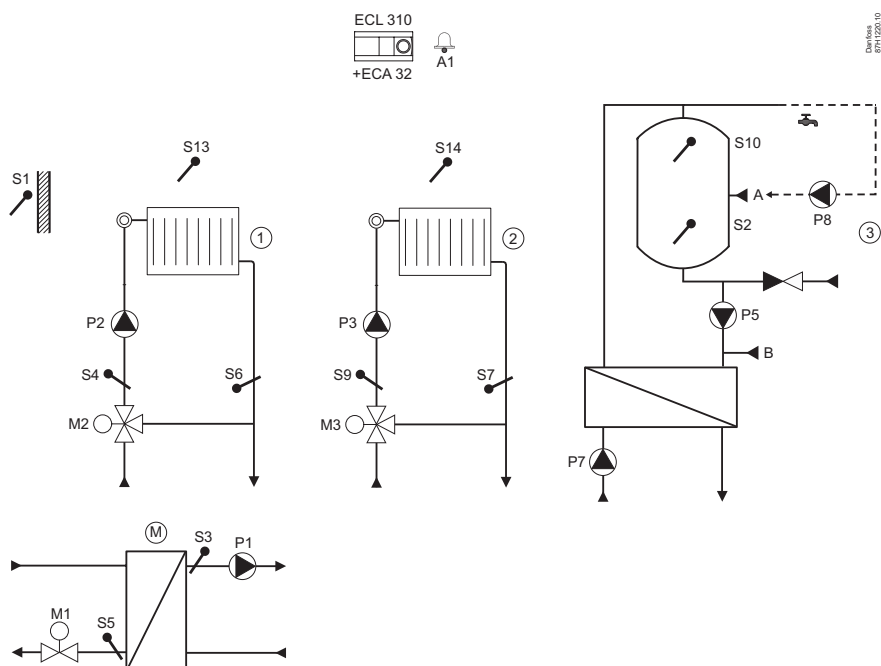


P330.11

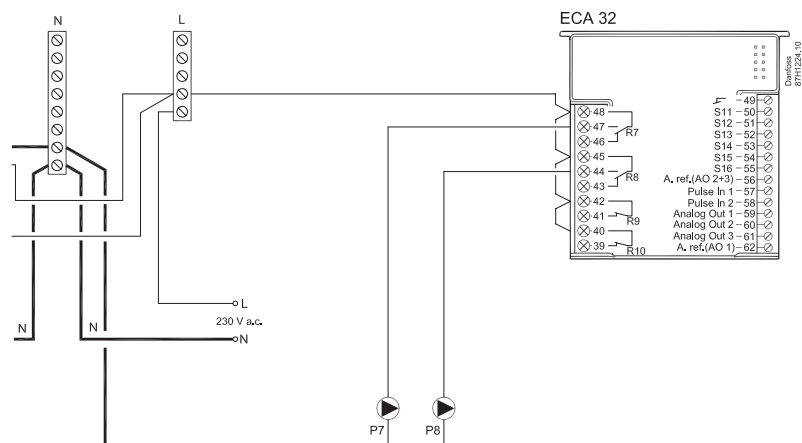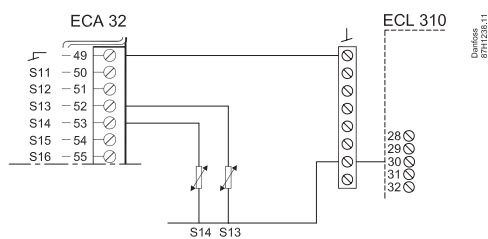


P330.12

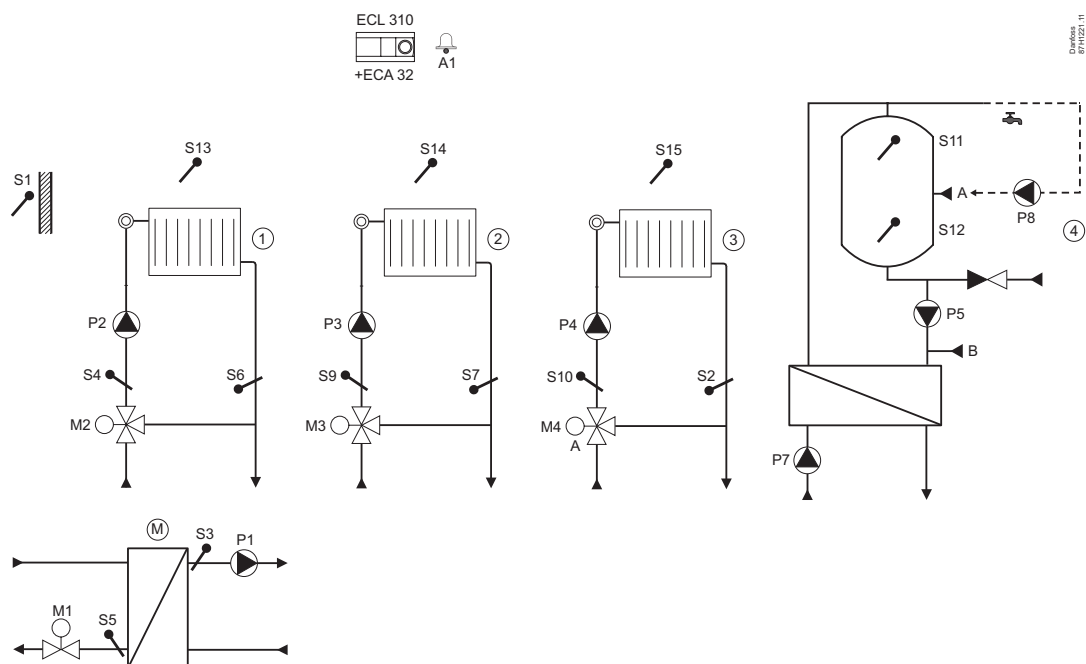




ECL 310 / 230 V a.c.

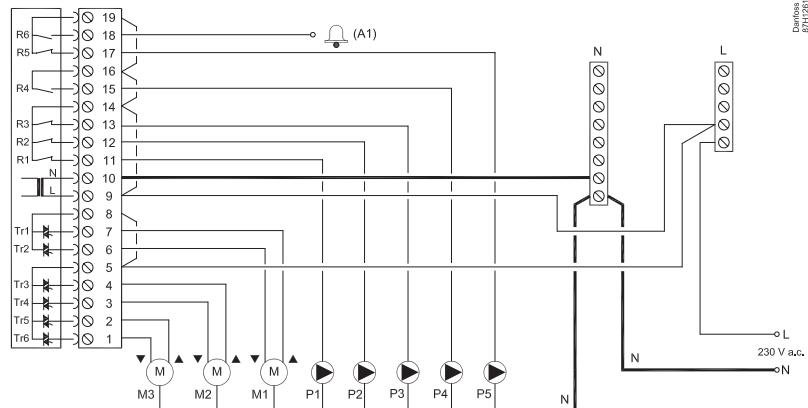




ECL 310

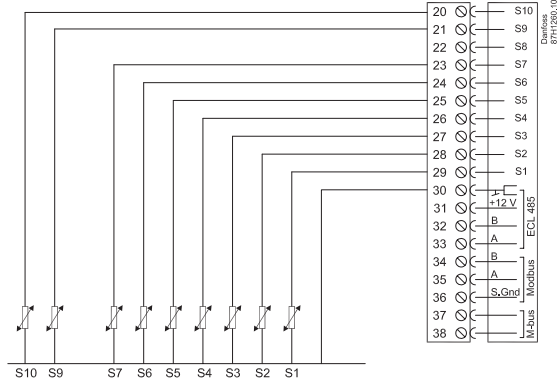



P330.12

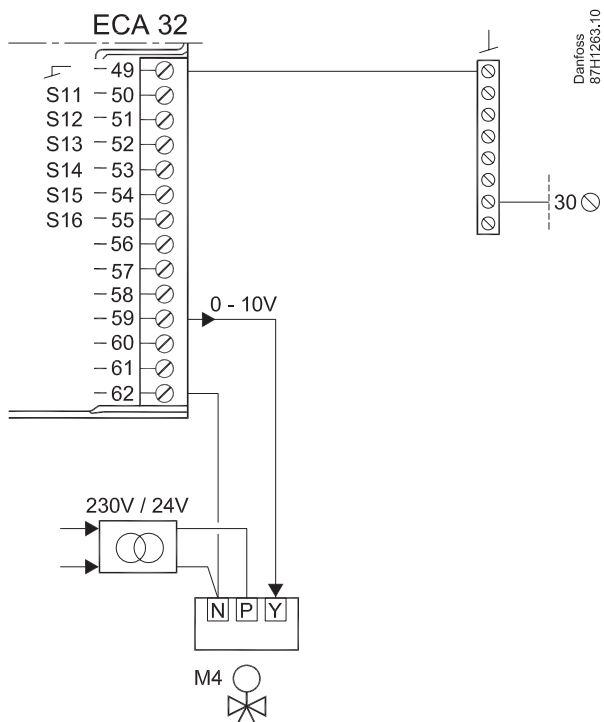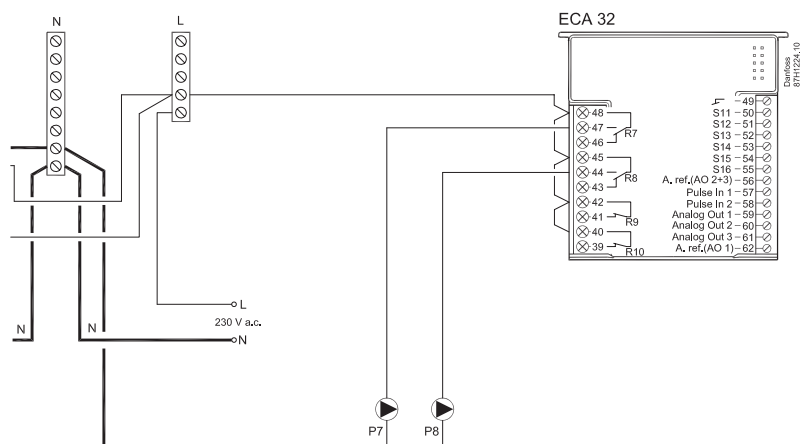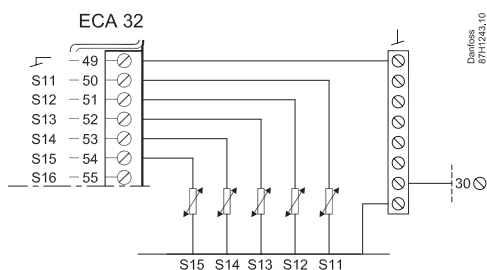




P330.13

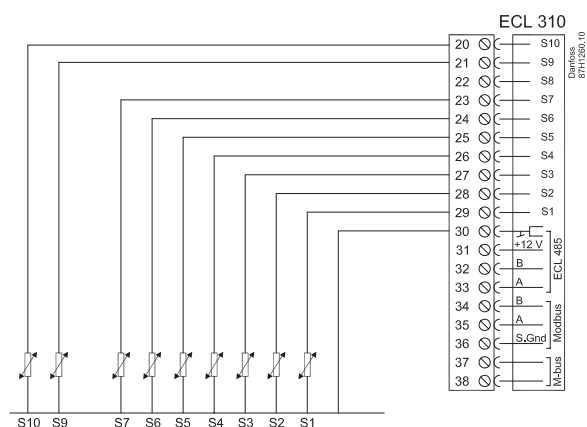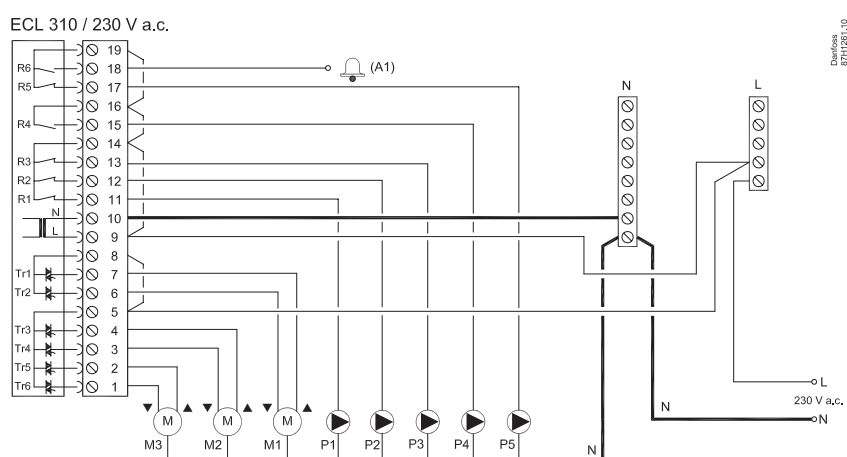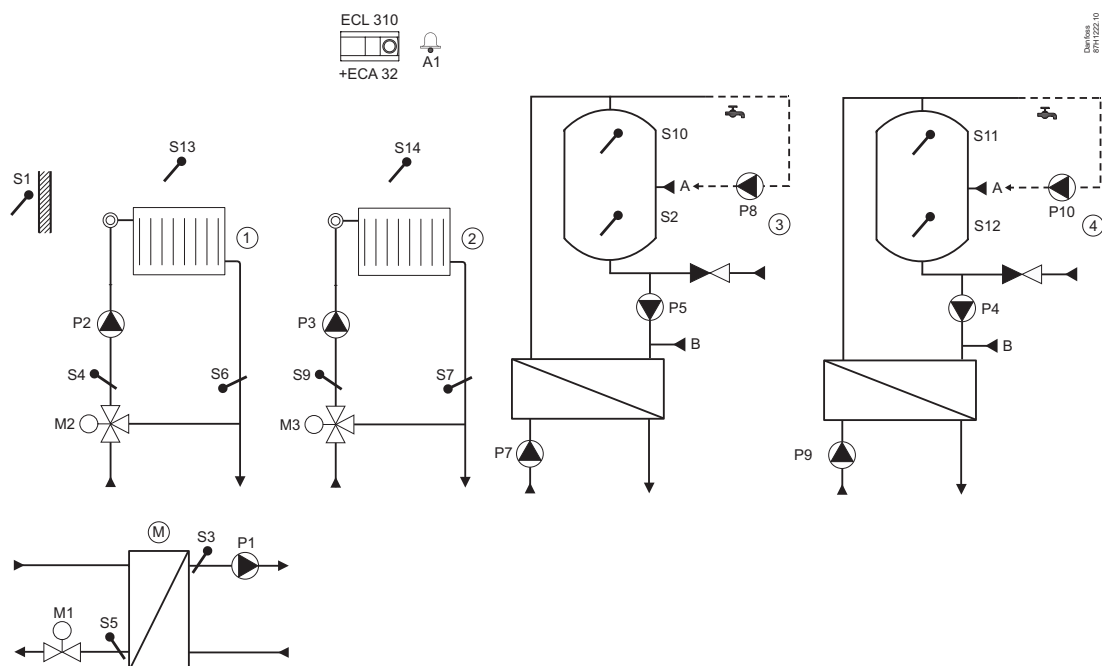



P330.13

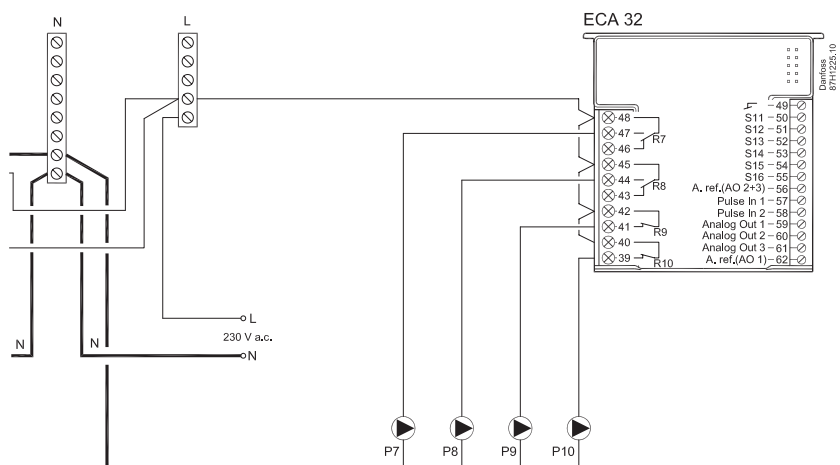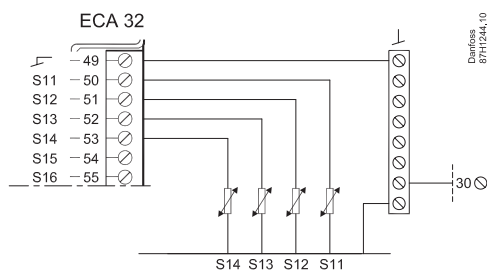




P330.14

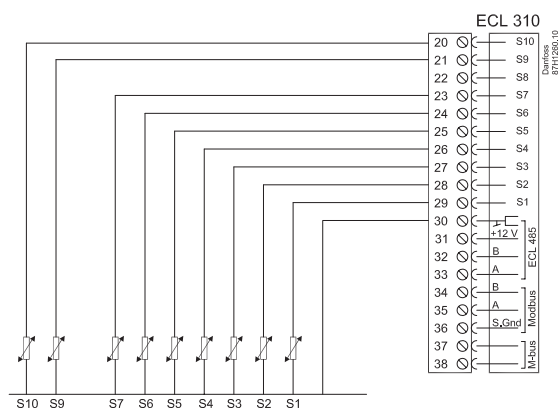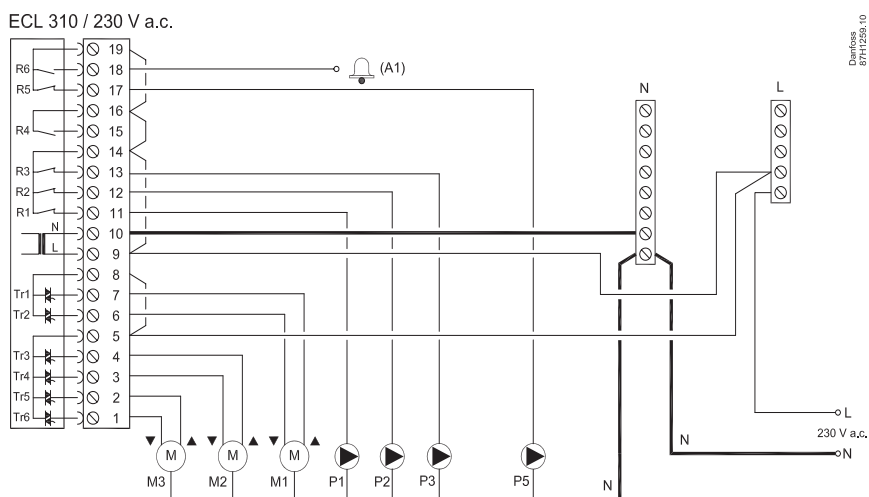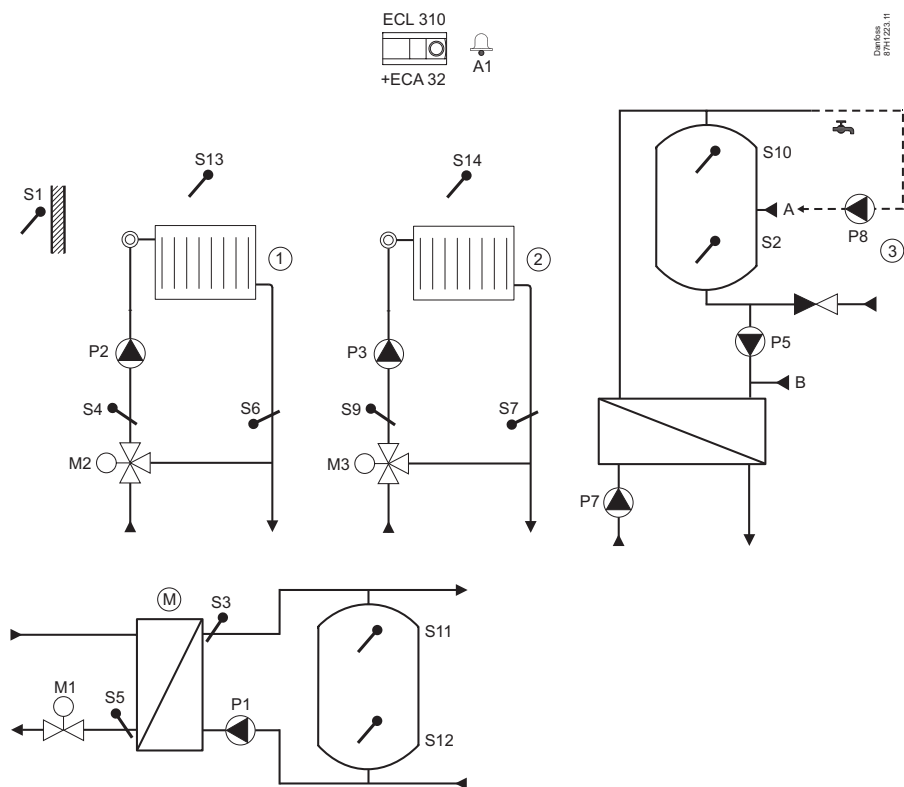



P330.14

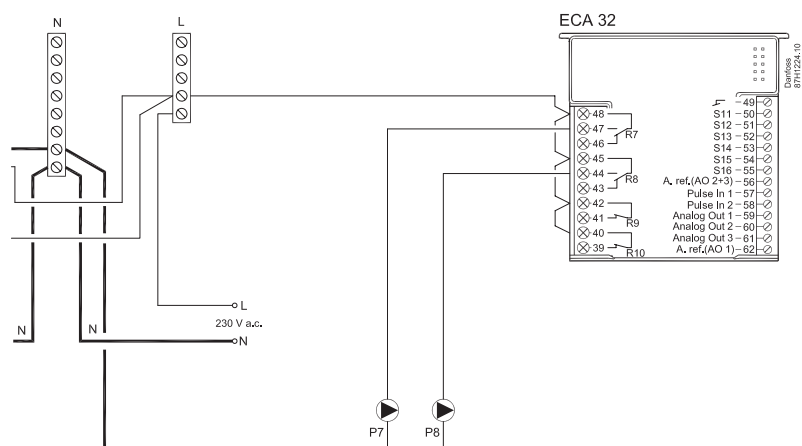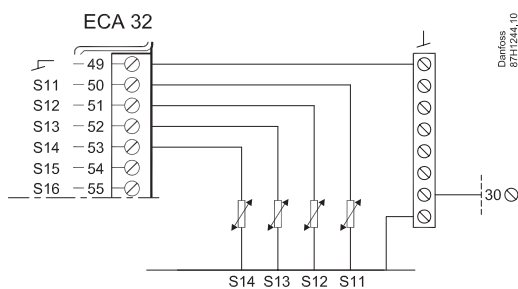





P330.15

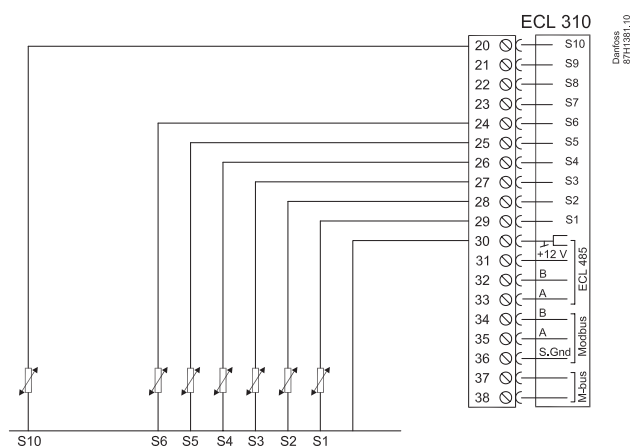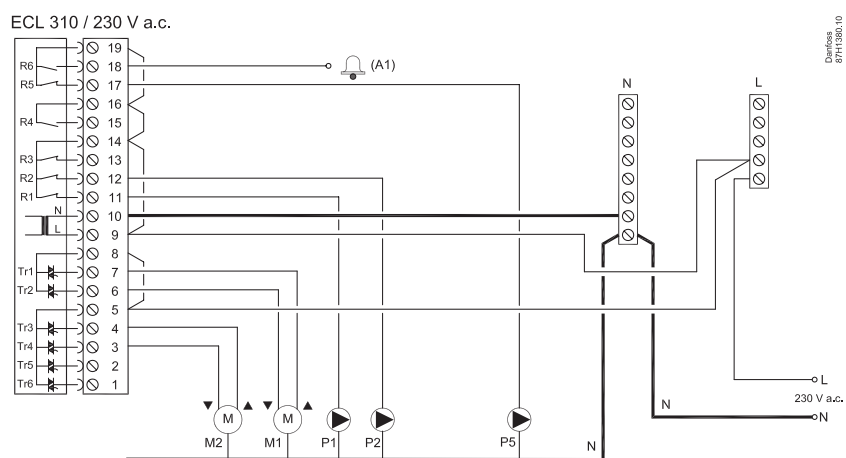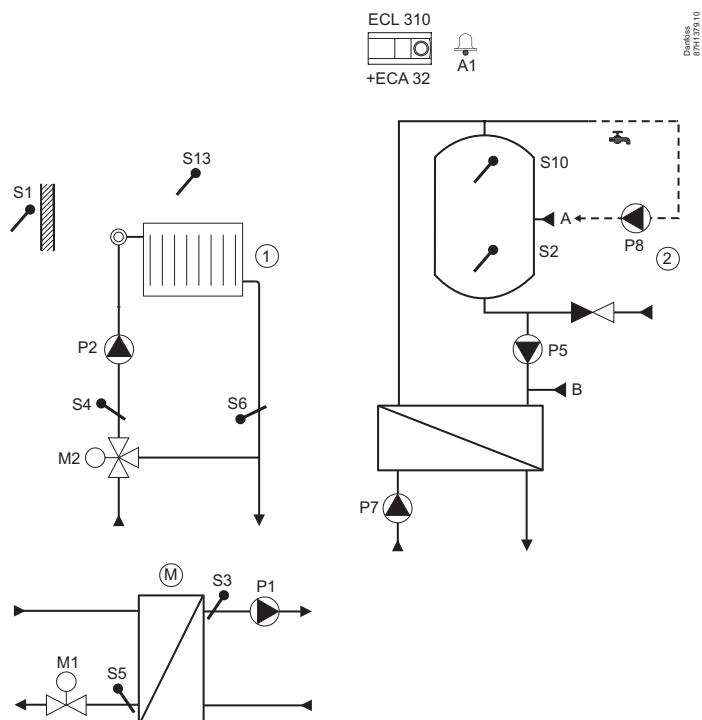

P330.15

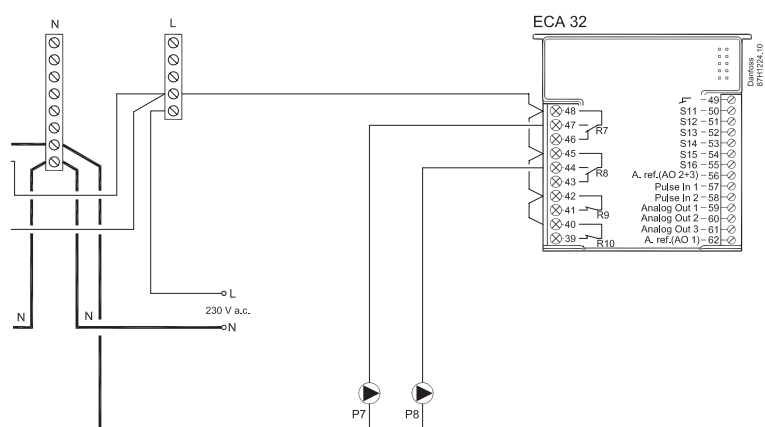
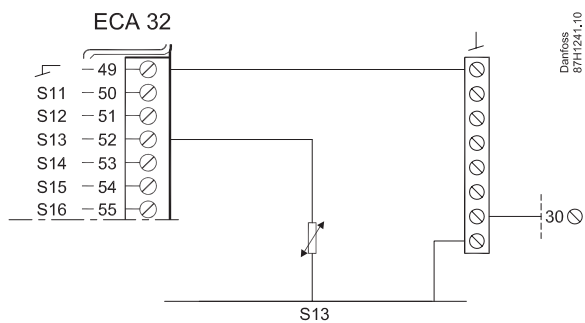


230 V a.c. safety thermostat
1-step closing

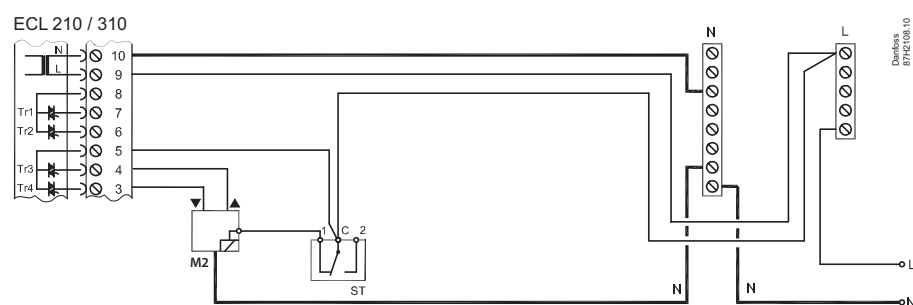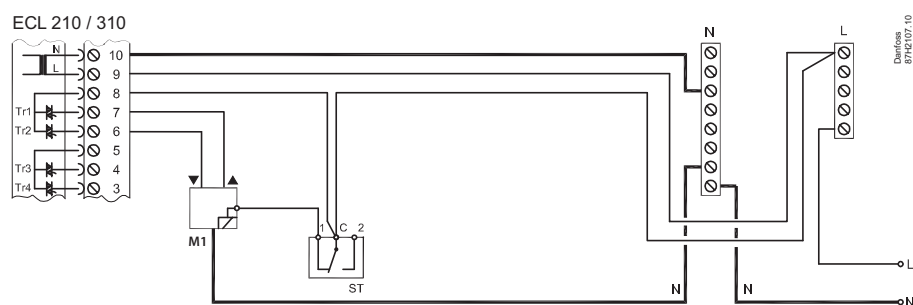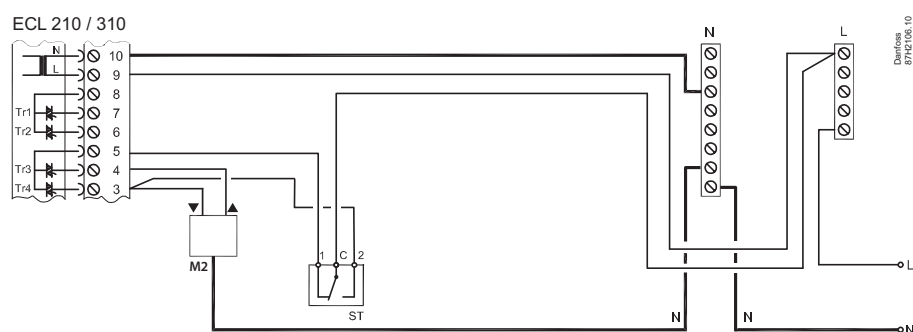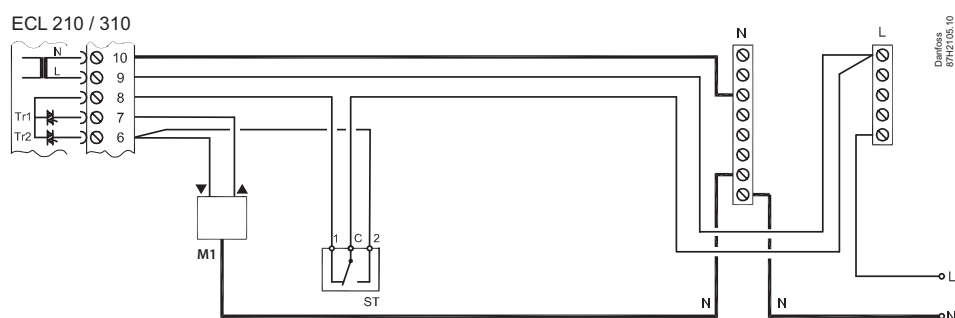


230 V a.c. safety thermostat



2-step closing

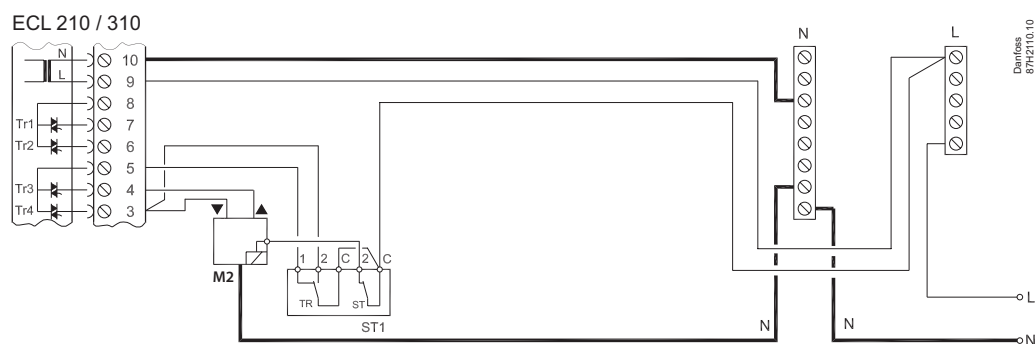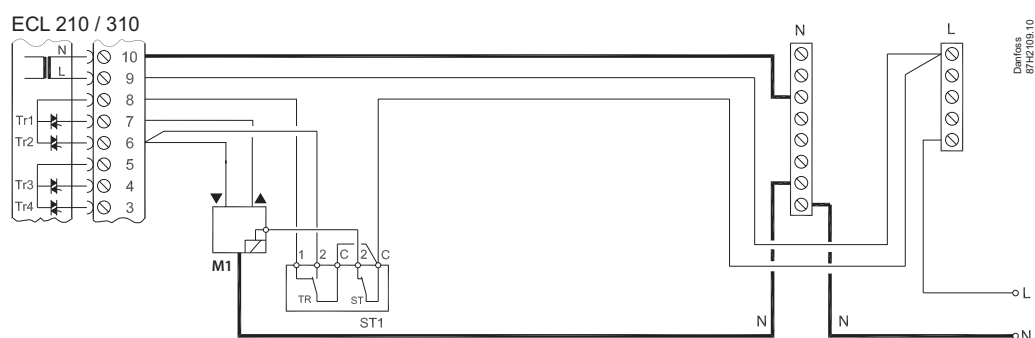


0-10 V

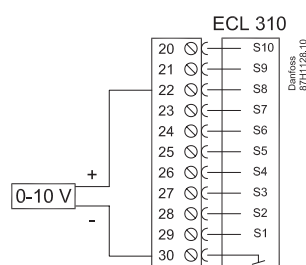

ECA 30 / 31

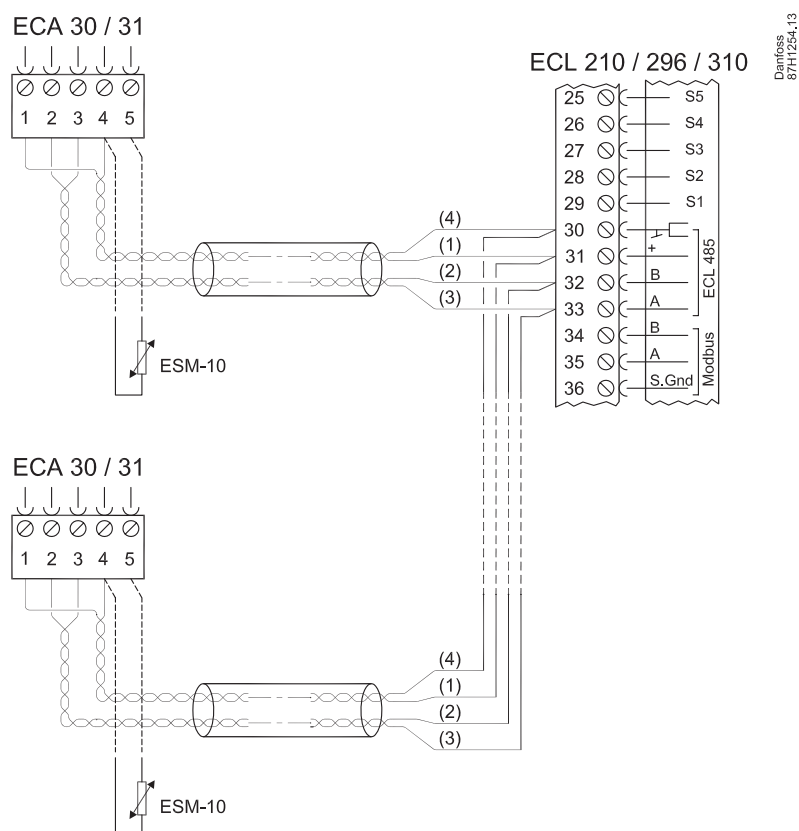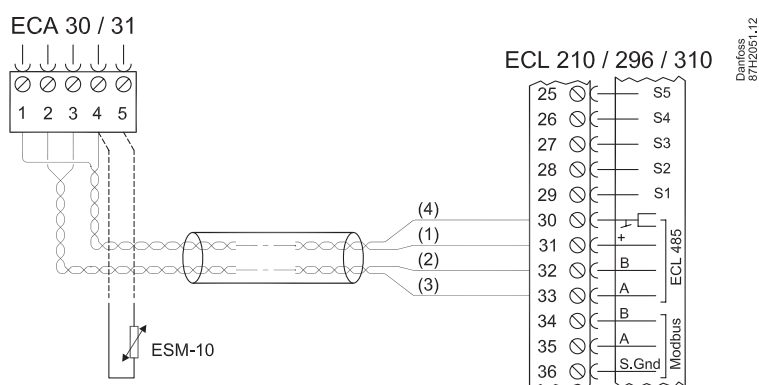


Master / slave

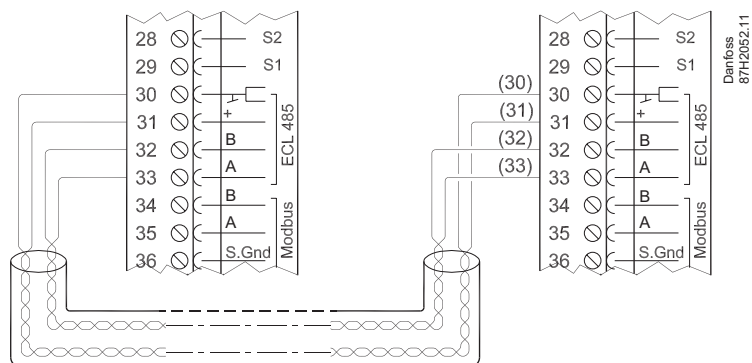


Modbus

ECL 210 / 296 / 310

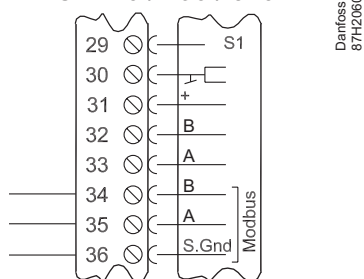


M-bus

ECL 296 / 310

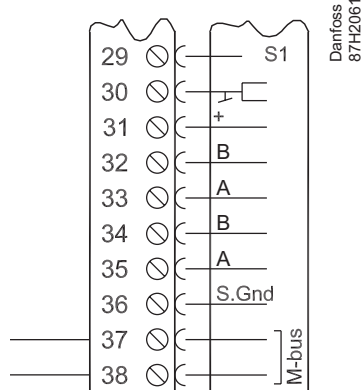



M-bus

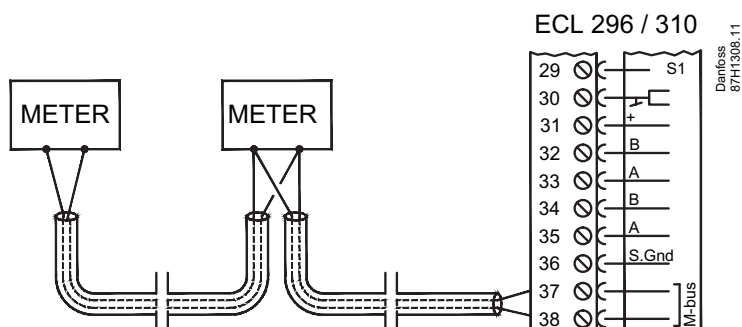


Installation Guide, ECL Comfort 310, P330

P330 (ECL 310)


 **Pt 1000** (1000 Ω / 0 °C)

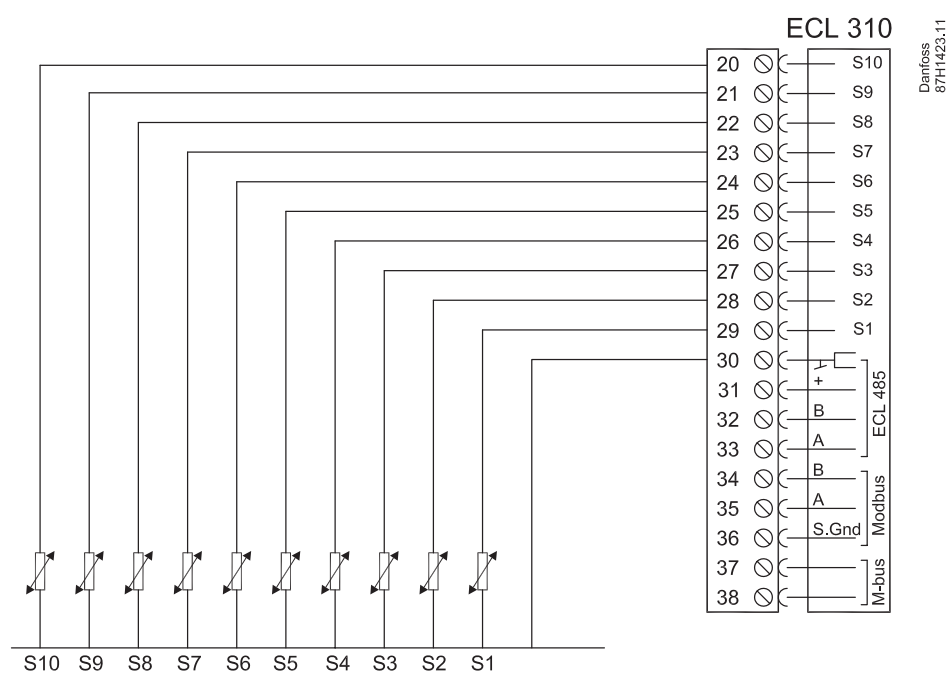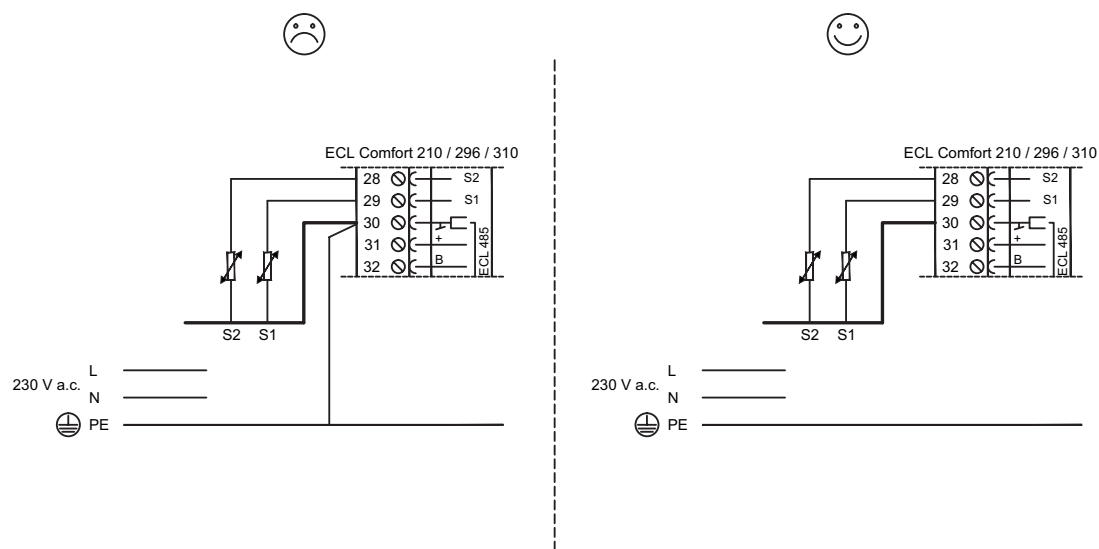

Pt 1000 (IEC 751B, 1000 Ω / 0 °C)

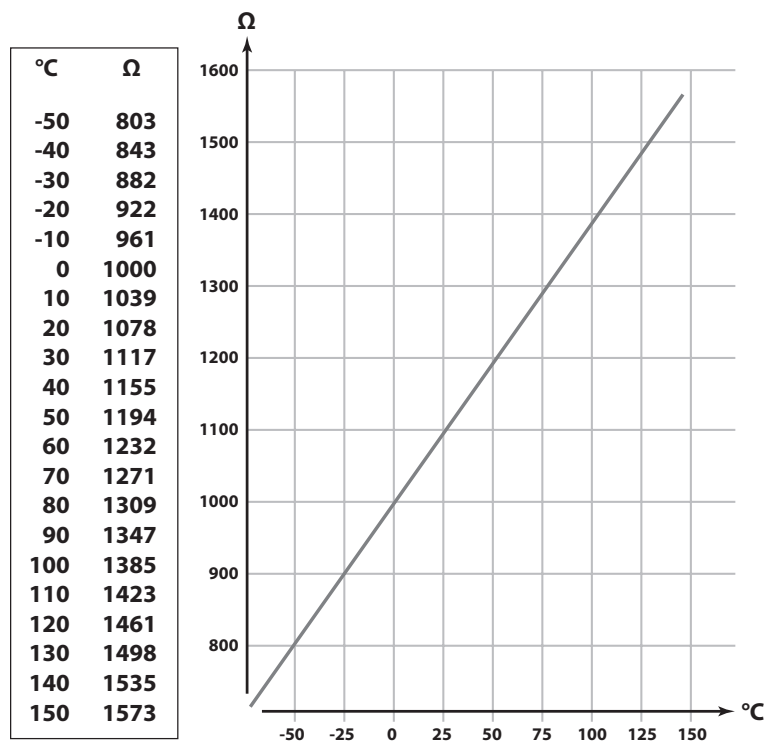


Heat curves

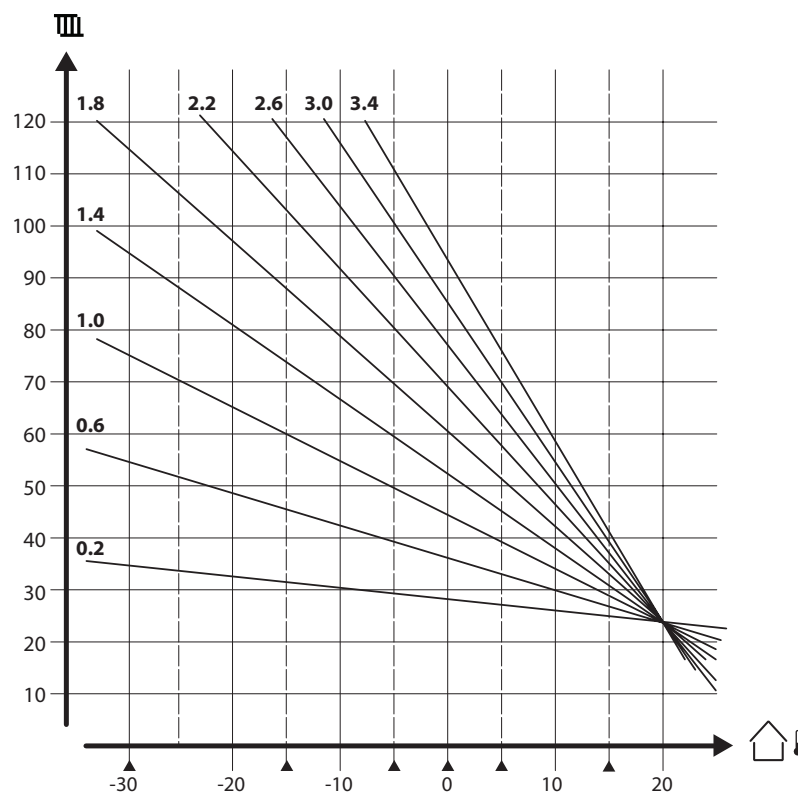


ECA 30


1

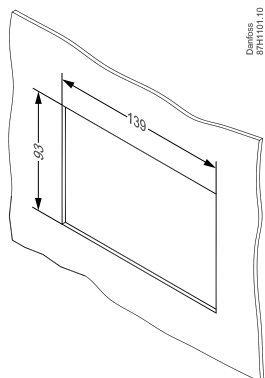


2

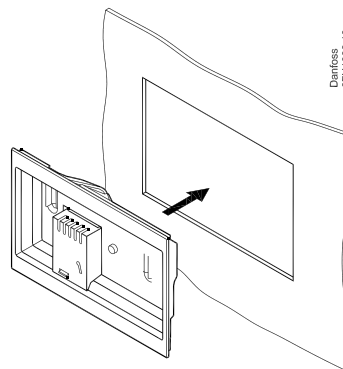


3

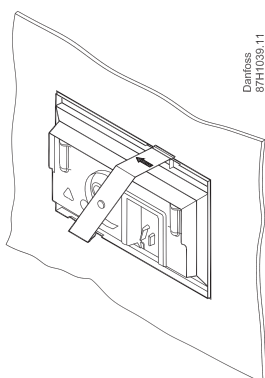


4

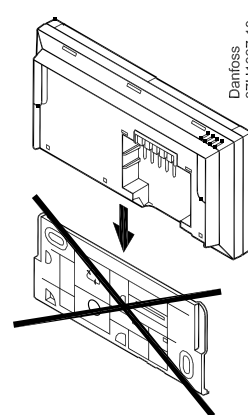


5

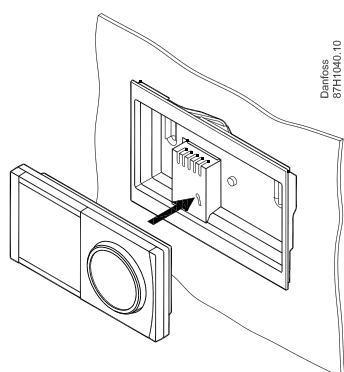


6

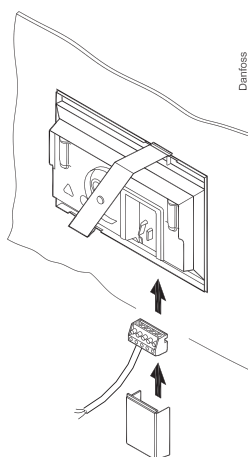




7

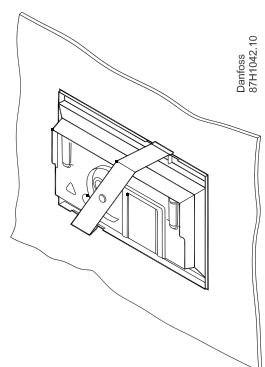

8

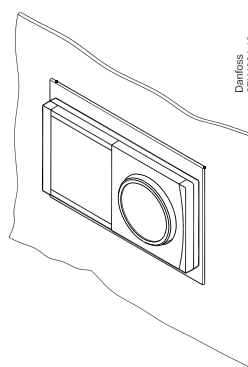

Installation Guide, ECL Comfort 310, P330

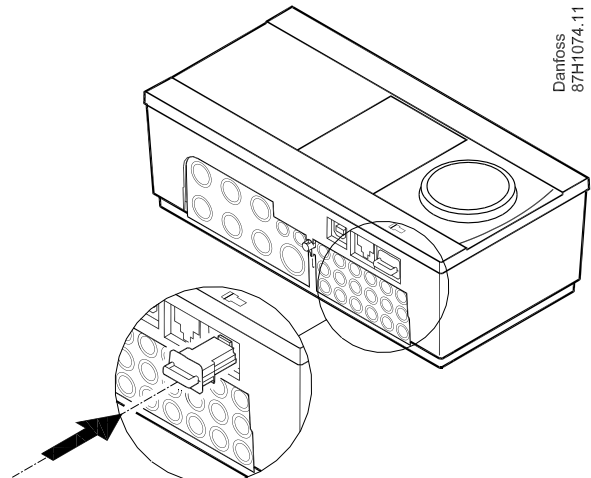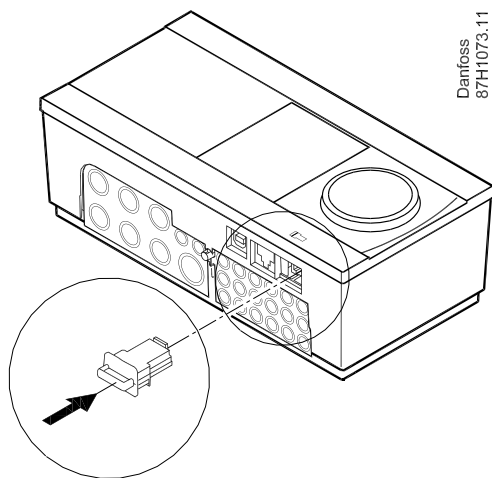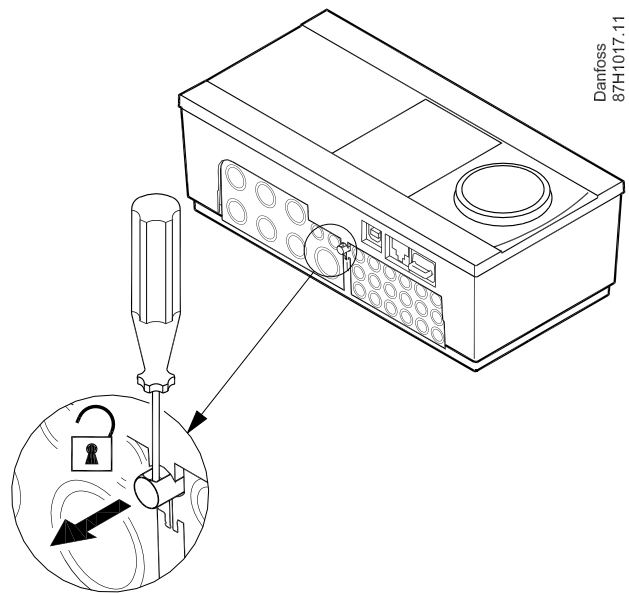

?  **ECL Comfort 310, P330: www.heating.danfoss.com**

?  **<https://www.youtube.com/user/DanfossHeating>**
-> Playlists -> How-to Videos -> District Energy installation videos



Danfoss A/S

Heating Segment • danfoss.com • +45 7488 2222 • E-Mail: heating@danfoss.com

Danfoss can accept no responsibility for possible errors in catalogues, brochures and other printed material. Danfoss reserves the right to alter its products without notice. This also applies to products already on order provided that such alterations can be made without consequential changes being necessary in specifications already agreed. All trademarks in this material are property of the respective companies. Danfoss and all Danfoss logotypes are trademarks of Danfoss A/S. All rights reserved.