

Appendix

Appendix to data sheet on Danfoss Leanheat® Monitor

List of application keys supported by Danfoss Leanheat® Monitor

Application key	Sub-application	Example	Danfoss Leanheat® Monitor without OPC	Danfoss Leanheat® Monitor with OPC Key version ¹⁾	Code no.
A214	A214.1	a + b + c + d + e	Supported	Not supported	087H3811
	A214.2	a + b	Supported	Not supported	
	A214.3	a + b	Supported	Not supported	
	A214.4	a + b	Supported	Not supported	
	A214.5	a + b + c	Supported	Not supported	
	A214.6	a + b	Supported	Not supported	
	A314.1	a + b + c	Supported	Not supported	
	A314.2	a + b + c + d	Supported	Not supported	
	A314.3	a + b	Supported	Not supported	
	A314.4	a + b + c + d + e	Supported	Not supported	
	A314.5	a + b + c + d + e	Supported	Not supported	
	A314.6	a + b + c	Supported	Not supported	
	A314.7	a + b + c	Supported	Not supported	
	A314.9	a	Supported	Not supported	
A217 / A317	A217.1	a + b + c + d	Supported	Not supported	087H3807
	A217.2	a + b	Supported	Not supported	
	A217.3	a + b + c + d	Supported	Not supported	
	A317.1	a + b + c + d	Supported	Not supported	
	A317.2	a + b	Supported	Not supported	
A230	A230.1	a + b	Supported	v1.14, v2.20, v2.23, v2.34	087H3802
	A230.1	c + d	Supported	Not supported	
	A230.2	a + b + c	Supported	Not supported	
A231 / A331	A231.1	a	Supported	Not supported	087H3805
	A231.2	a	Supported	Not supported	
	A331.1	a	Supported	Not supported	
	A331.2	a	Supported	Not supported	
A232 / A332	A232.1	a + b + c + d + e + f	Supported	Not supported	087H3812
	A332.1	a	Supported	Not supported	
	A332.2	a + b + c + d	Supported	Not supported	
	A332.3	a + b	Supported	Not supported	
	A332.4	a	Supported	Not supported	

¹⁾ DECS 2.0 - version 29 and up / newer
Key version is shown on the label on the application key and in the ECL Controller display menu:
General Controller Settings > Key Functions > Key overview

List of application keys supported by Danfoss Leanheat® Monitor (continued)

Application key	Sub-application	Example	Danfoss Leanheat® Monitor without OPC	Danfoss Leanheat® Monitor with OPC Key version ¹⁾	Code no.
A237 / A337	A237.1	a + b + c + d	Supported	v1.10, v2.14, v2.20, v2.23, v2.34	087H3806
	A237.2	a + b	Supported	v1.10, v2.14, v2.20, v2.23, v2.34	
	A337.1	a + b + c + d	Supported	v1.10, v2.14, v2.20, v2.23, v2.34	
	A337.2	a + b	Supported	v1.10, v2.14, v2.20, v2.23, v2.34	
A247 / A347	A247.1	a + b + c	Supported	v1.10, v2.20, v2.23, v2.34	087H3808
	A247.2	a + b + c	Supported	v1.10, v2.20, v2.23, v2.34	
	A247.3	a + b + c	Supported	v2.34	
	A347.1	a + b + c + d	Supported	v1.10, v2.20, v2.23, v2.34	
	A347.2	a + b + c + d	Supported	v1.10, v2.20, v2.23, v2.34	
	A347.3	a	Supported	Not supported	
A260	A260.1	a + b + c + d	Supported	v1.10, v2.20, v2.23, v2.34	087H3801
	A260.1	e + f + g	Supported	Not supported	
A266	A266.1	a + b + c	Supported	v1.10, v2.20, v2.23, v2.34	087H3800
	A266.2	a	Supported	v1.10, v2.20, v2.23, v2.34	
	A266.2	b + c	Supported	Not supported	
	A266.9	a	Supported	v2.23, v2.34	
	A266.10	a	Supported	Not supported	
A267	A267.1	a + b + c + d + e	Supported	Not supported	087H3816
A275 / A375	A275.1	a + b	Supported	Not supported	087H3814
	A275.2	a + b + c + d	Supported	Not supported	
	A275.3	a + b + c + d + e + f + g	Supported	Not supported	
	A375.1	a + b + c + d + e + f + g + h + i	Supported	Not supported	
	A375.2	a	Supported	Not supported	
	A375.3	a	Supported	Not supported	
	A375.4	a + b	Supported	Not supported	
	A375.5	a + e + f + g	Supported	Not supported	
A302 .dk only	A302.1	a + b + c + d + z	Supported	Not supported	087H3819
	A302.2	a + b	Supported	Not supported	
	A302.3	a + b + z	Supported	Not supported	
	A302.4	a	Supported	Not supported	
	A302.5	a	Supported	Not supported	
A302 .com only	A302.1	a + b + c + d	Supported	Not supported	087H3819
	A302.2	a + b	Supported	Not supported	
	A302.3	a + b	Supported	Not supported	
A318	A318.1	a + b + c + d	Supported	Not supported	087H3835

¹⁾ DECS 2.0 - version 29 and up / newer
Key version is shown on the label on the application key and in the ECL Controller display menu:
General Controller Settings > Key Functions > Key overview

List of application keys supported by Danfoss Leanheat® Monitor (continued)

Application key	Sub-application	Example	Danfoss Leanheat® Monitor without OPC	Danfoss Leanheat® Monitor with OPC Key version ¹⁾	Code no.
A319	A319.1	a	Supported	Not supported	087H3831
	A319.2	a	Supported	Not supported	
A333	A333.1	a + b + c + d + e	Supported	Not supported	087H3818
	A333.2	a	Supported	Not supported	
	A333.3	a	Supported	Not supported	
A361	A361.1	a	Supported	Not supported	087H3804
	A361.2	a	Supported	Not supported	
A367	A367.1	a + b + c + d + e	Supported	v1.10, v2.20, v2.23, v2.34	087H3813
	A367.2	a + b + c	Supported	v1.10, v2.20, v2.23, v2.34	
A368	A368.1	a	Supported	Not supported	087H3803
	A368.2	a	Supported	Not supported	
	A368.3	a	Supported	Not supported	
	A368.4	a	Supported	Not supported	
	A368.5	a	Supported	Not supported	
	A368.6	a	Supported	Not supported	
A376	A376.1	a + b	Supported	Not supported	087H3810
	A376.2	a + b	Supported	Not supported	
	A376.3	a + b	Supported	Not supported	
	A376.4	a	Supported	Not supported	
	A376.9	a + b	Supported	Not supported	
	A376.10	a	Supported	Not supported	
A377	A377.1	a + b + c	Supported	v1.10, v2.20, v2.23, v2.34	087H3817
	A377.2	a + b + c	Supported	v1.10, v2.20, v2.23, v2.34	
	A377.3	a	Supported	Not supported	
A390	A390.1	a + b + c	Supported	Not supported	087H3815
	A390.2	a	Supported	Not supported	
	A390.3	a + b	Supported	Not supported	
	A390.11	a + b + c + d + e	Supported	Not supported	
	A390.12	a + b	Supported	Not supported	
	A390.13	a + b	Supported	Not supported	

¹⁾ DECS 2.0 - version 29 and up / newer

 Key version is shown on the label on the application key and in the ECL Controller display menu:
 General Controller Settings > Key Functions > Key overview


Appendix Appendix to data sheet on Danfoss Leanheat® Monitor

List of application keys supported by Danfoss Leanheat® Monitor (continued)

Application key	Sub-application	Example	Danfoss Leanheat® Monitor without OPC	Danfoss Leanheat® Monitor with OPC Key version ¹⁾	Code no.
P314 .dk only	P314.4	a + c + d + e	Supported	Not supported	087H3841
	P314.5	a	Supported	Not supported	
	P314.6	a	Supported	Not supported	
	P314.7	a	Supported	Not supported	
	P314.8	a	Supported	Not supported	
	P314.10	a	Supported	Not supported	
	P314.11	a	Supported	Not supported	
P330 .at only	P330.1, P330.2, P330.3, P330.4, P330.5, P330.6, P330.7, P330.8, P330.9, P330.10, P330.11, P330.12, P330.13, P330.14	a	Supported	v2.16, v2.32, v2.34	087H3840
	P330.15	a	Supported	v2.32, v2.34	
P348 .com only	P348.1	a + b + c + d	Supported	Not supported	087H3843
P501 .dk only	P501.1	a	Supported	Not supported	087H3842

¹⁾ DECS 2.0 - version 29 and up / newer
Key version is shown on the label on the application key and in the ECL Controller display menu:
General Controller Settings > Key Functions > Key overview

Key version (example):

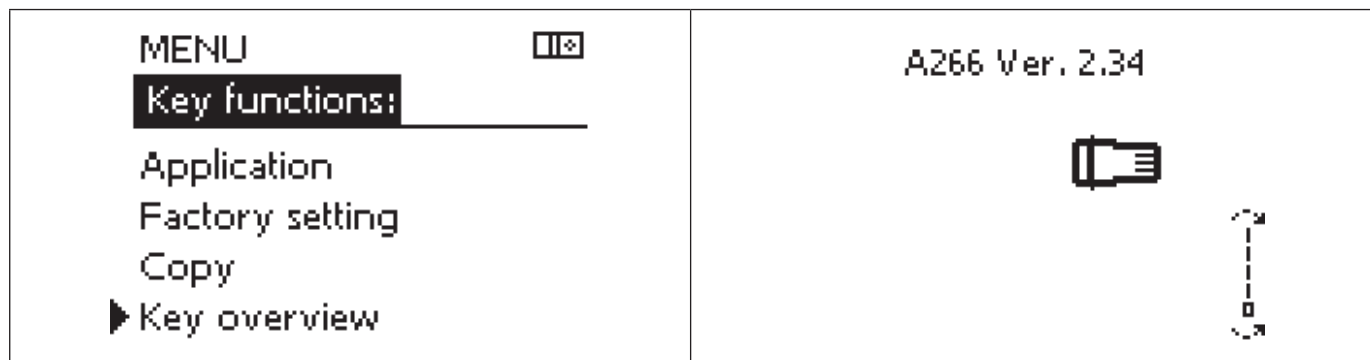

Danfoss A/S
Climate Solutions • danfoss.com • +45 7488 2222

Any information, including, but not limited to information on selection of product, its application or use, product design, weight, dimensions, capacity or any other technical data in product manuals, catalogues descriptions, advertisements, etc. and whether made available in writing, orally, electronically, online or via download, shall be considered informative, and is only binding if and to the extent, explicit reference is made in a quotation or order confirmation. Danfoss cannot accept any responsibility for possible errors in catalogues, brochures, videos and other material. Danfoss reserves the right to alter its products without notice. This also applies to products ordered but not delivered provided that such alterations can be made without changes to form, fit or function of the product.
All trademarks in this material are property of Danfoss A/S or Danfoss group companies. Danfoss and the Danfoss logo are trademarks of Danfoss A/S. All rights reserved.