

Instructions

AKS 25

Pt 500 ohm

 


084R9553



RI5FB100


084R9553




AKS25A



 AKS25W



AKS25W

 

AKS25W




AKS25D



AKS21W

084R9553

For serial application

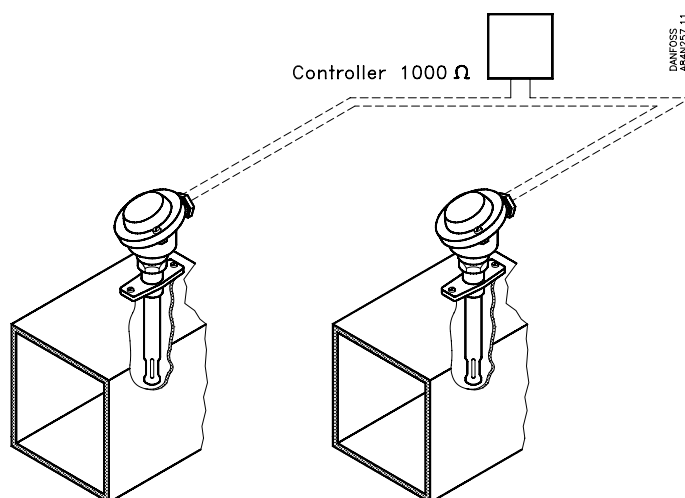

Pt 500 ohm

Ohm	°C	°F
402	-50	-58
404	-49	-56
406	-48	-54
407	-47	-53
409	-46	-51
411	-45	-49
413	-44	-47
415	-43	-45
417	-42	-44
419	-41	-42
421	-40	-40
423	-39	-38
425	-38	-36
427	-37	-35
429	-36	-33
431	-35	-31
433	-34	-29
435	-33	-27
437	-32	-26
439	-31	-24
441	-30	-22
443	-29	-20
445	-28	-18
447	-27	-17
449	-26	-15
451	-25	-13
453	-24	-11
455	-23	-9
457	-22	-8


Ohm	°C	°F
459	-21	-6
461	-20	-4
463	-19	-2
465	-18	0
467	-17	1
469	-16	3
471	-15	5
473	-14	7
475	-13	9
477	-12	10
479	-11	12
480	-10	14
482	-9	16
484	-8	18
486	-7	19
488	-6	21
490	-5	23
492	-4	25
494	-3	27
496	-2	28
498	-1	30
500	0	32
502	1	34
504	2	36
506	3	37
508	4	39
510	5	41
512	6	43
514	7	45

Ohm	°C	°F
516	8	46
518	9	48
520	10	50
522	11	52
523	12	54
525	13	55
527	14	57
529	15	59
531	16	61
533	17	63
535	18	64
537	19	66
539	20	68
541	21	70
543	22	72
545	23	73
547	24	75
549	25	77
551	26	79
553	27	81
555	28	82
556	29	84
558	30	86
560	31	88
562	32	90
564	33	91
566	34	93
568	35	95


Approx. 2 ohm/°C

Approx. 1.1 ohm /°F


AKS 25A

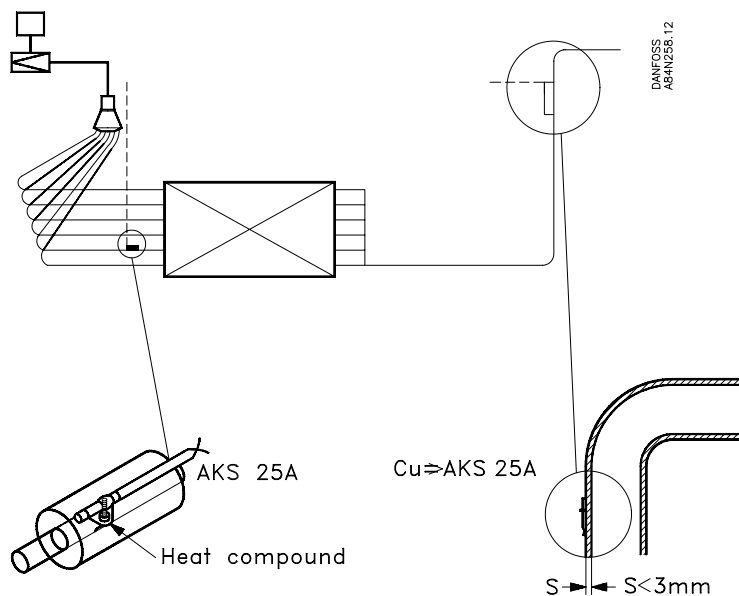


AKS 25W

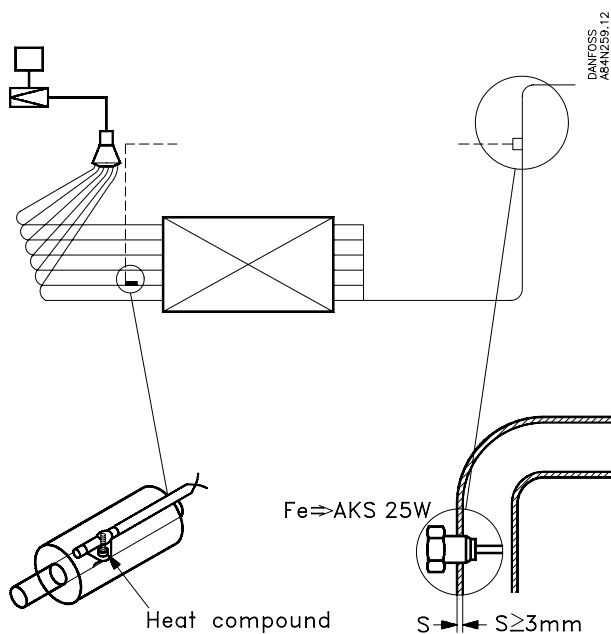

AKS 25W

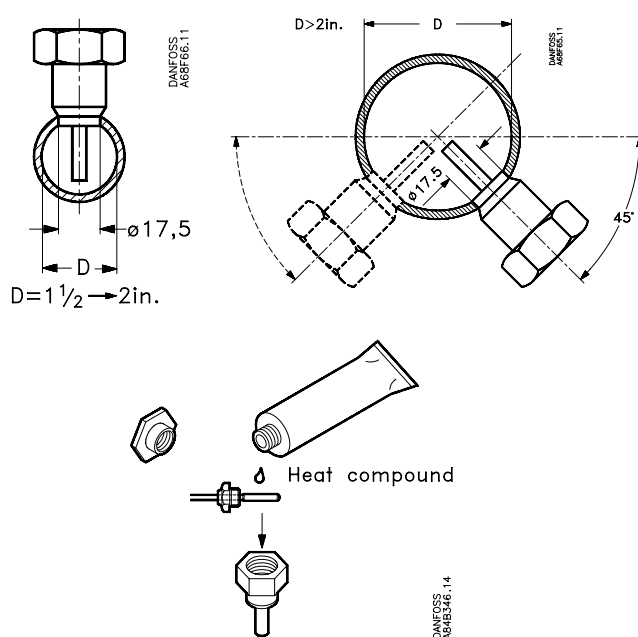

AKS 25W

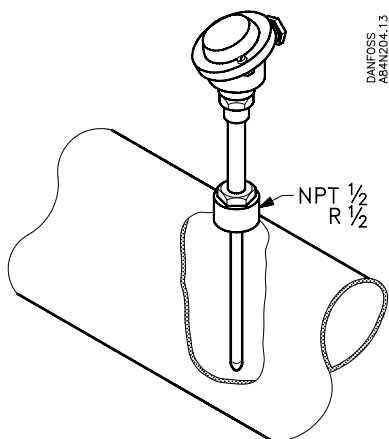

AKS 25D

