

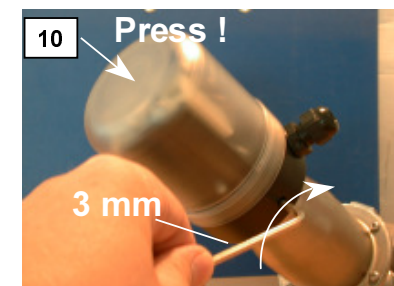
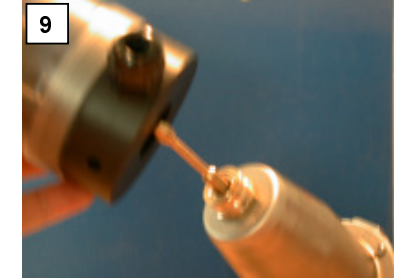
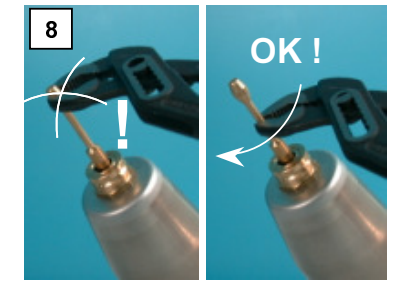
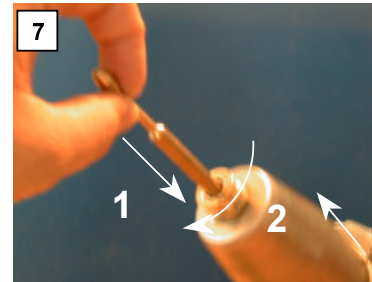
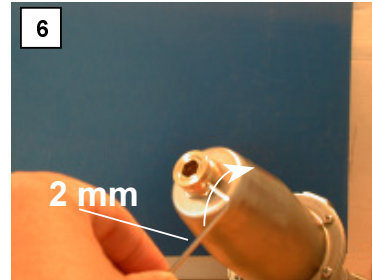
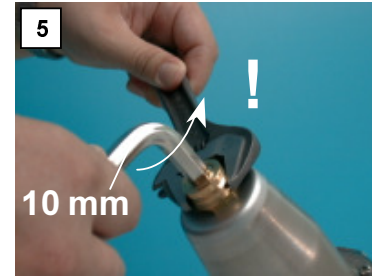
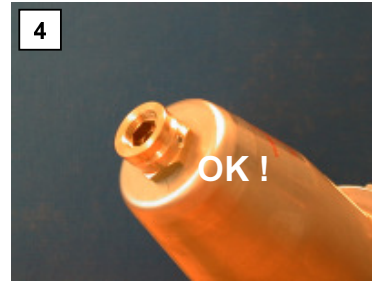
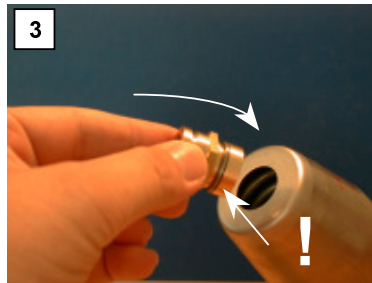


Instructions for position indicator

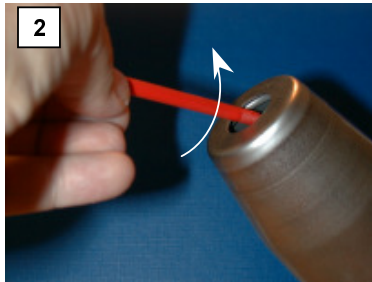





x 1 x 1 x 1

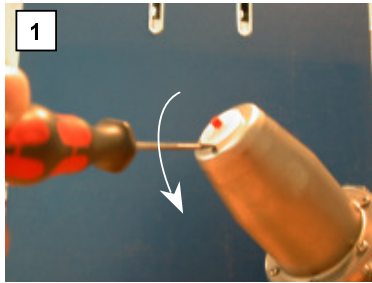




Indstilling
Adjustment
Einstellung
Ajustement



Indstilling
Adjustment
Einstellung
Ajustement

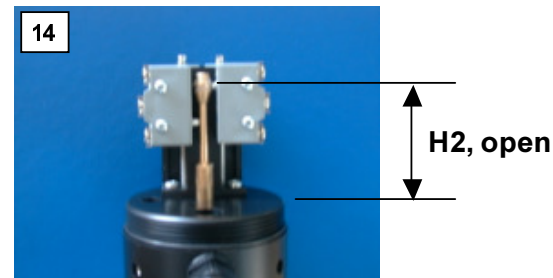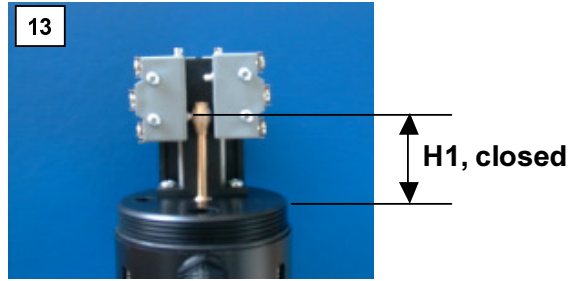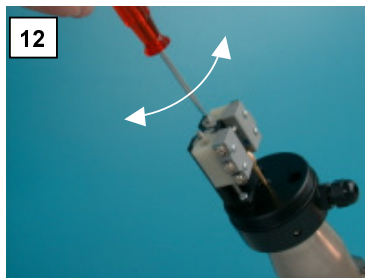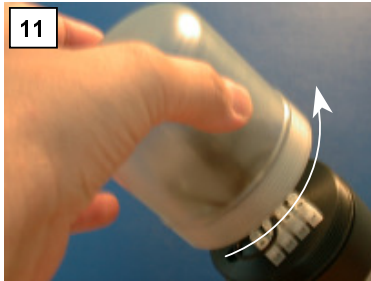

Forbindelse
Connection
Anschluß
Connection

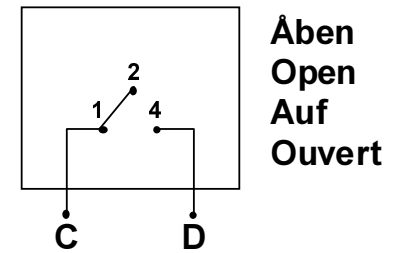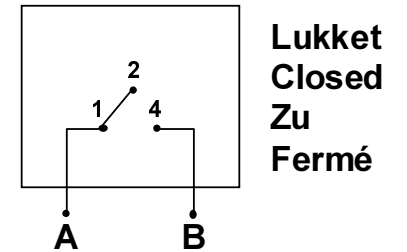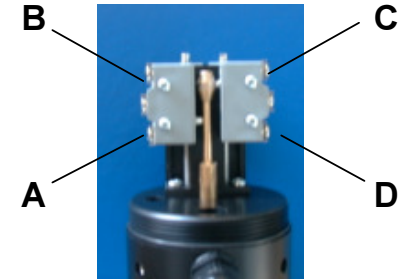

	HP 210 NC		
DN	H1, [mm]	H2, [mm]	
15	24	41	Preset Value
20	22	48	
25	22	53	
32	21	51	
40	21	51	
50	21	51	