




Instructions


EKA 163B

EKA 164B



REFRIGERATION AND
AIR CONDITIONING

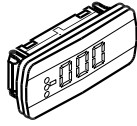




EKA 163B
Remote display
(084B8574)

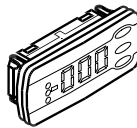

EKA 164B
Remote setting display
(084B8575, multi purpose)

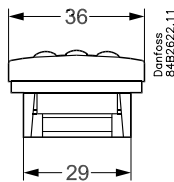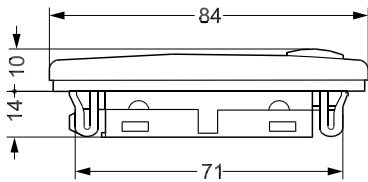

$0 < t_{amb} < +55^{\circ}\text{C}$
Non condensing
IP 20

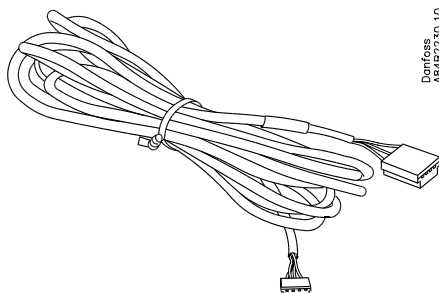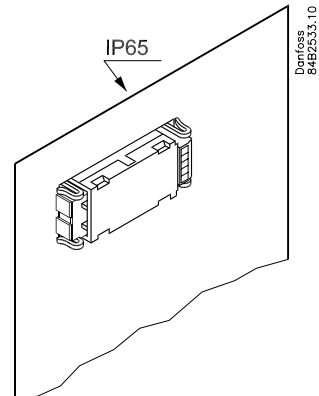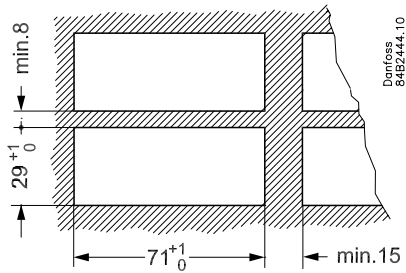

Max. 10 m
(2 m: 084B7298)
(6 m: 084B7299)