



REFRIGERATION AND
AIR CONDITIONING

Instructions

Analog output module


AK-OB 110






080R9267




RI8MH253

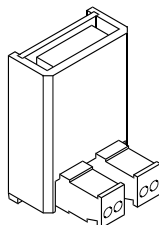

Montage / Assembly / Einbau / Montaje

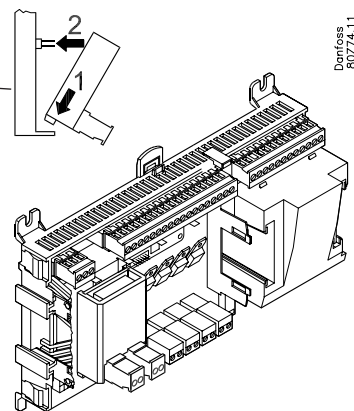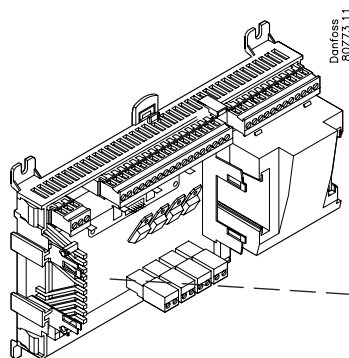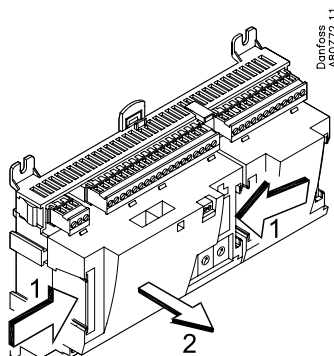

Tilslutning / Connection / Anschluß / Raccordement / Conexión

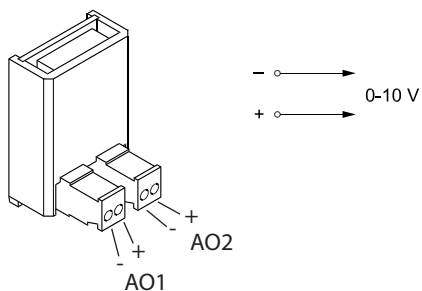

	Modul Module Módulo	Punkt Point Punto	Type Typ Tipo	Max
AO1	1	24	0 - 10 V	2.5 mA
AO2	1	25	0 - 10 V	2.5 mA

