

D Montagehinweis Rändelmutter

GB Installation instruction knurled nut

F Instruction de service écrou moleté

CN 滚花螺母安装说明

ENGINEERING
TOMORROW



Danfoss

Bei Montage von Magnetspulen mit $\varnothing 16$ mm,
die Rändelmutter mit Schaft verwenden.

When assembling solenoid coils with $\varnothing 16$ mm,
use the knurled nut with shank.

Pour le montage de bobines magnétiques de
 $\varnothing 16$ mm, utiliser l'écrou moleté avec tige.

当装配电磁线圈的孔为 $\varnothing 16$ mm 时，
请使用带柄的滚花螺母。

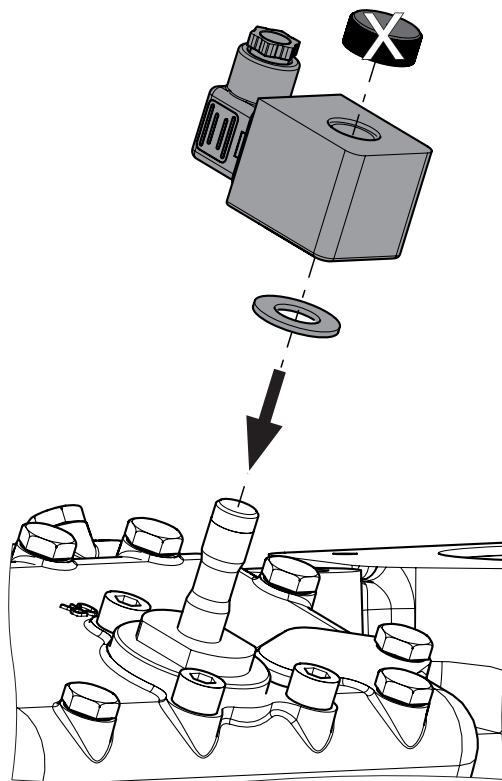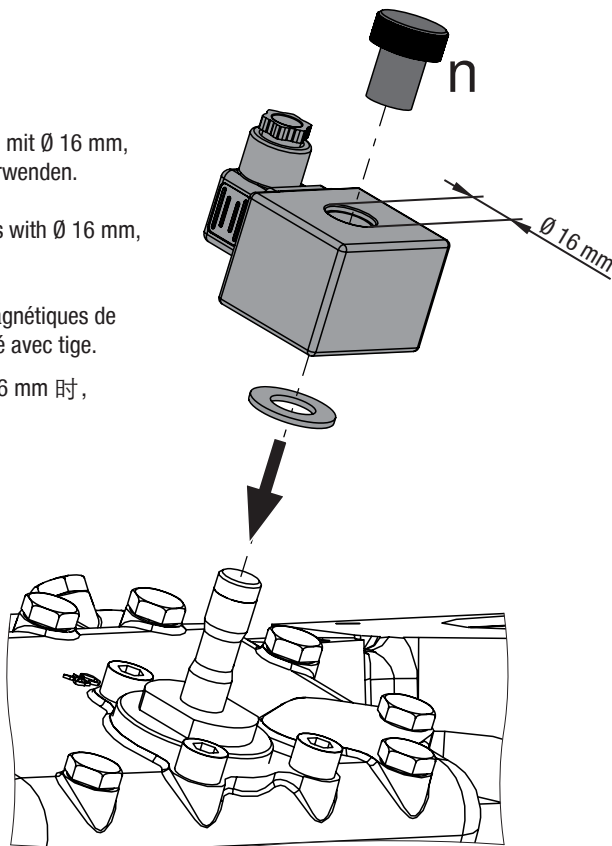

ENGINEERING
TOMORROW



Danfoss A/S

Climate Solutions • danfoss.com • +45 7488 2222

Any information, including, but not limited to information on selection of product, its application or use, product design, weight, dimensions, capacity or any other technical data in product manuals, catalogues descriptions, advertisements, etc. and whether made available in writing, orally, electronically, online or via download, shall be considered informative, and is only binding if and to the extent, explicit reference is made in a quotation or order confirmation. Danfoss cannot accept any responsibility for possible errors in catalogues, brochures, videos and other material. Danfoss reserves the right to alter its products without notice. This also applies to products ordered but not delivered provided that such alterations can be made without changes to form, fit or function of the product.

All trademarks in this material are property of Danfoss A/S or Danfoss group companies. Danfoss and the Danfoss logo are trademarks of Danfoss A/S. All rights reserved.