



Instructions


KF 2, KF 3

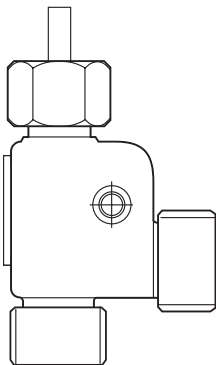


KF 2

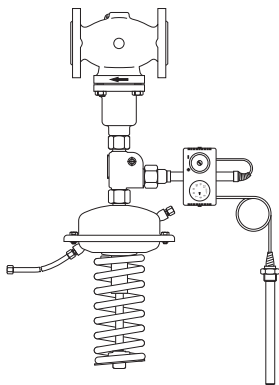


AFT./KF 2/AFD/VFG 2

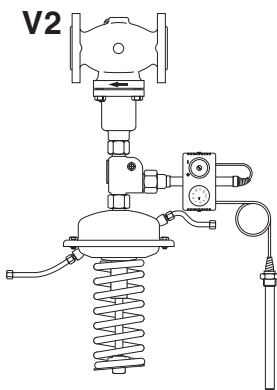


AFT./KF 2/AFP/VFG 2

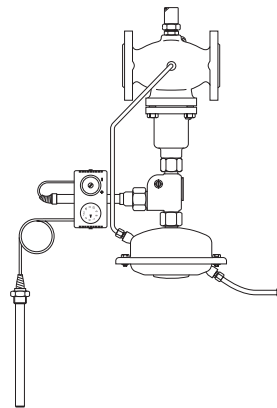


AFT./KF 2/AFP-B-F/VFQ 2

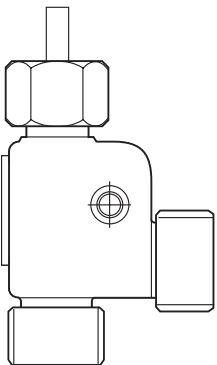


KF 3

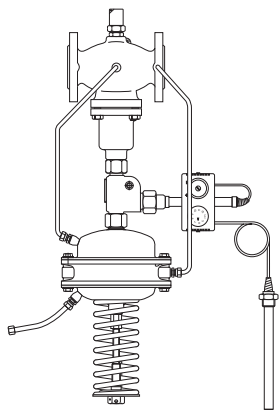


AFT./KF 2/AFPQ/VFQ 2

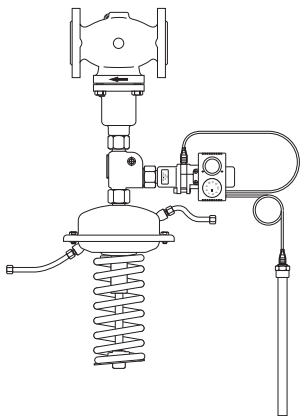

STFW/KF 2/AFP/VFG 2

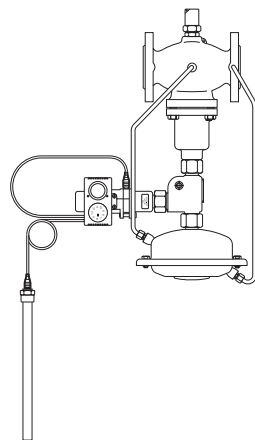

STWF/KF 2/AFQ/VFQ 2

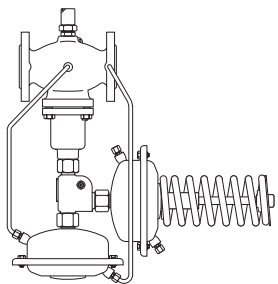

AFT./KF 3/AFQ/AFP/VFQ 2