

Installation Guide

Dry Levelling Compound for SpeedUp and SpeedUp Eco

1 Installation of dry levelling compound for SpeedUp and SpeedUp Eco



Fig. 1: Determine your datum and your compound level (min. 10 mm, max. 60 mm).



Fig. 2: Pour lines of compound to a moderate height, the distance of the lines depending on the width of the leveling rule.



Fig. 3: With large flat trowel spread and flatten the compound.



Fig. 4: Position the parallel guides on each of the lines and adjust according to the required height.



Fig. 5: Continue to fill the floor in sections with compound and then position the leveling rule on the parallel guides.



Fig. 6: During the leveling additional compound may be required.

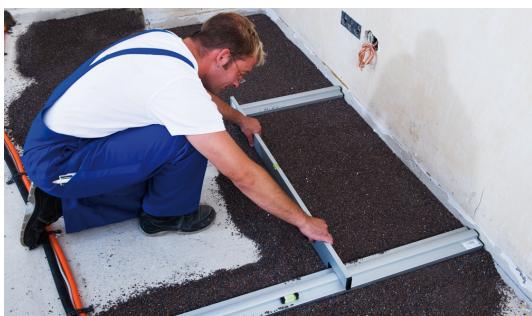


Fig. 7: In larger rooms the leveling of the compound will have to be finished in several adjacent lines.



Fig. 8: Compound at the edges may have to be worked again with trowel.



Fig. 9: Insulation panels serve as walk boards or walk islands and so prevent damage.



Fig. 10: Once finished begin laying of the additional insulation.

Danfoss A/S
Heating Solutions
Haarupvænget 11
8600 Silkeborg
Denmark
Phone: +45 7488 8000
Fax: +45 7488 8100
Email: ComfortControlsInternet@danfoss.com
www.heating.danfoss.com

Danfoss can accept no responsibility for possible errors in catalogues, brochures and other printed material. Danfoss reserves the right to alter its products without notice. This also applies to products already on order provided that such alterations can be made without subsequent changes being necessary in specifications already agreed. All trademarks in this material are property of the respective companies. Danfoss and the Danfoss logo are trademarks of Danfoss A/S. All rights reserved.