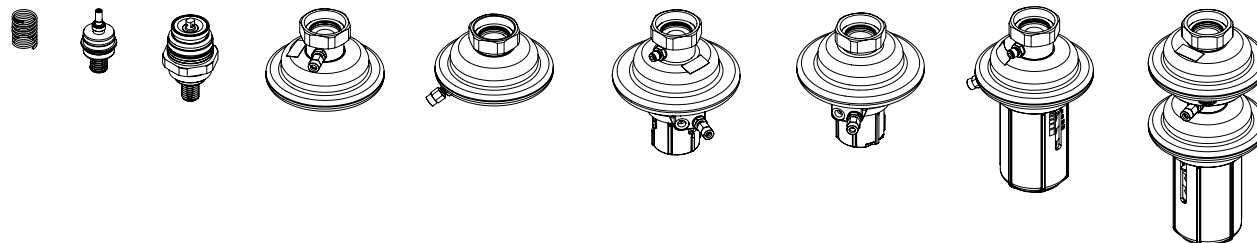


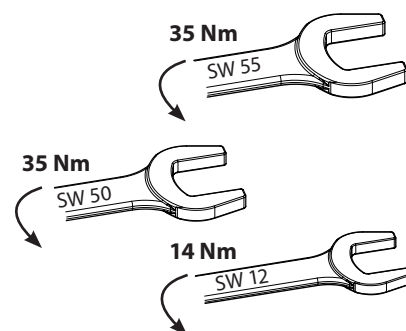
Installation Guide

Service kits



A	PN	DN	Δp (bar)							Code No.
			$0.05 \div 0.5$ $0.1 \div 0.5$	$0.2 \div 1.0$	$0.3 \div 2.0$	$0.8 \div 1.6$	0.2	0.3	0.5	
	16	15 ÷ 32	-	×		-	×	-	-	88802586
			-	-		-	-	×	-	88802519
			-	-		-	-	-	×	88802594
			-	-		×	-	-	-	88802608
	25	15 ÷ 50		-	-		×		-	88835920
		15 ÷ 25		-	-		-		×	88835930
		32 ÷ 50		-	-		-		×	88835940

B	PN	DN	Δp_s (bar)							Code No.
			$0.1 \div 0.5$	$0.2 \div 1.0$	$0.3 \div 2.0$	$0.8 \div 1.6$	0.2	0.3	0.5	
	16	15 ÷ 32					×			88802586
	25	15 ÷ 25					×			88835920
		32 ÷ 50					-			-

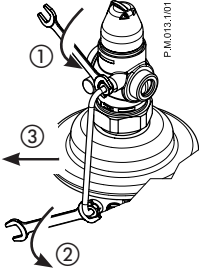
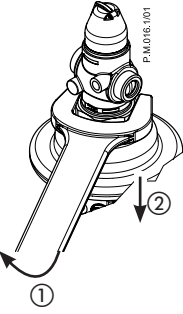
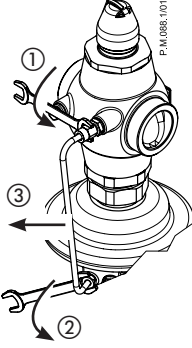
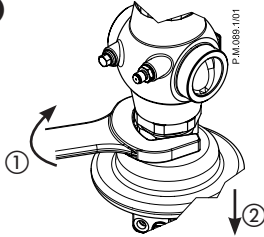
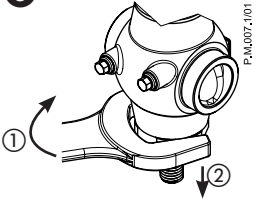
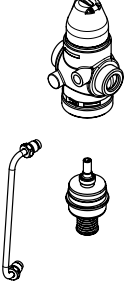
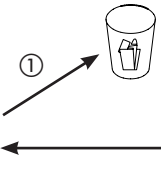
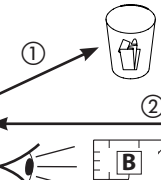
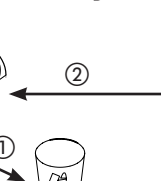
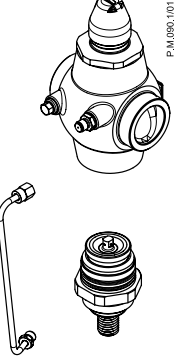
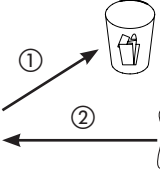
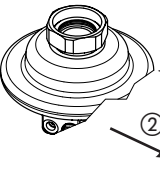
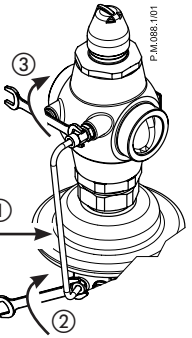
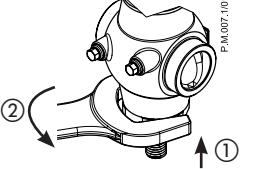
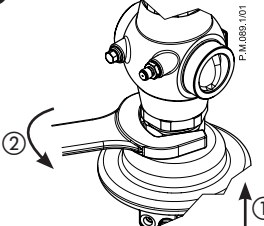
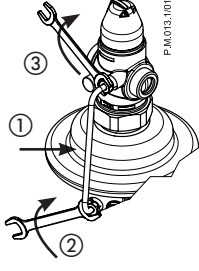
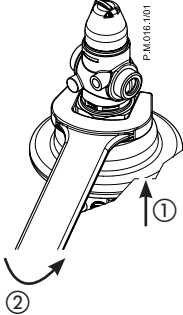
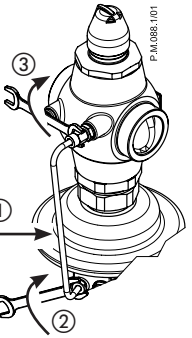
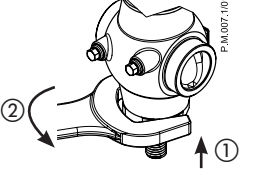
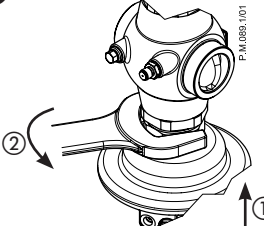


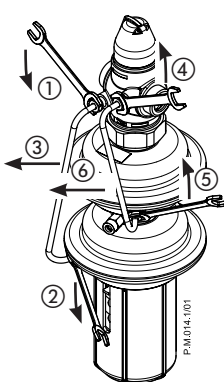
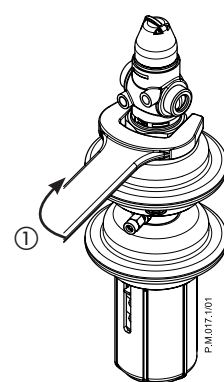
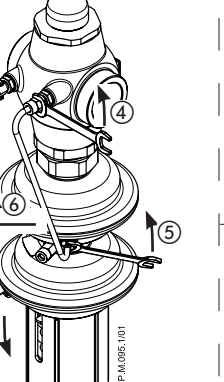
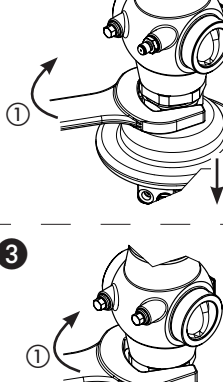
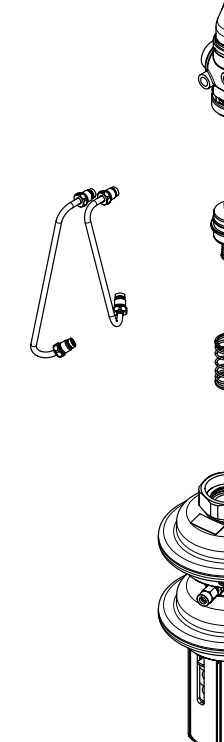
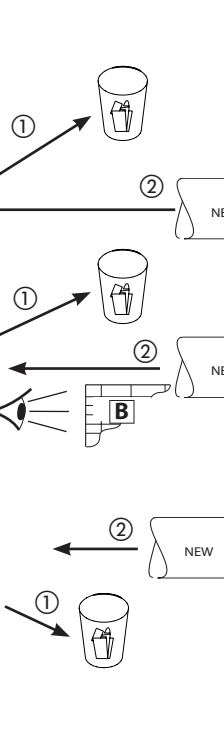
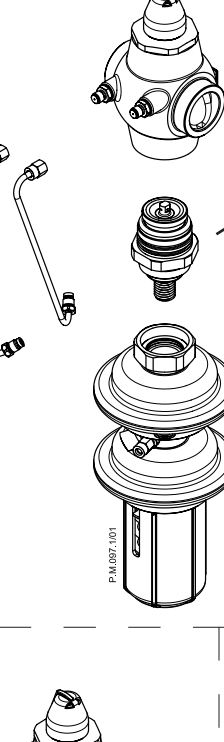
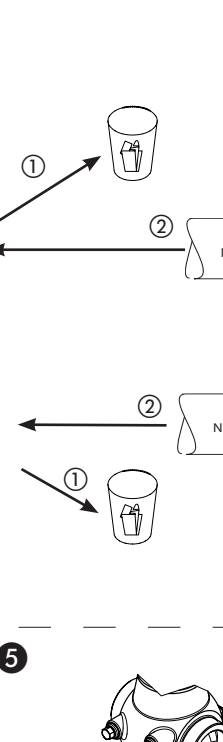
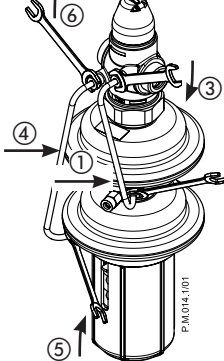
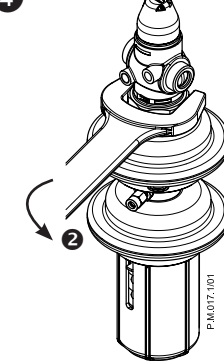
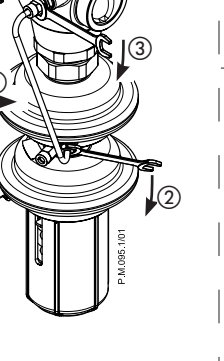
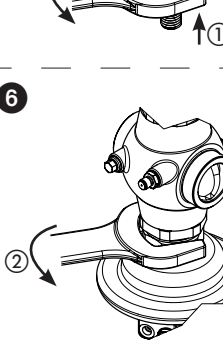
Pag No.	PN	Type	Valve body material
2	25	AVP, AVP-F, AVPB, AVPB-F, AVPBT-F, AVD, AVQ, AVQT, AVQM, AVQMT	M1
2			M2
3		AVPQ, AVPQ-F	M1
3			M2
4		AVPQ 4, AVPQ 4-F	M1
4			M2
5		AVPA	M1
5			M2

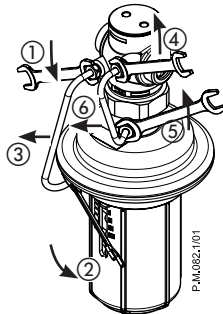
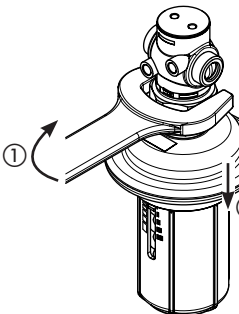
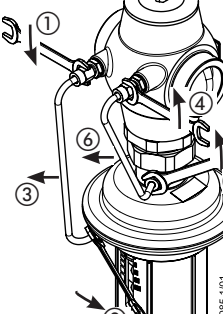
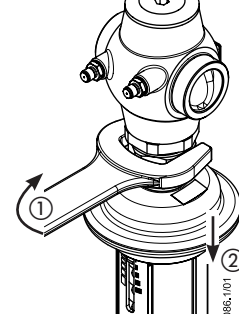
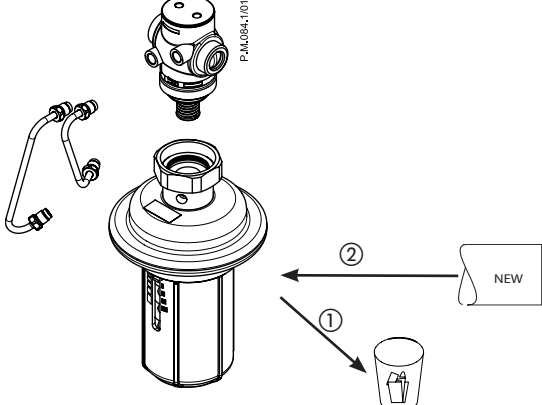
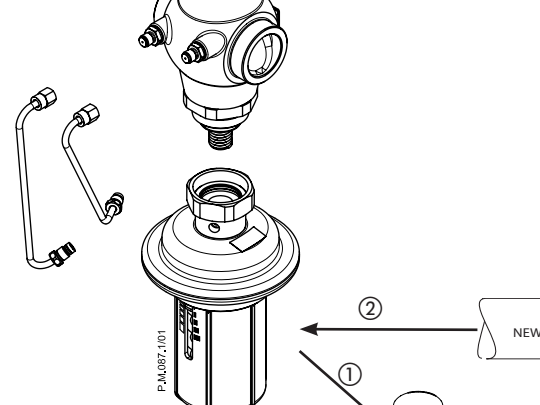
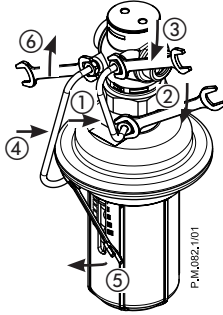
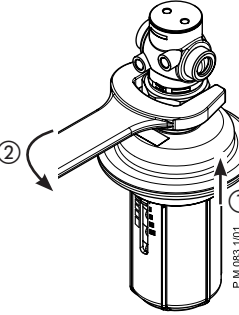
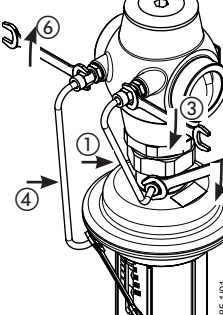
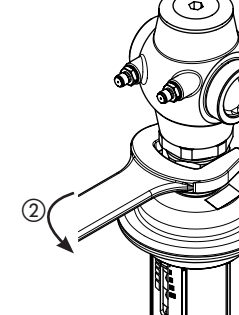
M1	CuSn5ZnPb (Rg5)
M2	EN-GJS-400-18-LT (GGG 40.3)

Installation Guide Service kits

PN 25	AVP, AVP-F, AVPB, AVPB-F, AVPBT-F, AVD AVQ, AVQT, AVQM, AVQMT	A B	M1	PN 25	AVP, AVP-F, AVPB, AVPB-F, AVPBT-F, AVD AVQ, AVQT, AVQM, AVQMT	M2
1	2		1	2 3		
3 AVD →	1 2 NEW 1 2 NEW 1 2 NEW		4 1 2 NEW 1 2 NEW 1 2 NEW	4 1 2 NEW 1 2 NEW 1 2 NEW		
5	4		7	5 6		

PN 25 AVPQ, AVPQ-F	B M1	PN 25 AVPQ, AVPQ-F	M2
1 	2 	1 	2  3 
3    	4    	7 	5  6 
5 	4 	7 	5  6 

PN 25	AVPQ 4, AVPQ 4-F	B	M1	PN 25	AVPQ 4, AVPQ 4-F	M2
1 	2 			1 	2 	
3 	2 			4 	2 	
5 	4 			7 	5 	

PN 25	AVPA	M1	PN 25	AVPA	M2
1  PAM082.1/01	2  PAM083.1/01	1  PAM085.1/01	2  PAM086.1/01		
3  PAM084.1/01	3  PAM087.1/01				
5  PAM082.1/01	4  PAM083.1/01	5  PAM085.1/01	4  PAM086.1/01		

