

Installation guide

Oil separator





 
Type OUB

Refrigerants:

R22, R1270*, R134a, R290*, R404A, R407A, R407C, R407F,
R438A, R448A, R449A, R450A, R452A, R507A, R513A, R600*, R600a*

For complete list of approved refrigerants, visit www.products.danfoss.com and search for individual code numbers, where refrigerants are listed as part of technical data.

*) OUB 1 only

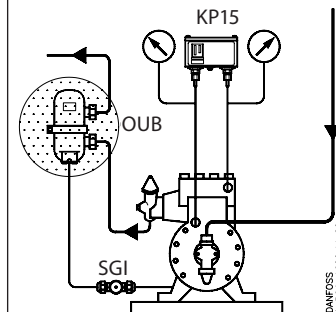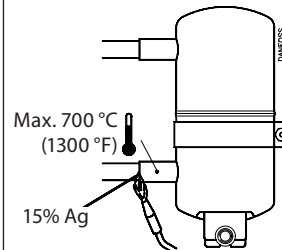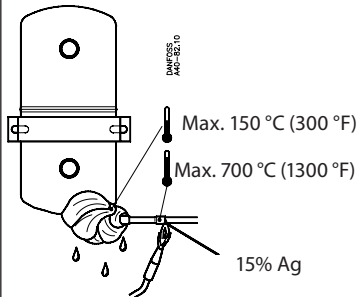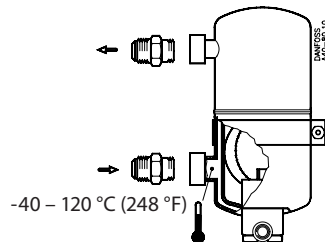

Recommended tightening torque of unions:

OUB 1: 40 Nm
OUB 4: 90 Nm

Max. working pressure:

PS/MWP = 28 bar/406 psig