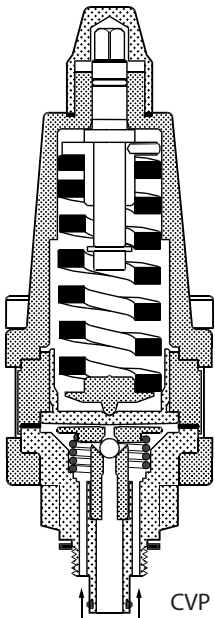
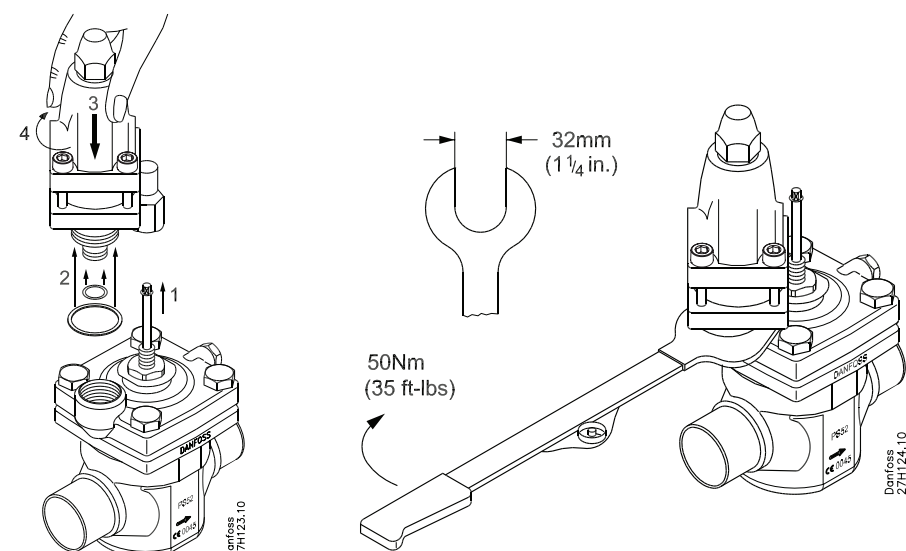
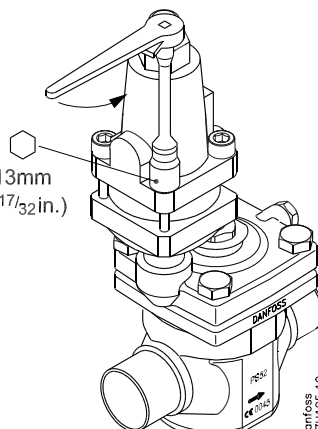
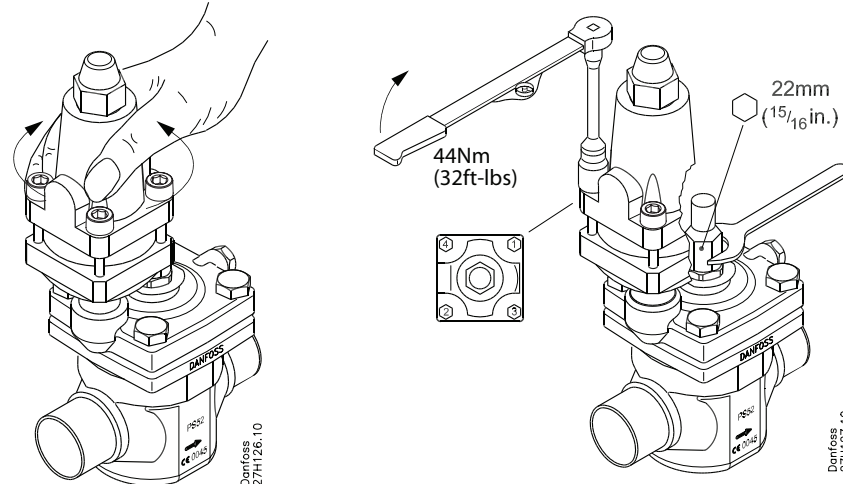
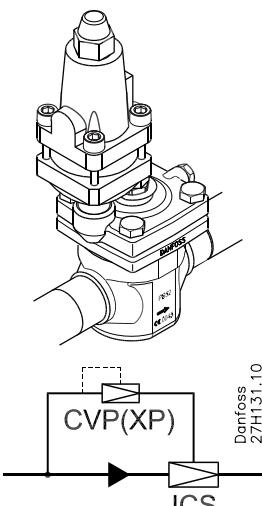
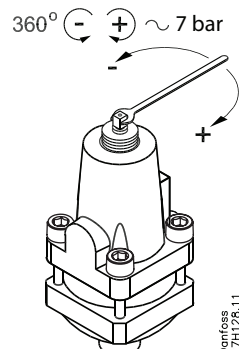
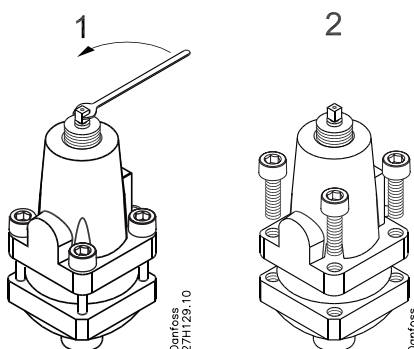


Installation Guide

CVP (XP)

Pilot valve (regulating range: 25 - 52 bar)

027R9780  CVP (XP) Danfoss 27H111.10	HCFC, HFC, R717 (Ammonia), R744 (CO₂)  32mm (1 1/4 in.) 50Nm (35 ft-lbs) Danfoss 27H123.10 Danfoss 27H124.10
 13mm (17/32 in.) Danfoss 27H125.10	 22mm (15/16 in.) 44Nm (32 ft-lbs) Danfoss 27H126.10 Danfoss 27H127.10
 CVP (XP) ICS Danfoss 27H131.10	 360° ~ 7 bar Danfoss 27H128.11  1 2 Danfoss 27H129.10 Danfoss 27H130.10 Danfoss 27H127.10

CVP (XP)

Pilot valve (regulating range: 10 - 40 bar)

