


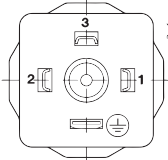
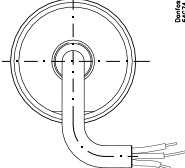
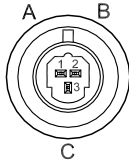

 

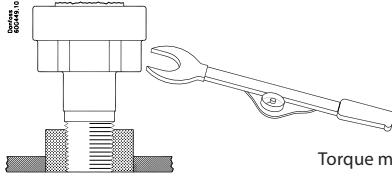




Installation Guide

Pressure Transmitters

MBS 1900

064R9301	 	<p>Electrical connection:See product label Elektrisk tilslutning:Se produktskilt Elektrischer Anschluss:Siehe Produktschild Raccordement électrique:.....Voir étiquette du produit Conexión eléctrica:.....Ver la pegatina en el producto Connessione elettrica:vedi etichetta sulla confezione</p>			064R9301
		<p>EN 175301-803</p>  <p>Not connected to enclosure Ikke forbundet til kapsling Kein Anschluss an Gehäuse Pas connecté au boîtier No conectado a la cubierta Non collegato al corpo</p>	<p>2 m cable</p> 	<p>Round Packard metripack 150.2</p> 	
					
		 <p>Torque max. 20Nm</p>			
	 	<p>American and Canadian approvals: Must be powered by Class 2 power supply Temperature indicating and regulating equipment acc. to UL 873, file no. E31024</p>			