 


Installation Guide 安装说明
Check Valves单向阀
Type CCV



Refrigerants:

制冷剂:

For a complete list of approved refrigerants, visit <http://store.danfoss.com/> and search for individual code numbers, where refrigerants are listed as part of product details.

对于完整的制冷剂列表, 请参考<http://store.danfoss.com/>网站搜索产品代码, 制冷剂是产品详细信息的一部分。

Max. working pressure:

最大工作压力:

CCV 6s-28s:

45 bar/653 psig

CCV 35s:

45 bar/653 psig (032B1039)

35 bar/508 psig (032B1035)

Media temperature:

介质温度:

-50 °C - 155 °C /

-58 °F - 311 °F

Max. backward differential pressure:

最大背向压差:


CCV 6s-22s:

45 bar/653 psig

CCV 28s-35s:

30 bar/435 psig in liquid line

40 bar/580 psig in gas line

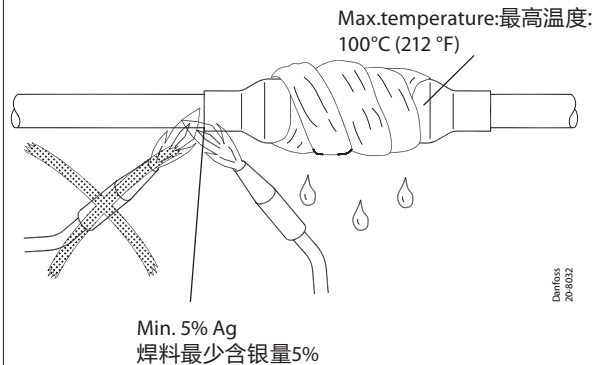

Danfoss
20-8032

Installation position:

安装位置:

