

Data Sheet

Connecto Connection Kits

For use with self-regulating cables

General Information



Danfoss Connecto NA is a family of connection kits for self-regulating heating cables (trace heaters). The Connecto NA connection kits are simple and safe to use, yet faster to install and more cost effective than conventional systems. They can be used with Danfoss:

- PX Pipe Trace Heating Systems
- RX-C Roof and Gutter De-Icing Systems

Ordering Information


Code No.	Product Description
088L0760	Power/End Kit : NA-B-PK
088L0761	Power Kit: NA-B-P
088L0762	Splice Kit: NA-B-S
088L0763	Powered Splice Kit: NA-B-PS
088L0764	T-Splice Kit: NA-B-T
088L0765	Powered T-Splice Kit: NA-B-PT
088L0766	X-Splice Kit: NA-B-X
088L0767	Silicone end seal (5 pcs.) NA-B-E

Technical Data






Operating Voltage	Max. 250 VAC
Current	Max. 16A
Ambient Temperature Range	-40 °F to 185 °F / -40 °C to 85 °C
Operation Temperature Range	-40 °F to 150 °F / -40 °C to 65 °C
Protection Class	NEMA Type 4X / IP66

Typical Application

For use with self-regulating cables.

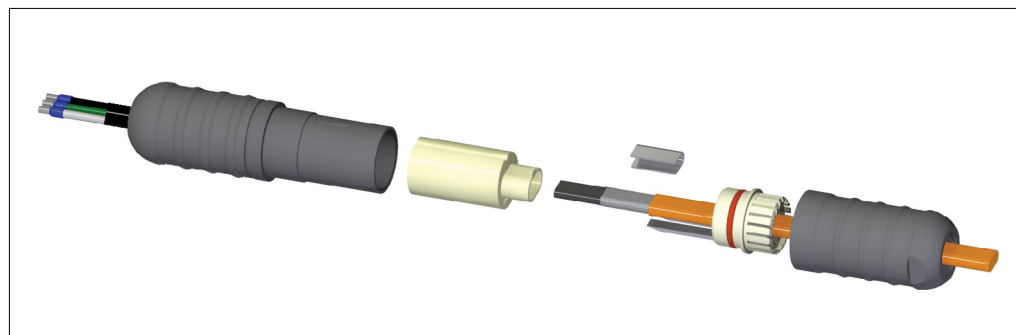

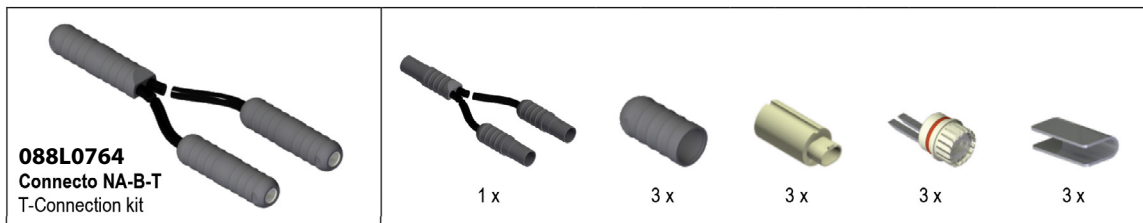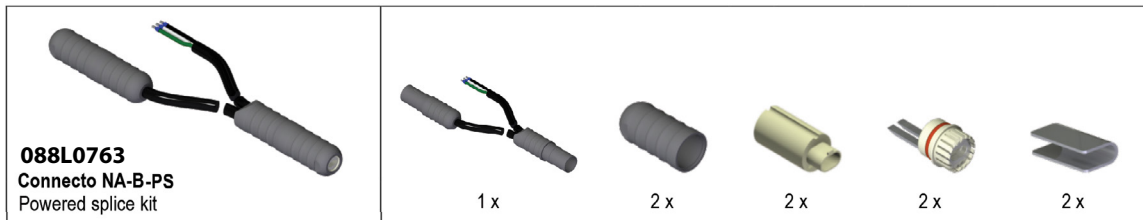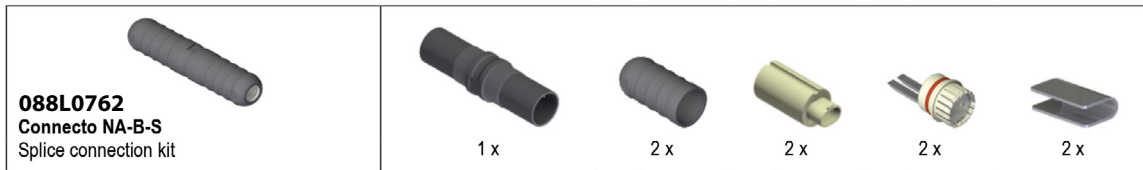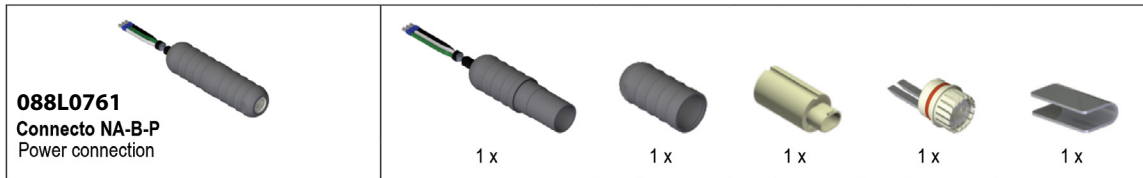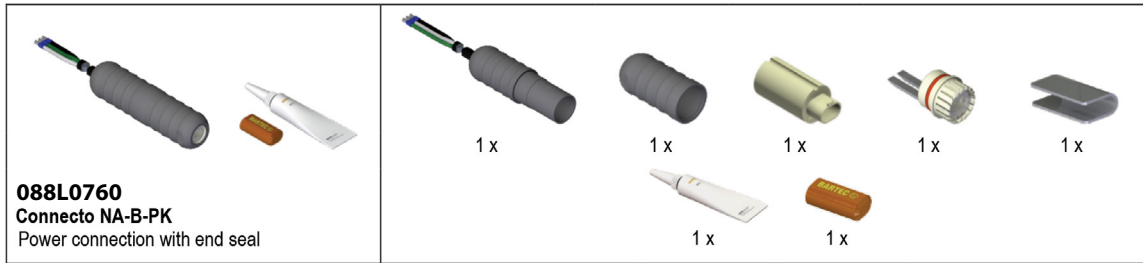


 








Kit Contents



Kit Contents (continued)

 <p>088L0765 Connecto /NA-B-PT Powered T-Connection kit</p>	 <p>1 x 3 x 3 x 3 x 3 x</p>
 <p>088L0766 Connecto NA-B-X X-Connection kit</p>	 <p>1 x 4 x 4 x 4 x 4 x</p>
 <p>088L0767 Connecto NA-B-E Silicone end seal (5X)</p>	 <p>1 x 5 x</p>

Component Identification

 <p>Threaded Cap</p>	 <p>End cap</p>	 <p>Powered splice assembly</p>
 <p>Sleeve</p>	 <p>Silicone adhesive</p>	 <p>T-Assembly</p>
 <p>Clamping sleeve</p>	 <p>Splice assembly</p>	 <p>Powered T-Assembly</p>
 <p>Clamping sheet</p>	 <p>Power connection assembly</p>	 <p>X-Assembly</p>

Danfoss
Electric Heating Segment
11655 Crossroads Circle Baltimore, MD 21220
Toll Free: 1-888-326-3677 | Fax: 416-352-5981 | www.LX.Danfoss.com

Danfoss can accept no responsibility for possible errors in catalogs, brochures, other printed materials, and website information. Danfoss reserves the right to alter its products without notice. This also applies to products already on order provided that such alteration can be made without subsequent changes being necessary in specifications already agreed upon. All trademarks in this material are property of the respective companies. Danfoss and Danfoss logotype are trademarks of Danfoss A/S. All rights reserved.