


DEVIfoil™ heating foil

(NO ONLY)

Product
is covered
by EPD*

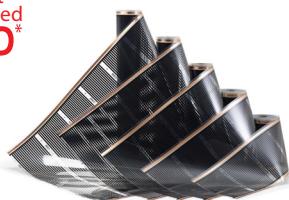

DEVIfoil™ heating foil is delivered in rolls and must be equipped with supply

wiring on site. The heating foil is very flexible, available in different widths. You roll out the desired length and cut the foil at the cutting zones. Used as a base is DEVIprom™ 300 or Depron boards which protects the bottom side of the foil, and at the same time ensure that the heat is conducted up into the floor. The heating foil is used under wooden floors, parquet, laminate. Can also be

mounted between joists. Must always be controlled by an appropriate thermostat. DEVIfoil™ heating foil has high quality, and comes with 10-year full DEVIfarranty and 25-year product DEVIfarranty.

Benefits:

- Flexible in length, due to 25 cm panel length 5 different widths to suit any room
- Dry Installation
- No need to use screed or concrete
- Clean easy and fast installation
- Very low installation height

Standard compliance:

- IEC 60335-1: 2012 (with amendments)
- IEC 60335-2-96: 2002 (with amendments)

Compliance symbols:



Type	Value
Nominal voltage	230 V~
Foil thickness	0,4 mm
Specific output	60 W/m ²
Construction height: DEVIprom™ 300	6,4 mm
Depron 3 mm	3,4 mm
Depron 6 mm	6,4 mm
The maximum load per one DEVIfoil™ line	6 A
Maximum fuse size	10 A (with 1,5 mm ² of cold lead cross section) 16 A (with 2,5 mm ² of cold lead cross section)
Max. permissible use temperature, Powered	80 °C
IP Class	IPX1

Types

DEVIfoil™	Item no.	Module width in cm Brutto	Power			At 6 A		Length pr. roll	EAN no.
			pr. m ²	pr. m	Panel pcs.	Maxi-mum panels*	Maxi-mum length		
40-60 W - 230 V	98931199	40 cm	60 W/m ²	24 W/m	6	230	57 m	100 m	5703466122266
60-60 W - 230 V	98931200	60 cm	60 W/m ²	36 W/m	9	153	38 m	100 m	5703466120255
80-60 W - 230 V	98931210	80 cm	60 W/m ²	48 W/m	12	115	28 m	50 m	5703466242773
100-60 W - 230 V	98931211	100 cm	60 W/m ²	60 W/m	15	92	23 m	50 m	5703466242780
120-60 W - 230 V	98931209	120 cm	60 W/m ²	72 W/m	18	76	19 m	50 m	5703466145944

* One panel is the lowest uncuttable length of approx. 25 cm.

Make it easy,
make it DEVI

DEVIfoil™ accessories

Item no.	Accessory	EAN no.
106010	Cold lead 1 x 1,5 mm ² , Black 50 m	5703466124086
106011	Cold lead 1 x 1,5 mm ² , Blue 50 m	5703466124093
106012	Cold lead 1 x 2,5 mm ² , Black 50 m	5703466124109
106013	Cold lead 1 x 2,5 mm ² , Blue 50 m	5703466124116
19806467	DEVIpron™ 300 - 6 mm 60 x 120 cm	7090019792143
140F7000	DEVIpron™ 500 - 6 mm 60 x 120 cm	5703466251553
106014	Depron 3 mm, 40 pcs. (1 box), -60 °C to +70 °C, 80 cm x 125 cm	5703466125137
106015	Depron 6 mm, 20 pcs. (1 box), -60 °C to +70 °C, 80 cm x 125 cm	5703466125144
19806454	Construction foil 0,2 mm, width 4 m, length 25 m	7090019787057
98931300	Duct tape 50 mm x 50 m	5703466147894
98931301	Double sided tape 25 mm x 50 m	5703466147900
98931302	Vulkape VM 38 mm x 6 m	5703466147917
98931203	Heating foil terminals (500 pcs. = 1 box)	5703466120286
98931205	Crimping tool	5703466120309