

Installation guide

**Solenoid valve**

Type EV220B 15 - EV220B 50





032R9329

032R9329

<p><b>A</b></p>	<p><b>B</b></p>	<p><b>C</b></p>
<p><b>1</b></p>	<p><b>2</b></p>	<p><b>3</b></p>
<p><b>4A 4B</b></p>	<p><b>5A 5B</b></p>	<p><b>6A 6B</b></p>
<p><b>4C</b></p>	<p><b>5C</b></p>	<p><b>6C</b></p>

Імпортер: ТОВ з іі "Данфосс ТОВ" 04080, Київ 80, п/с 168, Україна

Info for UK customers only: Danfoss Ltd., 22 Wyrcombe End, HP9 1NB, GB

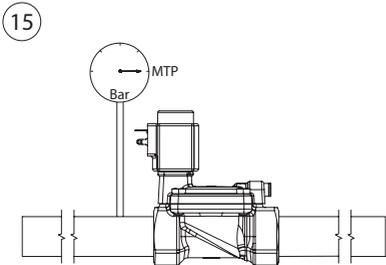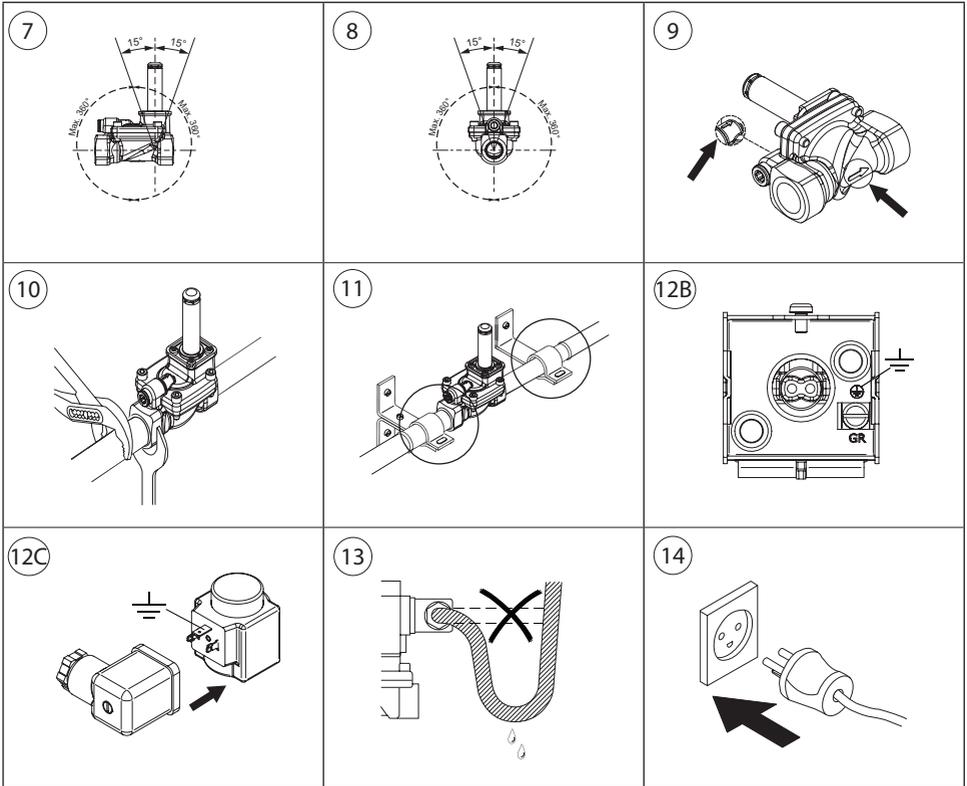

DN	MWP		Max. test pressure PT	
	[bar]	[psi]	[bar]	[psi]
15 - 20	15.5	225	23.25	338
25 - 50	12.4	180	18.6	270

EN 60730-2-8

Visit [www.products.danfoss.com](http://www.products.danfoss.com) for further technical data

All information, including, but not limited to information on selection of product, its application or use, product design, weight, dimensions, capacity or any other technical data in product manuals, catalogues descriptions, advertisements, etc. and whether made available in writing, orally, electronically, online or via download, shall be considered informative, and is only binding if and to the extent, explicit reference is made in a quotation or order confirmation. Danfoss cannot accept any responsibility for possible errors in catalogues, brochures, videos and other material. Danfoss reserves the right to alter its products without notice. This also applies to products ordered but not delivered provided that such alterations can be made without changes to form, fit or function of the product.

All trademarks in this material are property of Danfoss A/S or Danfoss group companies. Danfoss and the Danfoss logo are trademarks of Danfoss A/S. All rights reserved.