



Premium 2-wire braided

The best selling **GH781 MatchMate®** hydraulic hose

On average, **14% higher** pressures, **26% higher** temperatures and better abrasion resistance than the competition.



Standards/ Certificates:

Meets or exceeds: SAE 100R16 | EN 857 2SC | ISO 18752 | ISO 11237

Sizes and pressure (bar/psi):

-04 (448/6500)	-10 (276/4000)	-20 (172/2500)
-06 (400/5900)	-12 (241/3500)	-24 (138/2000)
-08 (345/5000)	-16 (207/3000)	-32 (110/1600)


Operating temperature:

-40°C to +127°C (-50°F to +260°F)

Available fittings:



1A Series

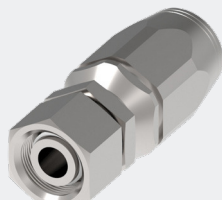

2R Series

Both crimp and reusable fittings are offered with Dura-Kote plating.

Inner Tube:

Synthetic rubber tube

Reinforcement:

2 wire braid

Cover:

DURA-TUFF™ synthetic rubber

Typical Application:

Low & medium pressure hydraulic system
Petroleum & water-based fluids
Construction equipment
Agriculture equipment.

MSHA approved
USCG approved
DNV
ABS