


Installation Guide

VMA DN 15

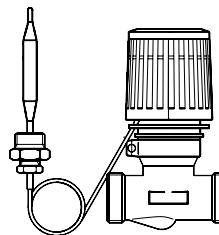


VMA




VMA / RAVI / RAVK / RAVV

HO98.1.1
DANFOSS

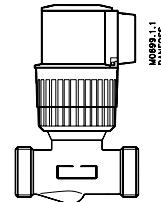


VMA/ABV

HO99.1.1
DANFOSS

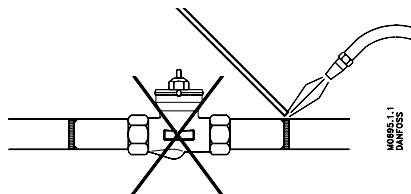


HO95.1.1
DANFOSS

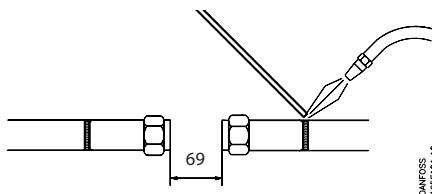


69

 
DANFOSS
A65F101.0



HO97.1
DANFOSS

 


HO98.1.1
DANFOSS

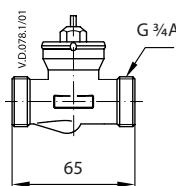


65


G 3/4A

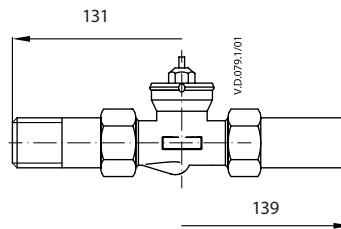

139

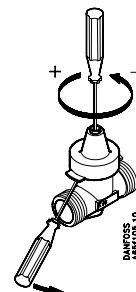

+ -
DANFOSS
A65F101.10

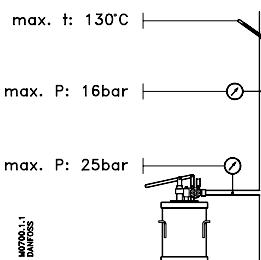

max. t: 130°C

max. P: 16bar

max. P: 25bar

HO98.1.1
DANFOSS

Installation Guide VMA DN 15

Danfoss can accept no responsibility for possible errors in catalogues, brochures and other printed material. Danfoss reserves the right to alter its products without notice. This also applies to products already on order provided that such alterations can be made without subsequent changes being necessary in specifications already agreed.
All trademarks in this material are property of the respective companies. Danfoss and the Danfoss logo type are trademarks of Danfoss A/S. All rights reserved.