

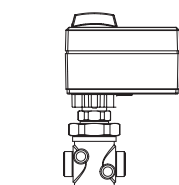


Руководство по монтажу


AMV 10

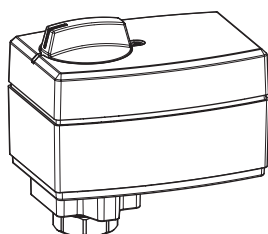


AMV 10 +
VM 2 ($D_y = 15-25 \text{ mm}$), VS 2

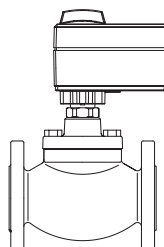

AMV 10 +
VB 2 ($D_y = 15-20 \text{ mm}$)

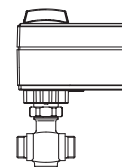


AMV 10 +
VMV

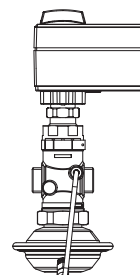


AMV 10 +
AVQM ($D_y = 15-20 \text{ mm}$)



1

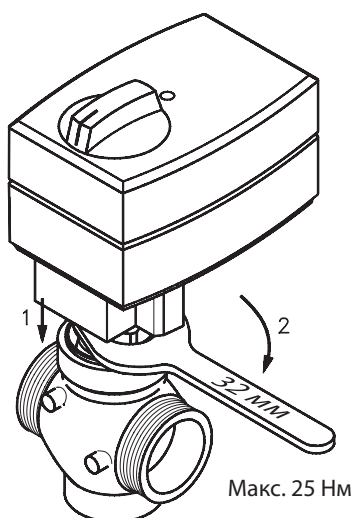




2

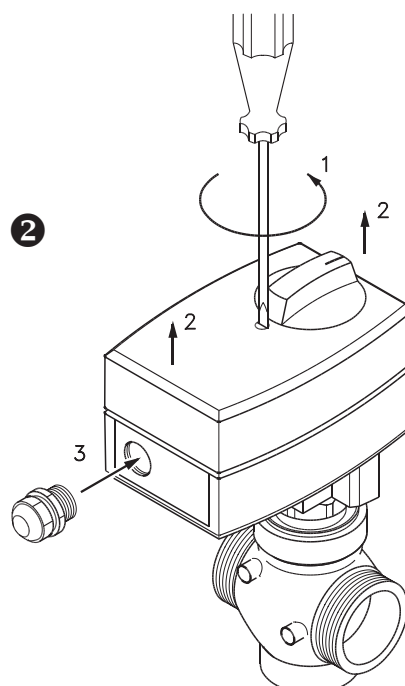


3

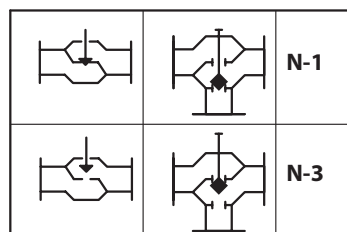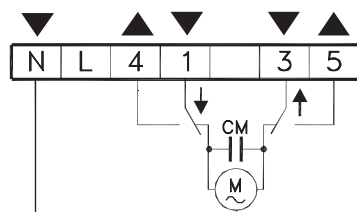


Руководство по монтажу

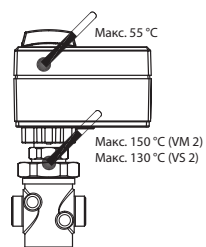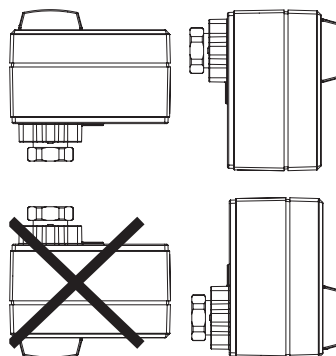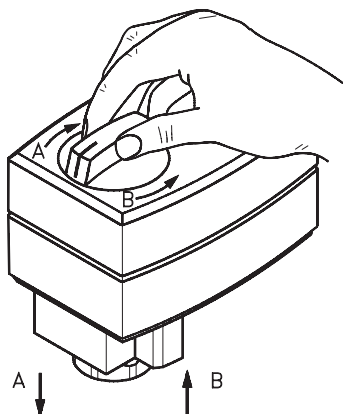


AMV 10 + VM 2, VS 2

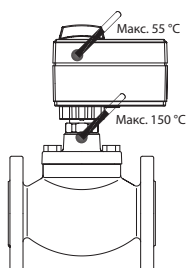

AMV 10 + VB 2

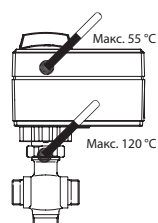

AMV 10 + VMV

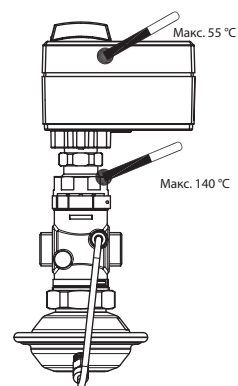

AMV 10 + AVQM