



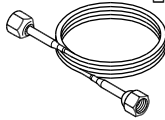
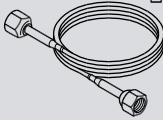
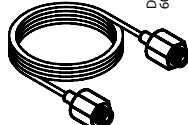


Spare parts and accessories

# Pressure switch RT

Description	Qty.	Code no.
	<b>Cover with pane</b> <b>017-436166</b>	
	Cover	1
	Screws	4
	<b>Cover without pane</b> <b>017-436266</b>	
	Cover	1
	Screw	4
	Seal screw for cover	1
	Seal screw for cap	1
	Protective cap	1
	Setting knob	1
	<b>Clamping band</b> <b>017-420466</b>	
	Band	1
	Screw	1
	Nut	1

Description	Code no. Multi pack	Code no. Industrial pack	
<b>Capillary tube, copper</b> 1/4 in. or 6 mm flare 	21 mm tube "tail"		
	0.5 m	-	<b>060-019066</b> <sup>1)</sup>
	1.0 m	<b>060-004866</b>	<b>060-019166</b> <sup>1)</sup>
	1.5 m	-	<b>060-019266</b> <sup>1)</sup>
	2.0 m	<b>060-016366</b>	<b>060-019366</b> <sup>1)</sup>
	2.25 m	<b>060-017666</b>	-
	50 mm tube "tail"		
	0.5 m	-	<b>060-007066</b> <sup>1)</sup>
	1.0 m	<b>060-017166</b>	<b>060-007166</b> <sup>2)</sup>
	1.5 m	-	<b>060-007266</b> <sup>1)</sup>
with Schraeder valve opener			
0.5 m	-	<b>060-000466</b> <sup>1)</sup>	
1.0 m	-	<b>060-000566</b> <sup>1)</sup>	
1.5 m	<b>060-002366</b>	-	
<b>Capillary tube, steel</b> 1/4 in. or 6 mm flare not for R717 (NH <sub>3</sub> ) 	1.0 m	<b>060-016766</b>	-
	1.5 m	<b>060-016866</b>	-
<b>Capillary tube, steel</b> G 3/8 and M10 x 0.75 for R717 (NH <sub>3</sub> ) 	1.0 m	<b>060-008266</b>	-

<sup>1)</sup> 50 pcs.

<sup>2)</sup> 40 pcs.

Description	Qty.	Code no.
<p><b>Solder nipple for G 3/8</b></p>		<b>017-436866</b>
	1. Union	1
	2. Nipple ID 8 mm / OD 10 mm	1
	3. Alu gasket	1
<p><b>Weld nipple for G 3/8</b></p>		<b>017-422966</b>
	1. Union	1
	2. Nipple, OD 10 mm	1
	3. Alu gasket	1
<p><b>Reducer G 3/8</b> 1/4 in. flare</p>		<b>017-420566</b>
	1. Reducer	1
	2. Alu gasket	1

Description	Qty.	Code no.
<p><b>Adaptor</b> 3/8 G x 1/4-18 NPT</p>		<b>060B030266</b>
	1. Adapter	
	2. Alu gasket	1
<p><b>Reducer M10 x 0.75</b> 1/4 - 18 NPT</p>		<b>060-014166</b>
	1. Nipple	1
	2. Alu gasket	1
<p><b>Alu gasket</b> for reducer and nipple</p>	2	<b>060B120866</b>
<p><b>Cutting ring coupling</b> for 6 mm steel tube</p>	1	<b>060B121066</b>