

SET Range

When simplicity is paramount
Easy to operate, **24 hour control**

- Easy to operate
- 24 Hour control
- Easy to use rocker switches
- British Gas standard wallplate
- Available in electro-mechanical and electronic versions



SET3E



SET3M



SET Time Controls

For situations where simplicity of control is paramount.

The SET range of time controls has been designed with simplicity of programming and use in mind.

The range includes an electronic timeswitch, a mini-programmer and a programmer, as well as an electro-mechanical programmer.

All models offer 24 hour control and are designed to fit the British Gas Standard Wallplate used by earlier SET models and some models from the Horstmann range.

All models have LED status indicators and have easy to use rocker switches for programme selection.

The On/Off times can be seen at a glance on the SET3M. Using the slider switch on the electronic models the on/off times are shown on the large, clear display.




Programmes can be manually overridden, by the thumbwheel on the SET3M and by the ADVANCE and +1HR buttons on the electronic models.



from top to bottom; SET1E, SET3M and SET3E.

| Features | SET1E | SET2E | SET3E | SET3M |
|--|------------------------------|---|--|--|
| Code No. | 087N654000 | 087N654100 | 087N654200 | 087N653200 |
| Timeswitch | • | | | |
| Mini-programmer | | • | | |
| Two channel programmer, with common timebase | | | • | • |
| Electronic | 24 hour | 24 hour | 24 hour | |
| Electro-mechanical | | | | 24 hour |
| Pumped/Gravity option | | | • | • |
| Programmes selectable | Off Timed On | Off Timed On HW or HW & CH | Off Timed On (Water) Off Timed On (Heating) | Off Timed On (Water) Off Timed On (Heating) |
| Factory pre-set programmes | | • | | |
| On & offs per day | 2 | 2 | 2 | 2 |
| Advance override | • | • | • | • |
| +1hour override | • | • | • | |
| Voltage rating | 230 Vac ± 15%, 50/60 Hz | | | |
| Contact Rating | 3 (1) A | | | |
| Switching action | 1 x SPDT (voltage free) | 2 x SPDT (voltage free) | | 2 x SPDT (voltage free) |
| Maximum ambient temperature | 45°C | | | |
| Memory back-up | Up to 24 hours | | | N/A |
| Dimensions (mm) | 158 wide x 98 high x 36 deep | | | 158 wide x 98 high x 63 deep |

Wiring Details

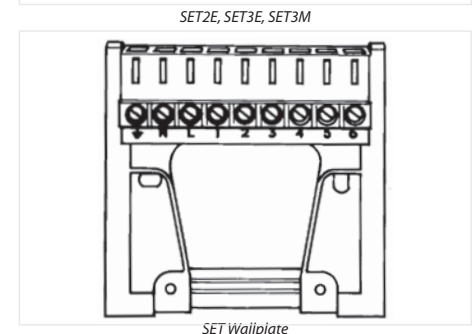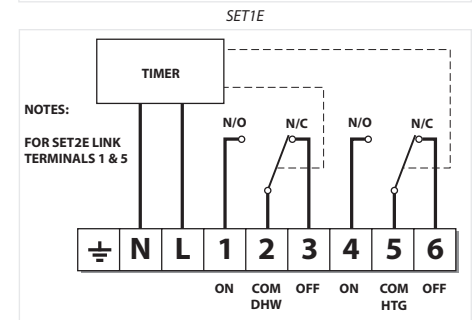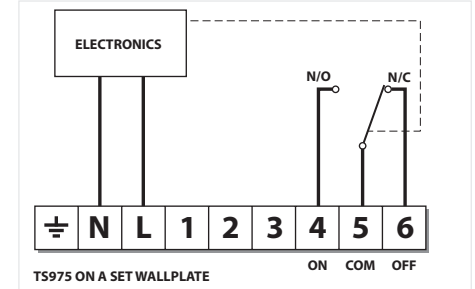

Danfoss Ltd

Ampthill Road, Bedford, MK42 9ER, T: 01234 364621, E: ukheating@danfoss.com, W: www.heating.danfoss.co.uk