


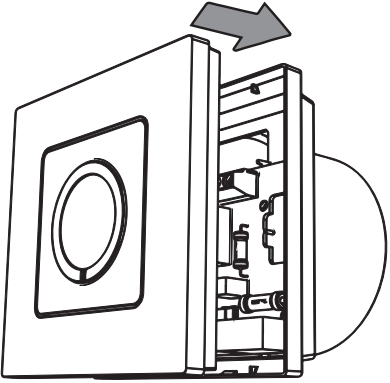
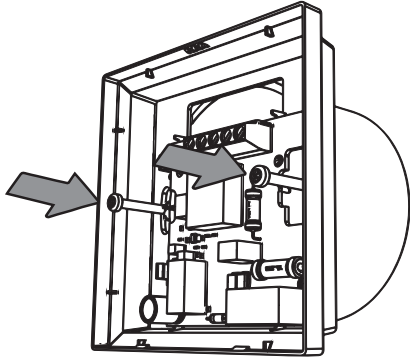


Danfoss A/S 6430 Nordborg Denmark		CE		
Icon™ Dial 230W OW		Max. load: 10W/50mA		
L	N	N	Load NC	Load NO
220-240V 50-60 Hz		M		

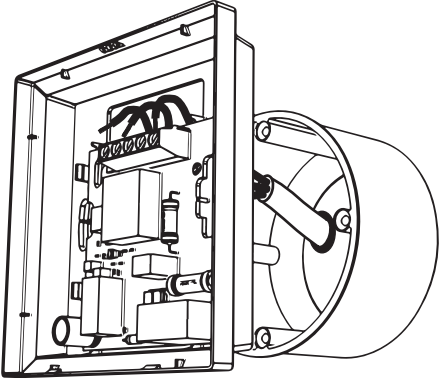


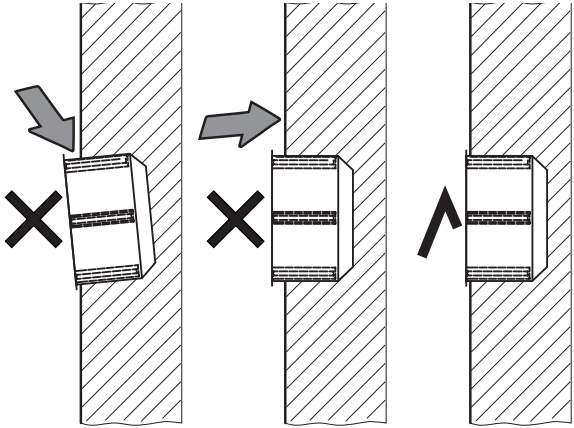


7.

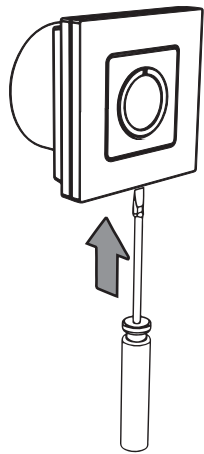



8.

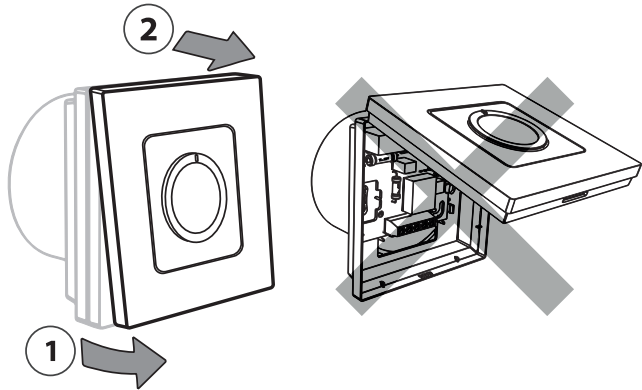

9.

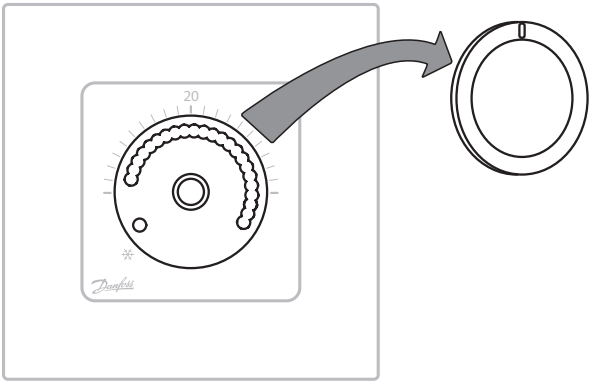

10.

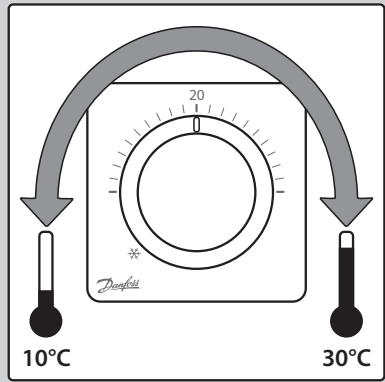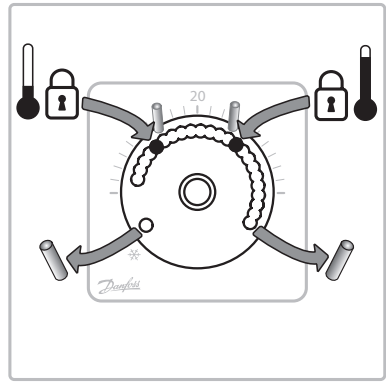

❄ = 5°C

13658 000 00 Manual Installation WRT Dial 230 F86 OW

ENGINEERING
TOMORROW



Installation & User Guide

Danfoss *Icon*™ Dial Room Thermostat

VICUY10F/088N3653

www.icon.danfoss.com