

서비스 가이드


솔레노이드 밸브

타입 EVR 32 – EVR 40 (버전 2)




032R9607

032R9607



NC 솔더

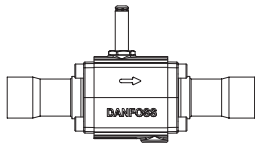


NO 솔더

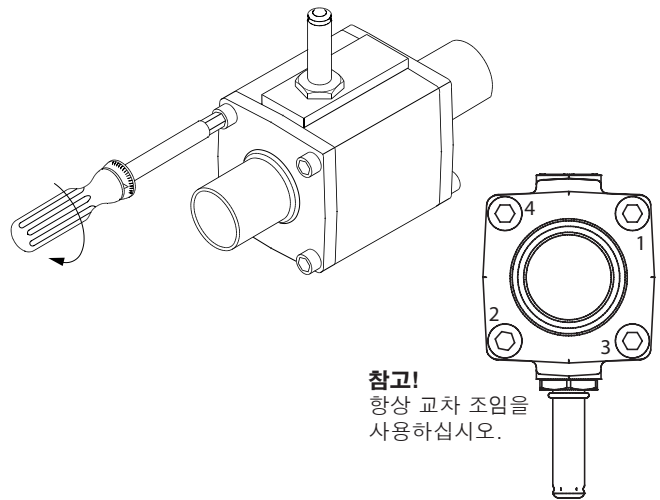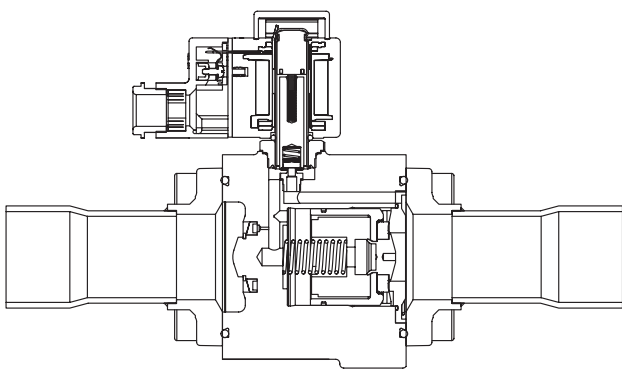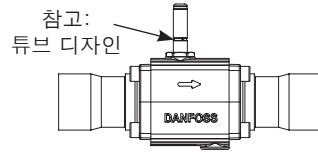

[Nm]	[kpm]	[ft-lbs]
30	2.0	15

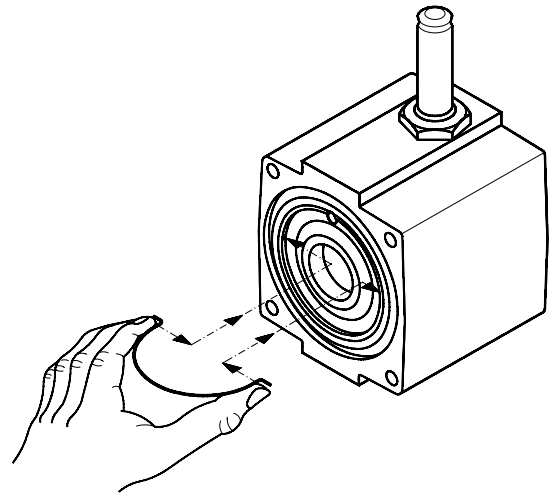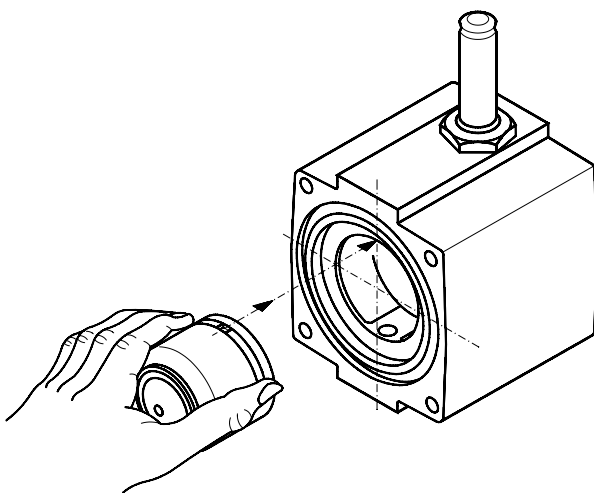

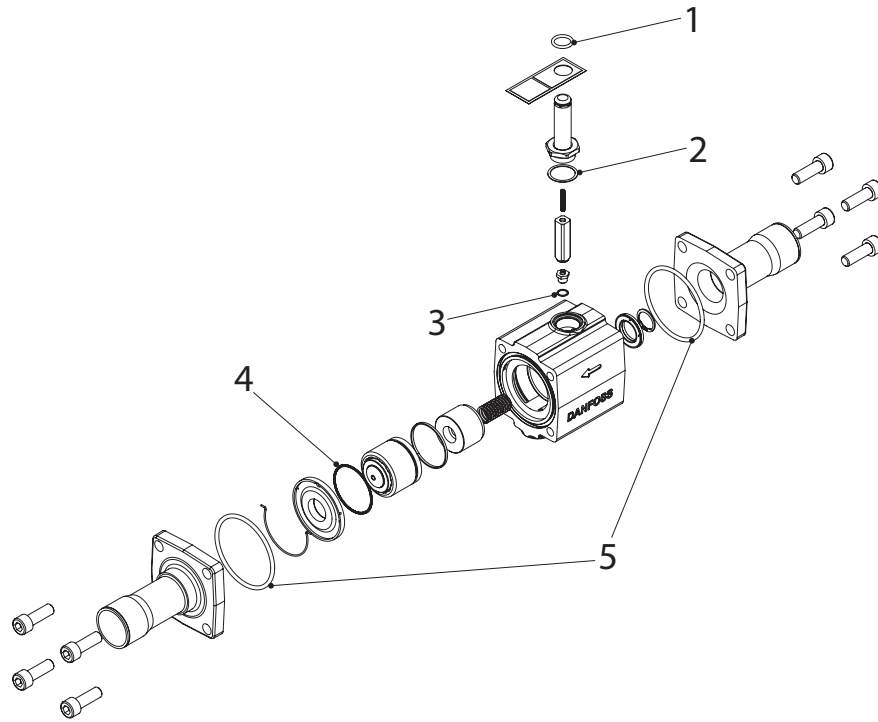

위치 번호	설명	치수	재질	재질	파일럿	검사 키트
1	오링	ID 14.30 x H 2.40	클로로프렌	.		.
2	개스킷	ID 22.5 x OD 26.4 x H 0.35	SS+NBR		.	.
3	AI-개스킷	ID 8.1 x OD 10.1 x H 0.5	AI			.
4	오링	ID 42.00 x H 1.50	클로로프렌	.		.
5	오링 x 2	ID 66.27 x H 3.53	클로로프렌	.		.