

Installation guide

Unloader flange valve

Type EVRF (NC/NO) - Flammable refrigerants

032R9796

Refrigerants:

Oil with R717, R22/R407C, R404A/R507A, R410A, R134a, R744, R23, R600, R600a, R290.

For other refrigerants, please contact Danfoss.

Note! The EVRF is, combined with an ATEX/Ex coil, approved for R600, R600a, and R290 by ignition source assessment in accordance with standard EN13463-1.

Max. working pressure:

Standard version: PS / MWP = 35 bar (508 psig)

High pressure version: PS / MWP = 63 bar (914 psig)

Medium temperature:


Min. -40 °C (-40 °F)

Max. 105 °C (221 °F)




Note! The media and ambient temperature ranges are limited for ATEX/Ex coils and should be complied with the coil installation guide.

032R9796



EVRF

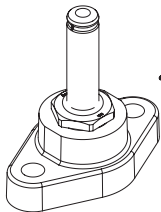


Standard coils

   


ATEX/Ex coils

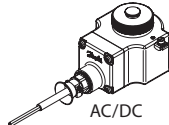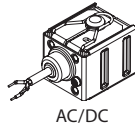

Note! Find further information about the coils in the coil installation guides.

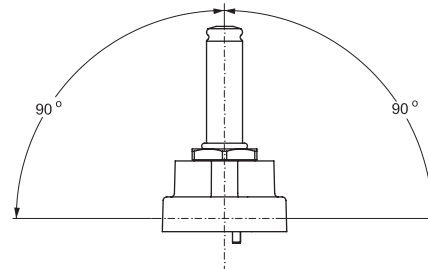

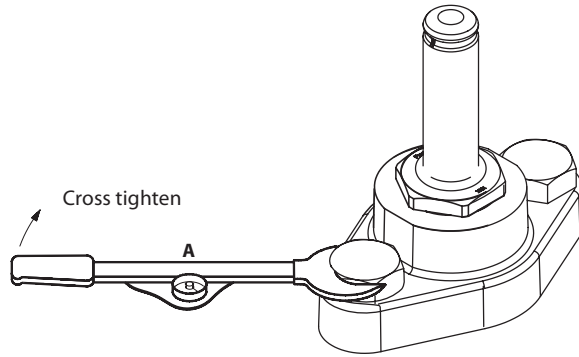

	[Nm]	[kpm]	[ft-lbs]
A	80	8.16	59

