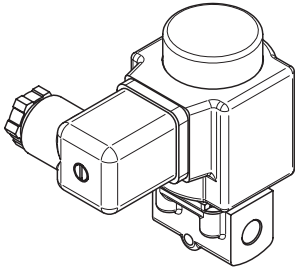
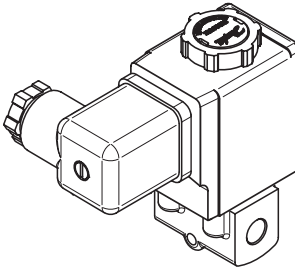
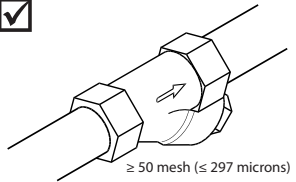
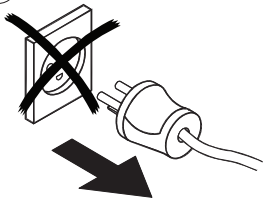
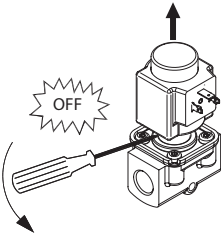
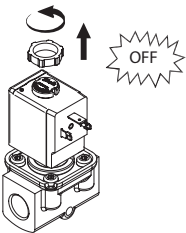
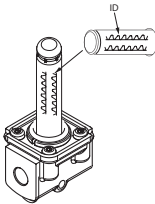
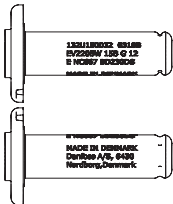
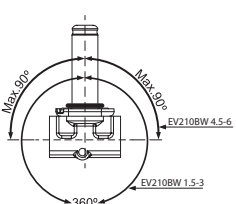
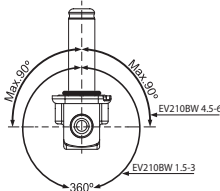
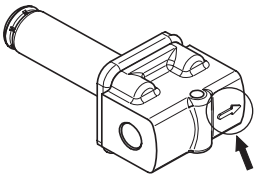
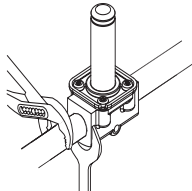




Installation guide

Solenoid valve
Type EV210BW

132R9002

132R9002

A 	B 	✓  ✓ ON OFF 
1 	2A 	2B 
3 	4 	5 
6 	7 	8 

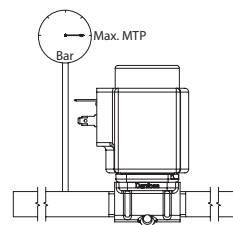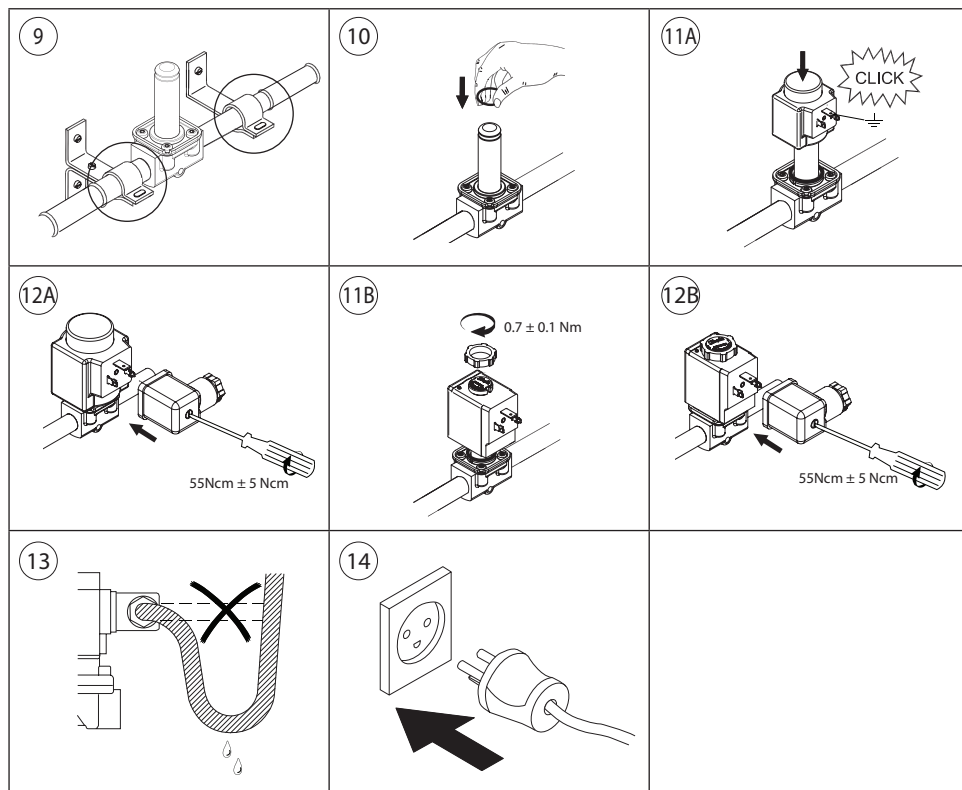

Drinking water approval			
 CERTIFIERAD 1002		Valid in	Certificate no.
 356 Inspected by DTI			
EV210BW 1.5-6 BE	DK, SE	SCO155-18*)	
*) http://publiccert.extweb.sp.se/sv/Product/List/ Wetted parts in accordance with DVGW, 4MS, KTW and W270			

DN	Max. Working Pressure (MWP)	Max. Test pressure (MTP)
	[bar]	[bar]
1.5-4.5	10	15
6	6	9
EN 60730-2-8		

Visit www.products.danfoss.com for further technical data

Para más información, visite www.products.danfoss.es

Rendez-vous sur le site www.products.danfoss.fr pour plus de données techniques