

Installation guide

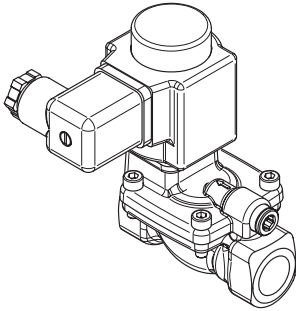
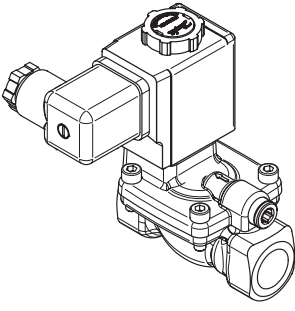
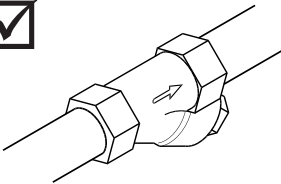
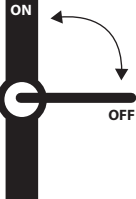
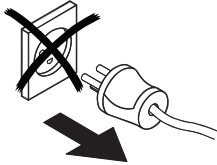
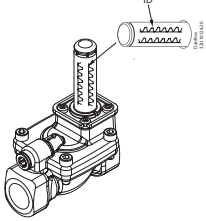
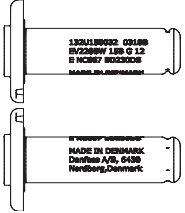
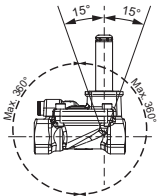
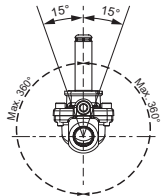
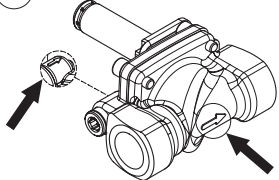
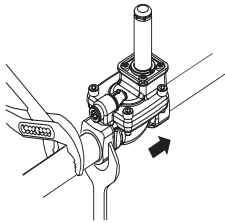
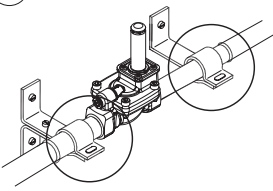
**Solenoid valve**

Type EV220BW 15-50

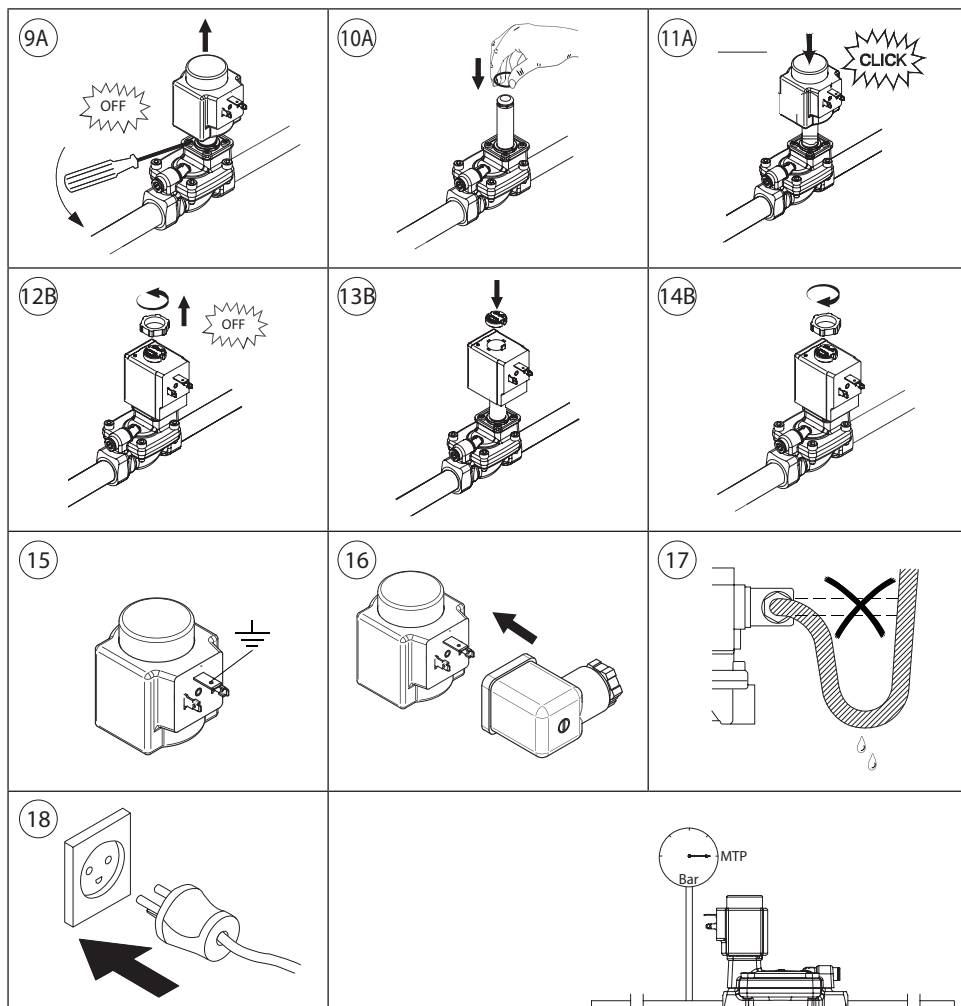
UK  
CA

132R9000

132R9000

|                                                                                                                                                                                         |                                                                                                                                                                                         |                                                                                                                                                                                                                                                                                                                                                                                                                 |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <p>A</p>                                                                                                | <p>B</p>                                                                                               | <p></p> <p></p> <p>≥ 297 Microns</p> <p></p> <p>ON</p> <p>OFF</p> <p></p> |
| <p>1</p>                                                                                               | <p>2</p>                                                                                               | <p>3</p>                                                                                                                                                                                                                                                                                                                       |
| <p>4</p> <p></p>  | <p>5</p> <p></p>  | <p>6</p>                                                                                                                                                                                                                                                                                                                    |
| <p>7</p>                                                                                             | <p>8</p>                                                                                             |                                                                                                                                                                                                                                                                                                                                                                                                                 |

Info for UK customers only: Danfoss Ltd, Oxford Road, UB9 4LH Denham, UK



| Drinking water approval                                                                                                                                                     |                                                                                                         |          |                    |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------|----------|--------------------|
| <br>1002                                                                                  | CERTIFIERAD                                                                                             | Valid in | Certificate<br>no. |
|                                                                                                                                                                             |                      |          |                    |
|                                                                                                                                                                             |  356 Inspected by DTI |          |                    |
| EV220BW 15-25BE                                                                                                                                                             |                                                                                                         | DK, SE   | SCO155-18 *)       |
| EV220BW 15-50SS                                                                                                                                                             |                                                                                                         |          |                    |
| *) <a href="http://publiccert.extweb.sp.se/sv/Product/List/">http://publiccert.extweb.sp.se/sv/Product/List/</a><br>Wetted parts in accordance with DVGW, 4MS, KTW and W270 |                                                                                                         |          |                    |

| DN      | Max. Working Pressure (MWP) | Max. Test pressure (PT) |
|---------|-----------------------------|-------------------------|
|         | [bar]                       | [bar]                   |
| 15 - 20 | 10                          | 25                      |
| 25 - 50 | 10                          | 25                      |

EN 60730-2-8

Besök [www.danfoss.se](http://www.danfoss.se) för mer tekniska data. Besøg [www.danfoss.dk](http://www.danfoss.dk) for flere tekniske data.

Rendez-vous sur le site [www.products.danfoss.fr](http://www.products.danfoss.fr) pour plus de données techniques.

Visit [www.products.danfoss.com](http://www.products.danfoss.com) for further technical data. Para más información, visite [www.products.danfoss.es](http://www.products.danfoss.es)