

Installation guide


Solenoid valve

Type EV220W 6 - EV220W 50


UK
CA

032R5092


032R5092

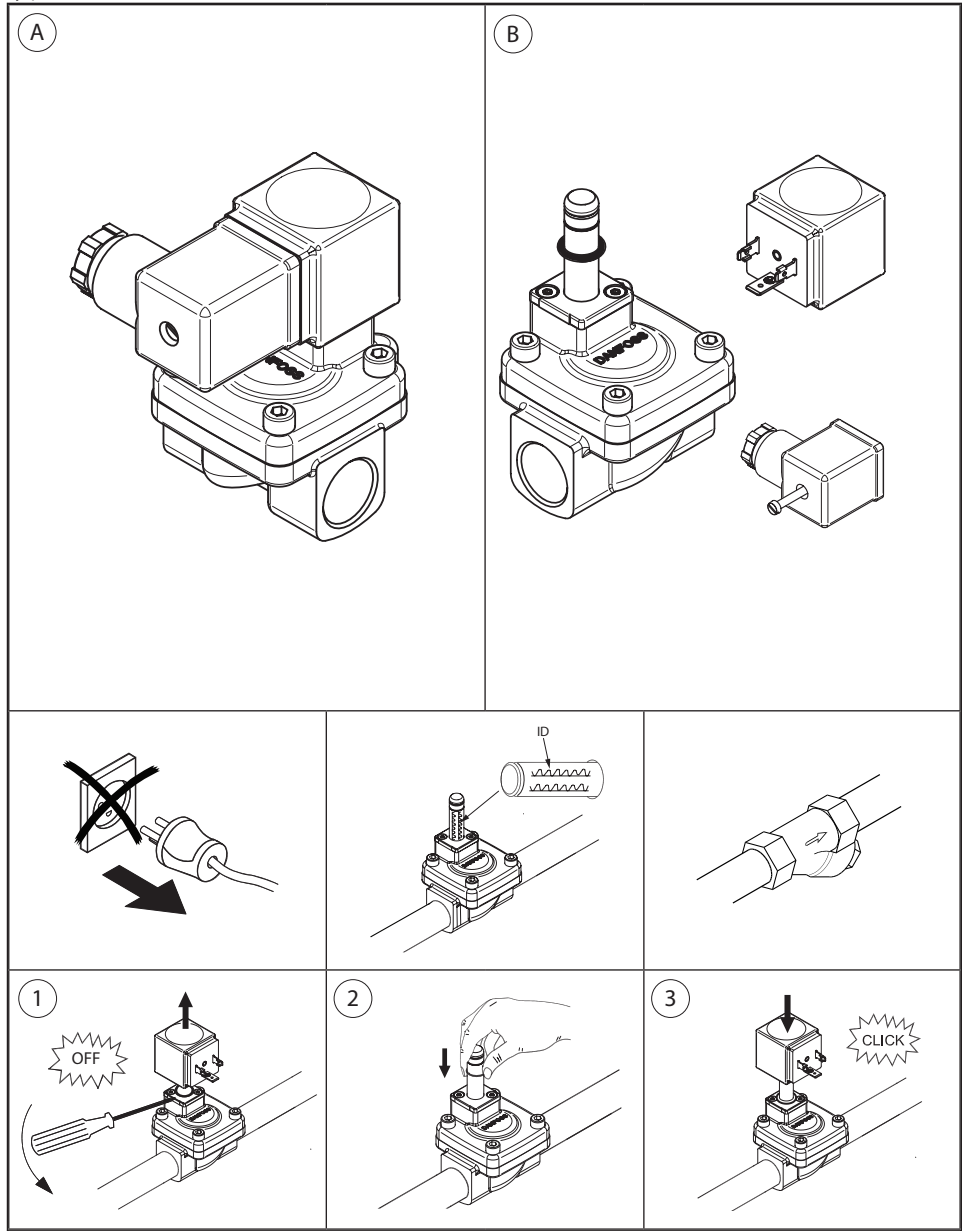

Info for UK customers only: Danfoss Ltd. Oxford Road, UB9 4LH Denham, UK

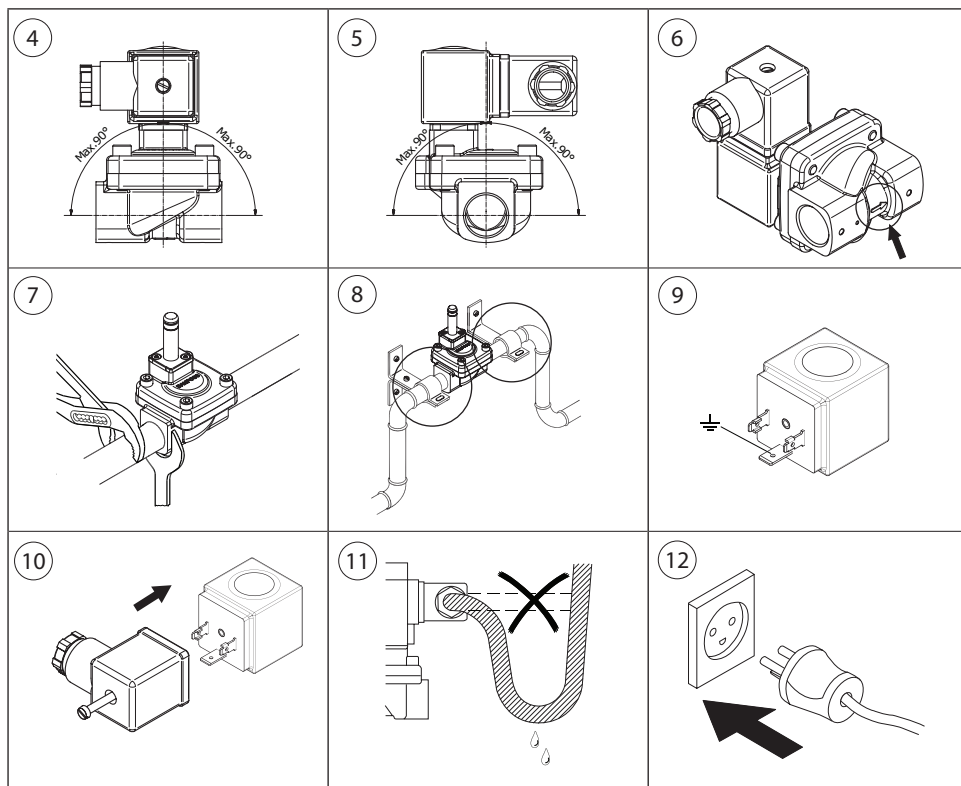

13

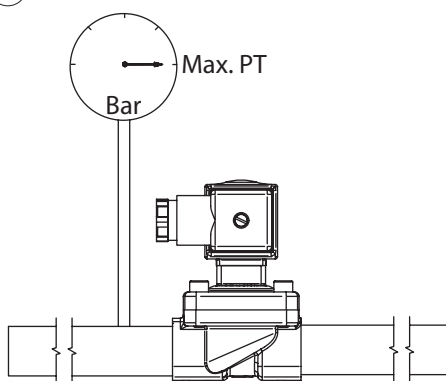

DN	MWP	Max. test pressure PT
	[bar]	[bar]
6 - 10	10	50
14 - 50	10	25

EN 60730-2-8

Visit www.products.danfoss.com for further technical data

Para más información, visite www.products.danfoss.es

Rendez-vous sur le site www.products.danfoss.fr pour plus de données techniques