



Installation guide


Differential pressure switch Type CAS 155

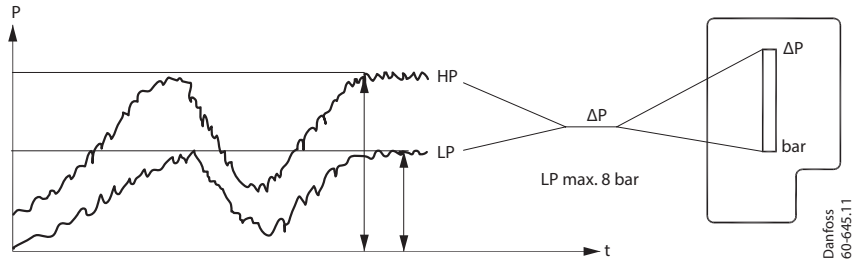





060R9303

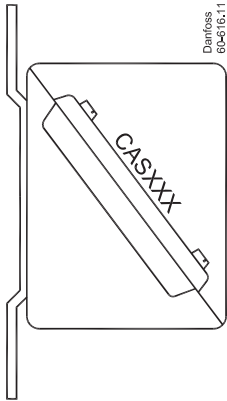

060R9303

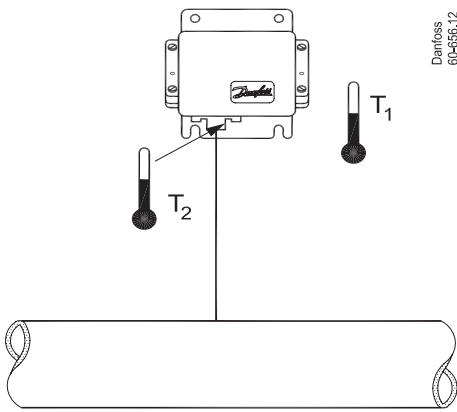

T_1 min.: -25 °C
 T_2 min.: -25 °C
 T_1 max.: 70 °C
 T_2 max.: 100 °C (For water and seawater, max. 80 °C)

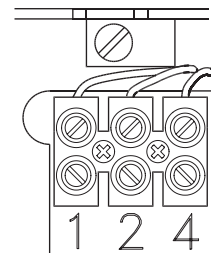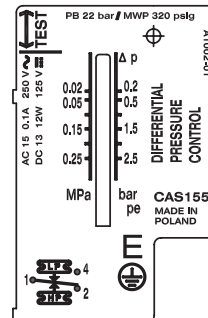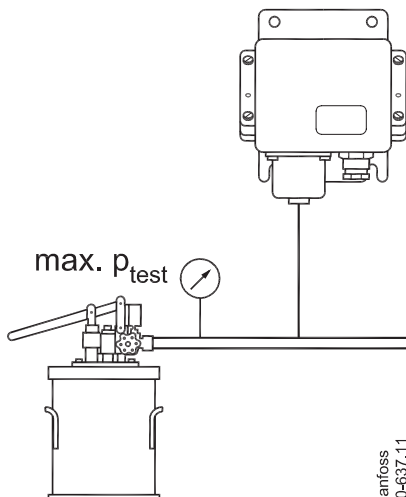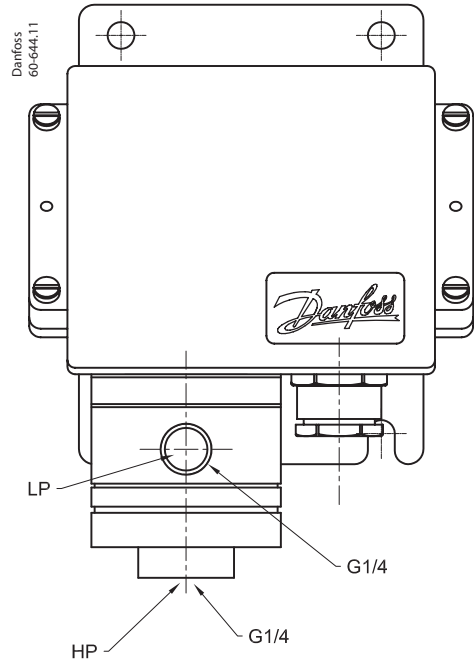

Danfoss
60L1050.11

Імпортер: ТОВ з іі "Данфосс ТОВ" 04080, Київ 80, п/с 168, Україна

Info for UK customers only: Danfoss Ltd., 22 Wycombe End, HP9 1NB, GB

