

ENGINEERING
TOMORROW

Danfoss

The One Stop **Online Shop**

Search and compare 600K products and documentation

24/7


availability
of product
information and
documentation



store.danfoss.com

Danfoss Product Store

Welcome to the new improved online platform where you can search, compare and order all Danfoss products directly.

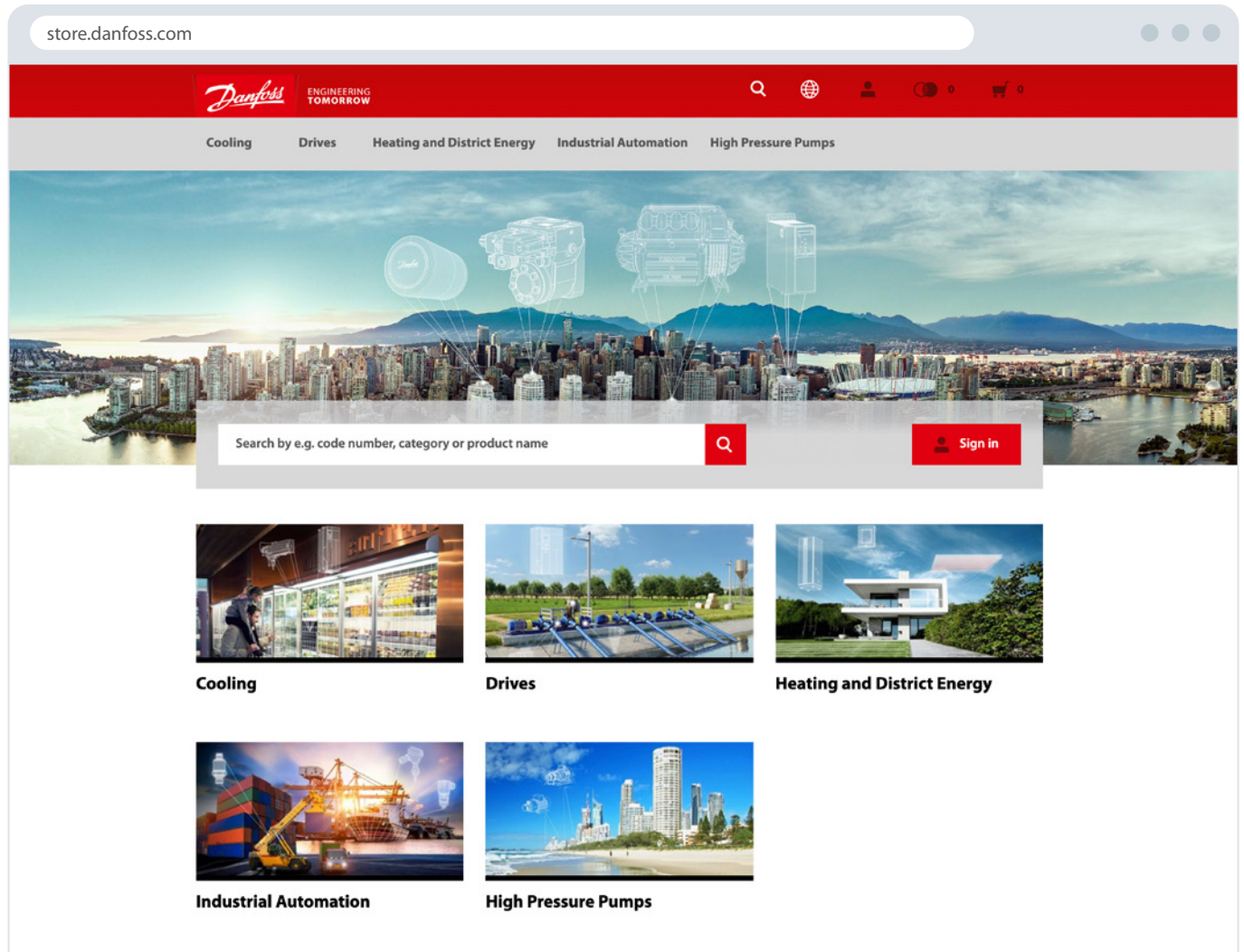

Danfoss Product Store explained in 90 seconds



We have made it easy for you



EASY TO BUY

24-hour self-service, 7 days a week, making it easy for you to shop at Danfoss.



PRODUCT SEARCH

Search and browse the product code or category in a quick and smart way.



COMPARE PRODUCTS

Compare products next to each other to make the best choice.



TECHNICAL DOCUMENTATION, SOFTWARE & DRAWINGS

Search for and download technical documentation, drawings and software for Danfoss Products.



PRICES & AVAILABILITY

As a Danfoss Direct Customer, you can order, check order status, history and track shipments.





MOBILE FRIENDLY

The Product Store is optimized to mobile, tablet and PC, making it available to you, wherever you are.





Product search

Advanced search and filters on technical specifications making product selection quick and simple.

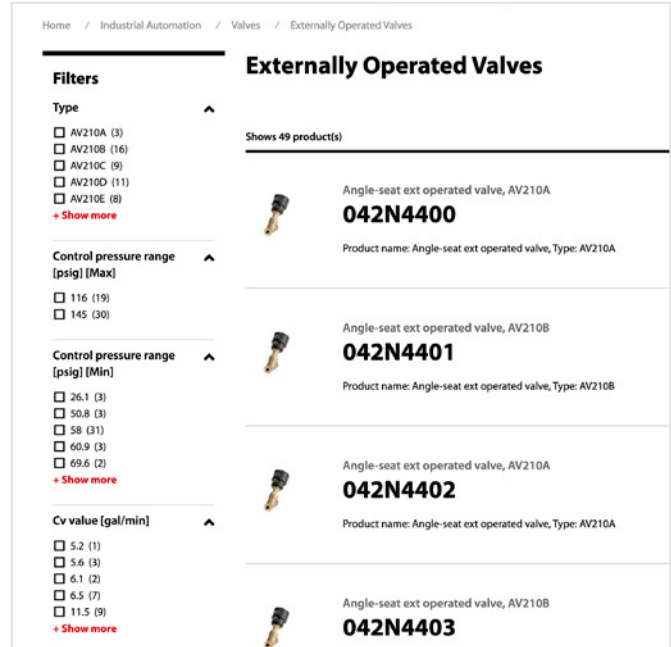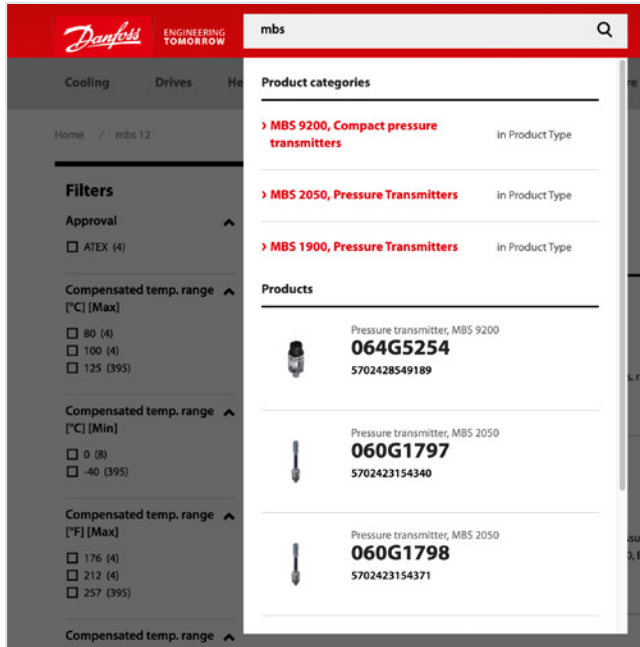

Technical documentation, software & drawings

Download relevant product information such as documents, specifications, images, software and more.

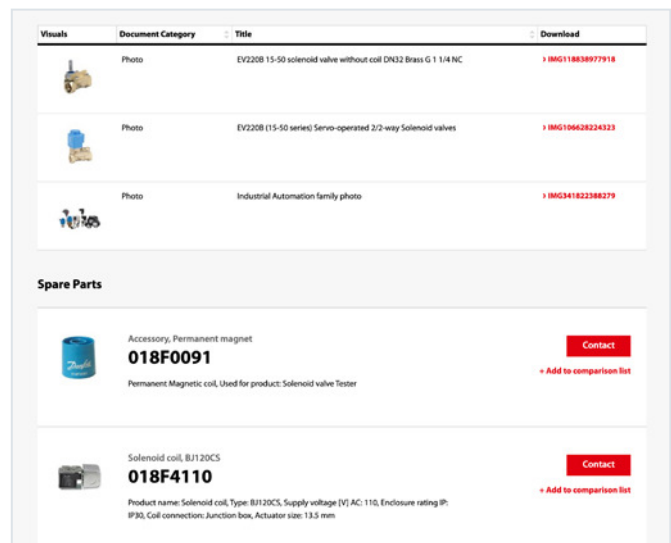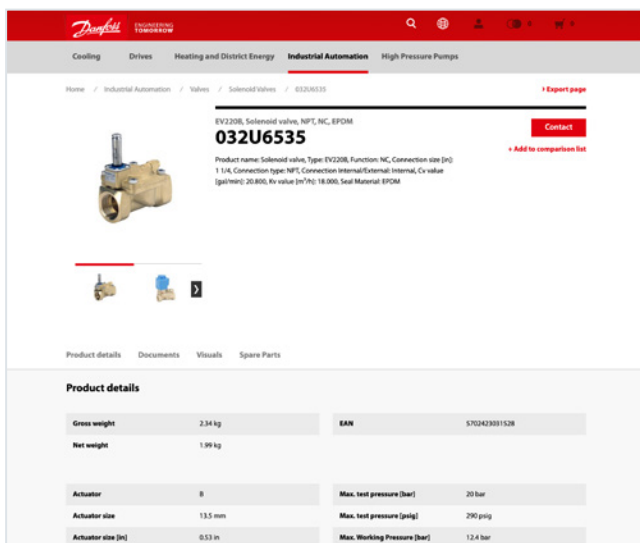



Product comparison

Compare products to find the right one among the different variants and versions.

Comparison (3)

> Show differences only
> Export page

EV220B, Solenoid valve, Flange, NC, NBR
016D3330

EV220B, Solenoid valve, Flange, NC, NBR
016D3331

EV220B, Solenoid valve, Flange, NC, NBR
016D3332

> Remove all

Contact

	016D3330	016D3331	016D3332
Gross weight	16.72 kg	26.5 kg	36.22 kg
Net weight	15.88 kg	25.18 kg	34.41 kg
EAN	5702422130802	5702422130734	5702422130758

	016D3330	016D3331	016D3332
Material	Cast iron	Cast iron	Cast iron
Size	2 1/2 in	3 in	3 in
Standard	EN 1092-1	EN 1092-1	EN 1092-1
Flange	Flange	Flange	Flange
Flow rate (l/min)	55.1 gal/min	87 gal/min	15
Differential pressure (bar) (Max)	10 bar	10 bar	10 bar
Differential pressure (bar) (Min)	0.25 bar	0.25 bar	0.25 bar
Differential pressure (psi) (Max)	145 psi	145 psi	145 psi
Differential pressure (psi) (Min)	3.6 psi	3.6 psi	3.6 psi
Est. time to close, water (ms)	7000 ms	15000 ms	29000 ms
Est. time to open, water (ms)	5000 ms	5000 ms	5000 ms
Flow direction	Single flow	Single flow	Single flow
Flow direction indicator	Embossed 1-way arrow	Embossed 1-way arrow	Embossed
Build Group	II	II	II
Material	NC	NC	NC
Flow rate (m³/h)	50 m³/h	75 m³/h	1
Flow rate (GPM)	50 cdt	50 cdt	50 cdt
Flow rate (GPM)	15 bar	15 bar	15 bar
Flow rate (GPM)	218 psig	218 psig	218 psig



Price & Availability

Only for direct Danfoss customers

Check prices and availability, look up your order history and track your current orders.

Home / My account / Order history

Order history

Search

Danfoss order no.

Customer order no.

Placed by username

Code number

Delivery number

Invoice number

From To

Shipments

> Expand all

	Code no.	Description	Quantity	Your reference note
10	> 030F6904	OD S nozzle 29030	30	0.0000000000000000
20	> 030F6908	OD S nozzle 29032	100	0.0000000000000000
30	> 030F6918	OD S nozzle 29037	20	0.0000000000000000
40	> 030F6924	OD S nozzle 29041	20	1.0000000000000000

Shipping address: Electric Energy A/S Hørsholmvej 14, Hørsholm 125, Building 0000, Denmark

Expected shipping date: 26/06/2018

Carrier: PostNord

Tracking ID: 1.0000000000000000

Invoice number: 22/06/2018

Delivery number: 8012040000



Status: (Danfoss) tracked



Easy to buy


Only for direct Danfoss customers

Stored baskets, quick order entry and re-ordering previous purchases, making order management easy.

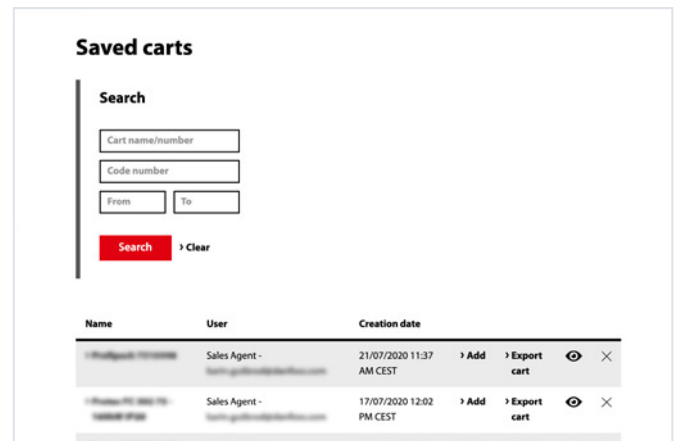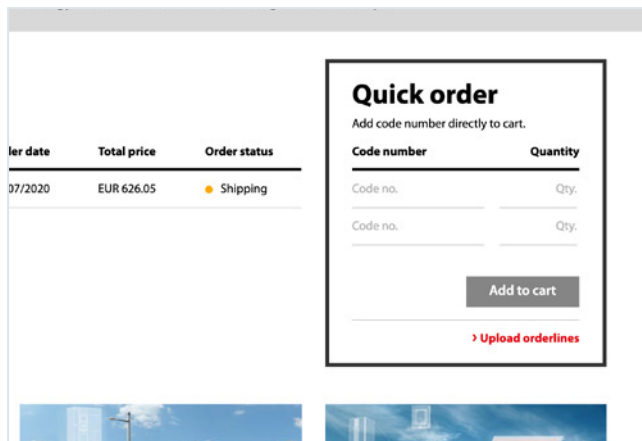

Mobile Friendly

Designed for an optimized experience on mobile phones, tablets or computers.

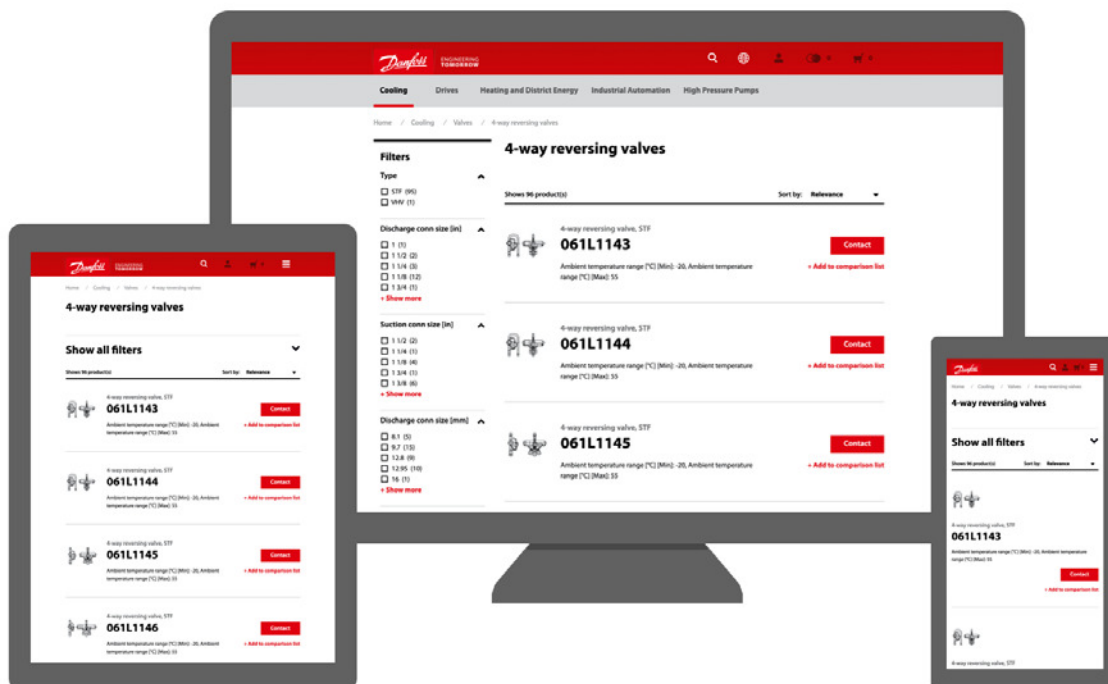



Login to the Product Store

Danfoss direct customers can log into the Product Store and manage orders. To do so, you'll need a login.

If you don't have one, you can contact your local Customer Service Center.

› [Click here to find your local Customer Service Center](#)

Contact list

London, UK

Business unit	Type (1)
Sondex (UK) Limited	785 km
Danfoss sales and services	View details
Danfoss Limited - Sales & Service	786 km
Danfoss sales and services	View details
Danfoss Power Solutions Limited	786 km



Danfoss Partners

If you're not a Danfoss direct customer, you can order your Danfoss products through our strong partner and distributor network.

› [Find your nearest distributor](#)

Find a distributor

☐ Find a distributor near me
☐ Enter your location

Enter your location

Danfoss Product Store

Online support

For any questions or necessary Support, please contact our

Customer Service Center:

Tlf: 0330 808 6888

Mail: customerservice.uk@danfoss.com



Danfoss Limited - Sales & Service

Capswood, Oxford Road, Denham
UB9 4LH Denham, Buckinghamshire
United Kingdom