

Aeroquip Performance Products

Assembly Instructions

SOCKETLESS® Hose Assembly

SOCKETLESS® Hose Assembly




Danfoss' AQP SOCKETLESS Performance Hose and Fittings are extremely easy to work with. Connecting the two is a snap since not even a wrench is needed! Simply slip the hose onto the fittings. It's that simple.

Applications: Gasoline, fuel and lubricating oils, air and water.



Step 1. Cut hose to required length with a sharp knife. Oil inside of hose and outside of nipple liberally.

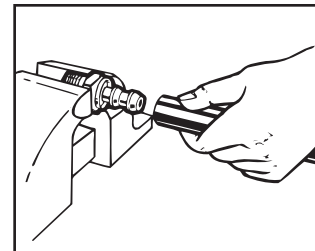


Step 2. Push hose on fitting until hose end bottoms under protective cap as shown. Clean, proof test to twice operating pressure and inspect all assemblies.

¹Never use a hose clamp with FBV SOCKETLESS™


SOCKETLESS
Black Anodized
Aluminum

SOCKETLESS
Steel Swivel

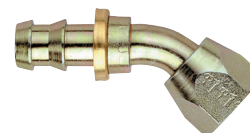


SOCKETLESS
Red/Blue Anodized
Aluminum

SOCKETLESS
Brass

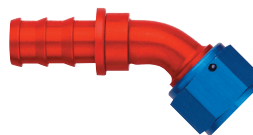

SOCKETLESS
Nickel-Plated
Aluminum

Important: It is recommended that all hose assemblies be proof pressure checked at twice the operating pressure using a proof test stand such as the Danfoss' Aeroquip Performance Products FT1058 stand.

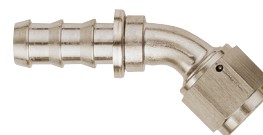

Compliments of Aeroquip Performance Product team. For more technical information please visit Aeroquipperformance.com

For more information on these and other AQP Performance Products see the catalog Aeroquip Performance Products by Danfoss A-SPPE-CC001-E

Products we offer:

- Cartridge valves
- DCV directional control valves
- Electric converters
- Electric machines
- Electric motors
- Gear motors
- Gear pumps
- Hydraulic integrated circuits (HICs)
- Hydrostatic motors
- Hydrostatic pumps
- Orbital motors
- PLUS+1® controllers
- PLUS+1® displays
- PLUS+1® joysticks and pedals
- PLUS+1® operator interfaces
- PLUS+1® sensors
- PLUS+1® software
- PLUS+1® software services, support and training
- Position controls and sensors
- PVG proportional valves
- Steering components and systems
- Telematics

Hydro-Gear

www.hydro-gear.com

Daikin-Sauer-Danfoss

www.daikin-sauer-danfoss.com

Danfoss Power Solutions is a global manufacturer and supplier of high-quality hydraulic and electric components. We specialize in providing state-of-the-art technology and solutions that excel in the harsh operating conditions of the mobile off-highway market as well as the marine sector. Building on our extensive applications expertise, we work closely with you to ensure exceptional performance for a broad range of applications. We help you and other customers around the world speed up system development, reduce costs and bring vehicles and vessels to market faster.

Danfoss Power Solutions – your strongest partner in mobile hydraulics and mobile electrification.

Go to www.danfoss.com for further product information.

We offer you expert worldwide support for ensuring the best possible solutions for outstanding performance. And with an extensive network of Global Service Partners, we also provide you with comprehensive global service for all of our components.

Local address:

**Danfoss
Power Solutions (US) Company**
2800 East 13th Street
Ames, IA 50010, USA
Phone: +1 515 239 6000

**Danfoss
Power Solutions GmbH & Co. OHG**
Krokamp 35
D-24539 Neumünster, Germany
Phone: +49 4321 871 0

**Danfoss
Power Solutions ApS**
Nordborgvej 81
DK-6430 Nordborg, Denmark
Phone: +45 7488 2222

**Danfoss
Power Solutions Trading
(Shanghai) Co., Ltd.**
Building #22, No. 1000 Jin Hai Rd
Jin Qiao, Pudong New District
Shanghai, China 201206
Phone: +86 21 2080 6201