 


060R9519


060R9519

## Pressure Transmitter Type AKS 3000



 $T_{amb} = \max 85^{\circ}\text{C} / 185^{\circ}\text{F}$

Operating temperature code T4  
MWP = 75 bar / 1088 psi



DANFOSS  
A60G205-10

### Pin 2:


Ikke i brug  
Not in use  
Nicht verwendet  
Non utilisé

Forsyngsspænding  
Supply voltage  
Versorgungsspannung  
Tension d'alimentation [ $U_B$ ]

15 - 30 V d.c.  
Must be provided by class 2 power supply when used as Refrigeration controller in hazardous locations

Udgangssignal  
Output signal  
Ausgangssignal  
Signal de sortie

1 - 7.5898 V d.c.

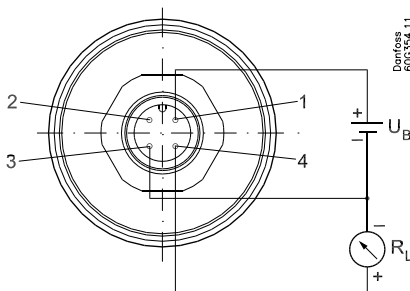

European approvals  
According to EMC Directive 89/366/EEC



American approvals:  
1. Temperature indicating and regulating equipment acc. to UL 873, file no E31024  
2. Class I, Div. 2, Group A,B,C and D acc. to UL 1604, file no E227388



Australian approvals  
According to N1297



Canadian approvals:  
1. Process control equipment acc. to CSA std. C22.2 no. 142-M1987  
2. Non-incendive electrical equipment for use in class I, Division 2, Group A, B, C and D acc. to CSA std. no. C22.2 no. 213-M1987