




REFRIGERATION AND  
AIR CONDITIONING


# Instructions

## EKA 163B



## EKA 164B

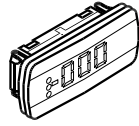




EKA 163B  
Remote display  
(084B8574)

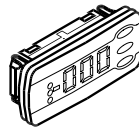

EKA 164B  
Remote setting display  
(084B8575, multi purpose)

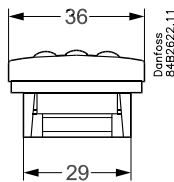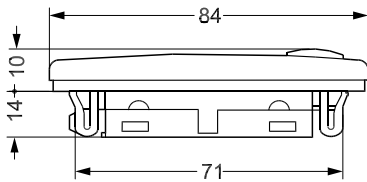

$0 < t_{amb} < +55^{\circ}\text{C}$   
Non condensing  
IP 20

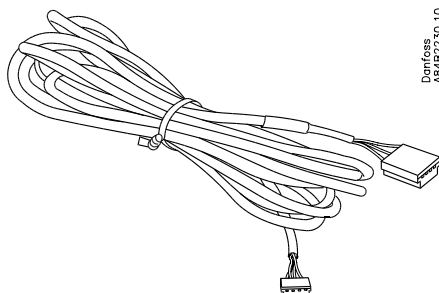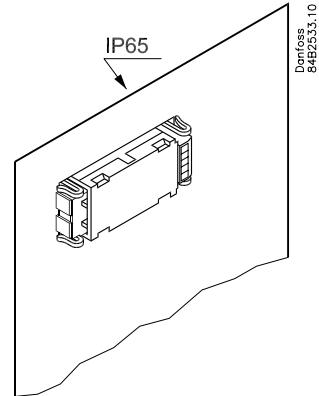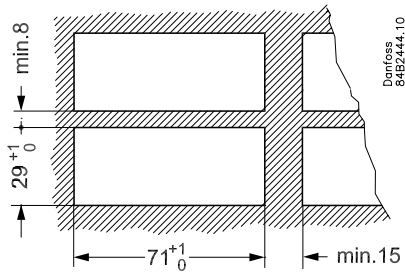

Max. 10 m  
( 2 m: 084B7298)  
( 6 m: 084B7299)