


Installation guide Pressure switch Types KP 1 and KP 7W

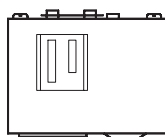

060R9760







060R9760




Type	Range	PS/MWP
KP 1	-0.2 – 7.5 bar	17 bar/245 psi
KP 7	8 – 32 bar	35 bar/510 psi




PS/MWP

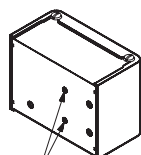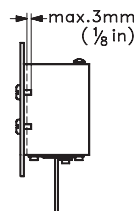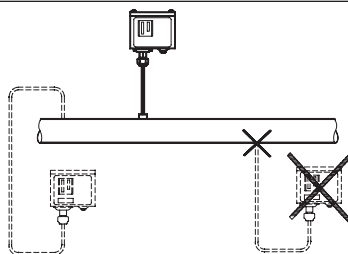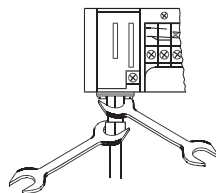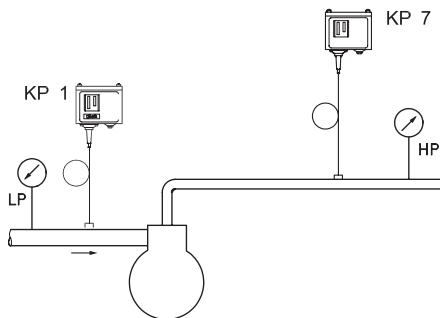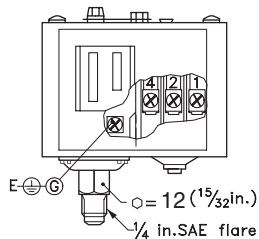

M4 (8 – 32 UNC)

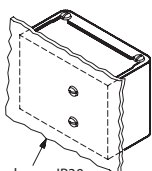

Enclosure IP30
(EN 60529)

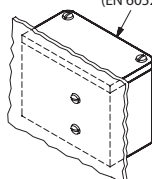



Enclosure IP44
(EN 60529)





CAUTION:

Disconnect power supply before wiring connections are made or service to avoid possible electrical shock or damage to equipment.
Do never touch live parts with your fingers or with any tool.



KP 1

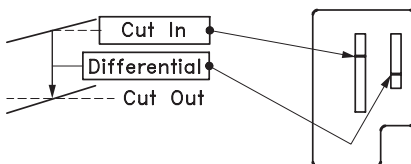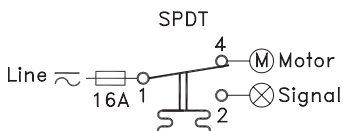

KP 7

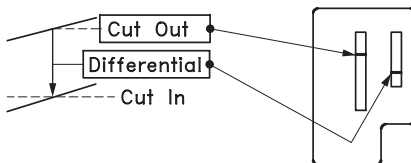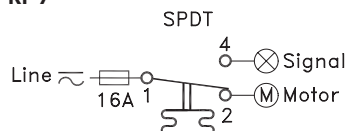

Manual trip function

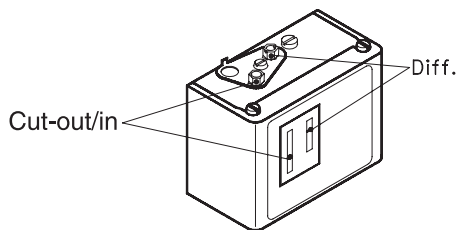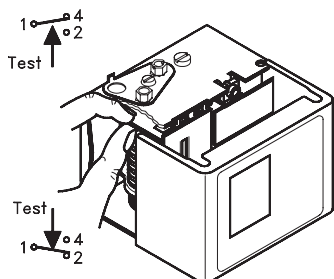

Electrical rating - General

LR 112A	AC 1: 16A	400 V	DC 11
	AC 3: 16A		
	AC 15: 10 A		
			12 W
			220 V

When used acc. to UL regulations



Listed refrigeration controller 61B5

Voltage	FL	LR	Resist.	Pilot
AC	DC	A	load	duty
240		8	48	8 A
120		16	96	16 A
	240			3 A
				12 W

Use copper wire only
Tightening torque 20 lb.in.

