


Installation guide


Solenoid valve

Type EV220B 6 - EV220B 22

032R9328

032R9328

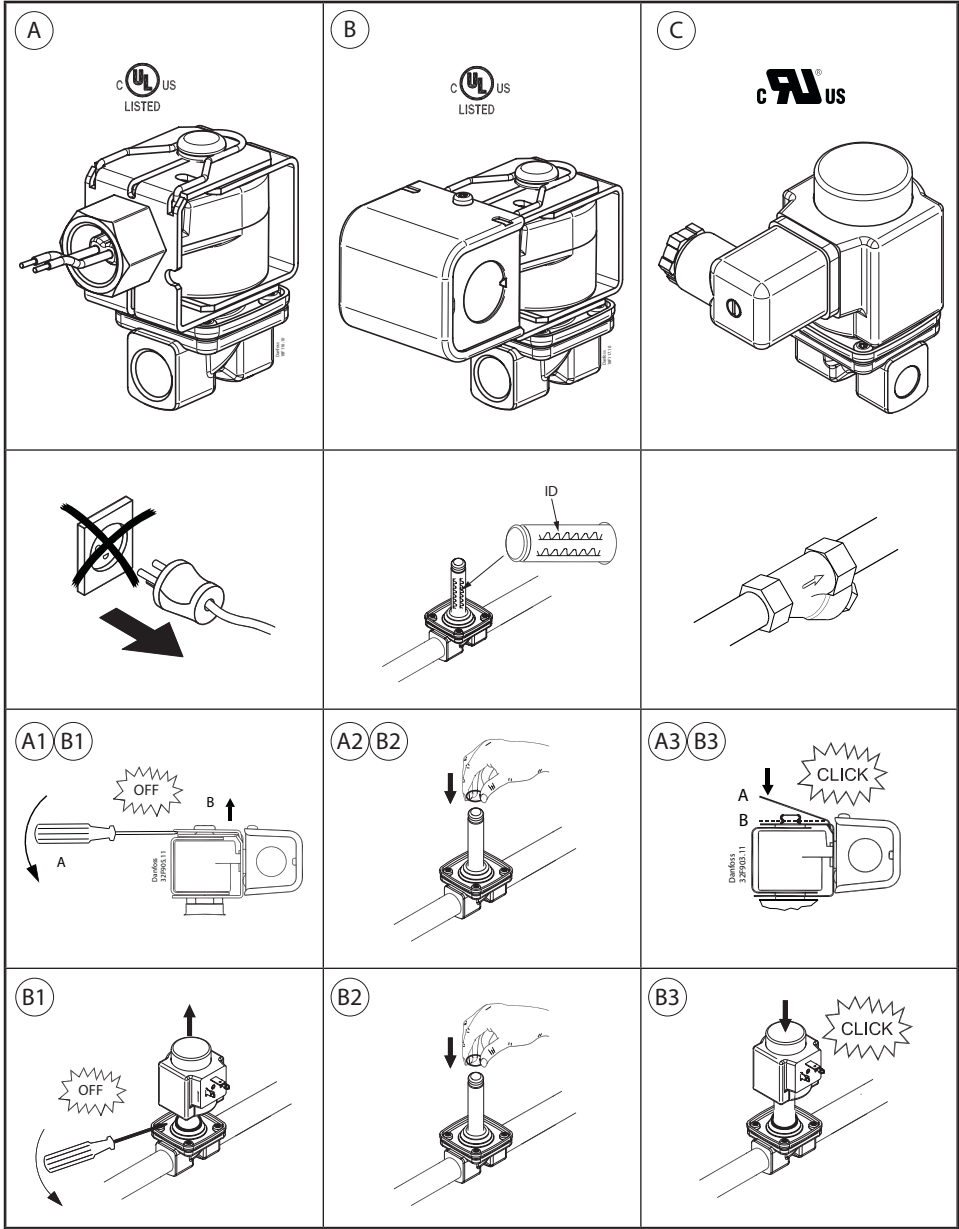

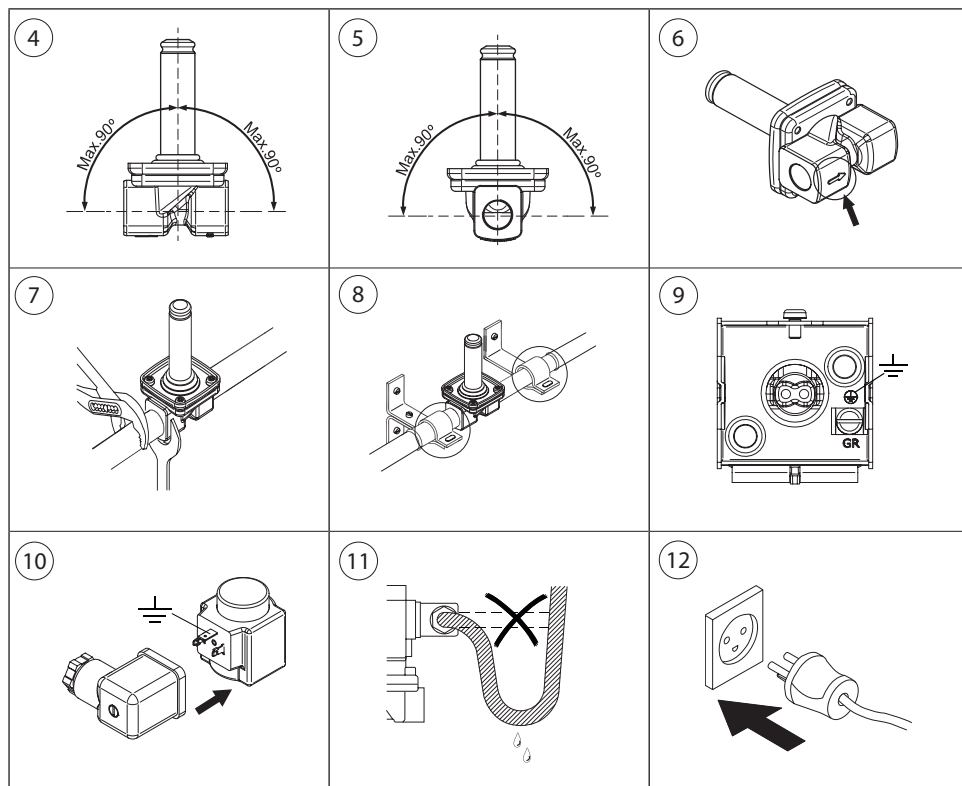

13

DN	MWP		Max. test pressure PT	
	[bar]	[psi]	[bar]	[psi]
6 - 10	20	290	30	435
11.5 - 22	10	145	15	225

EN 60730-2-8

Visit www.products.danfoss.com for further technical data