

Installation Guide **Differential pressure valve** **Type NRD**

020R9622


Refrigerants: **HCFC, HFC and HC**

Applicable to all common non-flammable / flammable refrigerants, excluding R717 and to noncorrosive gases / liquids dependent on sealing material compatibility.
 The design pressure shall not be less than the value outlined in Section 9.2 of ANSI / ASHRAE 15 for the refrigerant used in the system.

Max. Working Pressure:
 PS/MWP = 46 bar (667 psi)

Media temperature:
 Min. -50 °C (-58 °F)
 Max. 140 °C (285 °F)

020R9622

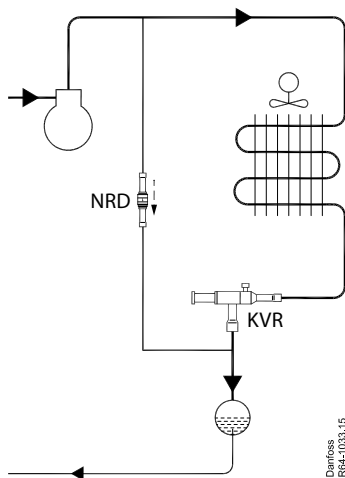

Danfoss
 R64-1035.15

