



Installation guide

Thermostatic element


Type AVTB

003R9085


003R9085

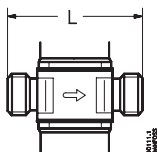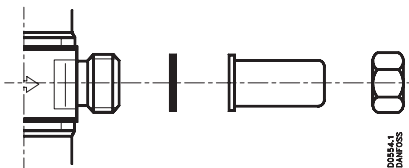




DN	L [mm]
15	75
20	80
25	83

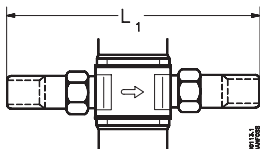

DN	L ₁ [mm]
15	141
20	152
25	167

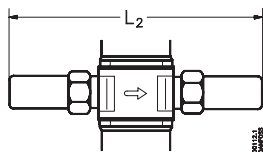

DN	L_2 [mm]
15	149
20	164
25	167

 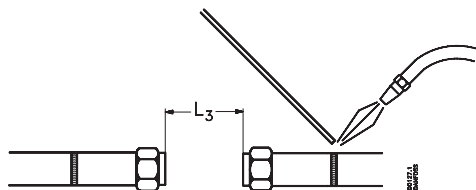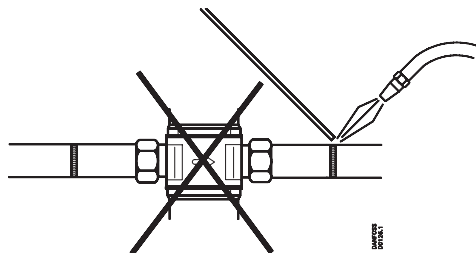

DN	L_3 [mm]
15	79
20	84
25	87