


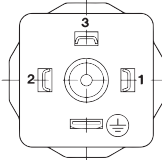
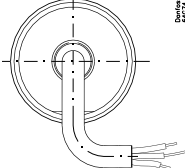
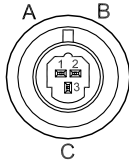

 

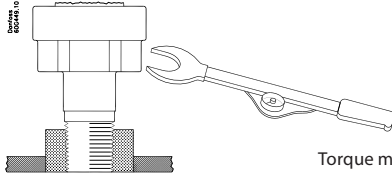




Installation Guide

**Pressure Transmitters**

MBS 1900

<p>064R9301</p>  	<p>Electrical connection: .....See product label          Elektrisk tilslutning: .....Se produktskilt          Elektrischer Anschluss: .....Siehe Produktschild          Raccordement électrique:.....Voir étiquette du produit          Conexión eléctrica:.....Ver la pegatina en el producto          Connessione elettrica: .....vedi etichetta sulla confezione</p>		
	<p>EN 175301-803</p>  <p>Not connected to enclosure          Ikke forbundet til kapsling          Kein Anschluss an Gehäuse          Pas connecté au boîtier          No conectado a la cubierta          Non collegato al corpo</p>	<p>2 m cable</p> 	<p>Round Packard metripack 150.2</p> 
			
	 <p>Torque max. 20Nm</p>		
		<p>American and Canadian approvals:          Must be powered by Class 2 power supply          Temperature indicating and regulating equipment acc. to UL 873,          file no. E31024</p>	

064R9301