

# Installation accessories

Fact sheet

**DEVI**®   
by Danfoss

Make it easy,  
make it **DEVI**









# Accessories

## Fact sheet

Make it easy,  
**make it DEVI**

### Index

1.	Fastening for down pipes	4
2.	Fastening for roof and gutters	6
3.	Fastening	8
4.	Fastening for ground and concrete constructions	9
5.	Tapes / Glue	11

# 1. Fastening for down pipes

## DEVIfast™ Double Special RB 25m



Art. no. **19808185**  
EAN no. **5703466240397**

Metal fixing tape for resistive heating cable.

Width	50 mm
Length	25 m
Fixing distance	10 cm (on one side)
Cable C-C distance	30-35 mm
Material	Galvanized steel
Minimum order quantity	1 roll with 25 m
Suitable products	<b>DEVIsafe™, DEVIsnow™</b>

## DEVIfast™ Double for SLC RB 25m



Art. no. **19808183**  
EAN no. **5703466240380**

Metal fixing tape for self-limiting heating cables.

Width	65 mm
Length	25 m
Fixing distance	15 cm (on one side)
Cable C-C distance	40-45 mm (SLC)
Material	Galvanized steel
Minimum order quantity	1 roll with 25 m
Suitable products	<b>DEVliceguard™ 18</b>

## Cable fixing for down - pipe suspension



Art. no. **19805258**  
EAN no. **5703466003763**

Plastic fixing elements for fixing resistive heating cable on the chain

Dimensions	37 x 20 x 6 mm
Chain hole size	8 mm
Packaging	1 bag with 25 pcs.
Minimum order quantity	1 bag with 25 pcs.
Suitable products	<b>DEVIsafe™, DEVIsnow™</b>

## Entlastungsseil



Art. no. **19406016**  
EAN no. **5703435003022**

Cord for fixing relief clip in downpipes

Dimensions	500 x 15 x 1 mm
Cut-to-length	1 m
Minimum order quantity	1 m
Suitable products	<b>Relief clip for drain pipes</b>

## Longlinked chain 4 mm c4 x 32 din 5685 fzn



Art. no. **19805241**  
EAN no. **5703435003060**

Chain for fixing down - pipe suspension in downpipes

Dimensions	Chain size 4x8 mm, 25 m
Chain hole size	8 mm
Cut-to-length	1...25 m
Minimum order quantity	1 m
Suitable products	<b>DEVIsafe™, DEVIsnow™, DEVliceguard™</b>

## Traverse v 2 a



Art. no. **19805449**  
EAN no. **5703435003077**

Traverse for fixing chain and cord on the top of downpipes

Dimensions	288 x 25 x 5 mm
Minimum order quantity	1 pcs.
Suitable products	<b>Longlinked chain, Entlastungsseil</b>

**Relief clip for drain pipes**

 Art. no. **19406008**  
 EAN no. **5703435003015**

Relief clip for fixing resistive heating cable to the cord

Dimensions 50 x 10 x 10 mm

Minimum order quantity 10 pcs.

 Suitable products **DEVIsafe™, DEVIsnow™**
**Relief clip single for drain pipes**

 Art. no. **19406007**  
 EAN no. **5703466154229**

Relief clip for fixing resistive heating cable to the cord

Dimensions 35 x 10 x 10 mm

Minimum order quantity 10 pcs.

 Suitable products **DEVIsafe™, DEVIsnow™**

**Fig. 1**
*Down pipes with DEVIfast™ Double for resistive and self-limiting heating cables.*



## 2. Fastening for roof and gutters

### DEVIfast™ Double Special RB 25m



Art. no. **19808185**  
EAN no. **5703466240397**

Metal fixing tape for resistive heating cable.

Width	50 mm
Length	25 m
Fixing distance	10 cm (on one side)
Cable C-C distance	30-35 mm
Material	Galvanized steel
Minimum order quantity	1 roll with 25 m
Suitable products	<b>DEVIsafe™ DEVIsnow™</b>

### DEVIfast™ Double for SLC RB 25m



Art. no. **19808183**  
EAN no. **5703466240380**

Metal fixing tape for self-limiting heating cables.

Width	65 mm
Length	25 m
Fixing distance	15 cm (on one side)
Cable C-C distance	40-45 mm (SLC)
Material	Galvanized steel
Minimum order quantity	1 roll with 25 m
Suitable products	<b>DEVliceguard™ 18</b>

### DEVIfast™ Copper 25 m In box



Art. no. **19808238**  
EAN no. **5703466214695**

Copper type is used for fastening heating cables and ensure the correct C-C distance.

Length	25 m
Width	21 mm
Material	Copper.
Minimum order quantity	25 m in 1 box
Cable C-C fixing	in each 25 mm
Suitable products	<b>DEVIsafe™, DEVIsnow™</b>

### DEVlclip™ roofhook, installation kit



Art. no. **19805192**  
EAN no. **5703466134757**

Fixing elements for heating cables fixed on the roof edges

Roofhook	25 pcs.
Cable Strip 7,6x203 mm, black	25 pcs.
Minimum order quantity	1 bag with 25 pcs.
Suitable products	<b>DEVIsafe™ DEVIsnow™, DEVliceguard™ 18</b>

### DEVlclip™ guardhook Install. kit



Art. no. **19805193**  
EAN no. **5703466145470**

Fixing elements for heating cables fixed on the roof edges

Base Roof accessories	20 pcs.
Angle Roof accessories	10 pcs.
Cable Strip 7,6x203 mm, black	30 pcs.
Minimum order quantity	1 bag with 20 + 10 +30 pcs.
Suitable products	<b>DEVIsafe™ DEVIsnow™, DEVliceguard™ 18</b>


### Roof Gutter Clip with hinge




Art. no. **140F1511**  
EAN no. **5703466229897**

Fixing elements for resistive heating cables fixed in the gutter

Minimum order quantity	1 bag with 25 pcs.
Suitable products	<b>DEVIsafe™, DEVIsnow™</b>

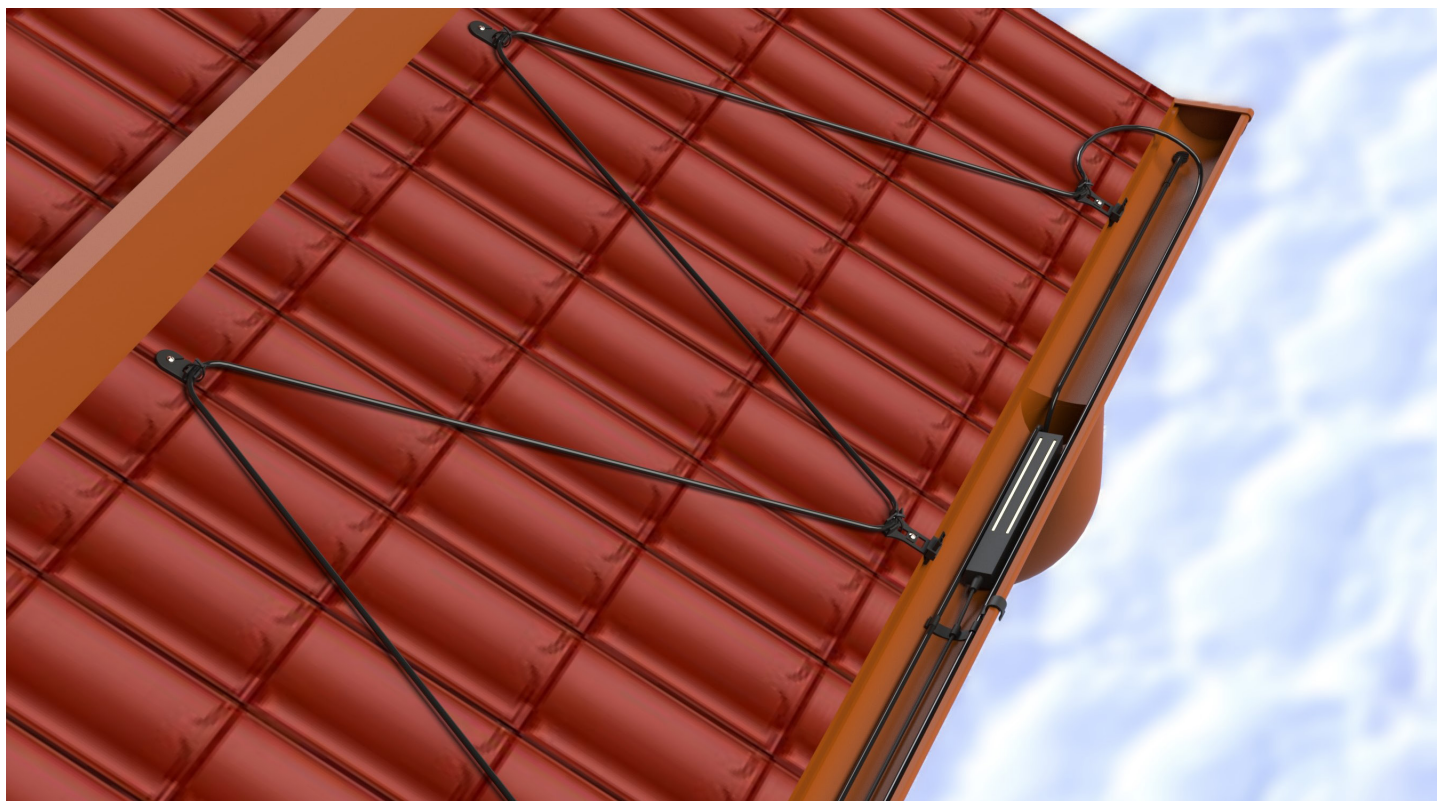**Fig. 2**

*Roofedges and gutters with DEVIClip™ guardhook, Roof Gutter Clip, DEVIClip™ roofhook and DEVIfast™ Double.*

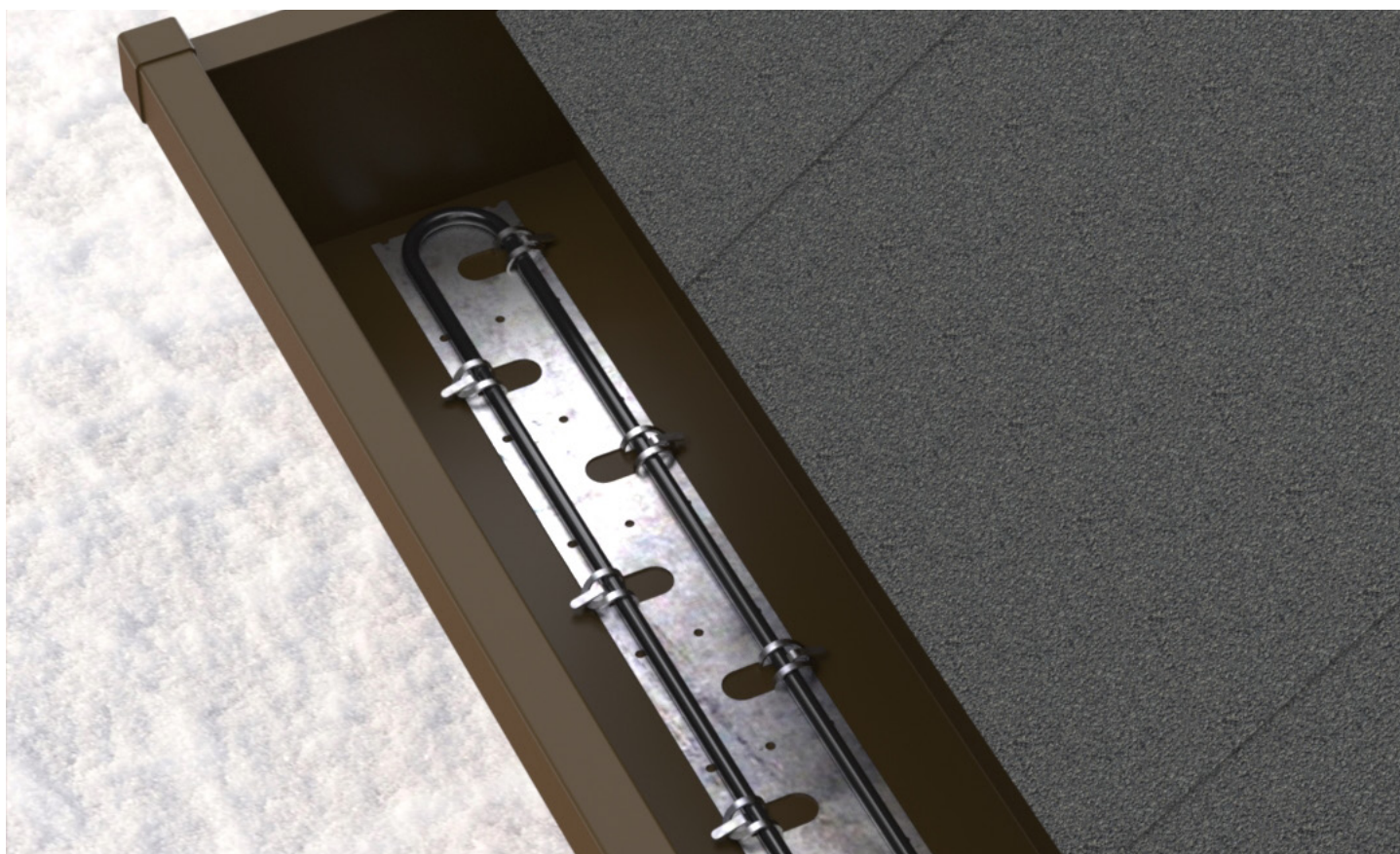

## 3. Fastening

### Heizbandhalter v2a 10 cm cc 10 cm



Art. no. **19805300**  
EAN no. **5703466075104**

Metal fixing elements for fastening heating cables and ensure the correct C-C distance

Dimensions 1000 mm x 30 mm

Cable C-C fixing in each 10 cm

Minimum order quantity 1 pcs.

Suitable products **DEVIsafe™ DEVIsnow™**  
**DEVliceguard™ 18**

### Heizbandhalter v2a 15 cm cc 15 cm



Art. no. **19805301**  
EAN no. **5703466195789**

Metal fixing elements for fastening heating cables and ensure the correct C-C distance

Dimensions 1000 mm x 30 mm

Cable C-C fixing in each 15 cm

Minimum order quantity 1 pcs.

Suitable products **DEVIsafe™ DEVIsnow™**  
**DEVliceguard™ 18**

### Spaceclip for self-limiting cables



Art. no. **19805746**  
EAN no. **5703435010501**

Dimensions 300 x 30 x 1,5 mm

Material stainless steel AISI 304

Cable C-C fixing in each 8 cm

Minimum order quantity 1 pcs.

Suitable products **DEVIsafe™ DEVIsnow™**  
**DEVliceguard™ 18**

### Cable ties



Art. no. **00109004**  
EAN no. **5703466090282**

Cable ties for fixing heating cable to fixing elements

Dimensions 187 x 4,7 x 1,5 mm

Minimum order quantity 1 bag with 100 pcs.

Suitable products All type of heating cable



# 4. Fastening for ground and concrete constructions

## DEVclip™ C-C



Art. no. **19805220**  
EAN no. **5703466173213**

Plastic fixing elements for fastening heating cables and ensure the correct C-C distance

Dimensions 500 x 46 x 10 mm

Cable C-C fixing in each 10 mm

Minimum order quantity 20 pcs. in bag.

Suitable products **DEVibasic™, DEViflex™, DEVIsnow™, DEVIsafe™**

## DEVICLIP™ Twisto



Art. no. **19805236**  
EAN no. **5703466172117**

Used with reinforcement mesh up to 6 mm

Minimum order quantity Plastic Bag with 1000 pcs.

Suitable products **DEVibasic™, DEViflex™, DEVIsnow™, DEVIsafe™**

## DEVifast™ Metal 5 m In box



Art. no. **19808234**  
EAN no. **5703466214671**

Metal type is used for fastening heating cables and ensure the correct C-C distance.

Length 5 m

Width 21 mm

Material Metal covered by galvanized zinc

Cable C-C fixing in each 25 mm

Minimum order quantity 1 box with 5 m

Suitable products **DEVibasic™, DEViflex™, DEVIsnow™, DEVIsafe™, DEVIsphalt™**

## DEVifast™ Metal 25 m In box



Art. no. **19808236**  
EAN no. **5703466214688**

Metal type is used for fastening heating cables and ensure the correct C-C distance.

Length 25 m



Width 21 mm

Material Metal covered by galvanized zinc

Cable C-C fixing in each 25 mm

Minimum order quantity 1 box with 25 m

Suitable products **DEVibasic™, DEViflex™, DEVIsnow™, DEVIsafe™, DEVIsphalt™**

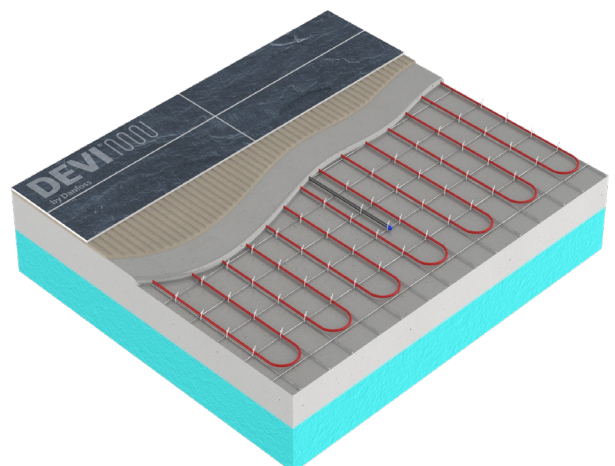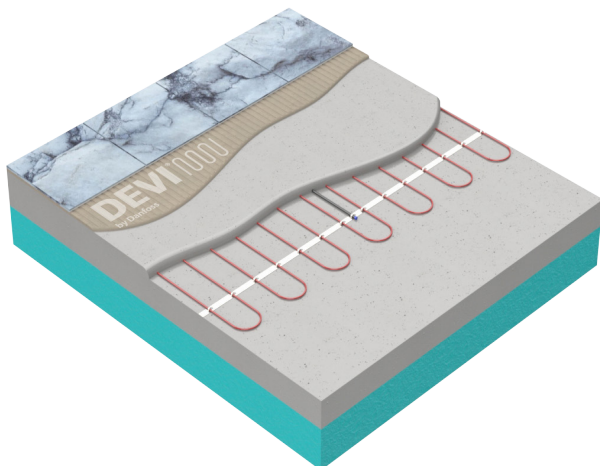


**Fig. 3**

Concrete installations with DEVifast™ Metal and DEVICLIP™ Twisto for reinforcement mesh.

## 4. Fastening for ground and concrete constructions

### Montagestege type ms 5,6-6,5 mm - 25mm

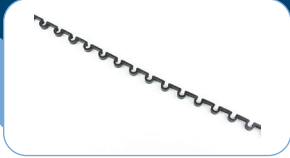

Art. no. **109030**  
EAN no. **5703466134740**

Plastic fixing elements for fastening heating cables and ensure the correct C-C distance

Dimensions 980 x 10 x 10 mm

Cable C-C fixing in each 25 mm

Minimum order quantity 1 pc

Suitable products **DEVlbasic™**

### Montagestege type ms 6,6-8,0 mm - 25mm



Art. no. **19805266**  
EAN no. **5703435009222**

Plastic fixing elements for fastening heating cables and ensure the correct C-C distance

Dimensions 980 x 10 x 10 mm

Cable C-C fixing in each 25 mm

Minimum order quantity 1 pc

Suitable products **DEVlflex™, DEVlsnow™, DEVIsafe™**

### Synthetic nail



Art. no. **19805907**  
EAN no. **5703466249536**

Synthetic nail for fixing heating mat to subfloor

Minimum order quantity 1 box with 40 pcs.

Suitable products **DEVlmat™, DEVlcomfort™, DEVlheat™**



# 5. Tapes / Glue

## Acrylic coated cloth tape 15 mm x 50 m (Textilklebeband)



Art. no. **19405877**  
EAN no. **5703435002971**

Strong acrylic coated cloth tape for almost every application with high adhesion even on rough surfaces, e.g. for fixing cable to concrete or on pipe, insulating of wires, etc.

Dimensions	15 mm x 50 m
Color	gray
Backing material	acrylic-coated cloth
Total thickness	310 µm
Type of adhesive	natural rubber
Adhesion to steel	3.3 N/cm
Tensile strength	100 N/cm
Temperature resistance	130 °C (30 min)
Minimum order quantity	1 plastic bag with 50 m
Suitable products	All type of heating cables

## Tape aluminium 38 mm x 50 m



Art. no. **19805076**  
EAN no. **5703435003053**

Self-adhesive, with 2-colour warning text, max. 160 °C

Dimensions	38 mm x 50 m
Backing	Aluminium foil
Adhesive	Waterbased Acrylic
Liner	Monosiliconized Paper
Adhesion/Steel	8 N/ 38 mm
Tensile strength	57,5 N/ 38 mm
Total thickness	60 µm
Minimum order quantity	1 plastic bag with 50 m
Suitable products	<b>Self-limiting heating cables</b>

## Tape aluminium 25 mm x 25 m



Art. no. **19805078**  
EAN no. **5703466130469**

Self-adhesive, with 2-colour warning text, max. 160 °C.

Dimensions	25 mm x 25 m
Backing	Aluminium foil
Adhesive	Waterbased Acrylic
Liner	Monosiliconized Paper
Adhesion/Steel	8 N/ 25 mm
Tensile strength	57,5 N/ 25 mm
Total thickness	60 µm
Minimum order quantity	1 plastic bag with 25 m
Suitable products	<b>Resistive heating cables</b>

## Hotmelt gluesticks



Art. no. **18055351**  
EAN no. **5703466114940**

Hotmelt gluesticks for fixing resistive heating cable to the floor

Dimensions	170 x 250 x 20 mm
Minimum order quantity	1 bag with 25 pcs.
Suitable products	<b>Resistive heating cables</b>

**Danfoss A/S**

DEVI • [devi.com](http://devi.com) • +45 7488 2222 • [EH@danfoss.com](mailto:EH@danfoss.com)

Any information, including, but not limited to information on selection of product, its application or use, product design, weight, dimensions, capacity or any other technical data in product manuals, catalogues descriptions, advertisements, etc. and whether made available in writing, orally, electronically, online or via download, shall be considered informative, and is only binding if and to the extent, explicit reference is made in a quotation or order confirmation. Danfoss cannot accept any responsibility for possible errors in catalogues, brochures, videos and other material. Danfoss reserves the right to alter its products without notice. This also applies to products ordered but not delivered provided that such alterations can be made without changes to form, fit or function of the product.

All trademarks in this material are property of Danfoss A/S or Danfoss group companies. Danfoss and the Danfoss logo are trademarks of Danfoss A/S. All rights reserved.