


DEVIflex™ 175T



Make it easy,
make it DEVI

Product
is covered
by **EPD***

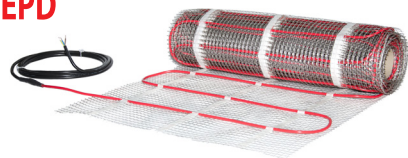

DEVIflex™ readymade heating mat is an extremely high-quality, 360° fully screened twin conductor cable with a tough outer sheath (not UV resistant) fixed on the plastic mesh. Its round profile

and robust construction ensures a fast, simple and safe installation in multiple indoor floor constructions.

Heating cable must be used together with an appropriate thermostat to secure against overheating and reduce energy consumption.

Heating mat is designed to be embedded in concrete or similar.

Cold lead connection point is protected from water ingress by a removable cap. The cold lead is an installation cable with solid conductors ensuring fast

installation. A clearly visible connection avoids accidentally installing the heated element in the wall.

To ensure a long life-time, all mats are minutely inspected including tests for Ohmic resistance, high voltage and material controls to ensure the quality. This means that we are proud to supply our full floor extended DEVI Warranty.

***An EPD** is a document used to communicate transparently, the quantified environmental impacts of a product over its life cycle stages.

Benefits:

- Fast and easy to install
- Safe and robust
- Long life-time
- Maximum protection
- Multiple application options

Standard compliance:

- IEC60800:2009

Compliance symbols:



20
YEAR
WARRANTY



Product



Installation



Floor/Surface

Type	Value
Nominal voltage	230 V~
Construction	Round, twin conductor with 360° screening, one cold lead
Output	175 W/m ² @ 230 V~
Max. permissible use temperature, powered	60 °C
Max. permissible use temperature, unpowered	90 °C
Cable thickness	6,9 mm
Deformation strength	1500 N
Pulling strength	400 N
Conductor insulation	XLPE
Outer sheath	PVC, red
Screen	100% coverage; alu-foil; 0,5 mm ² tinned copper drain wire
Cold lead	6 m DTCL, 3G (1,5 or 2,5)mm ²
Min. installation temperature	-5 °C
Bending Ø, min.	5 cm
IP Class	IPX7



[Click to download - BIM model](#)

Types: DEVIflex™ 175T

Item no.	Heated area	Dimensions (W x L)	Output @ 230V~	Resistance	Cold lead	EAN no.
140F1479	1,1 m ²	0,75 x 1,4 m	180 W	295,9 Ohm	3 x 1,5 mm ²	5703466253557
140F1480	1,5 m ²	0,75 x 2,0 m	265 W	201,5 Ohm	3 x 1,5 mm ²	5703466253113
140F1481	2,7 m ²	0,75 x 3,6 m	465 W	113,6 Ohm	3 x 1,5 mm ²	5703466253120
140F1482	3,8 m ²	0,75 x 5,0 m	665 W	79,8 Ohm	3 x 1,5 mm ²	5703466253137
140F1483	5,3 m ²	0,75 x 7,0 m	915 W	57,8 Ohm	3 x 1,5 mm ²	5703466253144
140F1484	7,5 m ²	0,75 x 10,0 m	1310 W	40,3 Ohm	3 x 1,5 mm ²	5703466253151
140F1485	8,6 m ²	0,75 x 11,4 m	1510 W	34,9 Ohm	3 x 1,5 mm ²	5703466253168
140F1486	12,0 m ²	0,75 x 16,0 m	2090 W	25,3 Ohm	3 x 2,5 mm ²	5703466253175
140F1487	15,6 m ²	0,75 x 20,8 m	2750 W	19,2 Ohm	3 x 2,5 mm ²	5703466253182