

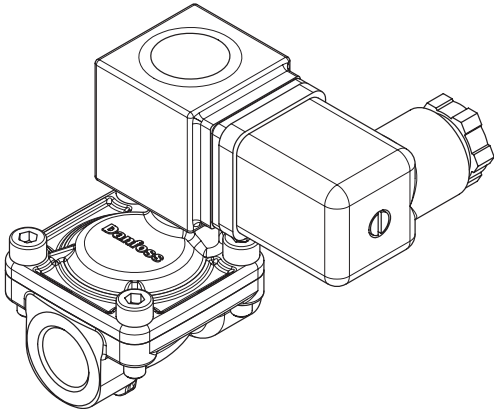
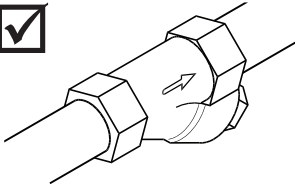
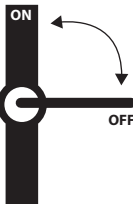
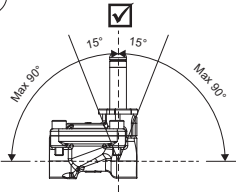
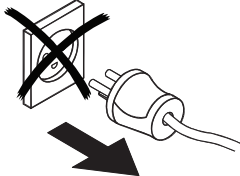
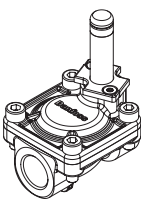
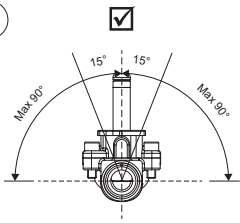
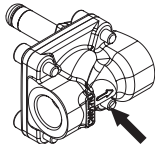
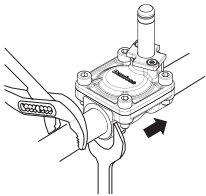
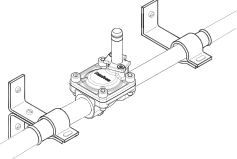
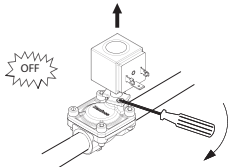
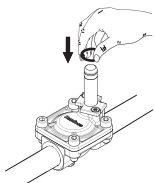
Installation guide

Solenoid valve
Type EV220S 10-50

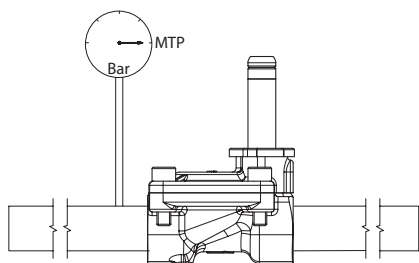
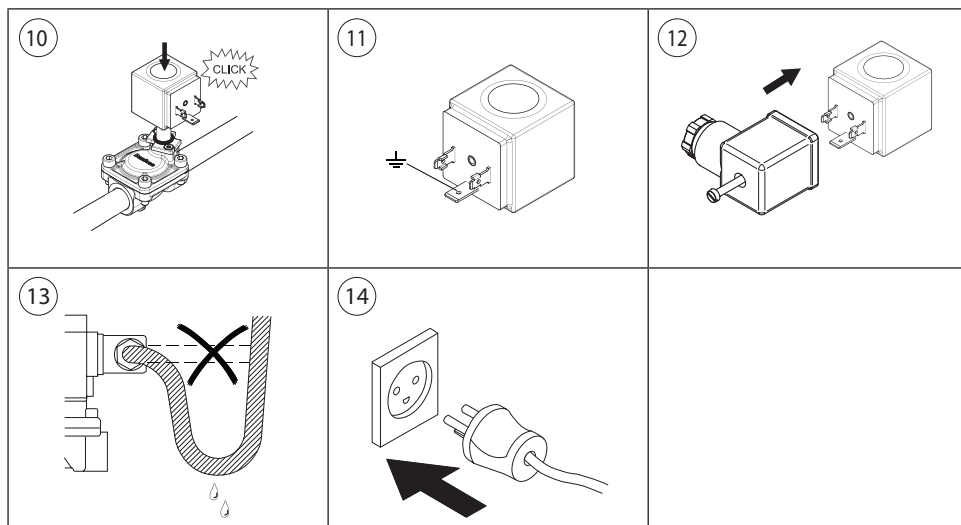
UK
CA

042R9000

042R9000

			  ≥ 297 Microns
			 ON OFF 
1	2	3	
			
4	5	6	
			
7	8	9	
			

Info for UK customers only: Danfoss Ltd. Oxford Road, UB9 4LH Denham, UK



DN	Max. Working Pressure (MWP)	Max. Test pressure (MTP)
	[bar]	[bar]
10 - 50	10	15
EN 60730-2-8		

Besök www.danfoss.se för mer tekniska data. Besøg www.danfoss.dk for flere tekniske data.

Rendez-vous sur le site www.products.danfoss.fr pour plus de données techniques.

Visit www.products.danfoss.com for further technical data. Para más información, visite www.products.danfoss.es