



# Installation guide

## Thermostat


### Types CAS 178, CAS 180, CAS 181




060R9305

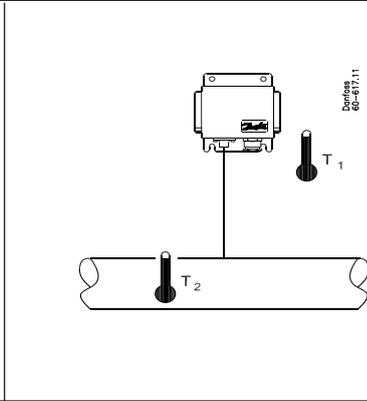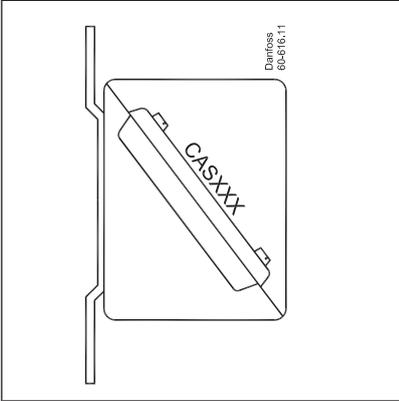



Type	T <sub>2</sub> max.	T <sub>1</sub> min.	T <sub>1</sub> max.
	[°C]		
CAS 178	130	-25	70
CAS 180	220		
CAS 181	250		

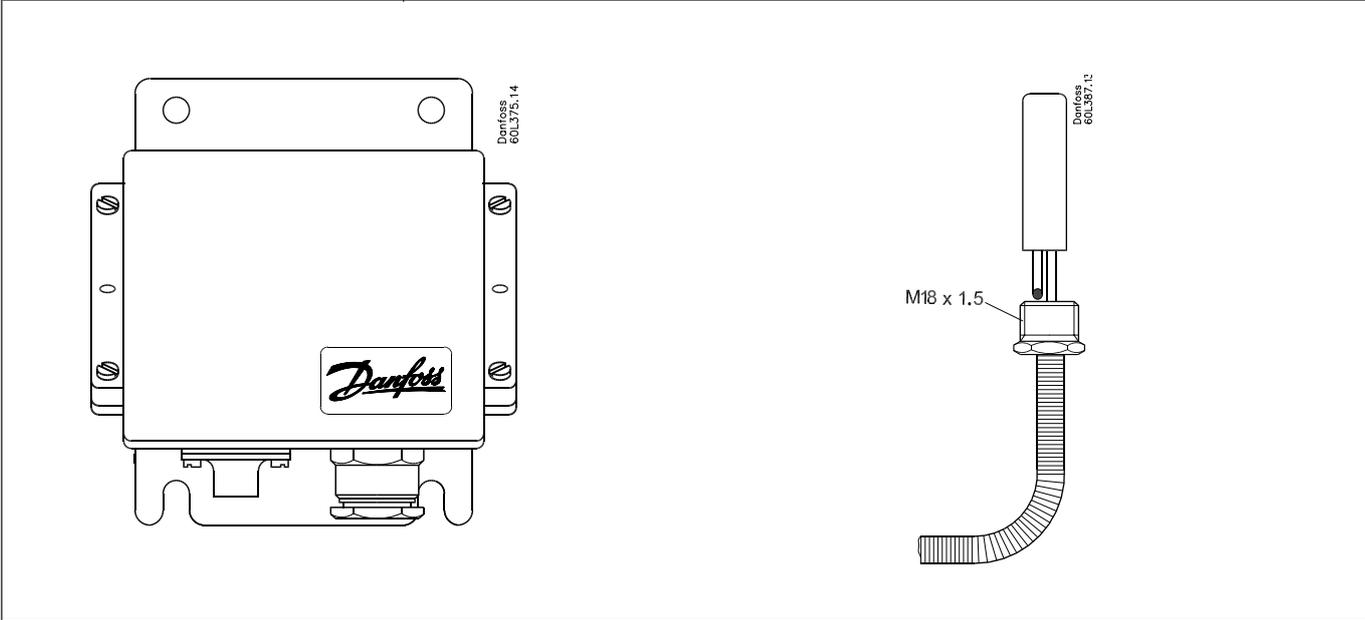

Імпортёр: ТОВ з іі "Данфосс ТОВ" 04080, Київ 80, п/с 168, Україна

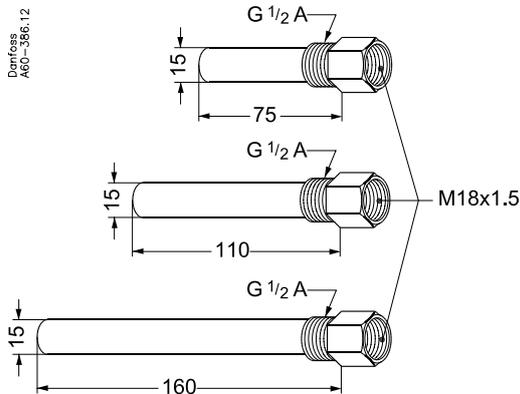

L [mm]	Code no.	
	Brass	Steel 18/8
75	060L326266	060L326766
110	060L327166	060L326866
160	060L326366	060L326966

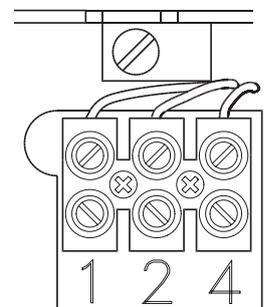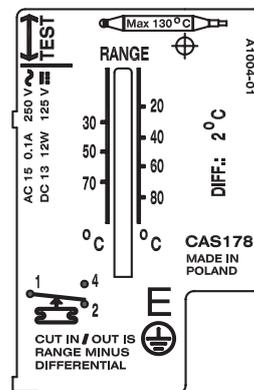

Danfoss  
60L1049.11

060R9305

Info for UK customers only: Danfoss Ltd., 22 Wycombe End, HP9 1NB, GB

