


Installation guide

Pressure switch

Types CAS 133 – CAS 147



060R9304

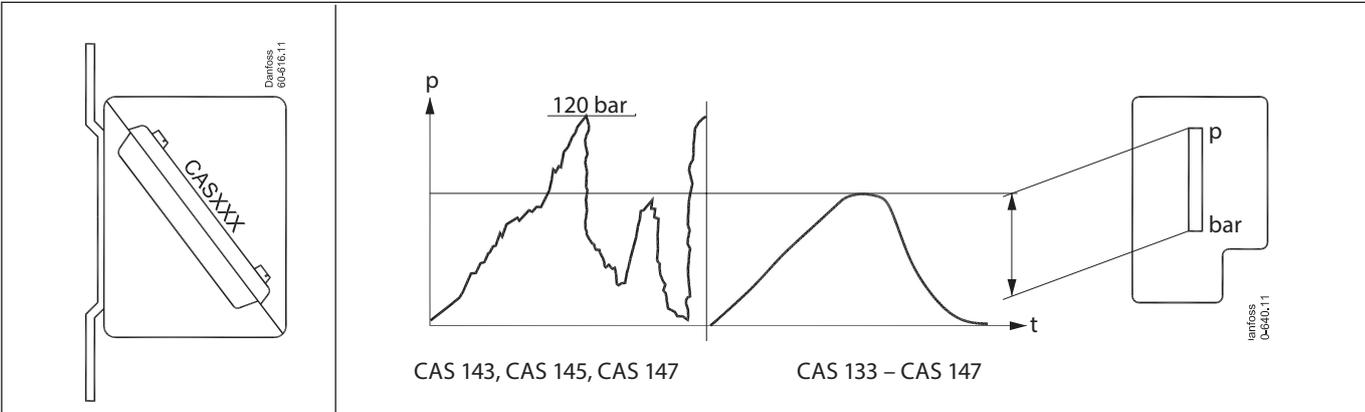

Type	T ₁ min.	T ₂ min.	T ₁ max.	T ₂ max.*
	[°C]			
CAS 133, CAS 136, CAS 137, CAS 139	-40	-40	70	100
CAS 143, CAS 145, CAS 147	-25	-25		

* T₂ max. for water and seawater, max. 80 °C


Імпортер: ТОВ з іі "Данфосс ТОВ" 04080, Київ 80, п/с 168, Україна

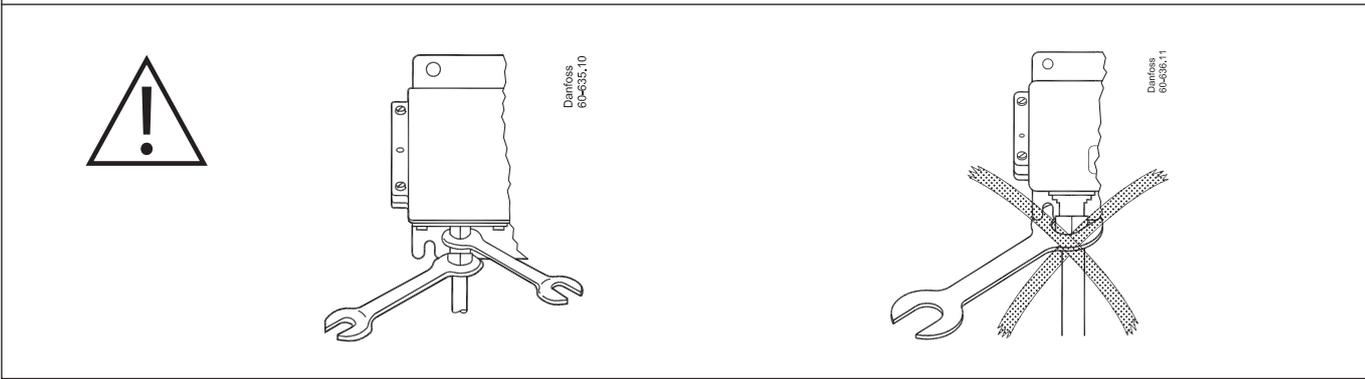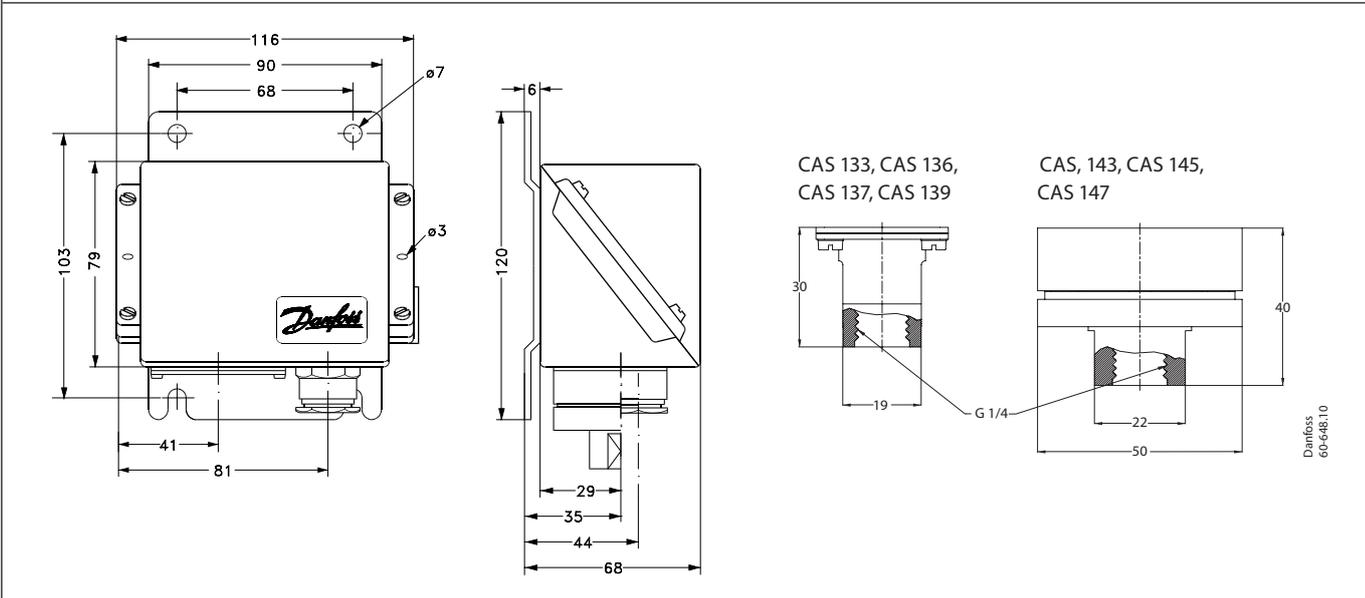



060R9304

Info for UK customers only: Danfoss Ltd., 22 Wycombe End, HP9 1NB, GB

Type	P max. [bar]
CAS 133	10
CAS 136	22
CAS 137	27
CAS 139	53
CAS 143	180
CAS 145	
CAS 147	


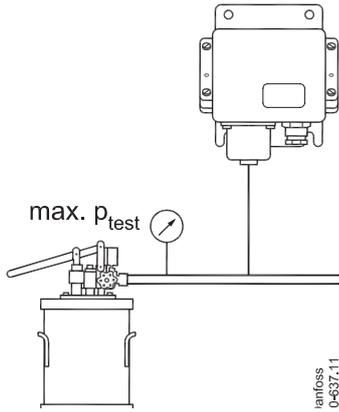


Danfoss 0-637.11

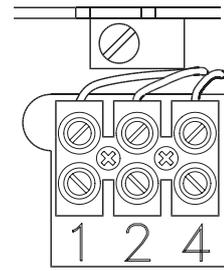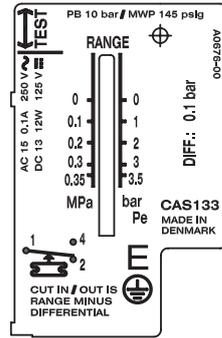


Danfoss 60L641.13


Type	Diff. [bar]
CAS 133	0.1
CAS 136	0.2
CAS 137	0.3
CAS 139	0.6
CAS 143	0.2 - 0.6
CAS 145	0.8 - 2.4
CAS 147	1.0 - 3.0

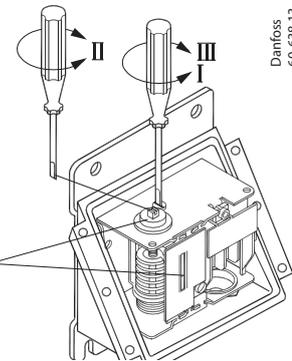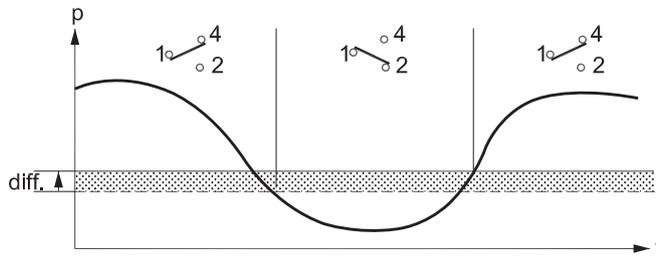


Danfoss 60-638.13

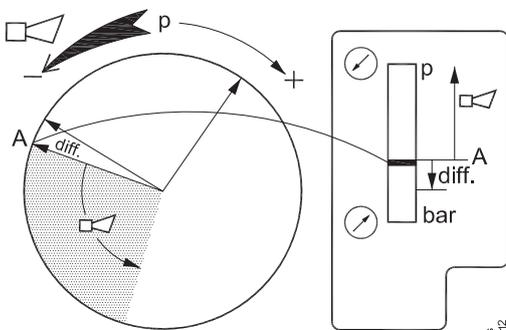


Danfoss 60-633.12

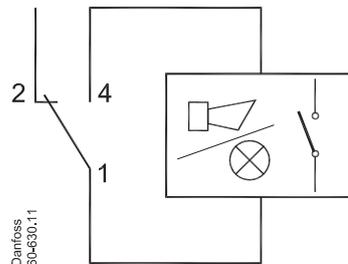


Danfoss 60-630.11

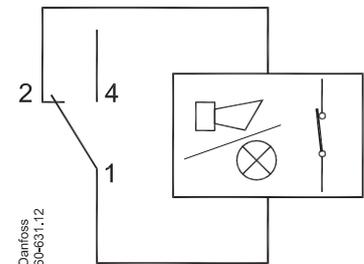


Danfoss 60-631.12

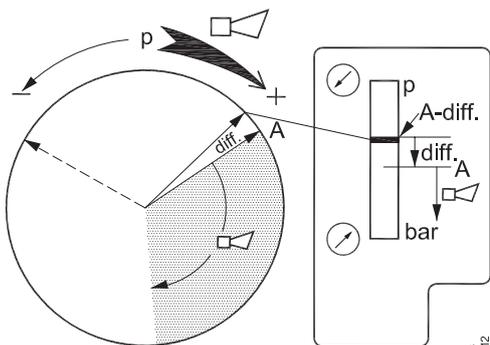

Danfoss 60-634.12

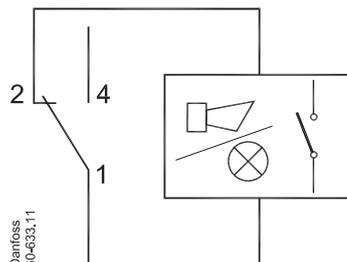

Danfoss 60-633.11

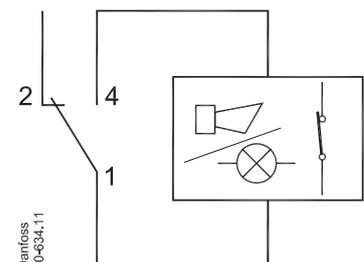

Danfoss 60-634.11