


Data sheet – Spare parts and accessories

Strainer housing, type FIA Strainer inserts and accessories

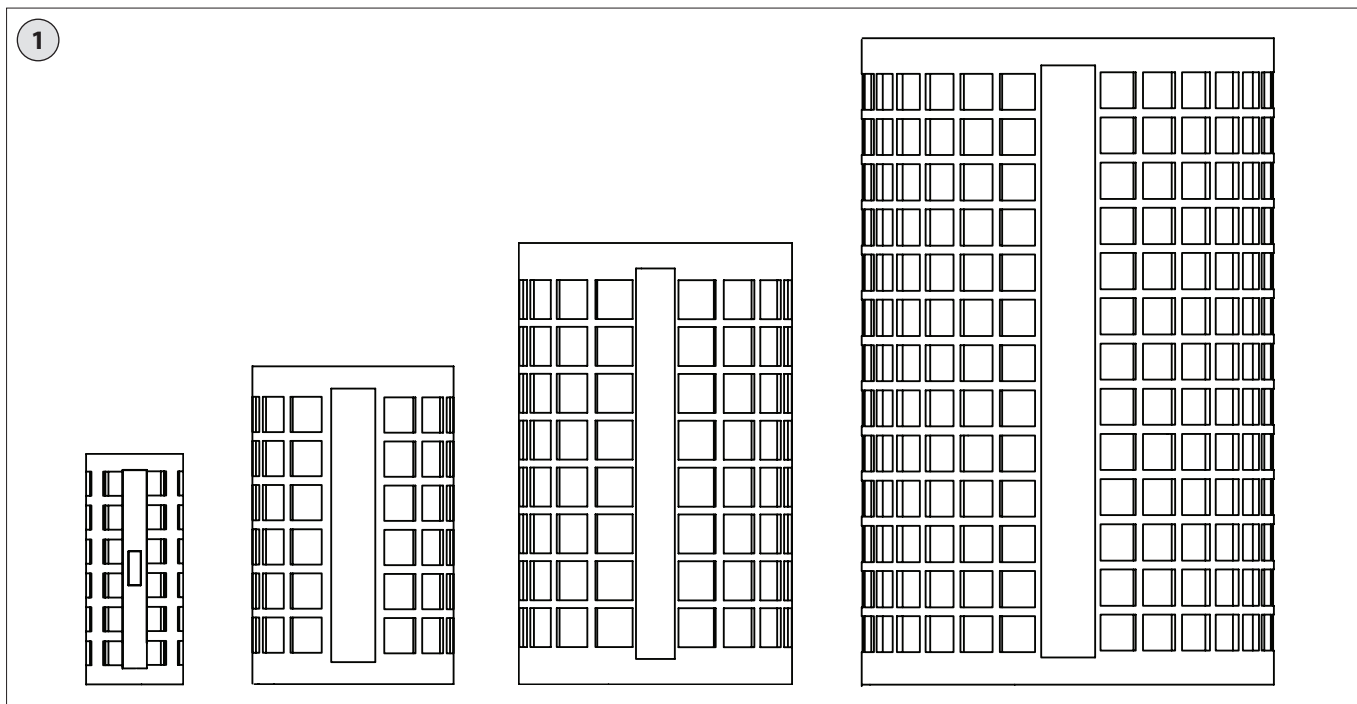

Size	Description	fig. #	Qty.	Code no.
------	-------------	--------	------	----------

Filter insert - plain

FIA 15	100µ / 150 mesh	1	1	148H3122
FIA 20	100µ / 150 mesh	1	1	148H3122
FIA 25	100µ / 150 mesh	1	1	148H3123
FIA 32	100µ / 150 mesh	1	1	148H3123
FIA 40	100µ / 150 mesh	1	1	148H3123
FIA 50	100µ / 150 mesh	1	1	148H3157

Filter insert - plain

FIA 15	150µ / 100 mesh	1	1	148H3124
FIA 20	150µ / 100 mesh	1	1	148H3124
FIA 25	150µ / 100 mesh	1	1	148H3125
FIA 32	150µ / 100 mesh	1	1	148H3125
FIA 40	150µ / 100 mesh	1	1	148H3125
FIA 50	150µ / 100 mesh	1	1	148H3130
FIA 65	150µ / 100 mesh	1	1	148H3131
FIA 80	150µ / 100 mesh	1	1	148H3119
FIA 100	150µ / 100 mesh	1	1	148H3132
FIA 125	150µ / 100 mesh	1	1	148H3133
FIA 150	150µ / 100 mesh	1	1	148H3134
FIA 200	150µ / 100 mesh	1	1	148H3135

Filter insert - plain

FIA 15	250µ / 72 mesh	1	1	148H3126
FIA 20	250µ / 72 mesh	1	1	148H3126
FIA 25	250µ / 72 mesh	1	1	148H3127
FIA 32	250µ / 72 mesh	1	1	148H3127
FIA 40	250µ / 72 mesh	1	1	148H3127
FIA 50	250µ / 72 mesh	1	1	148H3138
FIA 65	250µ / 72 mesh	1	1	148H3139
FIA 80	250µ / 72 mesh	1	1	148H3120
FIA 100	250µ / 72 mesh	1	1	148H3140
FIA 125	250µ / 72 mesh	1	1	148H3141
FIA 150	250µ / 72 mesh	1	1	148H3142
FIA 200	250µ / 72 mesh	1	1	148H3143

Filter insert - plain

FIA 15	500µ / 38 mesh	1	1	148H3128
FIA 20	500µ / 38 mesh	1	1	148H3128
FIA 25	500µ / 38 mesh	1	1	148H3129
FIA 32	500µ / 38 mesh	1	1	148H3129
FIA 40	500µ / 38 mesh	1	1	148H3129
FIA 50	500µ / 38 mesh	1	1	148H3144
FIA 65	500µ / 38 mesh	1	1	148H3145
FIA 80	500µ / 38 mesh	1	1	148H3121
FIA 100	500µ / 38 mesh	1	1	148H3146
FIA 125	500µ / 38 mesh	1	1	148H3147
FIA 150	500µ / 38 mesh	1	1	148H3148
FIA 200	500µ / 38 mesh	1	1	148H3149

Size	Description	fig. #	Qty.	Code no.
------	-------------	--------	------	----------

Filter insert - pleated

FIA 15	150µ / 100 mesh	1	1	148H3303
FIA 20	150µ / 100 mesh	1	1	148H3303
FIA 25	150µ / 100 mesh	1	1	148H3304
FIA 32	150µ / 100 mesh	1	1	148H3304
FIA 40	150µ / 100 mesh	1	1	148H3304
FIA 50	150µ / 100 mesh	1	1	148H3179
FIA 65	150µ / 100 mesh	1	1	148H3180
FIA 80	150µ / 100 mesh	1	1	148H3181
FIA 100	150µ / 100 mesh	1	1	148H3182
FIA 125	150µ / 100 mesh	1	1	148H3183
FIA 150	150µ / 100 mesh	1	1	148H3226
FIA 200	150µ / 100 mesh	1	1	148H3297

Filter insert - pleated

FIA 15	250µ / 72 mesh	1	1	148H3363
FIA 20	250µ / 72 mesh	1	1	148H3363
FIA 25	250µ / 72 mesh	1	1	148H3269
FIA 32	250µ / 72 mesh	1	1	148H3269
FIA 40	250µ / 72 mesh	1	1	148H3269
FIA 50	250µ / 72 mesh	1	1	148H3184
FIA 65	250µ / 72 mesh	1	1	148H3185
FIA 80	250µ / 72 mesh	1	1	148H3186
FIA 100	250µ / 72 mesh	1	1	148H3187
FIA 125	250µ / 72 mesh	1	1	148H3188

Filter insert - pleated

FIA 50	500µ / 38 mesh	1	1	148H3189
FIA 65	500µ / 38 mesh	1	1	148H3190
FIA 80	500µ / 38 mesh	1	1	148H3191
FIA 100	500µ / 38 mesh	1	1	148H3192
FIA 125	500µ / 38 mesh	1	1	148H3193

Other accessories

FIA 80-100	Magnet insert	-	1	148H3447
FIA 125-200	Magnet insert	-	1	148H3448
FIA 15-20	Filter element µ150 with removable element µ50 for the first start up	-	1	148H3301
FIA 25-40	Filter element µ150 with removable element µ50 for the first start up	-	1	148H3302
FIA 50	Filter bag	-	1	148H3150
FIA 65	Filter bag	-	1	148H3151
FIA 80	Filter bag	-	1	148H3152
FIA 100	Filter bag	-	1	148H3153
FIA 125	Filter bag	-	1	148H3154
FIA 150	Filter bag	-	1	148H3155
FIA 200	Filter bag	-	1	148H3156
FIA 50 - 300	Purge valve complete	-	1	148B3745
FIA 50 - 300	Blind nut with gasket	-	1	148H3450