
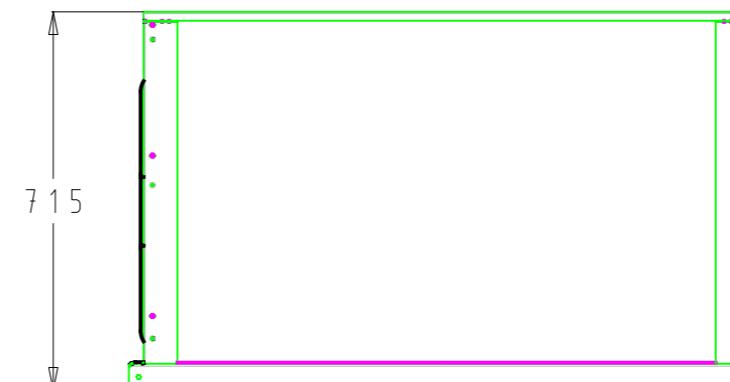
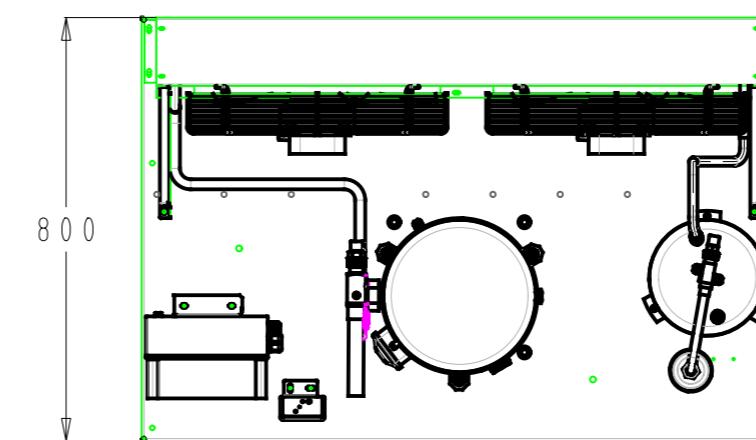
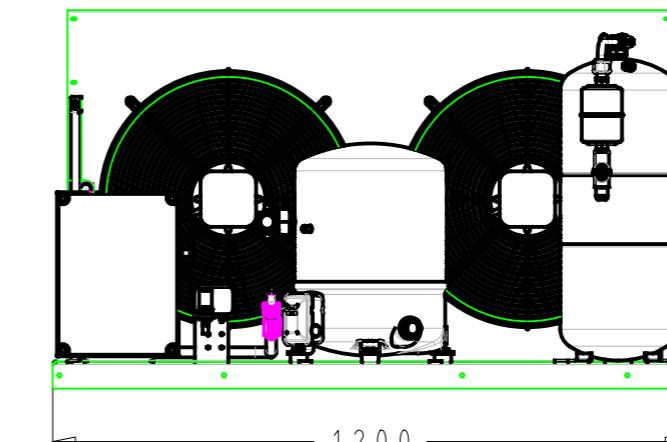
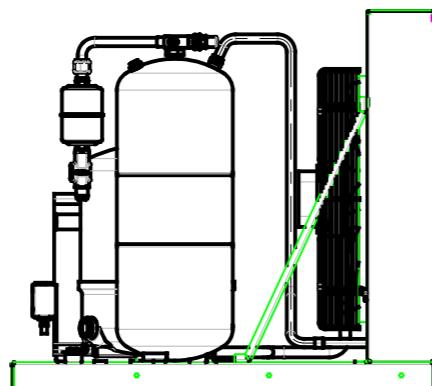
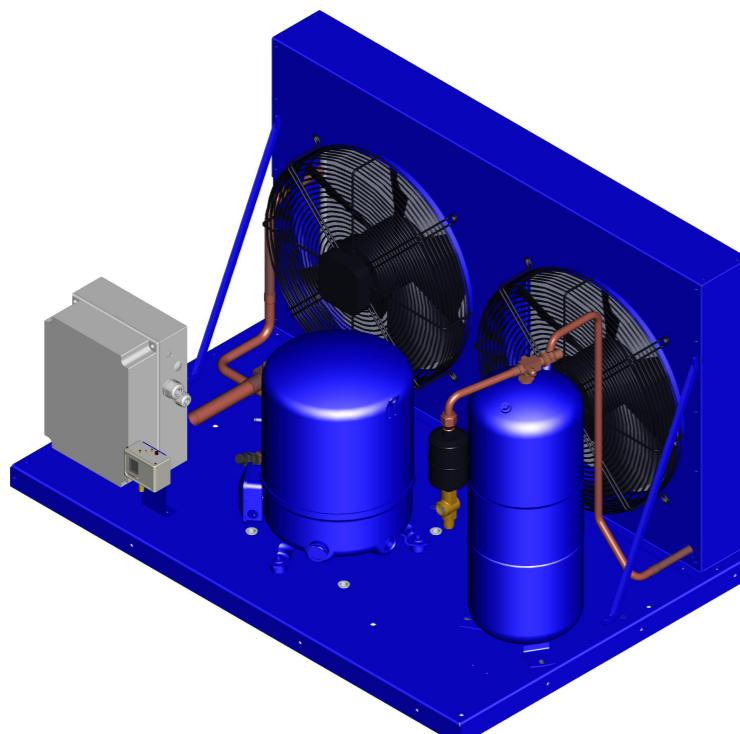


This Version is available only for
Mexico Market

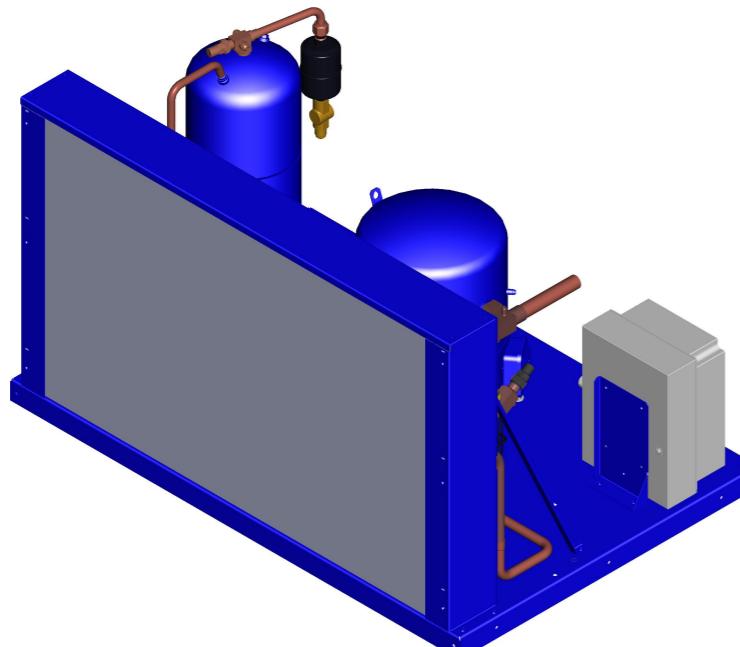

General
Tolerances
Table

Ver Tabela
See Table

Roughness (μm)

ISO 8015

ISO 1101

Drawing Status :

Surface Area (m²)

Estimated Mass (Kg)

Projection

Scale

7/100

Size
A3

Key characteristic
Critical characteristic
According to Danfoss
standard 50220024

Material : See Notes

Production print

Danfoss

HGM064D39

Designation

Sheet 2 of 2

A.4 Dwg N°

115F0654

A

Confidential: Property of Danfoss Commercial Compressors. Not to be handed over to copied or used by third party. Two or three dimensional reproduction of contents to be authorized by Danfoss CC.