



8.407 [ 213,54 ]

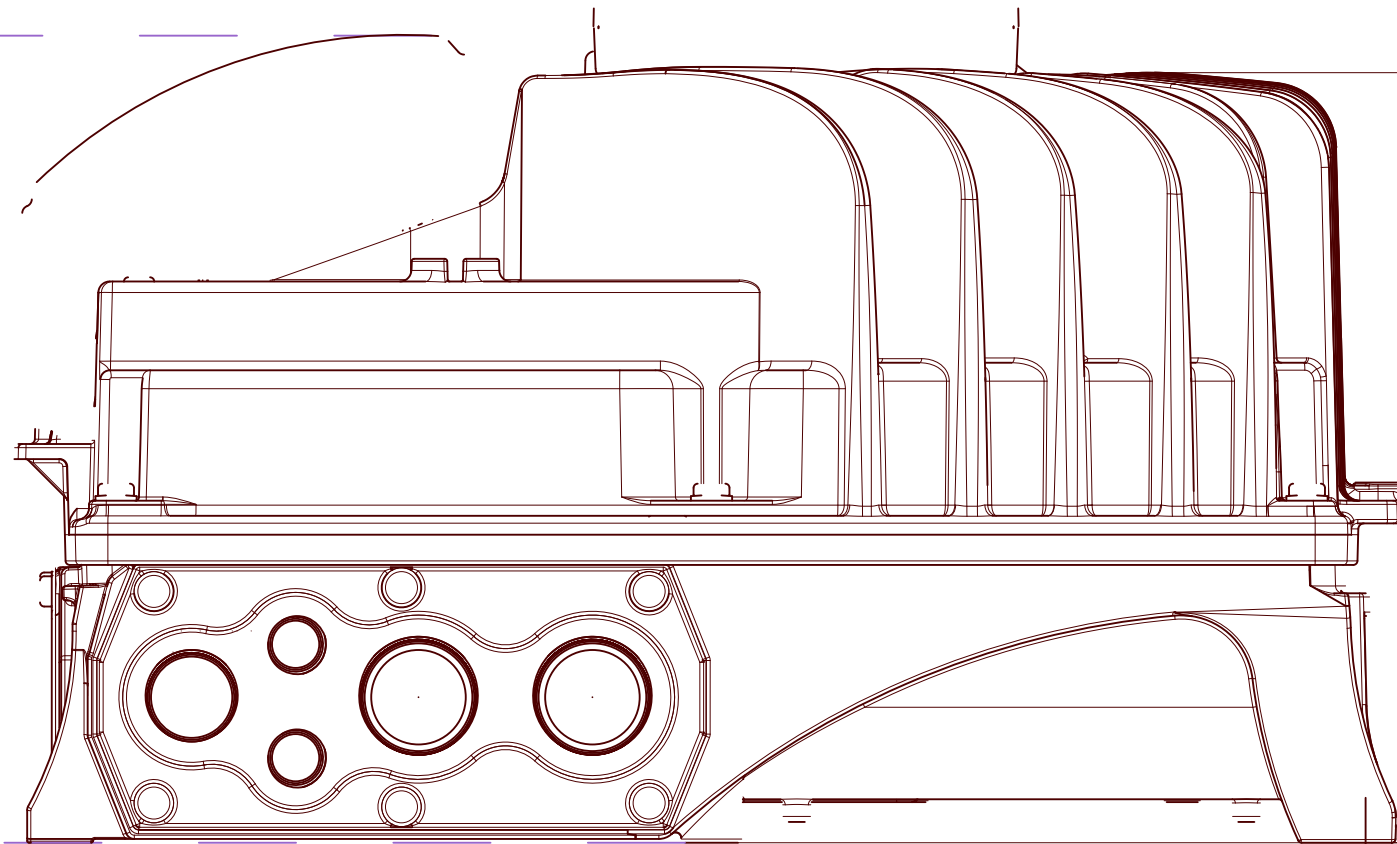

8.022 [ 203,746 ]

[ 230,758 ]

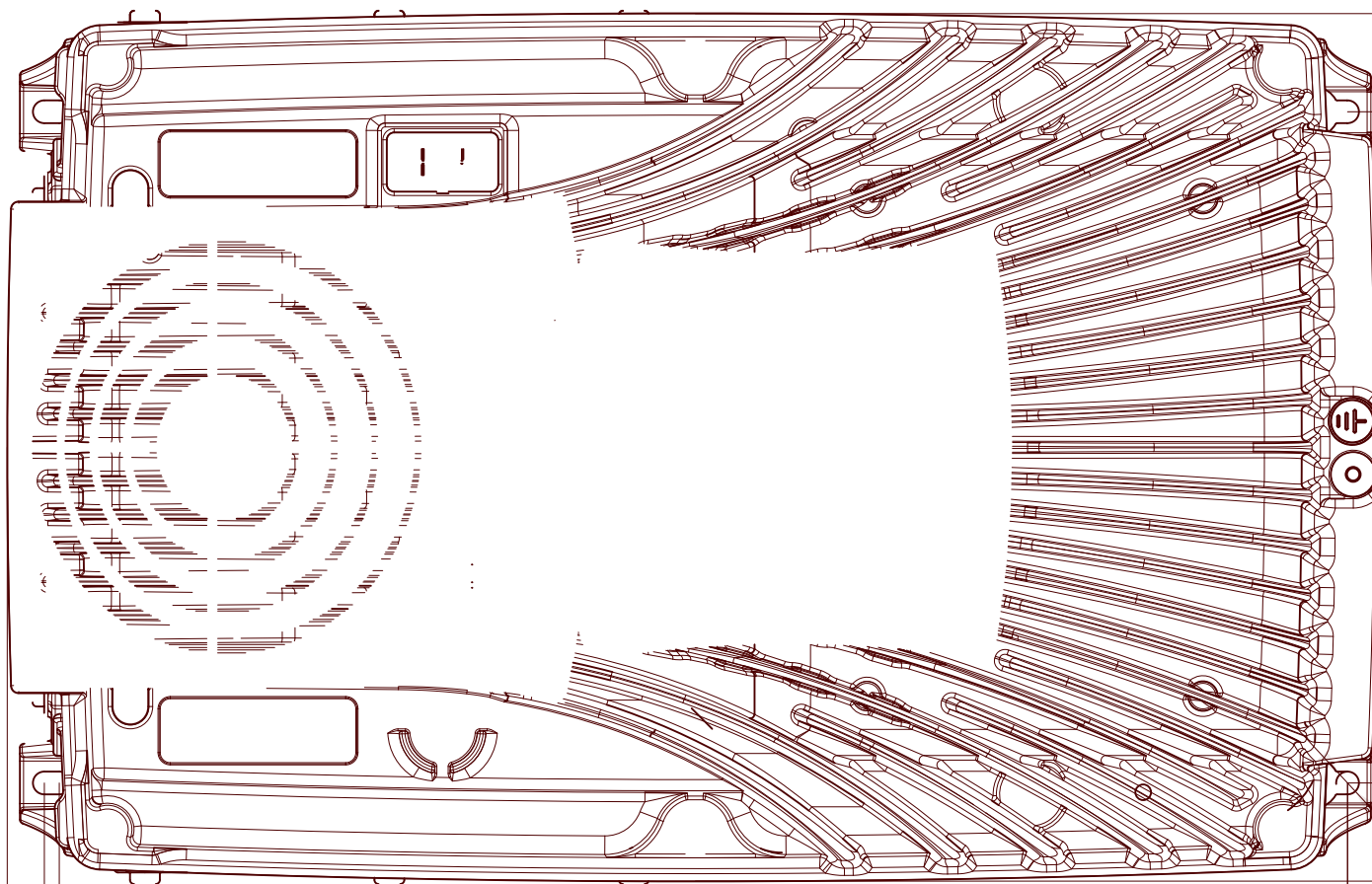

7.087 [ 180 ]

9.159 [ 232,648 ]

13.591 [ 345,202 ]

13.748 [ 349,202 ]

14.464 [ 367,397 ]

Ø .24 [ 6,1 ]

