



8.407 [213,54]

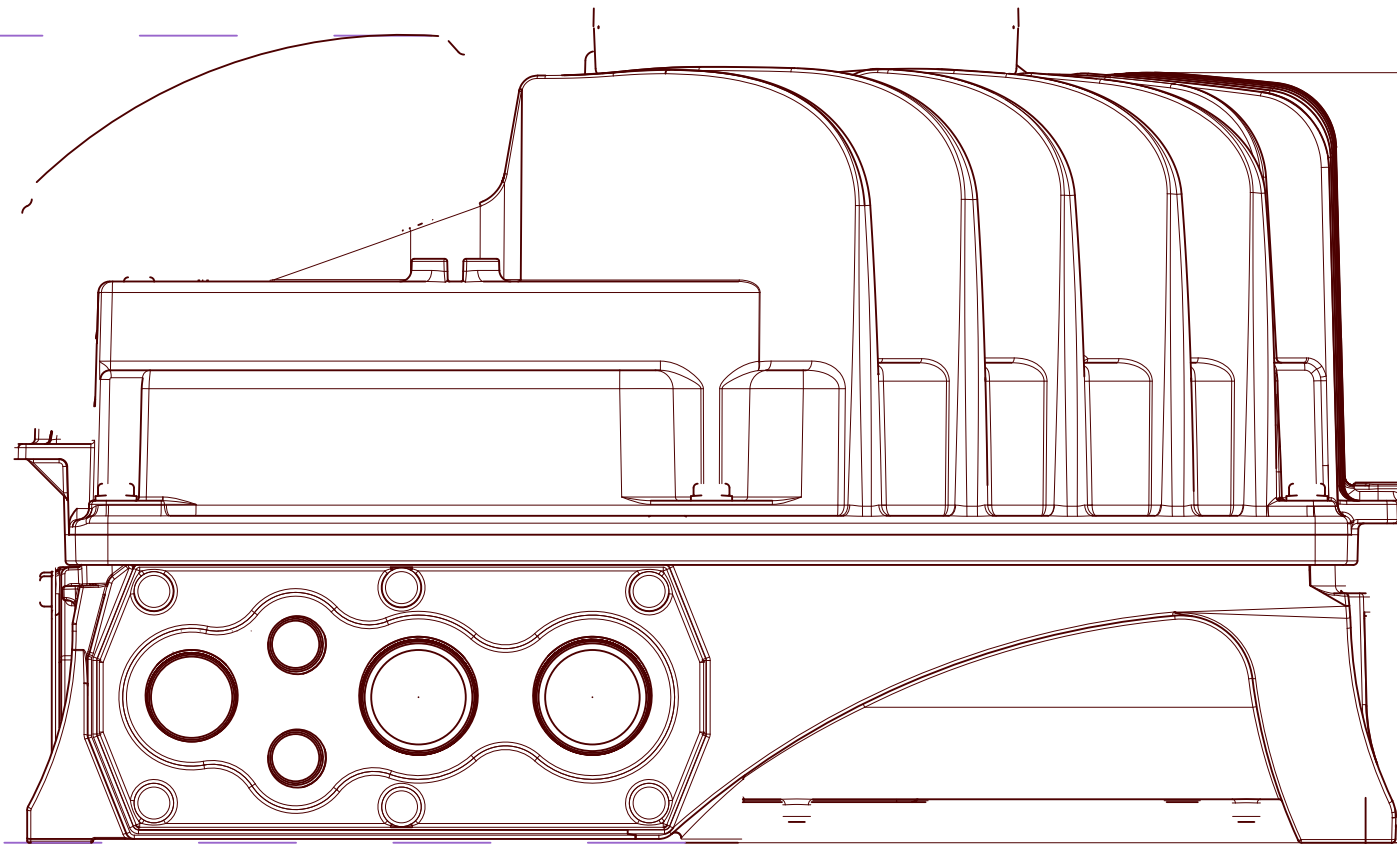

8.022 [203,746]

[230,758]

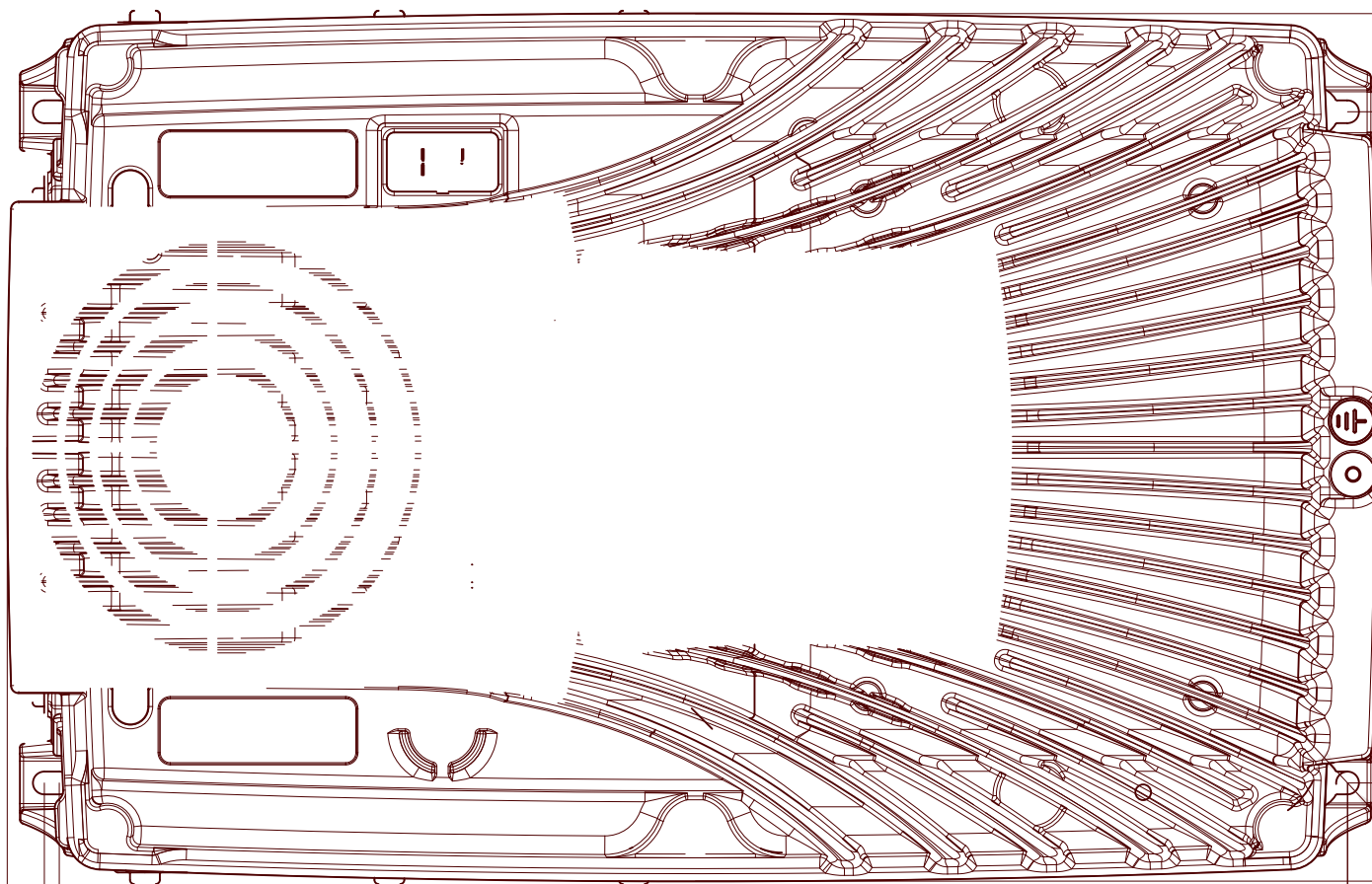

7.087 [180]

9.159 [232,648]


13.591 [345,202]

13.748 [349,202]

14.464 [367,397]


Ø .24 [6,1]

8.407 [213,54]

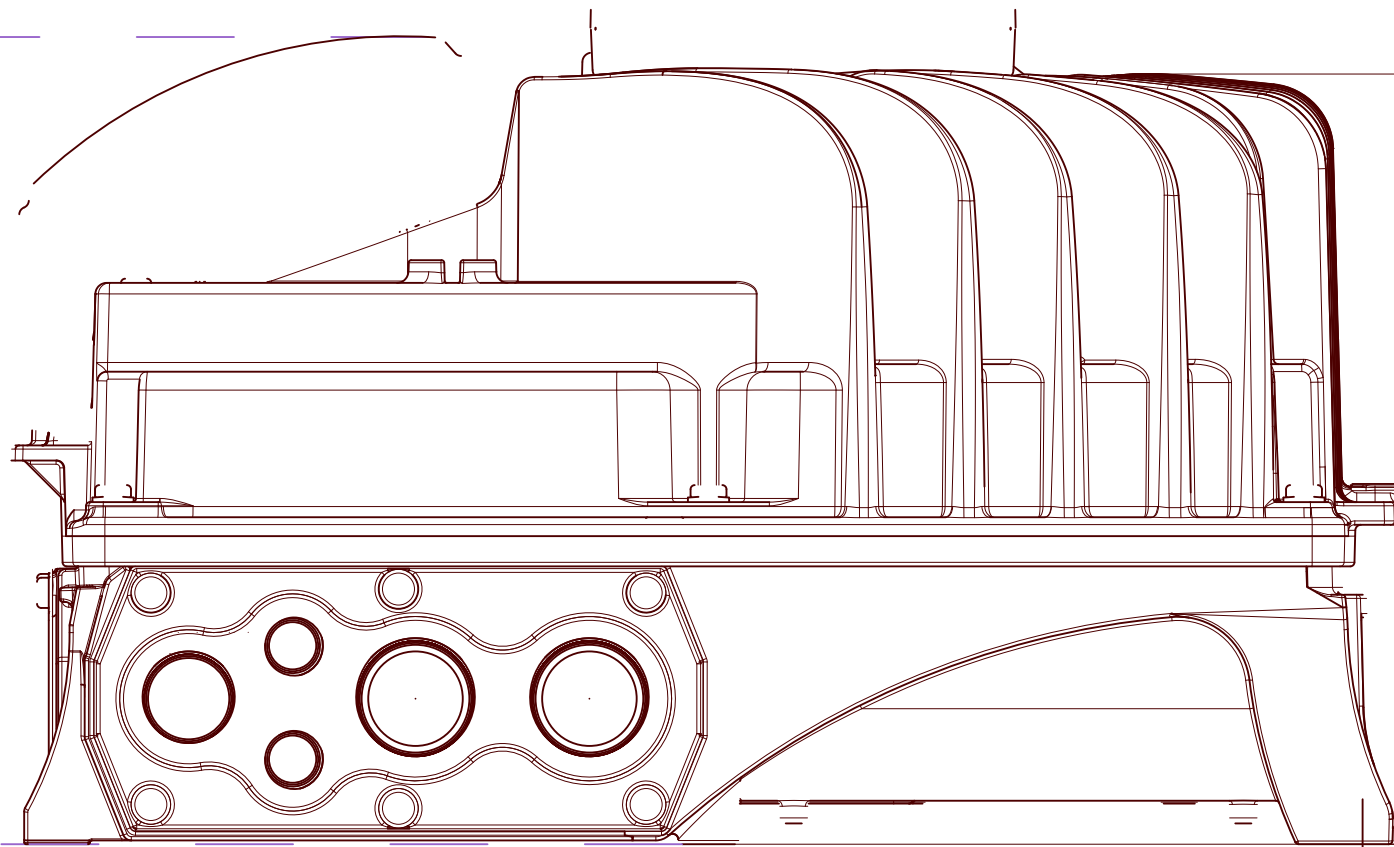

8.022 [203,746]

[230,758]

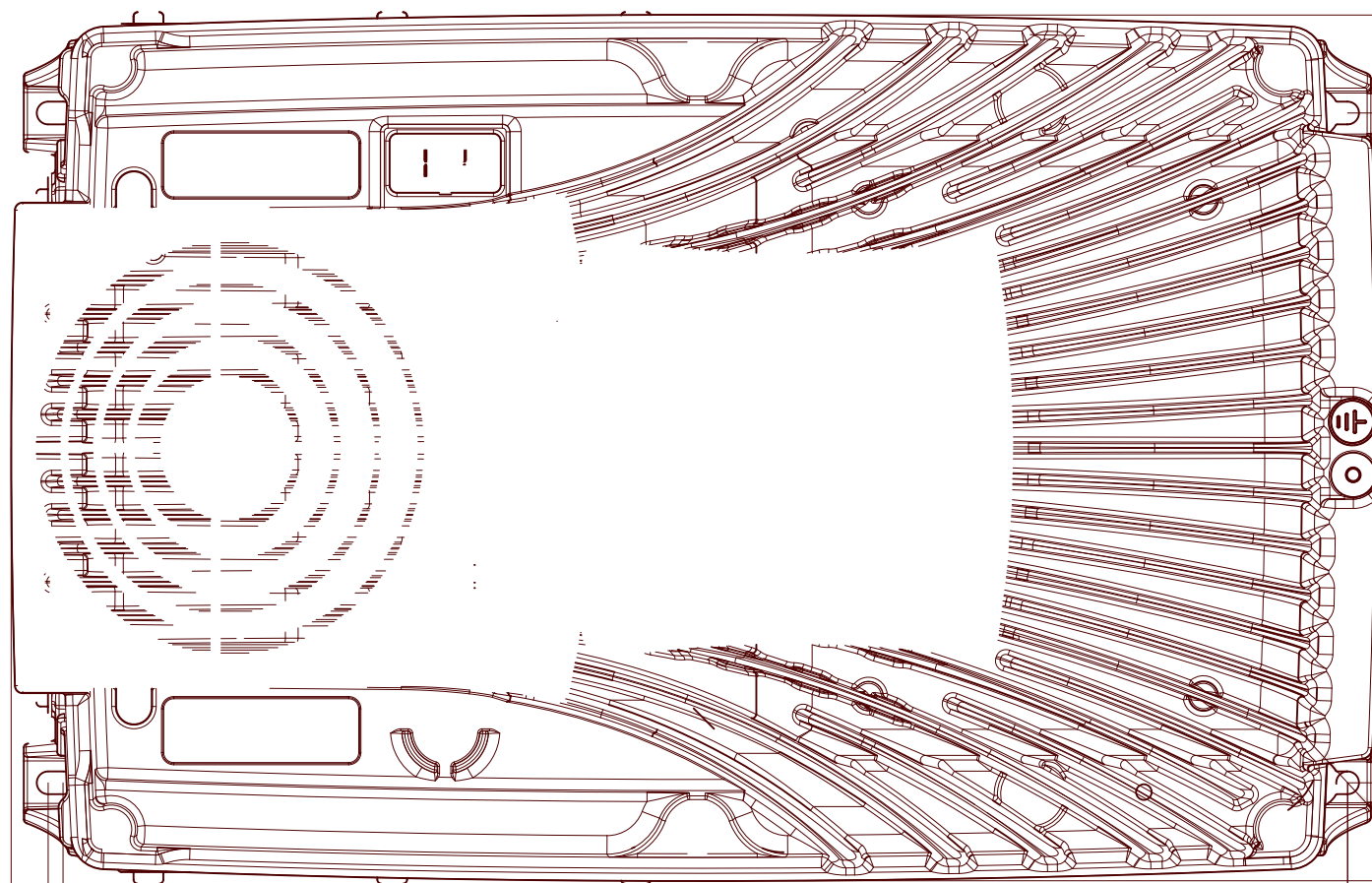

7.087 [180]

9.159 [232,648]

13.591 [345,202]

13.748 [349,202]

14.464 [367,397]

Ø .24 [6,1]